


**IMPORTANT SAFETY INFORMATION. READ AND FOLLOW ALL SAFETY INSTRUCTIONS.** Follow label information and instructions concerning Wet or Damp Locations, installation near combustible materials, insulation, building materials, and proper lamping. Do not install in areas subject to combustible vapors or gases. Before wiring to power supply and during servicing or relamping, turn off power at fuse or circuit breaker. **All servicing or relamping must be performed by qualified service personnel. Product must be grounded to avoid potential electric shock or other potential hazard. Product must be mounted in locations and at heights and in a manner consistent with its intended use, and in compliance with the National Electrical Code and local codes.** The use of accessory equipment not recommended by the manufacturer or installed contrary to instructions may cause an unsafe condition. Do not block light emanating from product in whole or part, as this may cause an unsafe condition. Do not allow items such as drapes, curtains, screens or the like to come into contact with the product or to block light from the product, as this may cause an unsafe condition.

## INSTALLATION INSTRUCTIONS WALL OR CEILING MOUNT—#S-4 STRAP

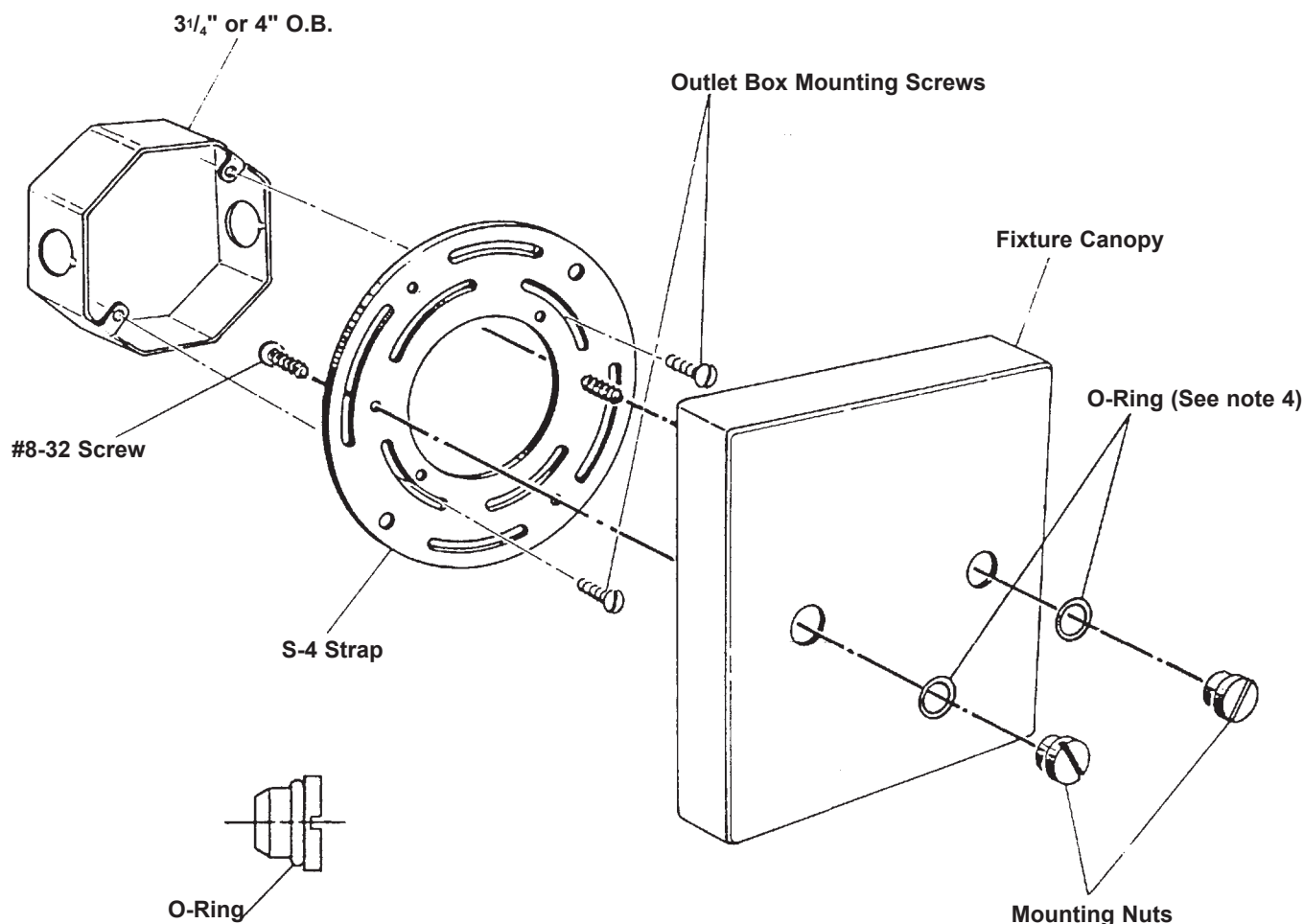

Tools Required: Screwdriver (Note: A right angle screwdriver may be helpful in mounting some models)

1. Insert two #8-32 screws in strap thru tapped holes located on inner slot pattern ( $2\frac{3}{4}$ " dia.). Holes in canopy must line up with these screws.
2. Use screws in O.B. to mount strap with inserted screw stems (Step 1) facing outward. Rotate strap to adjust fixture to correct position.
3. Secure fixture canopy with two mounting nuts.
4. Fixtures located in wet locations must utilize the two o-rings. Place the o-rings under the heads of the mounting screws and secure fixture to mounting strap. Apply callk to the 4 sides of the canopy.