



# Instructions for RACO® "Flip Up" Box Stabilizer

For 4" Square and 4-11/16" Square, 2-1/8" Deep Boxes with  
NEMA Standard .250" Diameter, 1.5" Center Hole Locations




**STEP 1.** If required, bend cable support to access far side support.

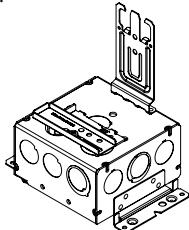


**STEP 2.** For 2.5" stud, use out of carton position of far side support.

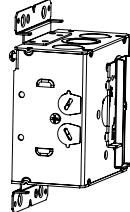


**STEP 3.** For studs greater than 2.5", rotate far side support perpendicular to box and follow instructions below based on stud depth. **3b** Using pliers, bend straight tab in opposite direction of pre-bent tab. **3c** Tab must be bent in opposite direction to positively secure support to box.

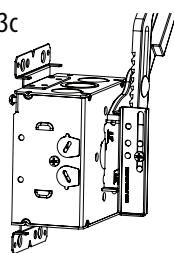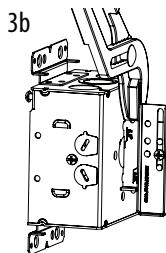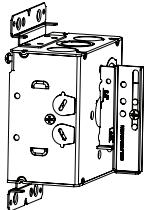


**STEP 4.** For 3.5" stud, lock base perpendicular to box and discard extension.

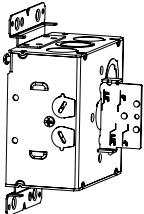


**STEP 5.** For 3.625" stud, lock base perpendicular to box.

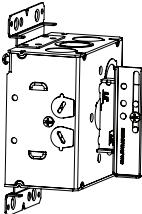


**STEP 6.** For 4" stud, lock base perpendicular to box, loosen screw and rotate extension 180°. Tighten screw.

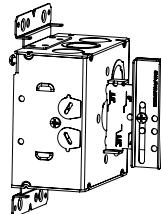

**STEP 7.** For 5.5" stud, lock base perpendicular to box, loosen screw and rotate 90°. Position as shown and tighten screw.

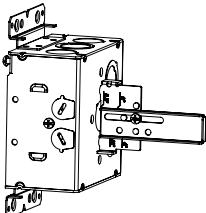

**STEP 8.** For 6" stud, lock base perpendicular to box, loosen screw and rotate 90°. Position as shown and tighten screw.

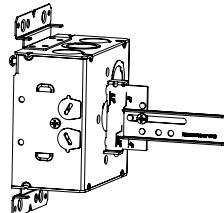

**NOTICE:** Bottom knockouts are  
NOT usable with the FS Support.