

CRB

ROUND HIGH BAY

NOTE: Components shown in images are representative only and may vary based on the configuration ordered.

APPLICATION

For use in settings such as warehouses, manufacturing plants, sporting venues, big-box retailers and similar locations.

CAUTION: Read all instructions before starting installation.

- This product must be installed in accordance with the applicable installation codes by a qualified electrician familiar with the construction and operation of the product and the hazards involved.
- Disconnect power at circuit breaker or fuse before starting installation.
- To avoid injury, wear gloves during installation.
- Line voltage must match fixture voltage requirement.
- To reduce the risk of electrical shock and product damage, do not install this luminaire during rain or other storms.
- Do not test luminaire using an electric generator before installation.
- Use minimum 90°C Supply Wires.

KEEP THESE INSTRUCTIONS

HOOK MOUNT INSTALLATION:

STEP 1

Thread the enclosed eyebolt hook into the top of the luminaire housing, and tighten securely. Tighten the set screw to prevent the eyebolt from loosening.



STEP 2


Use a chain, cable, mounting hook or other mounting hardware (supplied by others) to suspend the luminaire. Make sure the mounting hardware is securely attached to a stationary structure and is strong enough to safely suspend the luminaire.




STEP 3

Refer to wiring diagram to make electrical connections. Wire in accordance with local code requirements.

WIRING DIAGRAM

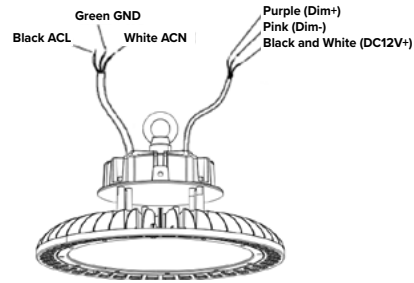

Line Voltage : Black
Neutral : White
Ground : Green
DIM+ : Purple
DIM- : Pink
DC12V+ : Black and White

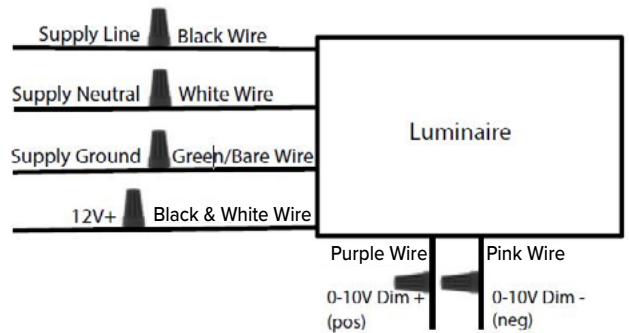

For dimming wires, use class 1 wiring methods.
Cap dimming wires (separately) if not used.