



Instructions for AW Series 4-11/16" STAB-IT® II box assemblies

Your wall assembly may not include all of these components shown below.


Instructions for using the RACO 2-1/8" deep boxes Universal Box Support

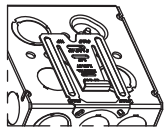


For 2-1/2" deep studs.
Comes preset.

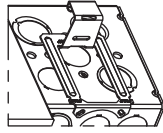


For 3-1/2" deep studs.
Bend center tab as shown
in 2 places.

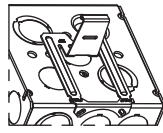


For 3-5/8" deep studs.
Bend center tab as shown.

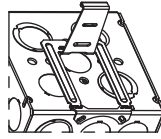

For 4" deep studs.
Bend center tab as shown.

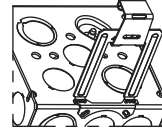

For 5-1/2" deep studs.
Bend both tabs as shown.

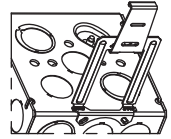


For 6" deep studs.
Bend both tabs as shown.


NOTICE: Back knockouts are NOT usable with the FS support on certain stud depths.

Instructions for using RACO® cable support bracket with STAB-IT® II boxes



STEP 1. Install box to stud

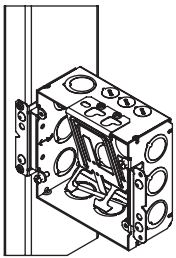


STEP 2. Pre-bend cable support bracket as shown

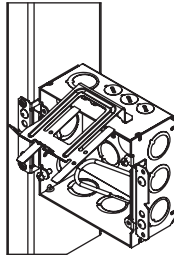


STEP 3. Remove pry-out(s) and install cable(s)
(single bracket shown) (double bracket shown)

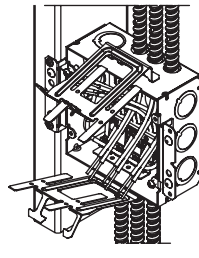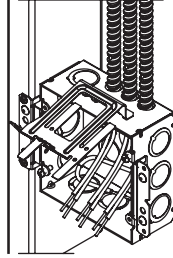

STEP 4. Position cable support bracket as shown


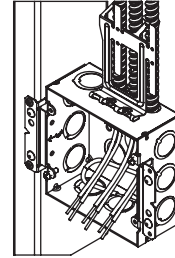


STEP 5. Bend down center tabs to lock cables as shown

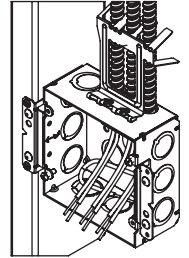


Alternate instructions for installing larger diameter cables in RACO® STAB-IT® II boxes (if needed)



1. Loosen up screw

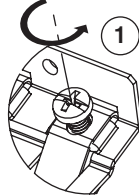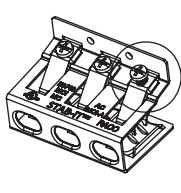


2. Push in cable

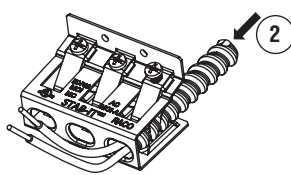



3. Tighten up screw

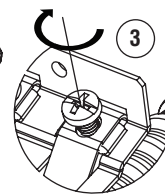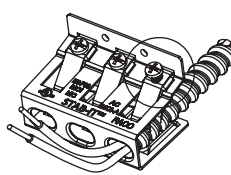

4. Push in cable until it snaps into place

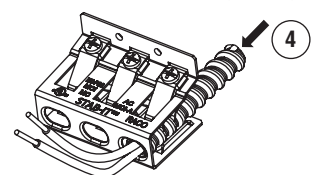


Instructions for removing cables from RACO® STAB-IT® II boxes

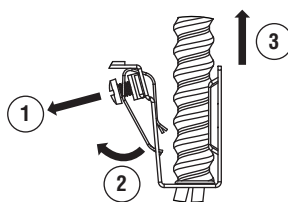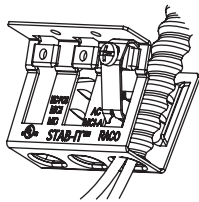


1. Loosen screw
2. Pull the spring clip away from cable as shown
3. Pull cable out


Instructions for using RACO® Hinged Adjustable Mud Ring 768HAMR, 769HAMR, 818HAMR & 843HAMR

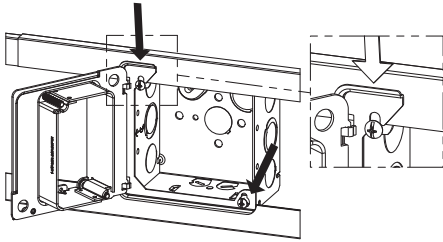


STEP 1.
Place hinged adjustable mud ring over screws and slide it down.
NOTE: The device may be installed before or after the mud ring installation.

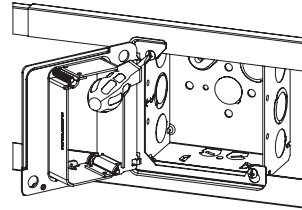

STEP 2.
Tighten top screw.

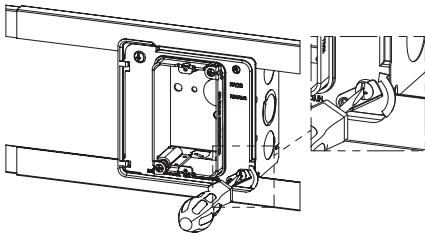


STEP 3.
Close hinged adjustable mud ring and position bottom screw into key hole.

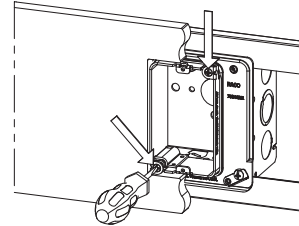


STEP 4.
After drywall is mounted, adjust height of mud ring with adjustment screws until flush with drywall.

Instructions for using RACO® Adjustable Open Center Bracket 9020R


To retain cUL listing in Canada, RACO boxes with the UBS (Universal Box Stabilizer) must be used.

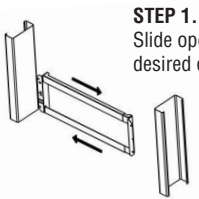


STEP 1.
Slide open center bracket to desired opening between studs

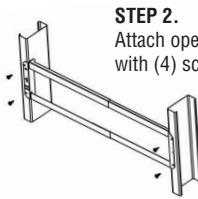

STEP 2.
Attach open center bracket with (4) screws

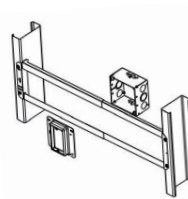

STEP 3.
Install box and cover as shown. Box and cover not included with open center bracket.

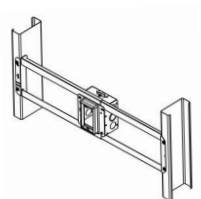

Cable Types & Ranges for STAB-IT® II Clamp

CABLE TYPE	CABLE RANGE	CABLE DIA. RANGE
AC STEEL	14-2,14-3, 14-4, 12-2, 12-3, 12-4, 10-2, 10-3	0.44" - 0.62"
HCF AC STEEL	12-2, 12-3, 10-2, 10-3	
AC ALUMINUM	14-2,14-3, 14-4, 12-2, 12-3, 12-4, 10-2, 10-3	0.44" - 0.62"
HCF AC ALUMINUM	12-2, 12-3, 12-4, 10-2, 10-3	
MC STEEL	14-2,14-3, 14-4, 12-2, 12-3, 12-4, 10-2, 10-3	
MCI-A STEEL	14-2, 12-2, 12-3, 12-4, 10-2, 10-3	
HCF MCI-A STEEL	12-2, 12-3, 10-2	
MC-PCS STEEL	12-2/16-2, 12-3/16-2, 10-2/16-2	
MC ALUMINUM	14-2,14-3, 14-4, 12-2, 12-3, 12-4, 10-2, 10-3	0.38" - 0.62"
MCI-A ALUMINUM	14-2,14-3, 14-4, 12-2, 12-3, 12-4, 10-2, 10-3	
HCF MCI-A ALUMINUM	12-2, 12-3, 12-4, 10-2, 10-3	
MC-PCS ALUMINUM	12-2/16-2, 12-3/16-2, 10-2/16-2	

Cable Armor must comply with NEC 250.96.
To install more cables use any of the knockouts with RACO® connectors.