

Catalog Number: Female Inline HBL20SPF Hubbell
20A/125V - 15A/250V

Use with 16/3 type SJO, 0.34" nom. through 12/3 type
SO, 0.62" nom. Remove outer jacket 1-5/8" strip
conductors 3/8" (DO NOT TIN).


Place wire shoe over all loose wire strands of each
conductor.

Insert wires into barrel of terminal (green wire in middle
terminal) torque screws to 12 in-lbs.

Install strain relief inserts if required.

Attach cover and secure with (3) mounting screws – 12
in-lbs torque.

Cord holding system has six (6) different combinations
offering openings from 0.50" to 0.60". Typical uses are
depicted below.

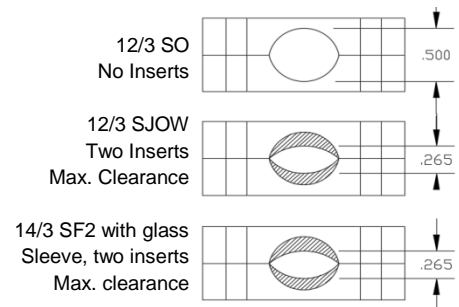

Wiring Device-Kellems
Hubbell Incorporated (Delaware)
1-800-288-6000
Shelton, CT 06484
www.hubbell-wiring.com
PD2827 09/17

