



**KIM LIGHTING**

16555 East Gale Ave.  
City of Industry, California 91716-0080  
626/968-5666 • FAX 626/330-3861



# Scarab™ Accent Light Series Installation Instructions

## IMPORTANT SAFETY INSTRUCTIONS PERTAINING TO A RISK OF FIRE, OR INJURY TO PERSONS!

**WARNING:** Fixtures must be grounded in accordance with local codes or the National Electrical Code. Portable spear or tree mounts using a cord and plug, must be plugged into a receptacle protected by a Ground Fault Circuit Interrupter (GFCI) in accordance with the National Electrical Code. Failure to take these steps may result in serious personal injury. DO NOT operate luminaire with missing or damaged lens. Lighted lamp is HOT! Do not touch hot lens, guard or enclosure.

**MAINTENANCE:** To maintain light efficiency and prevent fixture overheating, lenses must be kept clean and free of dirt, dust, leaves, trash and mineral deposits from water. For optimum performance a regularly scheduled maintenance program should be followed.

**KEEP THIS SHEET FOR FUTURE REFERENCE.**

Your KIM fixture is supplied with 1/2" NPSM male mounting threads. It may be installed so that fixture is aimed up or down.

**Tools Required:**  1/8" Allen Wrench  Phillips Head Screwdriver  Flat Head Screwdriver  
 Adjustable Wrench  Thread Sealant  Silicone Grease


**!** Make certain the electrical supply is **OFF** before starting fixture installation.



**1.** Loosen set screw at bottom of mounting device\* with Phillips Head screwdriver.



**2.** Coat coupling threads with a good sealant and tighten coupling onto mounting device\*. Re-tighten set screw.

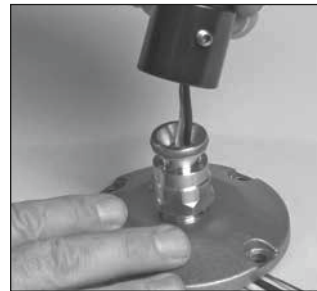

**3.** Install fixture onto coupling and attach fixture leads observing polarity ...



**4.** white-to-common, black-to-voltage. Screw on Junction box cover, making sure gasket is securely in place.

**IMPORTANT! For LED fixtures, verify input voltage. See CAUTION above.**




**5.** For non-LED fixtures, remove screws holding shield. Install lamp shown on fixture label and chart on pg. 2.


**Do not exceed maximum wattage. For HID/Fluorescent lamps see warning on pg. 2.**



**6.** After installing lamp, coat shield screw threads with silicone grease and tighten screws progressively. Always install shield with short side down for proper drainage.

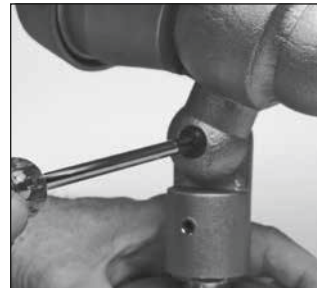

**7.** Loosen screw, adjust fixture angle, and tighten.

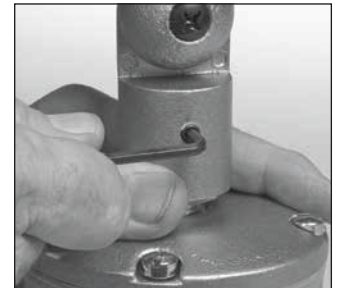

**8.** Loosen setscrew, adjust fixture rotation, and tighten.

\*Consult KIM Landscape Lighting Collection Catalog for mounting device options.

# Scarab Accent Light Series Installation Instructions

LAMP INFORMATION		
CATALOG NO.	LAMP TYPE	MAX. WATTS
C700 /EL700	LED by Kim	9W for 7L 11W for 9L 14W for 12L

How may we serve you better? Please let us know.  
Visit our website at: [www.kimlighting.com](http://www.kimlighting.com)  
Your concerns are important to us

## KIM LIGHTING LIMITED WARRANTY

When installed in accordance with Kim Installation Instructions and accepted trade practices, the following shall apply:

### General Product Limited Warranty Coverage

All material and component parts used in the manufacture of Kim Products, are warranted to be free from defects of material and/or workmanship for a period of 5 year from date of sale, with the following exceptions:

### Auxiliary Equipment:

All auxiliary equipment (such as lamps, ballasts, and transformers) provided by and/or included in Kim Products shall carry the components manufacturer's warranty.

### Copper, Bronze and Brass Landscape Components

Copper and Bronze Landscape fixture components shall be warranted against defects of material and/or workmanship, and failure due to corrosion, for a period of 25 years from date of sale.

Kim Lighting's brass components are constructed from several brass parts that are manufactured by various methods at various times. Since brass naturally deepens in color as it ages through the normal oxidation process, these parts may exhibit subtle differences in coloration when the product is new. This is normal and expected. These color differences will be eliminated shortly after installation through the normal brass oxidation process.

### Composite In-Grade Components

Composite In-Grade fixture components installed below grade, shall be warranted against defects of material and/or workmanship, and failure due to corrosion, for a period of 7 years from date of sale.

### Aluminum Landscape Components

Aluminum Landscape fixture components not in direct contact with soil, shall be warranted against defects of material and/or workmanship for a period of 3 years from date of sale. Aluminum fixture components in direct contact with soil shall be warranted from defects of material and failure from corrosion for a period of 1 year from date of sale.

### Limit of Liability and General Conditions

Only products which are installed, used and maintained in accordance with applicable Kim instructions, specifications and accepted trade practices, are covered by the Kim Warranty. During the warranty period, with proof of purchase, Kim will repair or replace with the same or similar product, at Kim's option without charge. Labor costs are the owner's responsibility and are excluded from this warranty. This warranty is void if the product is modified, tampered with, misapplied, poorly installed, improperly maintained, or subjected to abnormal conditions.

Repair or replacement as provided under this warranty is the exclusive remedy of the purchaser. This warranty is in lieu of all other warranties, expressed, or implied, including any implied warranty of fitness for a particular application. Kim Lighting shall not be liable to the purchaser for indirect or consequential damages.