


Liteforms® Collection



LE Series Edge-Lit LED Exit Signs

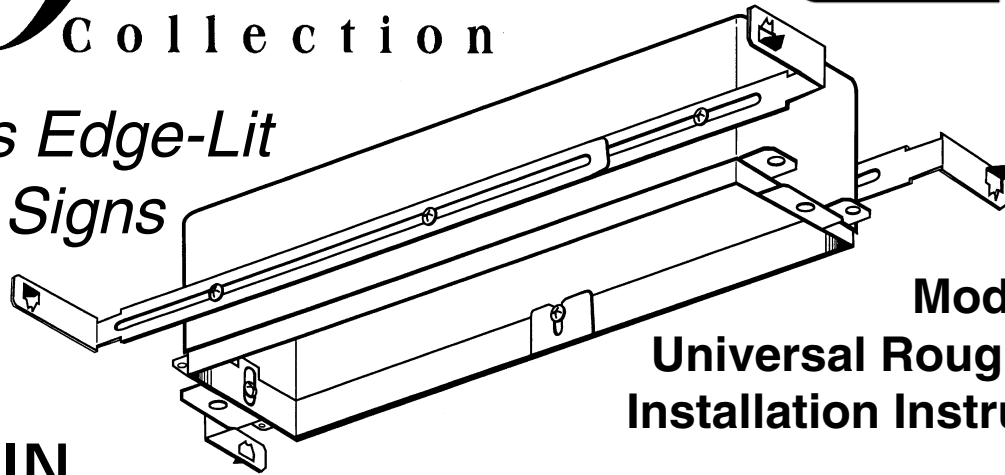


Model URK Universal Rough-In Kit Installation Instructions

ROUGH-IN

1. Attach mounting bars to universal rough-in back box (if required) using #8 sheet metal screws supplied.
For side mount bar applications, use six screws (three per side). See **Fig. A**.
For end mount bar applications use four screws (two per end). See **Fig. B**.
2. Install back box as shown in **Figures A, B or C**.
CAUTION: On all ceiling grid applications, use locking clips (supplied) to secure rough-in box to T-bars. See **Fig. A**
NOTE: It is recommended that locking clips be attached to mounting bars prior to installing bar sets on rough-in box.
3. Adjust internal trim ring flush with wall or ceiling surface and tighten four retaining screws. See **Fig. D**
4. Attach electrical cable to back box using approved connectors (supplied by installer) and make electrical connections to transformer as shown in **Fig. E** using wire nuts or other approved fasteners.

SUSPENDED CEILING GRID INSTALLATION USING SIDE MOUNTED BARS

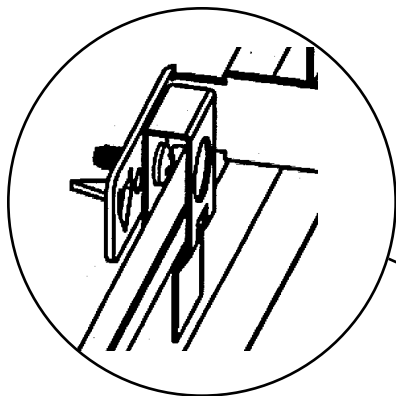

IMPORTANT:
Secure box to T-bars
using locking clips and
#8 machine screws
provided.

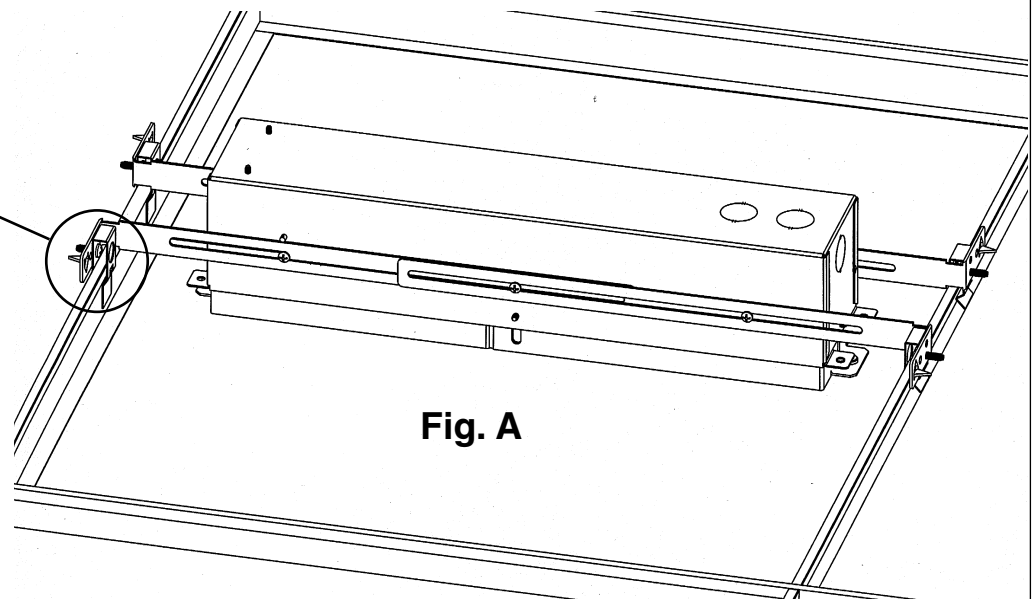


Fig. A

INSTALLATION USING BARS END MOUNTED

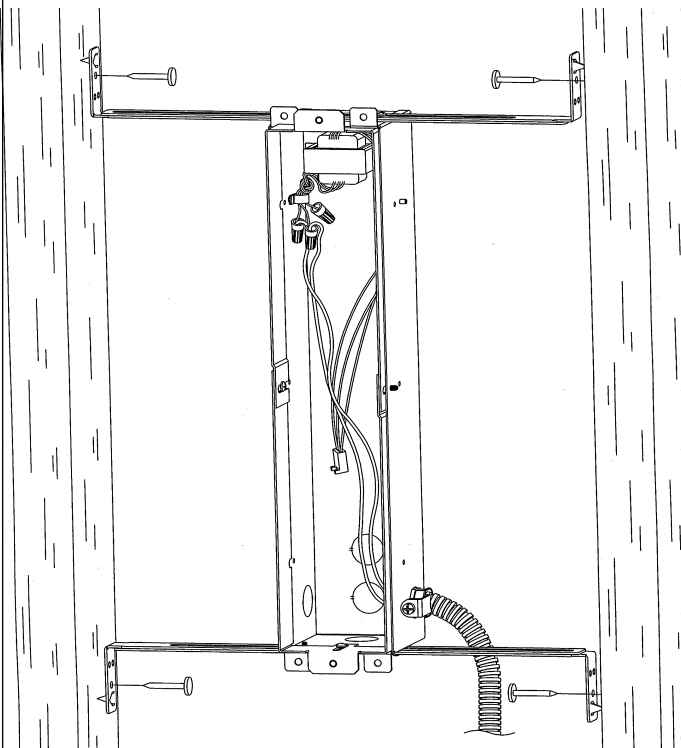


Fig. B

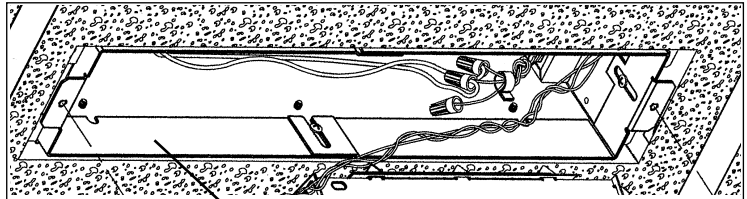


Fig. D

Internal trim ring allows 3/4" adjustment range. Set trim ring flush with wall or ceiling surface and tighten four retaining screws

ELECTRICAL CONNECTIONS

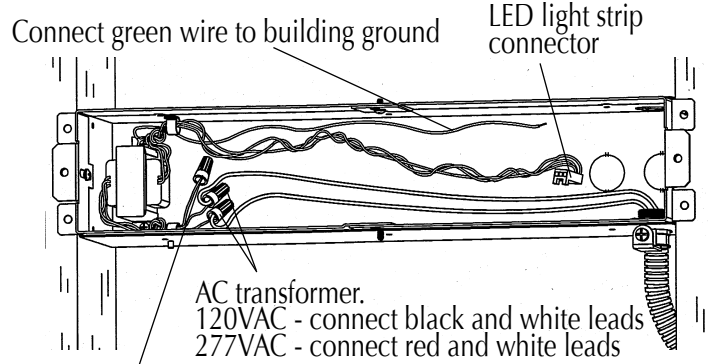


Fig. E

IMPORTANT: Cap off unused red or black wire lead

INSTALLATION DIRECT TO BUILDING MEMBERS

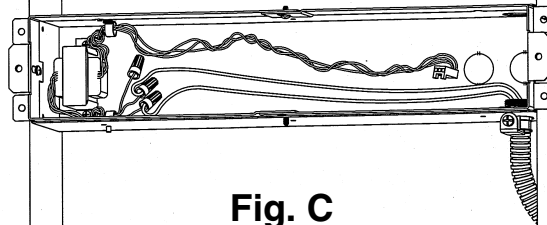


Fig. C

DUAL LITE