

Burndy DCatalog - Interactive Master Catalog

Enhanced Search Capabilities and New Functionality

Auto Latest Link: <https://Hubbell.dcatalog.com/r/BURNDY-Full-Line-Catalog/>

BURNDY
Master Catalog

We're very pleased to announce the release of the newly updated Interactive Digital Catalog.

The hyperlink above will always bring you the most updated edition that is active. For the people that want to add the link to their email address, make sure you're using the link above! The edition will be updated on a quarterly basis going forward.

With this new update, we've added some videos on some product pages, we'll try and add (or update) links during the quarterly updates.

The entire document is searchable with the results on the left side so you can easily see which result is most applicable for you.

There is a Table of Contents to the left on the screen that you can click on to bring it up and easily get to the section you're looking for.

At the beginning of each section is also a table of contents for that section with hyperlinks to the pages on there as well.

BURNDY

Table of Contents

Table of Contents

BURNDY Master Catalog

Section A - Mechanical Connectors

Section B - Small Terminals

Burndy DCatalog - Interactive Master Catalog

Enhanced Search Capabilities and New Functionality

Auto Latest Link: <https://Hubbell.dcatalog.com/r/BURNDY-Full-Line-Catalog/>

SERVIT® Split-bolts;

TYPES KS & KS-3 SERVIT®

Copper, Copperweld



Compact, high strength, high copper alloy SERVIT® split-bolt has free-running threads and easy to grip wrench flats. Highly resistant to season cracking and corrosion, the SERVIT® provides maximum pressure and assures a secure connection on all combinations of run and tap conductors. Type KS-3 accommodates 3 maximum size conductors.

▲ Listed torque values are for maximum conductor combinations accommodated. Consult UL486 Tables 7-4, 7-5, 7-6 for smaller conductor combinations.

See note LIGHTNING PROTECTION INFO. on page A-2

* Not UL Listed or CSA Certified.

* In addition to UL Listed for wire conn items are also UL rated for direct burial

Catalog Number	Cross Flats	L	W	Conductor				
				Copper		Copperweld		
				Equal Run & Tap	Min Tap with Max Run	Sol.	Str.	Type A
↑ KS90	0.50	0.85	0.38	12 - 10 Str.	16 Str.	#10	—	—
↑ KS15	0.50	0.85	0.38	10 - 8 Str.	14 Str.	#8	—	—
↑ KS17	0.63	1.34	0.45	8 Str. - 6 Sol.	14 Str.	#6	3 #12	BA
* KS173	0.62	0.98	0.70	8 Str. - 6 Sol.	16 Str.	#6	3 #12	BA
↑ KS20	0.69	1.20	0.51	8 Str. - 4 Sol.	14 Str.	#4	3 #10	BA

Most (not all) catalog numbers when you put the cursor on one will show a light pink box and if clicked brings up a pop-up box that shows the Specification Sheet for that part.

Add Item:

Item Number: KS22 Item Count:

Save to List

1 of 1 Automatic Zoom

KS22, Split Bolt Connector, Run/Tap: #8 AWG Str-6 AWG Sol

By Burndy
Catalog # KS22

Copper Split Bolt, Cu: 8 AWG (Str) - 6 AWG (Sol) (Run & Tap), Length: 1.50

Products: ×

Catalog Reference	Spec Sheet	Catalog Page	Quantity	Additional Note
KS22	Download	A-3	<input type="text" value="1"/>	<input type="text"/>
KS15	Download	A-3	<input type="text" value="1"/>	<input type="text"/>

EMAIL

Email:

Your name: *

Your email: *

Company: *

To: *

Comments:

SEND

You may click the “Save to List” button and it will add to the list as you Save. The heart icon at the top tool bar counts your saves.



Once you’ve Saved all the items you want to the List, click on the heart icon and you’ll see the list and options to Download or E-mail the Spec Sheet(s).

If you choose email, another screen pops up. Fill in the information (*it will NOT have your information stored; you type it in each time; it will NOT show in your ‘sent’ work email).*

Click “Send”

Burndy DCatalog - Interactive Master Catalog

Enhanced Search Capabilities and New Functionality

Auto Latest Link: <https://Hubbell.dcatalog.com/r/BURNDY-Full-Line-Catalog/>



Print Pages* (see screen shot below)



Table of Contents
Click here for Table of Contents to appear on the left side



1 or 2 page view Toggle Switch
Click to change to different view of pages



Share
Click to share on social media (Facebook, Twitter, LinkedIn) or send link via email



First page
Brings you to the first page of the catalog



Previous page
Brings you to the previous page (or spread)



Next page
Bring you to the next page (or spread)



Last page
Brings you to the last page of the catalog



Thumbnail View
Brings up small thumbnails of the pages at the bottom of your screen



PDF Export ** (see screen shot below)
Download All is not recommended



Search
Click to bring up search option on the left, it will search the catalog and bring back full search results underneath



Add a Note
Click to place a note on a specific page for your reference




Wish List
If you click on a product and then click "add to list" it will save the items in an easily emailed list



View Documents

***Print Pages:** click on icon will bring up pop up shown. You have the option to print as a single or double (facing) pages for a range of pages by filling in the start and end range you desire.

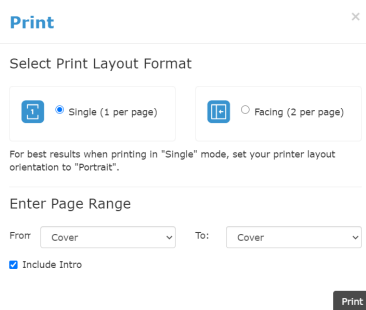

Print

Select Print Layout Format

Single (1 per page) Facing (2 per page)

For best results when printing in "Single" mode, set your printer layout orientation to "Portrait".


Enter Page Range

From: To:

Include Intro

Print

****PDF Export:** click on icon will bring up pop up below. You have the option to download the entire catalog (**not recommended**) or a range of pages by filling in the start and end range you desire.

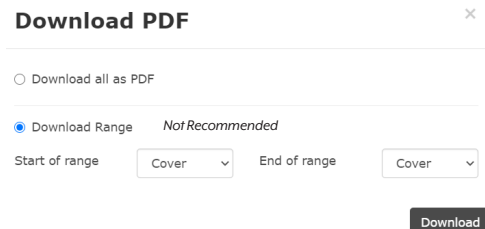

Download PDF

Download all as PDF

Download Range *Not Recommended*

Start of range: End of range:

Download



A proud member of the Hubbell family.