




BRYANT[®]

Temporary Industrial Lighting

Flexible and Dependable
Illumination for Construction
Sites, Work Areas and
Harsh Environments

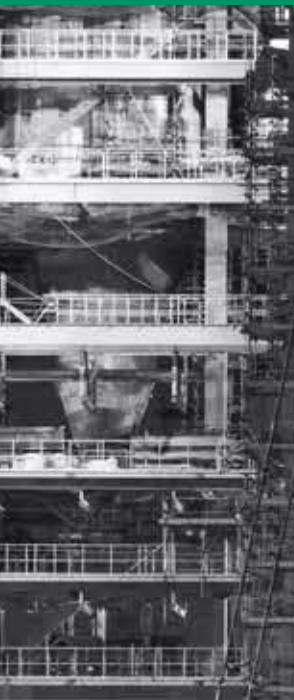

Construction Site Lighting



Bryant's outdoor approved construction site lighting line includes both heavy-duty metal halide lights and light strings for working in rugged environments. The metal halide fixtures feature extremely strong and compact heads with bulbs rated to last 10,000 hours. All frames are powder-coated yellow for safety and are constructed of a durable 1.25 inch, 12 gauge steel tube.

Light strings for all applications are available in a variety of models as well as a choice of metal or plastic guards. Light sockets are spaced 10 feet apart and all sockets, plugs, and connectors are molded for added durability. In addition, the highly impact-resistant material makes for easy transportation and storage when not in use. Bulbs can be incandescent, fluorescent or LED. Consider choosing LED lighting for a durable bulb that saves energy, provides instant illumination and are rated to last 50,000 hours.

Metal Halide Lights

| Description | Rating | Watts | Lumen Output | Cord Length | Catalog Number |
|--|----------|-------|--------------|-------------|-------------------|
| 5 -10 ft. metal halide cart light with portable detachable ballast | 15A 125V | 1,000 | 110,000 | — | BRYMH1000 |
| 6 -12 ft. metal halide cart light | 15A 125V | 2,000 | 220,000 | — | BRYMH2000 |
| High bay metal halide light with wire guard | 15A 125V | 400 | 29,000 | 3 ft. | BRYMHHB400 |



BRYMH1000



BRYMHHB400

LED Stringer Lights

| Description | No. of Fixtures | Rating | Cord Type | Lumen Output | Cord Length | Catalog Number |
|---|-----------------|----------|--------------|--------------|-------------|----------------------|
| 90 LEDs per fixture, light string with magnetic base included | 1 | 15A 125V | 18/2 SJTW | 450* | 20 ft. | BRY182S20LED |
| 90 LEDs per fixture, light string | 5 | 15A 125V | 18/2 SJTW | 450* | 50 ft. | BRY182S50LED |
| | 10 | 15A 125V | 18/2 SJTW | 450* | 100 ft. | BRY182S100LED |
| 28W High power LED light string with in line ON/OFF switch | — | 15A 125V | 16 AWG SJTOW | 2,928 | 6 ft. | BRYLS2834 |
| Magnetic clip bracket for LED lights switch, single fixture | — | — | — | — | — | BRYSTMC |

Note: *Lumens per fixture.

A Type (Edison) Locking and Straight Blade Light Strings

| Description | Max Watts* | Rating | Cord Type | Fixtures | Cord Length | Catalog Number |
|--|------------|----------|-----------|----------|-------------|----------------------|
| Locking light string, plastic guards | 150 | 20A 125V | 12/3 STW | 10 | 100 ft. | BRY123S100PT |
| | 150 | 20A 125V | 12/3 STJW | 10 | 100 ft. | BRY123SJ100PT |
| Locking light string, metal guards | 150 | 20A 125V | 12/3 STW | 10 | 100 ft. | BRY123S100MT |
| Straight blade light string, plastic guards | 150 | 15A 125V | 14/2 STJW | 10 | 100 ft. | BRY142SJ100PS |
| | 150 | 15A 125V | 12/3 STW | 10 | 100 ft. | BRY123S100PS |
| | 150 | 15A 125V | 12/3 STJW | 10 | 100 ft. | BRY123SJ100PS |
| Straight blade light string, metal guards | 150 | 15A 125V | 12/3 STW | 10 | 100 ft. | BRY123S100MS |
| Straight blade light string, plastic guards | 150 | 15A 125V | 12/3 STW | 5 | 50 ft. | BRY123S50PS |
| Straight blade light string, metal guards | 150 | 15A 125V | 12/3 STW | 5 | 50 ft. | BRY123S50MS |
| Replacement plastic guard for temporary light strings | — | — | — | — | — | BRYSTPG |
| Replacement heavy duty metal guard for temporary light strings | — | — | — | — | — | BRYSTMG |

Note: *Max watts per fixture.

Fluorescent Light Strings

| Description | Wattage | Rating | Cord Type | Lumen Output | Cord Length | Catalog Number |
|---|---------|----------|--------------|--------------|-------------|------------------|
| Fluorescent light string, 34.5 in. single fixture with hanging straps | 50 | 15A 125V | 16 AWG SJTOW | 3,750 | 6 ft. | BRYFS5035 |
| Fluorescent light string, 48.5 in. single fixture with hanging straps | 25 | 15A 125V | 16 AWG SJTOW | 2,125 | 6 ft. | BRYFS2549 |



BRYFS2549
Straps not Shown

Maintenance and Worklights

LED Maintenance Worklights

| Description | Outlet Rating | Rating | Wattage | Lumen Output | Cord Type | Cord Length | Catalog Number |
|---|---------------|----------|---------|--------------|------------|-------------|--------------------|
| LED Industrial maintenance light | N/A | 15A 125V | 28 | 2,928 | 16/3 SJEOW | 25 ft. | BRYML2825L |
| LED worklight with end light feature | N/A | 15A 125V | 9 | 920/120 | 18/2 SJTOW | 25 ft. | BRYWL25LED |
| LED worklight with end light feature and tool tap | 12 Amp | 15A 125V | 9 | 920/120 | 16/3 SJTOW | 25 ft. | BRYWL25LEDT |

Fluorescent Maintenance Worklights

| Description | Outlet Rating | Rating | Wattage | Lumen Output | Cord Type | Cord Length | Catalog Number |
|--|---------------|----------|---------|--------------|------------|-------------|------------------|
| Fluorescent worklight with straight blade plug | N/A | 15A 125V | 13 | 825 | 16/3 SJTOW | 25 ft. | BRYTW25F1 |
| Fluorescent worklight with locking plug and tool tap | 12 Amp | 20A 125V | 13 | 825 | 16/3 SJTOW | 25 ft. | BRYTW25F2 |
| Fluorescent maintenance light, 34.5 in. | N/A | 15A 125V | 50 | 3,750 | 16/3 SJEOW | 25 ft. | BRYML5025 |
| Fluorescent maintenance light, 48.5 in. | N/A | 15A 125V | 25 | 2,125 | 16/3 SJEOW | 25 ft. | BRYML2525 |
| Fluorescent worklight, 45 in. | N/A | 15A 125V | 25 | 2,125 | 16/3 SJTOW | 25 ft. | BRYWL2525 |

Accessories and Replacement Parts

| Description | Catalog Number |
|--|----------------------|
| Magnetic mounting bracket for ML style lights, 82 lb. capacity | BRYMLMM |
| Magnetic mounting bracket for WL style lights, 58 lb. capacity | BRYWLMM |
| Replacement rough service fluorescent bulb for 13 watt style lamps | BRYREPPFB |
| Metal halide replacement bulb, 400W | BRYREP400MH |
| Metal halide replacement bulb, 1,000W | BRYREP1000MH |
| Replacement LED panel fixture, 90 LEDs, 450 lumen | BRYREP450LED |
| 5 base LEDs string only, 50 ft., 18/2 | BRYREP182S50 |
| 10 base LEDs string only, 100 ft., 18/2 | BRYREP182S100 |



Explosion Proof/Confined Space Lighting

Hazardous Location Lights

| Description | Wattage | Lumen Output | Cord Type | Cord Length | Catalog Number |
|--|---------|--------------|------------|-------------|--------------------|
| Fluorescent, Class 1, Div 1 Groups C & D, Class 2, Div 1 Groups F & G, 12V, inline transformer | 26 | 1,800 | 16/3 SOW | 60 ft. | BRYXF6012V |
| Incandescent, Class 1, Div 1 Groups C & D, 12V, inline transformer | 75 | 720 | 16/3 SOW | 60 ft. | BRYXI6012V |
| Fluorescent, Class 1, Div 1 Groups C & D, Class 2, Div 1 Groups F & G, 120V, less plug | 26 | 1,800 | 16/3 SOW | 50 ft. | BRYXF50120V |
| Incandescent, Class 1, Div 1 Groups C & D, 120V less plug | 100 | 1,230 | 16/3 SOW | 50 ft. | BRYXI50120V |
| Fluorescent, non-explosion proof, wet location, 12V, inline transformer | 13 | 825 | 18/2 SJTOW | 60 ft. | BRYWT6012V |

Cordless Hazardous Location Light

| Description | Wattage | Lumen Output | Rating | Catalog Number |
|---|---------|--------------|--------|-----------------|
| Intrinsically safe, Class 1, Div 1 Groups C & D, with universal charger | 9 | 378 | 4.8V | BRYIS300 |



BRYML2825L



BRYWL25LED



BRYTW25F2



BRYML5025



BRYWL2525



BRYXF6012V



BRYXI6012V



BRYXF50120V



BRYIS300

WORKLIGHTS AND EXPLOSION PROOF

Commercial Lighted Cord Reels with Hand Lamps

| Description | Wattage | Lumen Output | Light Amps /Outlet Amps | Volts | Cord Type | Cord Length | Catalog Number |
|---|---------|--------------|-------------------------|-------|------------|-------------|---------------------|
| Reel with LED hand lamp, with flashlight end, white | 9 | 920/120 | 0.065 / N/A | 125 | 18/2 SJTOW | 40 ft. | BRYC40182LED |
| Reel with non-metallic incandescent hand lamp and automatic shut off switch, yellow | 75 Max | 1,150 Max | N/A / N/A | 125 | 16/3 SJT | 25 ft. | BRYC25163AIN |
| Reel with metallic incandescent hand lamp with receptacle, yellow | 75 Max | 1,150 Max | N/A / 10 | 125 | 16/3 SJT | 25 ft. | BRYC25143IN |
| Reel with fluorescent hand lamp and automatic shut off switch, white | 13 | 825 | 0.3 / N/A | 120 | 18/2 SJTOW | 40 ft. | BRYC40182AFL |
| Reel with fluorescent hand lamp and in-line receptacle, white | 13 | 825 | 0.3 / 12 | 120 | 16/3 SJT | 40 ft. | BRYC40163FL |



BRYC40182LED

Also from Bryant

Watertight Devices



Bryant offers an extensive line of plugs, connectors, receptacles and accessories rated to withstand harsh and wet environments.

Cam-Type Device and Power Distribution Boxes



Bryant offers a complete line of high quality, Cam-Type plugs, receptacles and accessories. Temporary Electrical Power solutions for demanding applications and environments are also available.

Electric Cord and Cable Reels



Bryant's NEMA 4X Waterproof, Industrial and Commercial Cord Reels are built to provide safe, convenient power and lighting for demanding industrial applications and institutional environments.

BRYANT®

www.bryant-electric.com

