

EXTRA DUTY® Metallic While-In-Use Covers

BRYANT®

One Product...Multiple Configurations

Non-Metallic While-in-Use Cover

- High-impact resistant polycarbonate construction provides maximum durability
- Each box contains three or six plates to make a variety of configurations (16 or 55)
- Covers meet or exceed the extra duty rating per UL 514D, and are NEMA 3R rated



Applications

- Commercial
- Mixed-Use Buildings
- Retail and Restaurants
- Hospitality
- Education
- Dormitories
- Residential



The NEMA 3R Rated EXTRA DUTY® Metallic and Non-Metallic While-in-Use Covers offer weather protection for outlets when they are in use

- Patented keyhole mounting system allows installation in under a minute
- Pre-configured for GFCI with patented technology for alternate devices
- Lockable tab for OSHA Compliance
- Sealed-in-place gasket

Metallic While-in-Use Cover



- Premium Paint
- External cord retention chamber
- Each box contains three or six plates to make a variety of configurations (8 or 55)
- Covers meet or exceed the extra duty rating per UL 514D, and are NEMA 3R rated

Applications




- Industrial
- Manufacturing
- Material Handling
- Commercial
- Loading Docks
- Labs and Medical Facilities





EXTRA DUTY® Metallic While-In-Use Covers

BRYANT®

Non-Metallic EXTRA DUTY® While-in-Use Covers

| Description | | Dimensions In (mm) Height x Width x Depth | Catalog # |
|---|---|--|-----------|
| Standard 1-gang box with clear tinted cover, for horizontal or vertical mounting; 16-in-1 configurations |  | 5.90" x 4.18" x 2.75" (149.8 x 106.1 x 69.9) | RW58300 |
| Extra deep 1-gang box with clear tinted cover, for horizontal or vertical mounting; 16-in-1 configurations |  | 5.92" x 4.20" x 4.75" (150.4 x 106.7 x 120.7) | RW58350 |
| Standard 2-gang box, clear tinted cover, for horizontal or vertical mounting; 55-in-1 configurations |  | 5.54" x 5.43" x 2.75" (140.7 x 138.0 x 69.9) | RW58750 |

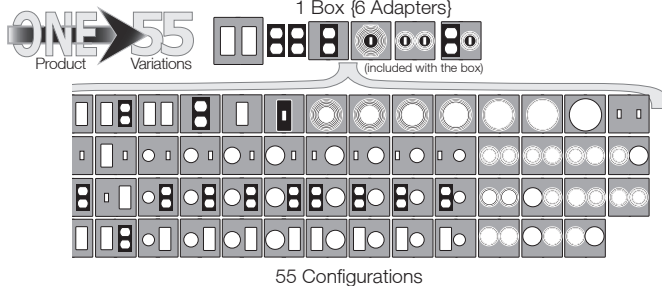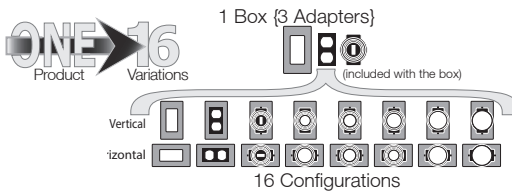

RW58300






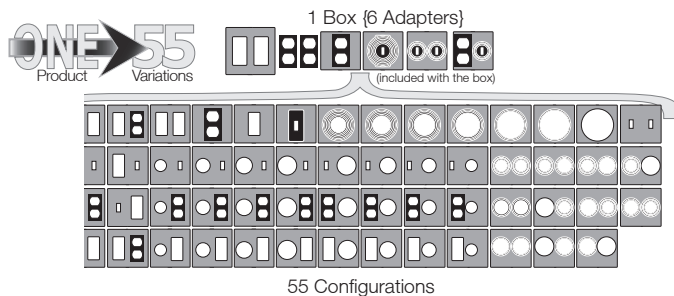
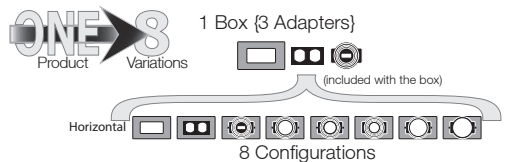
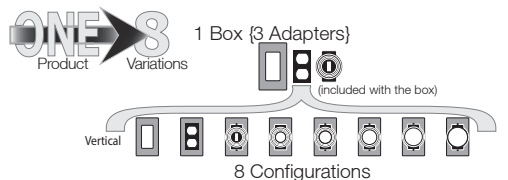
RW58350



RW58750

Metallic EXTRA DUTY® While-in-Use Covers

| Description | | Dimensions In (mm) Height x Width x Depth | Catalog # |
|---|---|--|-----------|
| Heavy duty die-cast aluminum 1-gang box with gray lid for vertical mounting; 8-in-1 configurations |  | 6.12" x 3.37" x 3.5" (155.4 x 85.6 x 89.0) | WPB26E |
| Heavy duty die-cast metal 1-gang box with gray lid for horizontal mounting; 8-in-1 configurations |  | 4.37" x 5.12" x 3.5" (111.0 x 130.0 x 89.0) | WPB26EH |
| Heavy duty die-cast metal 2-gang box with gray lid for vertical mounting; 55-in-1 configurations |  | 6.12" x 5.12" x 3.5" (155.4 x 130.0 x 89.0) | WPB262E |



WPB26E




WPB26EH



WPB262E

EXTRA DUTY® While-in-Use Covers Dimensions - inches (mm)

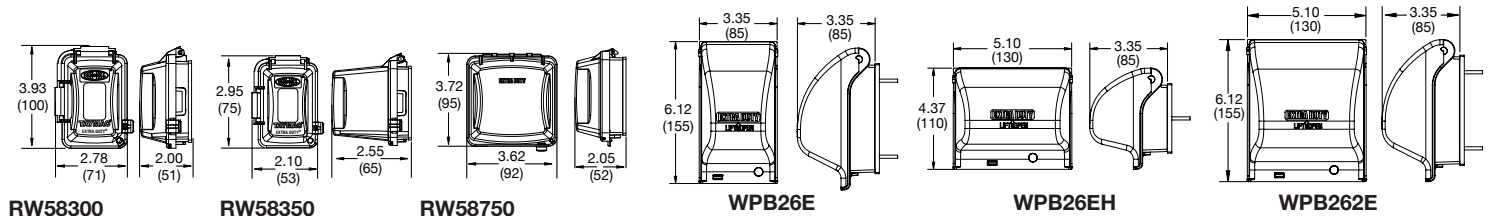

BRYANT®

www.bryant-electric.com

