

## Link-Style Pole Bands

Link-Style Pole Bands are a versatile banding option for guying and deadending that can be installed on wood, steel, or concrete poles. Components can be ordered separately and configured at the job site or as a custom ordered band that is shipped assembled.

### Features:


- 15,000 lbs. rated capacity
- Modular design allows for limitless configurations
- Each band link assembly (PSCCLP2) provides 6" of circumference adjustment

### Material:

Link material: Ductile iron, galvanized per ASTM A-153

Hardware: Galvanized steel per ASTM A-153


Clevis pin: Galvanized steel per ASTM A-325

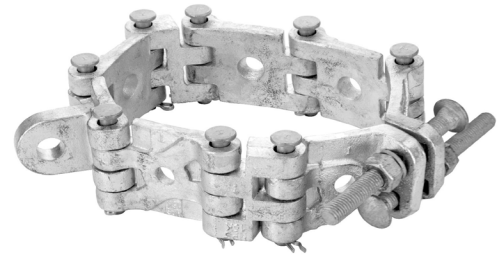

Custom Ordered Band Assembly  
(PSC203AA12 Shown)




PSCCLP2  
Adjustable Link

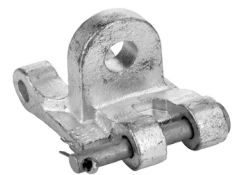

PSCPEL15  
Eye Link



PSCP  
Standard Link

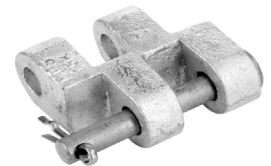

PSCP12  
Short Link

### Ordering Information:

Catalog Number	Description	Approx. Ship Wt. per Each
PSCP12	Short link	.35 lb.
PSCP	Standard link	1.67 lb.
PSCCLP2	Adjustable link	5.08 lb.
PSCPEL15	Eye link	2.57 lb.

### PSC 203 AA 12

STANDARD HUBBELL POWER  
SYSTEMS CATALOG NUMBER PREFIX

STANDARD POLE BAND LINK  
CATALOG NUMBER 3 DIGIT IDENTIFIER

POLE BAND DIAMETER W/ DECIMAL  
MISSING (EX. 12" DIA)

CONFIGURATION TYPE  
(SEE TABLE)

#### CONFIGURATION

AA  
AB  
AC  
AD  
AE  
AF

#### CONFIGURATION DESCRIPTION

SINGLE EYE LINK, SINGLE ADJUSTMENT LINK SET  
TWO EYE LINKS 180° APART, SINGLE ADJ. LINK SET  
TWO EYE LINKS 90° APART, SINGLE ADJ. LINK SET  
FOUR EYE LINKS 90° APART, SINGLE ADJ. LINK SET  
SINGLE EYE LINK, DOUBLE ADJ. LINK SET  
SINGLE ADJUSTMENT LINK SET



A proud member of the Hubbell family.