


Sectionalizing Enclosure

CW300 series single and three phase, 200A or 600A, 15kV to 25kV, sectionalizing enclosure, mild-steel enclosure, Munsell green

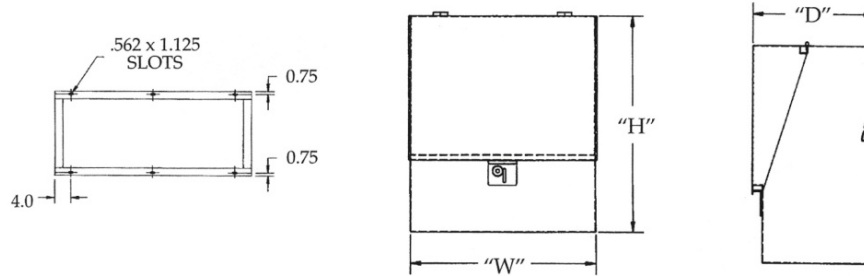

Phase	Max # of junction points			No. of parking stand per phase	Steel Gauge	Height (in)	Width (in)	Depth (in)	Catalog No. ² (mild steel)
	200A		600A						
	15 kV	25 kV	15/25 kV						
1	4	4	-	2	14	30	26	18	CW326-18TH (R) Standard
	4	4	-	2	14	30	30	18	CW330-18TH (R) Standard
	4	4	-	2	12	30	30	22	CC330-22TH (R) Standard
	4	4	-	2	12	30	36	22	CC336-22TH (R) Standard
3	4	3	3 ¹	1	14	30	48	18	CW348-18TH (R) Standard
	4	3	3 ¹	1	12	30	48	22	CC348-22TH (R) Standard
	4	3	3 ¹	1	12	30	48	24	CC348-24TH (R) Standard
	4	4	-	2	14	30	60	18	CW360-18TH (R) Standard
	4	4	-	2	12	30	60	18	CC360-18TH (R) Standard
	4	4	-	2	12	30	60	22	CC360-22TH (R) Standard
	4	4	-	2	12	30	60	30	CC360-30TH (R) Standard
	4	4	4	1	12	30	66	22	CC366-22TH (R) Standard
	4	4	4	1	12	30	78	22	CC378-22TH (R) Standard
	4	4	4	1	12	30	84	22	CC384-22TH (R) Standard

Note:

¹ The enclosure is suitable for a maximum number of 3-point Cooper junctions. For Elastimold and Hubbell junctions, the maximum number of junctions is 2-point.

² Alternate materials and colors are available upon request.

Please consult the factory or your local sales representative for any requirements not listed here.