


Experience the smart home evolution

Make the everyday extraordinary

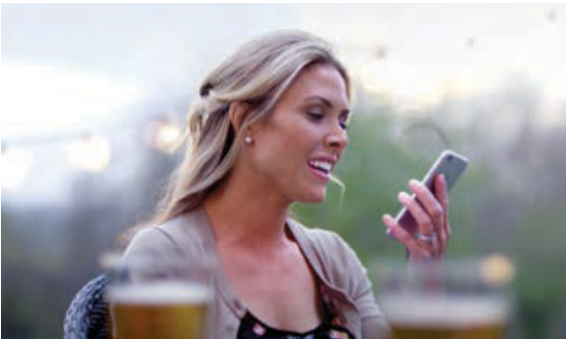

Lighting control is a frequently requested smart home category. Give your homebuyers the security and convenience of smart lighting and electrical products. No matter what your smart home strategy is, iDevices has the solution for you.



Looking for a Wi-Fi or Z-wave solution? We've got you covered either way.



Our Wi-Fi products allow your homebuyers to personalize their smart home to suit their needs. Works with all leading voice assistants*, so you don't have to commit to one platform. No hubs and no monthly fees. Integration into the leading security platform for buyers that want monitored solutions.

*Instinct works with Alexa only



Our Z-Wave products are compatible with today's popular security and hub-based systems, allowing your trades to seamlessly pull lighting and power control into a one-app solution with your other smart home products.



All products supported with Bryant's



TWO-YEAR WARRANTY



A proud member of the Hubbell family.

© 2022 Hubbell Incorporated. All rights reserved.

Smart Home Product Enhancements

Innovation and Convenience from Bryant

iDevices® Smart Home Products

Description	Rating	Catalog Number
Wall Switch Multi-way enabled, single pole, 3- and 4-way setup operation, white	Input/output: 15A 120V AC, 6.5A 277V AC, 50/60Hz, 1HP @ 120 & 277V AC	IDEV0008HW
Dimmer Switch Multi-way enabled, CFL/LED, supports forward-phase dimming, single pole, 3- and 4-way setup operation, white	Input/output: 15A 120V AC, 60Hz, 400W Incandescent/halogen, 150W CFL/LED	IDEV0009HW
Wall Outlet 15 amp tamper-resistant receptacle, individual control of each outlet with energy-monitoring on both outlets, white	Input/output: 15A 125V AC, 60Hz, 1/2 HP	IDEV0010HW
Instant Switch Wireless transmitter, takes 1 CR2032 coin cell battery, wallplate included, white	3V DC, 5.4mA	IDEV0020
Instinct™ Switch With Built-In Alexa, features premium SOEN® Audio technology, speaker and microphone, wallplate included, white	Input/output: 120V AC, 60Hz, 150W CFL/LED, 600W Incandescent, 1000 Resistive, ½HP @ 120V AC	IDEV0022
Thermostat Heating/cooling: 1 and 2 stages, heat pump: 1 and 2 stage with aux or emergency heat, fan control, converts to Fahrenheit or Celsius, white	24V systems	IDEV0005AND5
Universal Thermostat Wire Adapter Share two signals over one wire to add a C/Common wire to a system	18 to 30VAC, 50Hz or 60Hz, 5A Terminals: RC, RH, Y, W, C, G	IDEV0011

© 2022 iDevices, LLC. All Rights Reserved. iDevices and Sweetblue are trademarks owned by iDevices, LLC. Apple, the Apple logo, iPad, iPhone, and iPod Touch are trademarks of Apple Inc., registered in the U.S. and other countries. App Store is a service mark of Apple Inc. The Bluetooth® word mark and logos are registered trademarks owned by Bluetooth SIG, Inc. and any use of such marks by iDevices, LLC is under license.



Z-Wave Smart Home Products

Description	Rating	Catalog Number
Z-Wave Smart Switch Multi-way enabled, single pole, 150ft range, decorator, white	Input/output: 15A 120V AC, 1800W resistive, 960W incandescent, 1/2 HP	IDEVZ01DW
Z-Wave Smart Dimmer Multi-way enabled, CFL/LED, universal dimming, single pole, 150ft range, decorator, white	Input/output: 120V AC, 60Hz, 400W-600W incandescent/halogen, 300W CFL/LED	IDEVZ05DW
Z-Wave Add-on Switch 3- and 4-way add-on switch or dimmer, 150ft range, decorator, white	Input/output: 15A 120V AC, 60Hz, 1/2 HP	IDEVZ03DW
Z-Wave Smart Receptacle 15A tamper-resistant receptacle, one smart controllable outlet, 150ft range	Input/output: 15A 120V AC, 60Hz, 1/2 HP	IDEVZ08W
Z-Wave Smart Fan Switch Adjusts fan speeds, light control separately, 150ft range, white	Input/output: 120V AC, 60Hz, 1/2 HP	IDEVZ07W
Z-Wave Smart Motion Sensing Switch Built-in motion sensor, multi-way enabled, single pole, 150ft range, white	Input/output: 15A 120V AC, 1800W resistive, 960W incandescent, 1/2 HP	IDEVZM01W



Looking for more standout homebuyer options? Hubbell products enhance your home technology offerings.



USB1528AC
Wireless Wall Mount
Charger & USB Receptacle



USB15ACW
USB Receptacle
with USB A & C ports



RCT600W
Countertop Pop Up
Receptacles



USB15AC5GYWR
Weather-resistant
Fast-charge Receptacle
with USB A & C ports

Ask us about our Builder Program, including a unique model home program partnership with  Utour