

# FCR-X Series Premium Rack Mount Solution

## FIBERHUBB™

*Let Hubbell Be Your Fiber Connection*

### Next generation enclosures expand on capacity, access and ease of installation

Hubbell's new FCR-X enclosures deliver innovation and enhancements to splice capacity, cable management and port administration. The 17-inch depth maximizes space for interconnections, splice trays and cable slack storage. The slide-out, tilt-down bottom tray and two removable top covers provide optimum internal access, from the front to the rear of enclosure. A user-friendly clip-on labeling system facilitates port assignments and accepts user-generated labels. Cable management features and hardware optimizes cable bend radius for standards-compliant installation.

#### Features

- 17-inch depth relieves cable congestion
- Two removable top covers for optimum internal access
- Patented cable bend relief bezels
- Easy entry rear grommets
- User-friendly clip-on labeling on front door
- Magnetic catches to secure front door and push-pins on rear door
- Slide-out, tilt-down bottom tray allows for optimum access to adapter cassettes and panels
- Easy push tab to secures bottom tray
- 16 gauge steel construction
- 19" and 23" universal rack mounting brackets
- Optional lock kits for front and rear plexi doors
- 9 staggered slots available in a 2U elevation
- 12 vertical slots available in a 4U elevation

#### Compatibility


- FiberHubb FSP Series Adapter Panels
- FiberHubb OC Series MPO Cassettes
- FiberHubb OC Series Splice Cassettes



# FCR-X Series Premium Rack Mount Solution


## FCR-X Series Enclosures

Configuration	FSP Panels	Splice Trays	Maximum LC Ports	Catalog No.
1U	3	3	72	<b>FCR1U3SPX</b>
2U	6	6	114	<b>FCR2U6SPX</b>
2U, Staggered Slots	9	6	216	<b>FCR2U9SPX</b>
3U	12	12	288	<b>FCR3U12SPX</b>
4U, Vertical Slots	12	16	288	<b>FCR4U12SPVX</b>
4U	15	16	360	<b>FCR4U15SPX</b>

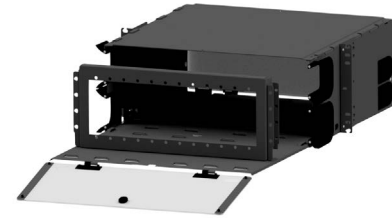

## FSP Adapter Panels

Strand Count	Fiber Type	Color	Catalog No.
12	LC Duplex	Aqua	<b>FSPNLCDS6AQ</b>
12	LC Duplex	Blue	<b>FSPNLCDS6B</b>
12	LC Duplex	Yellow	<b>FSPNLCDS6Y</b>
6	SC Duplex	Aqua	<b>FSPNSCDS3AQ</b>
6	SC Duplex	Blue	<b>FSPNSCDS3B</b>
24	LC Duplex	Aqua	<b>FSPNLCDS12AQ</b>
6	LC Duplex	Aqua	<b>FSPNLCDS3AQ</b>

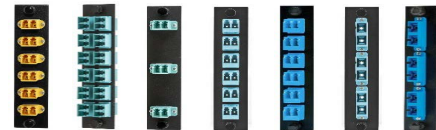

### Our Most Popular FSP Adapter Panels

- Premium zirconia ceramic components
- Multimode or singlemode use

## Cassettes

Fiber	Ports	Port Configuration	Color	Catalog No.
OM4	24	2 LC Duplex to 2 MPO	Aqua	<b>OCLCD50G4</b>
OM4	24	2 LC Duplex to 2 MPO	Aqua	<b>OCLCQ50G4</b>
OM4	24	2 LC Duplex to 2 MPO	Violet	<b>OCLCD50G4VI</b>
OM4	12	2 LC Duplex to MPO	Aqua	<b>OCLC50G4</b>
OS2	24	2 LC Duplex to 2 MPO	Blue	<b>OCLCDSM</b>



### Our Most Popular MPO Cassettes

- 100% factory tested and made in the USA
- Premium zirconia ceramic components
- Multimode or singlemode use

## Splice Cassettes

Adapter Type	Fiber Type	Fiber Strand Count	Adapter Color	Catalog No.
LC	OM3/OM4	12	Aqua	<b>OCSPLCD12M4</b>
	OS2 SM	12	Blue	<b>OCSPLCD12S2</b>
	OM3/OM4	6	Aqua	<b>OCSPLCD6M4</b>
	OS2 SM	6	Blue	<b>OCSPLCD6S2</b>
LC/APC	OM3/OM4	24	Aqua	<b>OCSPLCQ24M4</b>
	OS2 SM	24	Blue	<b>OCSPLCQ24S2</b>
LC/APC	OS2 SM	6	Green	<b>OCSPLCDA6S2</b>
	OS2 SM	12	Green	<b>OCSPLCDA12S2</b>
SC/APC	OS2 SM	6	Green	<b>OCSPSCA6S2</b>
	OS2 SM	12	Green	<b>OCSPSCDA12S2</b>
SC	OM3/OM4	12	Aqua	<b>OCSPSCD12M4</b>
	OS2 SM	12	Blue	<b>OCSPSCD12S2</b>
	OM3/OM4	6	Aqua	<b>OCSPSCD6M4</b>
	OS2 SM	6	Blue	<b>OCSPSCD6S2</b>



### OC Series Splice Cassettes

- Enhanced management of pigtails/fiber slack
- 6, 12, 24-fiber cables or 12-fiber sub-units route into the cassette
- Cleaner install and quicker repairs
- Installation flexibility for small fiber requirements

**Contact your Hubbell representative about our full line of panels and cassettes**



A proud member of the Hubbell family.