


FIBERHUBB™

Let Hubbell Be Your Fiber Connection

Passive Optical LAN (POL) Solution

Hubbell Passive Optical LAN (POL) components are specifically designed to create a flexible end-to-end POL connectivity solution to meet the needs of the progressive, modern, cost-conscious enterprise. Our expertise in fiber and copper connectivity permit us to offer robust POL solutions from single buildings to large campuses, and commercial offices to mixed-use retail, cruise line, healthcare, education and manufacturing.

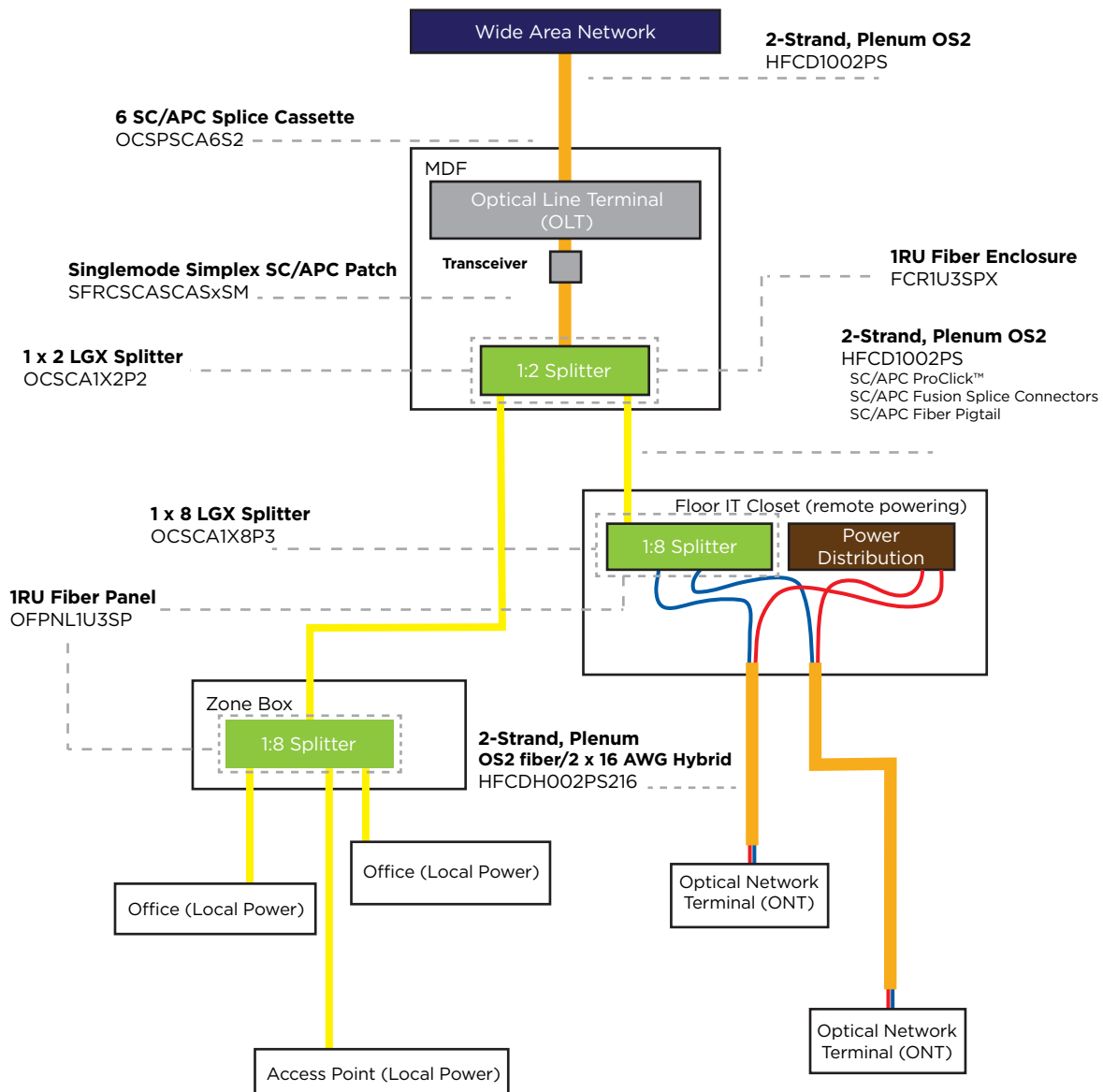

FIBERHUBB™

Passive Optical LAN (POL) Components

Combine these components with Hubbell's existing portfolio of Information and Communications Technology (ICT) products to design, engineer and construct a robust end-to-end Passive Optical LAN (POL) solution. From the smallest office to the largest campus or cruise ships, Hubbell has what it takes. The solution can reach 20km and provide power locally or remotely. POL reduces the installation cost, as well as ongoing operational costs, associated with traditional distributed Ethernet switched networks.

Splitter Cassettes LGX

Adapter Type	Fiber Type	Input x Output	Catalog No.
SC/APC	OS2 SM	1 x 2	OCSCA1X2P2
		1 x 4	OCSCA1X4P2
		1 x 8	OCSCA1X8P3
		1 x 16	OCSCA1X16P3
2 Input Redundant	OS2 SM	2 x 8	OCSCA2X8P3



Splitter Panels 1U x 19"

1U, 19-inch			
Adapter Type	Fiber Type	Input x Output	Catalog No.
SC/APC	OS2 SM	1 x 16	OFPNLSCA1X16P3
		1 x 32	OFPNLSCA1X32P3
2 input redundant			
SC/APC	OS2 SM	2 x 16	OFPNLSCA2X16P3
		2 x 32	OFPNLSCA2X32P3



Splice Cassettes

Adapter Type	Fiber Type	Strand Count	Catalog No.
SC/APC	OS2 SM	6	OCSPSCA6S2
		12	OCSPSCDA12S2



Connectors

SC/APC		
Type	Fiber Type	Catalog No.
ProClick™	ProClick™	FCSC900KASM12
Fusion Splice Connectors	ProClick™	FCSCF900SMA6PK
Fiber Pigtail, Tight Buffer, 3m	ProClick™	FPSCAS3SM




Patch Cords

Duplex			
Description	Fiber Type	Length (meters)	Catalog No.
SC/APC-SC/APC	OS2	1	DFPCSCASCAS1SM
		2	DFPCSCASCAS2SM
		3	DFPCSCASCAS3SM
		4	DFPCSCASCAS4SM
		5	DFPCSCASCAS5SM
		10	DFPCSCASCAS10SM



Fiber Cable

Plenum			
Description	Fiber Type	Strand Count	Catalog No.
Tight Buffer	OS2	2	HFCD1002PS
Tight Buffer, 2x16 AWG Hybrid	OS2	2	HFCDH002PS216

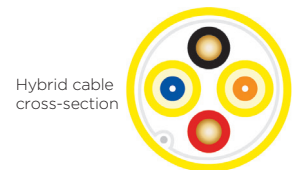

Hybrid cable cross-section

Fiber Enclosure/Panels

LGX		
Description	Fiber Type	Catalog No.
1U, 3-slot enclosure	3	FCR1U3SPX
4U, 15-slot enclosure	15	FCR4U15SPX
1U, 3-slot panel	3	OFPLN1U3SP



A proud member of the Hubbell family.

©2024 Hubbell Premise Wiring. All rights reserved. Hubbell and the Hubbell logo are registered trademarks or trademarks of Hubbell Incorporated. All other trademarks are the property of their respective owners.

23 Clara Drive, Suite 103, Mystic, CT 06355
www.hubbell.com/hubbellpremisewiring | 800-626-0005