


# Upgraded Grand Slam Box now with built in STAB-iT® II Connectors

Better than a Home Run

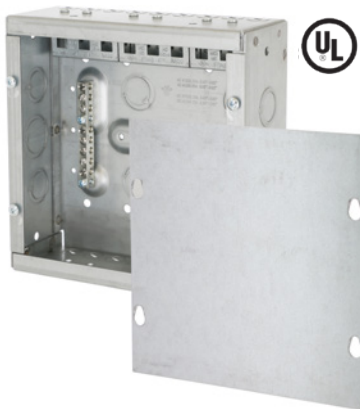

**STAB-iT® II connectors accept 3 cables and larger cable sizes**




Surface Mount Cover & Ground Bar Included

## Applications

RACO's Grand Slam Box is the quickest and easiest way to terminate home runs branch circuits and other electrical wiring. Specifically designed for commercial applications, the Grand Slam Box offers both the flexibility and space desired in a junction box. Featuring RACO's STAB-iT® II connectors for MC, built-in ground bar, and cable management. The Grand Slam Box offers the most labor savings and flexibility of any home run box on the market.

## Features

- STAB-iT® II clamp has been field proven to be over 3X's faster than traditional MC connectors
- Ground bar pre installed
- Cable management with 2 multifunction clips
- Surface mount cover
- Available with and without concentric knockouts on side and back for easy access
- Optional conduit support plate
- NEMA 1 Rating for Indoors
- Additional STAB-iT® II connectors can be added

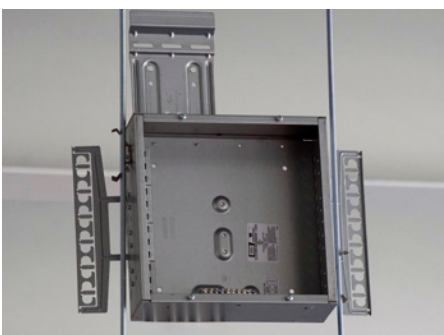

Grand Slam Box installed using Multi-Function Clips on threaded rod

GRAND SLAM BOX

Cat. No.	Description	Dimensions	Knockouts	Built-in STAB-IT® II Clamps	Cu.In. Cap.	Carton Qty.
GS883S	8" x 8" Junction Box (Surface Cvr. & Grnd. Bar Included)	8" x 8" x 3"	(12) 1/2" & 3/4" Concentric (5) 3/4" & 1" Concentric	3 (14/2 to 10/3) Up to 9 Cables	179	1
GS12124S	12" x 12" Junction Box (Surface Cvr. & Grnd. Bar Included)	12" x 12" x 4"	(12) 1/2" & 3/4" Concentric (9) 3/4" & 1" Concentric (8) 1" & 1-1/4" Concentric	4 (14/2 to 10/3) Up to 12 Cables	546	1
GS883SNK	8" x 8" Junction Box (No Knockouts, Surface Cvr. & Grnd. Bar Included)	8" x 8" x 3"	—	3 (14/2 to 10/3) Up to 9 Cables	179	1
GS12124SNK	12" x 12" Junction Box (No Knockouts, Surface Cvr. & Grnd. Bar Included)	12" x 12" x 4"	—	4 (14/2 to 10/3) Up to 12 Cables	546	1
GS883SCM	8" x 8" Junction Box (Cable management, Surface Cvr. & Grnd. Bar Included)	8" x 8" x 3"	(12) 1/2" & 3/4" Concentric (5) 3/4" & 1" Concentric	3 (14/2 to 10/3) Up to 9 Cables	179	1
GS12124SCM	12" x 12" Junction Box (Cable management, Surface Cvr. & Grnd. Bar Included)	12" x 12" x 4"	(12) 1/2" & 3/4" Concentric (9) 3/4" & 1" Concentric (8) 1" & 1-1/4" Concentric	4 (14/2 to 10/3) Up to 12 Cables	546	1
GS883SNKCM	8" x 8" Junction Box (No Knockouts, Cable management, Surface Cvr. & Grnd. Bar Included)	8" x 8" x 3"	—	3 (14/2 to 10/3) Up to 9 Cables	179	1
GS12124SNKCM	12" x 12" Junction Box (No Knockouts, Cable management, Surface Cvr. & Grnd. Bar Included)	12" x 12" x 4"	—	4 (14/2 to 10/3) Up to 12 Cables	546	1



Accessories		
Cat. No.	Description	Carton Qty.
9100SP	Grand Slam conduit support plate	10
989ST2	STAB-iT® II Connector (accepts 3 cables) Works with all Grand Slam boxes	50



Conduit Support Plate  
(sold separately)



STAB-iT® II  
Connector

Cable types and ranges of stab-it® ii clamp		
Cable Type	Cable Range	Cable Range Diameter
AC Steel & Aluminum	14-2, 14-3, 14-4, 12-2, 12-3, 12-4, 10-2, 10-3	0.44" · 0.62"
HCF AC Steel	14-2, 14-3, 14-4, 12-2, 12-3, 10-2, 10-3	
HCF AC Aluminum	12-2, 12-3, 12-4, 10-2, 10-3	0.42" · 0.62"
MC Steel & Aluminum	14-2, 14-3, 14-4, 12-2, 12-3, 12-4, 10-2, 10-3	
MCI-A Steel & Aluminum	14-2, 14-3, 14-4, 12-2, 12-3, 12-4, 10-2, 10-3	
HCF MCI-A Steel	12-2, 12-3, 10-2	0.38" · 0.62"
HCF MCI-A Aluminum	14-2, 14-3, 14-4, 12-2, 12-3, 12-4, 10-2, 10-3	
3/8 TRADE SIZE FLEX. RWFC CONDUIT STEEL & ALUMINUM Anti Short Bushing Required		
CABLE RANGE .400" DIA. MIN. TO .605" DIA. MAX.		

Cable Armor must comply with NEC 250.96  
To remove cable unscrew clamp from the box then pull clamp off cable.  
To install more cables use any of the RACO 38RAC or 40RAC push-in cable connectors



A proud member of the Hubbell family.

©2024 Raco. All rights reserved.  
Hubbell and the Hubbell logo are registered trademarks or trademarks of Hubbell Incorporated. All other trademarks are the property of their respective owners.  
3902 W. Sample St., South Bend, IN 46619  
www.hubbell.com/raco | 574-234-7151