

Round Metallic Floor Boxes

We offer five different styles of round concrete metallic floor boxes, satisfying the requirements of almost any commercial building application. These traditional solutions include two versions, cast iron base with sheet metal adjustable tops with a green powder paint finish and non-painted sheet metal. These boxes can be finished with either brass or aluminum covers and flanges for several floor finishes including finished concrete, tile, VCT, wood, and carpet. All Hubbell floor box assemblies exceed UL Scrubwater exclusion requirements.

Features

Box

- Cast Iron floorboxes include cast iron bases, 16 gauge galvanized sheet metal adjustable tops, 3/4" or 1" threaded hubs (1" includes 3/4" to 1" threaded reducers) and fusion-bonded, green epoxy paint for on-grade use
- Sheet metal floor boxes include 16 gauge galvanized sheet metal bases and adjustable tops, concentric knockouts for side and bottom conduit entry
- 3" to 4" minimum depth of pour
- Pre-pour and post-pour adjustment
- Disposable metallic flange allows for combination one piece cover/flange mounting






Cover and Flanges

- Available in brushed brass and brushed aluminum
- Cover adapter rings are purchased separately for tile or finished concrete flush applications
- Carpet flanges are purchased separately for carpet and surface applications
- Metallic covers and flanges have 2,000 lbs. static load rating with 2x safety factor
- Listed to UL 514A and UL Scrubwater compliant
- All covers are ADA compliant



Round Metallic Floor Boxes

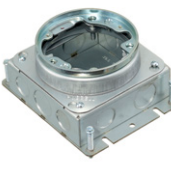Style	Cast Iron			Stamped Steel	
					
Catalog Numbers	FB2536	FB2537	FB2546	FB2527	FB2529
Cover Frame Material	Steel	Steel	Steel	Steel	Steel
Min. Depth of Pour	3.25" (82.6)	3.00" (76.2)	3.75" (95.3)	4.00" (101.6)	3.00" (76.2)
Post Pour Adjustment	.50" (12.7)	.50" (12.7)	.625" (15.9)	.50" (12.7)	.50" (12.7)

For two piece cover installation. Choose either cover adapter ring or carpet flange and a cover.

Cover Adapter Ring, Flush Application

Required for Tile or Finished Concrete Applications

S5016



Brass

SA5016



Aluminum

Carpet Flanges, Surface Application

Required for Carpet and Surface Applications

6.25 in. Dia

5.25 in. Dia

S3082



Brushed Brass

SA3082




Brushed Aluminum

Single Service Covers

Brass
Aluminum
3.88 in. Dia.

S3925
SA3925

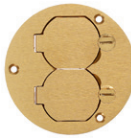

Duplex
Flap

S3725
SA3725



Duplex
Screw

S2525
SA2525



2 1/8" x 3/4"
Combination

S2725
SA2725



2 1/8" x 1"
Combination

S2925
SA2925



2 1/8" Single
Receptacle

S3525
-



2 3/8" Single
Receptacle

S3325
-



2 1/8" Single
Receptacle
(Terrazzo
Floor)

S3913
SA3913



Blank

For one piece cover installation. Choose one piece cover and carpet flange.
Mounts to round floor box metallic flange.

One Piece Brass and Aluminum Cover/ Carpet Flanges

Brass
Aluminum
6.25 in. Dia.

SF3925
SFA3925



Duplex
Flap

SFB3926*
SFA3926



Style Line®
Decorator
Opening

SF2525
-



2 1/8" x 3/4"
Combination

SF2725
-



2 1/8" x 1"
Combination

SF2925
-



2 1/8" Single
Receptacle

Note: *Brass plated aluminum

Cover load rating; metallic covers and flanges 2,000 lbs. with 2x safety factors. Load applied through a 3 in. (76) mandrel at the center of the cover.



A proud member of the Hubbell family.

hubbell.com/wiringdevice-kellems | 40 Waterview Drive,
Shelton, CT 06484 | 800-288-6000

©2023 Hubbell Incorporated. All rights reserved.
Hubbell and the Hubbell logo are registered trademarks or
trademarks of Hubbell Incorporated.
All other trademarks are the property of their respective owners.

EP-WDK-SF-EN-01551 | 12/2023