

# 6-Gang Recessed Floor Boxes

Increased power, data, and AV capacity is what the Hubbell SystemOne 6-Gang Recessed Concrete Floor Box was designed to handle. Four styles allow the floor box to work within almost any commercial application to enhance connectivity. Four removable knockout plates allows for 2" conduit feed-thru. Rectangular and round covers are available in a variety of finishes that work with any aesthetic or finish.


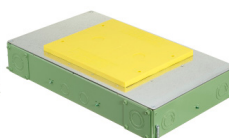


## Box

- 3.75" deep wiring device chambers
- 14 gauge galvanized sheet metal
- Optional fusion-bonded, green epoxy paint for on-grade use
- Floor boxes accept field installed metallic 2" threaded hubs and PVC hubs
- Patented PVC conduct adapters can be used on the floor boxes—**CFBHUB200PVC** (2 in. feed-thru) and **CFBHUB125PVC** (1¼" feed-thru)
- Pre-pour and post-pour adjustment
- Single screw, labor saving, easy mount device plates



## Cover

 
- Rectangular covers- maximum static load of 1,500 lbs. with 2x safety factor
- Round covers- maximum static load of 1,000 lbs. with 2x safety factor
- Available in round and rectangular, recessed and furniture feed styles
- Recessed covers open a full 180°
- Large hide-away cable egress doors
- Listed to UL 514A and UL Scrubwater compliant
- Die cast aluminum cover construction
- All covers are ADA compliant

Style	Rectangular Cover		Round Cover	
				
Standard Box	<b>CFB6G30E</b>	-	<b>CFB6G30RE</b>	-
Corrosion-Resistant (On-grade)	-	<b>CFB6G30CRE</b>	-	<b>CFB6G30RCRE</b>
Recommended Pour Depth	3.50" (88.9)	3.50" (88.9)	3.75" (95.3)	3.75" (95.3)
Min. Depth of Pour	3.00" (76.2)	3.00" (76.2)	3.75" (95.3)	3.75" (95.3)



## Rectangular Covers

### Available finishes



Aluminum  
Powder Coat

Black  
Powder Coat

Brass  
Powder Coat

Bronze  
Powder Coat

Satin Nickel  
Powder Coat

Finish	Surface Cover Dimensions 11½ in. x 10 in.			Flush Cover Dimensions 10½ in. x 9 in.		
	Without Insert	With Insert	Furniture Feed (2) 1 in. & (2) 2 in. Plugs)	Without Insert	With Insert	Furniture Feed (2) 1 in. & (2) 2 in. Plugs)
Aluminum Powder Coat	<b>610GCCVRALU</b>	<b>610GCCVRALUC</b>	<b>610GCFFCVRALU*</b>	<b>610GTCVRALU</b>	<b>610GTCVRALUC</b>	<b>610GTFFCVRALU*</b>
Black Powder Coat	<b>610GCCVRBK</b>	<b>610GCCVRBK</b>	<b>610GCFFCVRBK*</b>	<b>610GTCVRBK</b>	<b>610GTCVRBK</b>	<b>610GTFFCVRBK*</b>
Brass Powder Coat	<b>610GCCVRBRS</b>	<b>610GCCVRBRSC</b>	<b>610GCFFCVRBRS*</b>	<b>610GTCVRBRS</b>	<b>610GTCVRBRSC</b>	<b>610GTFFCVRBRS*</b>
Bronze Powder Coat	<b>610GCCVRBRZ</b>	<b>610GCCVRBRZC</b>	<b>610GCFFCVRBRZ*</b>	<b>610GTCVRBRZ</b>	<b>610GTCVRBRZC</b>	<b>610GTFFCVRBRZ*</b>
Satin Nickel Powder Coat	<b>610GCCVRNK</b>	<b>610GCCVRNK</b>	<b>610GCFFCVRNK*</b>	<b>610GTCVRNK</b>	<b>610GTCVRNK</b>	<b>610GTFFCVRNK*</b>

\*For 6-gang box dual service, **CFB6FFDIVKIT** required with furniture feed covers. Purchased separately.



## 8 Inch Round Covers

### Available finishes



Brushed  
Aluminum

Black  
Powder Coat

Brass  
Plated

Bronze  
Plated

Gray  
Powder Coat

Satin Nickel  
Plated

Finish	Flush Surface	Furniture Feed (¾ in. and 2 in. Plugs)
Brushed Aluminum	<b>CFBS1R8CVRALU</b>	<b>CFBS1R8FFCVRALU**</b>
Black Powder Coat	<b>CFBS1R8CVRBLK</b>	<b>CFBS1R8FFCVRBLK**</b>
Brass Plated	<b>CFBS1R8CVRBRS</b>	<b>CFBS1R8FFCVRBRS**</b>
Bronze Plated	<b>CFBS1R8CVRBRZ</b>	<b>CFBS1R8FFCVRBRZ**</b>
Gray Powder Coat	<b>CFBS1R8CVRGRY</b>	<b>CFBS1R8FFCVRGRY**</b>
Satin Nickel Plated	<b>CFBS1R8CVRNKL</b>	<b>CFBS1R8FFCVRNKL**</b>



\*\* For 6-gang box dual service, **CFBS1R8FF6GDIVKIT** required with Furniture Feed covers.

## Plates for use in SystemOne 6-Gang floor boxes

Cat. No.	Plate Style	Cat. No.	Plate Style
<b>FBMPREC</b>	(1) Decorater opening	<b>FBMPDUP</b>	(1) Duplex opening
<b>FBMP139</b>	(1) Simplex opening 1.40 in. diameter	<b>FBMP156</b>	(1) Twist-Lock® opening 1.60 in. diameter
<b>FBMP6DJ</b>	(1) Hubbell keystone jack openings and (4) jack KOs with label field	<b>FBMP6KS</b>	(1) Opening with Hubbell 6-Port frame for keystone jacks
<b>FBMP15IM</b>	(1) 1.5U Hubbell iStation opening	<b>FBMP2IM</b>	(2) 1U Hubbell iStation openings
<b>FBMPBNK</b>	1-gang blank plate	<b>FBMPFT</b>	Cable feed through with bushing
<b>FBMPAAP</b>	(4) Extron® AAP openings	<b>FBMPMAAP</b>	(2) Extron® MAAP openings
<b>FBMPTRAC</b>	(1) opening for Tracjack® or Series II®	<b>FBMPSIEMONCT</b>	Siemon CT Series

Extron® is a registered trademark of Extron Electronics. TracJack®, Series II® and Ortronics® are registered trademarks of Ortronics/Legrand.

## Pre-Wired Device Plates for use with 6-Gang floor boxes

Description	Type	15A	20A
Duplex, gray	Standard Tamper-Resistant	<b>PWFBMPCR15GRY</b> <b>PWFBMPCR15GRYTR</b>	<b>PWFBMPCR20GRY</b> <b>PWFBMPCR20GRYTR</b>
Decorator, gray	Standard Tamper-Resistant	<b>PWFBMPDR15GRY</b> <b>PWFBMPDR15GRYTR</b>	<b>PWFBMPDR20GRY</b> <b>PWFBMPDR20GRYTR</b>
2-Cubes, single circuit	Standard Marked Controlled	-	<b>PWFBMP2R*</b> <b>PWFBMP2RC*</b>
3-Cubes, single circuit	Standard Marked Controlled	-	<b>PWFBMP3R*</b> <b>PWFBMP3RC*</b>

Note: \*Includes isolated ground sticker



A proud member of the Hubbell family.

hubbell.com/wiringdevice-kellems | 40 Waterview Drive,  
Shelton, CT 06484 | 800-288-6000

©YYYY Company Name. All rights reserved.  
Hubbell and the Hubbell logo are registered trademarks or  
trademarks of Hubbell  
Incorporated. All other trademarks are the property of their  
respective owners.

EP-WDK-SF-EN-01474 12/23