

HUBBELL SYSTEMONE ETERNAL™ SERIES

# 4-Gang Rectangular Floor Boxes

The Hubbell SystemOne 4-Gang Recessed Raised Access or Wood Floor Box delivers AV plus power. Similar to the 2-gang recessed raised access floor box, the 4-gang 2 ½ inch box depth provides a solution for floors using short pedestals. The 5 inch depth is ideal for applications with a lot of requirements. Rectangular covers in a variety of finishes will match any existing or new style.

**Features and Benefits**

**Rectangular Box**

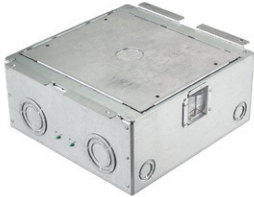
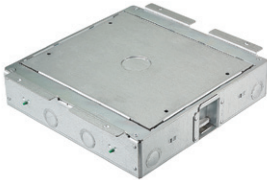
- For Use in Raised Access and Wood Floors
- 16 gauge galvanized sheet metal
- Many boxes allow for 2 in. conduits
- Mounts in tiles ¾ in. to 2 in. thick
- Single screw labor saving, easy mount device plates
- Plenum rated box assemblies

**Cover**

- 180° cover opening
- Two large cable egress doors
- Rectangular covers- maximum static load of 1,500 lbs. with 2x safety factor
- Listed to UL 514A and UL scrubwater compliant
- Die cast aluminum cover construction
- Available in rectangular and furniture feed styles
- All covers are ADA compliant



**4-Gang Floor Boxes**

Rectangular Cover		
Style		
		
Box Type		
Standard	<b>AFB4G50</b>	<b>AFB4G25</b>
Chicago (No Knockouts)	<b>AFB4G50CHI</b>	<b>AFB4G25CHI</b>
Minimum Depth from Top of Floor Tile	5.32" (135.1)	2.88" (73.2)



## Rectangular Covers

### Available finishes



Aluminum Powder Coat    Black Powder Coat    Brass Powder Coat    Bronze Powder Coat    Satin Nickel Powder Coat

Surface Cover Dimensions 13 in. x 13¼ in.		
Finish	Without Insert	With Insert
Aluminum Powder Coat	<b>4GAFBCVRALU</b>	<b>4GAFBCVRALUC</b>
Black Powder Coat	<b>4GAFBCVRBK</b>	<b>4GAFBCVRBKC</b>
Brass Powder Coat	<b>4GAFBCVRBRS</b>	<b>4GAFBCVRBRSC</b>
Bronze Powder Coat	<b>4GAFBCVRBRZ</b>	<b>4GAFBCVRBRZC</b>
Satin Nickel Powder Coat	<b>4GAFBCVRNK</b>	<b>4GAFBCVRNKC</b>



Aluminum Powder Coat    Black Powder Coat    Bronze Powder Coat    Brass Powder Coat

## Plates for use in SystemOne AFB4G-Gang floor boxes

- UL 514A listed

Cat. No.	Plate Style		Cat. No.	Plate Style	
<b>FBMPREC</b>	(1) Decorater opening		<b>FBMPDUP</b>	(1) Duplex opening	
<b>FBMP139</b>	(1) Simplex opening 1.40 in. diameter		<b>FBMP156</b>	(1) Twist-Lock® opening 1.60 in. diameter	
<b>FBMP6DJ</b>	(1) Hubbell keystone jack openings and (4) jack KOs with label field		<b>FBMP6KS</b>	(1) Opening with Hubbell 6-Port frame for keystone jacks	
<b>FBMP15IM</b>	(1) 1.5U Hubbell iStation opening		<b>FBMP2IM</b>	(2) 1U Hubbell iStation openings	
<b>FBMPBNK</b>	1-gang blank plate		<b>FBMPFT</b>	Cable feed through with bushing	
<b>FBMPAAP</b>	(4) Extron® AAP openings		<b>FBMPMAAP</b>	(2) Extron® MAAP openings	
<b>FBMPTRAC</b>	(1) opening for Tracjack® or Series II®				

Extron® is a registered trademark of Extron Electronics. TracJack®, Series II® and Ortronics® are registered trademarks of Ortronics/LeGrand.

## Pre-Wired Devices Plates

Description	Type	15A	20A
Duplex, gray	Standard Tamper-Resistant	<b>PWFBMPCR15GRY</b> <b>PWFBMPCR15GRYTR</b>	<b>PWFBMPCR20GRY</b> <b>PWFBMPCR20GRYTR</b>
Decorator, gray	Standard Tamper-Resistant	<b>PWFBMPDR15GRY</b> <b>PWFBMPDR15GRYTR</b>	<b>PWFBMPDR20GRY</b> <b>PWFBMPDR20GRYTR</b>
2-Cubes, single circuit	Standard Marked Controlled	- -	<b>PWFBMP2R*</b> <b>PWFBMP2RC*</b>
3-Cubes, single circuit	Standard Marked Controlled	- -	<b>PWFBMP3R*</b> <b>PWFBMP3RC*</b>

\*Includes isolated ground sticker



A proud member of the Hubbell family.