

# All USB receptacles are not the same

## USB RECEPTACLES

### Offer USB charging solutions for any need

Prepare for the transition from legacy Type A devices to the latest USB-C<sup>®</sup> electronics with our line of USB chargers. We offer more ways to charge faster with Type C, Type A & C, or specialty configurations.

These durable USB chargers/power receptacles deliver convenience. They eliminate the need for power adapters and maintain tamper-resistant electrical outlets for higher current requirements.

#### Base-grade USB Receptacles

Available with Type A & C ports.


#### Fast-charge USB Receptacles

Charge devices up to twice as fast as base-grade USB receptacles.

Available with Type A & C ports.

#### Power Delivery USB Receptacles

Provide more power with receptacles featuring USB-C Power Delivery (PD) technology. Users can quickly charge laptops and large devices without power adapters. Phone and tablets charge up to 3-4 times faster.

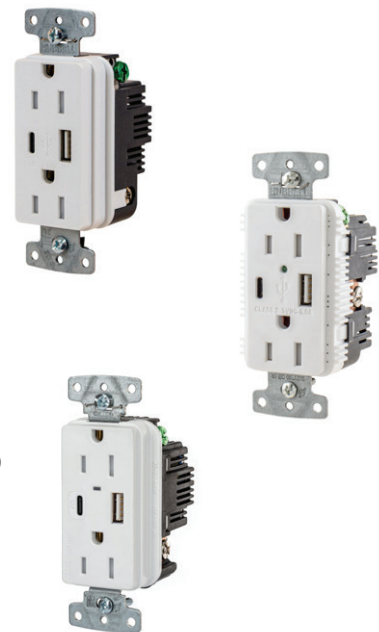

## STAINLESS STEEL PORTS

All Hubbell USB receptacles feature ports rated for a minimum of 10,000 insertion cycles



# Specialty Charging Products

## Weather-resistant Fast-charge USB Receptacles

Weather-resistant models offer fast-charge Type A & C ports. Designed for outdoor use with weatherproof covers. Perfect for front porches and back patios.

## Combination Wireless & USB Charging Receptacles

Use a standard single-gang opening! Our wireless/USB charger combines the power of a fast-charge Type A & C receptacle with convenient Qi Certified wireless charging.

## 4-Port Fast-charge USB Receptacles

Our 4-port charger outlets feature a USB port door, which shuts off power when closed. This eliminates all current flow for a no-load draw. Ideal for energy-efficient design.



Power Delivery USB Receptacle Type C

Description	Color	15A 125V	20A 125V
Two Type C port configurations, (1) USB-C® Power Delivery port with up to 55W output and (1) USB-C Convenience port 1.5A, 5V output, Tamper-Resistant duplex receptacle, USB ports rated 10,000 cycles	Ivory	USB15CPDI	USB20CPDI
	Light Almond	USB15CPDLA	USB20CPDLA
	White	USB15CPDW	USB20CPDW

Power Delivery USB Receptacle Type A & C

Description	Color	15A 125V	20A 125V
(1) USB-C Power Delivery port with up to 55W output and (1) USB Type-A Convenience port 1.5A, 5V output, Tamper-Resistant duplex receptacle, USB ports rated 10,000 cycles	Ivory	USB15ACPD1	USB20ACPD1
	Light Almond	USB15ACPDLA	USB20ACPDLA
	White	USB15ACPDW	USB20ACPDW

Fast Charge USB Tamper-Resistant Duplex Receptacles

Description	Color	15A 125V	20A 125V
Type-C USB Charger Receptacle, two Type-C port configurations, high power 5 Amp, 5 Volt USB output	Ivory	USB15C5I	USB20C5I
	Light Almond	USB15C5LA	USB20C5LA
	White	USB15C5W	USB20C5W

Description	Color	15A 125V	20A 125V
Type A&C USB Charger Receptacle, one Type A and one Type-C port configuration, high power 5 Amp, 5 Volt USB output	Ivory	USB15AC5I	USB20AC5I
	Light Almond	USB15AC5LA	USB20AC5LA
	White	USB15AC5W	USB20AC5W

Base Grade USB Charger Tamper-Resistant Duplex Receptacles

Description	Color	15A 125V	20A 125V
Type A & C USB charger duplex receptacle, USB ports rated 10,000 cycles One Type A and one Type-C configuration	Ivory	USB15ACI	USB20ACI
	Light Almond	USB15ACLA	USB20ACLA
	White	USB15ACW	USB20ACW

4 Port USB Charger Outlets

Description	Color	4 Type A ports	2 Type A and 2 Type-C ports	4 Type-C ports
USB Charger Outlets, 4 USB ports, 5 Amp, 5 Volt DC, Style Line® decorator	Ivory	USB4I	USB4ACI	USB4CI
	Light Almond	USB4LA	USB4ACLA	USB4CLA
	White	USB4W	USB4ACW	USB4CW

Weather Resistant USB Charger Duplex Receptacles

Description	Color	15A 125V 20A 125V	2 Type A and 2 Type-C ports
Type A&C USB Charger Receptacle, One Type A and one Type-C port configurations, high power 5 Amp, 5 Volt USB output, Tamper-Resistant USB ports rated 10,000 cycles; Commercial Grade	Gray	USB15AC5GYWR	USB20AC5GYWR

Note: Outdoor circuits should be GFCI protected per national and local electric codes.  
NEC® is a registered trademark of the National Fire Protection Association (NFPA).

Combination Wireless Chargers

Description	Color	Rating	Receptacle	Catalog Number
Combination wireless wall mount phone charger, inductive coil with USB Type A&C ports, and tamper-resistant receptacle	White	Coil: 7.5 watt inductive USB: 5A 5V DC Input: 125V AC	15A 125V	USB1528AC
			20A 125V	USB2028AC

Additional colors available, please visit our website or contact your Hubbell representative.



A proud member of the Hubbell family.

©2024 Hubbell Incorporated. All rights reserved.  
Hubbell and the Hubbell logo are registered trademarks or trademarks of Hubbell Incorporated.  
All other trademarks are the property of their respective owners.  
hubbell.com/wiringdevice-kellems | 40 Waterview Drive,  
Shelton, CT 06484 | 800-288-6000