



## EdgeConnect™ Termination vs Standard Push Wire

Just push the plunger to activate Hubbell's patented, internal lever spring clamp. It applies dynamic, continuous pressure to hold wire tight, unlike push-in or back-stab termination.

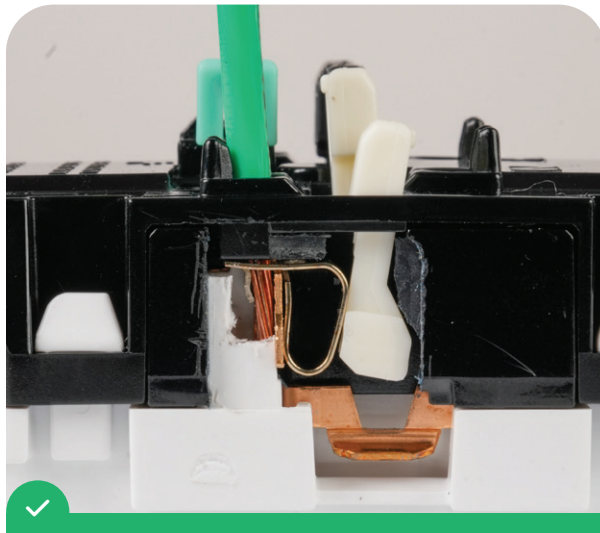


### EdgeConnect termination

- Termination that won't let go!
- Suitable for 20A/14-10AWG stranded or solid
- Reusable

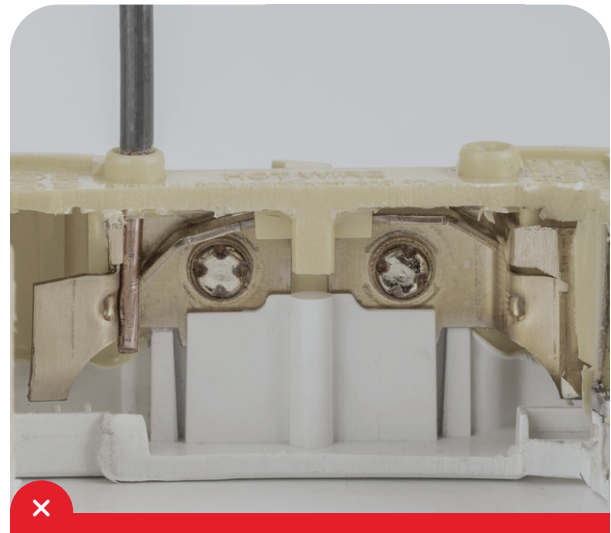

### Standard push wire

- Relaxes over time
- No stranded wire, only for solid 15A/14AWG
- Difficult to unwire

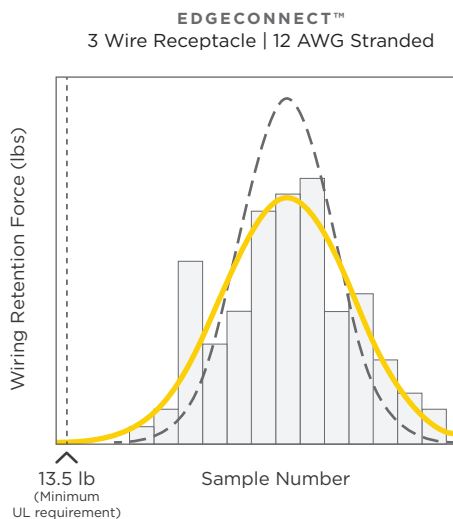

### Over 2x the holding power!

- Requires over 40 lbs of force to disengage
- Grip actually gets stronger over time

### Not a WAGO connector either!

Those splice connectors don't apply pressure. EdgeConnect technology makes terminations—better, faster, safer.