

Features

- Integrates with GAI-TRONICS IP Systems
- Programmable Alarm Buttons
- Point-to-Point, Serverless Audio & Video
- Zone Paging and Intercom
- 7-inch Touchscreen
- Intuitive Operation
- PoE / PoE+ or 24 V dc Input
- Dual RJ45 Network Connections
- Integral Speaker
- Handset with Noise-cancelling Microphone
- HD 720P Integral Camera
- SIP Telephone
- Bluetooth and Wi-Fi Connection



GAI-TRONICS **IP Access Panel Lite** model number 319-02-HZ00200 provides alarm activation in conjunction with a GAI-TRONICS IP public address and general alarm system. This product is simple to configure using GAI-TRONICS Console firmware. Once configured, the IP Access Panel Lite can be used to activate and reset alarm tones.

The IP Access Panel Lite allows for control of up to 11 alarm tones or pre-recorded messages along with an alarm reset button. Common alarms include “FIRE” and “SEVERE WEATHER”. However, these alarms can be customized.

The IP Access Panel Lite can be configured to provide zone specific live audio paging. This can be done via the GAI-TRONICS Portal firmware.

Being part of the family of IP products, the IP Access Panel Lite will seamlessly integrate with GAI-TRONICS’ SP2, Elemec3, HUBBCOM, and IP Controller.

To use in a system, simply place the IP Access Panel Lite on the same customer supplied network as the other IP devices. Up to 256 Access Panels can be placed on the same IP network. Network connection allows for system monitoring and fault reporting.



• *Programmable User Interface*

GENERAL SPECIFICATIONS

Electrical/Network

- Network Power: PoE / PoE+, 802.3af compliant (via RJ45)
- Local Power Requirements: 24 V dc (a separate, isolated power supply must be provided for each unit)
- Network: 10 / 100 / 1000 BaseT
- Call Control Signalling (telephone): SIP (RFC3261 compliant)
- Handset: 6ft. PVC Cord, Noise-cancelling microphone
- WiFi: 802.11 a / b / g / n + MIMO
- Bluetooth: Version 4.1 + CSA2 support / BLE

Audio

Integral Speaker: 8 Ohm, 2 watt
External Speaker Output: 8 Ohm,
8 watt maximum

NOTE:
External power supply is required
for external speaker use

Mechanical Control

- Configurable Inputs (volt-free): 2
- Configurable Outputs: 2 (125 mA max.)

Electronic Control/Input

- Touchscreen: 7-inch Capacitive

Environment

- Operating Temperature Range: 0° C to 50° C
- Relative Humidity: up to 95%, non-condensing

Construction

- Housing and Front Panel: Gray ABS Plastic
- Flush-mount Back Box: 16-gauge cold-rolled steel with black polyurethane finish

Dimensions

- 10.2 W x 8.3 H x 3.3 D inches; (260 W x 210 H x 86 mm)



Weight

- Unit weight: 3 lbs

Approval Standards

- Compliance to Standards: FCC CFR 47 Part 15

DIMENSION DRAWINGS

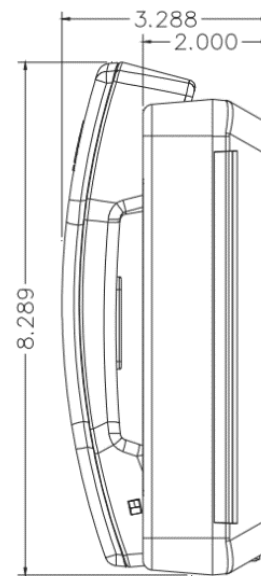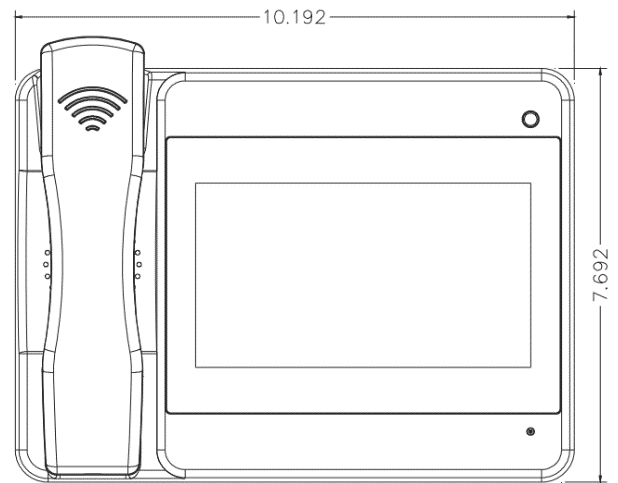

ORDER INFORMATION

MODELS	DESCRIPTION
319-02-HZ00200	IP Access Panel Lite
10125-001	Replacement Handset

