




HUBBELL NextFrame Ladder Rack

Modular System: Easily Configured for New and Existing Cable Routing.

Mounts to Floors, Walls, Ceilings, Equipment Racks, and Cabinets.

Tip: Secure Ladder to Cabinet Tops Using J-bolt Kit and Drilling Holes as Required.

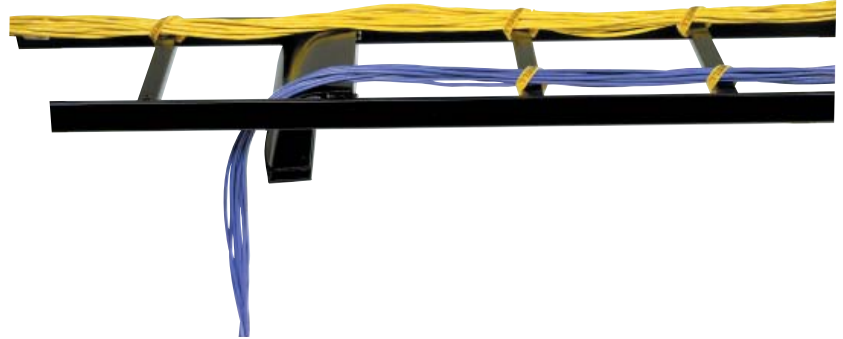

FEATURES

- Supports horizontal/vertical and overhead cable management.
- Durable black or gray powder coat finish.
- Supports UTP or fiber cabling.
- Complete family of accessories includes: wall supports and brackets, cable drops, retaining posts, splice kits, and ceiling mounting kits.

SPECIFICATIONS

- ◆ Material: 16 ga. tubular steel.
- ◆ Durable powder coat.
- ◆ Stringer dimensions: 0.375"W x 1.5"H.
- ◆ Rung spacing: 9.0".
- ◆ Weight capacity: 45 lbs./foot.

APPLICATIONS

Use in data centers, the equipment room, and telecommunications room to provide racking, cable management, and grounding for network hardware.

Hubbell Premise Wiring's **NEXTFRAME**® Ladder Rack is the effective and widely used cable runway that supports and delivers bundles of cable between cabinets, racks, and closets, along walls, and suspended from ceilings.

The Ladder Rack System features light, rugged, tubular steel construction. It is designed for mechanical support and strain relief in long runs of cable and creates a smooth gradual bend for cable. Rail and stringer material is 16 ga steel tubing.

The **NEXTFRAME**® Ladder Rack is available in popular gray and black finishes to complement equipment in any data center. The complete **NEXTFRAME**® Ladder Rack system features a broad line of sizes and fittings required for proper installation.

Ladder Rack



Order Information

STRAIGHT SECTION

Width	Catalog No. Black 6' (1829) Length	Catalog No. Gray 6' (1829) Length	Catalog No. Black 10' (3048) Length	Catalog No. Gray 10' (3048) Length
6" (152)	HLS0606B	HLS0606G	HLS1006B	HLS1006G
12" (305)	HLS0612B	HLS0612G	HLS1012B	HLS1012G
18" (457)	HLS0618B	HLS0618G	HLS1018B	HLS1018G
24" (610)	HLS0624B	HLS0624G	HLS1024B	HLS1024G

Please order straight sections in multiples of 10 pieces.
Width = outside to outside dimensions.




90° TURNS

Color: Black Width	Inside Radius 90° Catalog No.	Flat Turns 90° Catalog No.	Outside Radius 90° Catalog No.
6" (152)	HLI0690B	HLF0690B	HLO0690B
12" (305)	HLI1290B	HLF1290B	HLO1290B
18" (457)	HLI1890B	HLF1890B	HLO1890B
24" (610)	HLI2490B	HLF2490B	HLO2490B

Color: Gray Width	Inside Radius 90° Catalog No.	Flat Turns 90° Catalog No.	Outside Radius 90° Catalog No.
6" (152)	HLI0690G	HLF0690G	HLO0690G
12" (305)	HLI1290G	HLF1290G	HLO1290G
18" (457)	HLI1890G	HLF1890G	HLO1890G
24" (610)	HLI2490G	HLF2490G	HLO2490G

Ladder Rack Accessories

Mounting Kit to Relay Rack

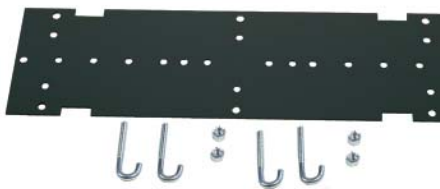

Use to secure ladder rack to top of 19" or 23" equipment rack.

Depth: 5.4"; Color: Black

Catalog No. **HLMPK19**

Triangle Wall Support



Use to run ladder rack along wall. Recommended spacing: 5'.

Width	Finish: Black Catalog No.	Finish: Gray Catalog No.
6" (152)	HLTSB06B	HLTSB06G
12" (305)	HLTSB12B	HLTSB12G
18" (457)	HLTSB18B	HLTSB18G
24" (610)	HLTSB24B	HLTSB24G

Wall Angle Support

Use to terminate ladder rack to wall.

Width	Finish: Black Catalog No.	Finish: Gray Catalog No.
6"-12" (152-305)	HLX0612	HLX0612G
18" (457)	HLX1518	HLX1518G
24" (610)	HLX24	HLX24G



Cable Radius Drop

Assembled to stringers or rungs to provide gradual transition for cable.

Width	Finish: Black Catalog No.
6" (152)	HLCD06*
12" (305)	HLCD12
18" (457)	HLCD18
Stringer	HLCD5

* Can also be mounted on stringer



Cable Retaining Fence Posts

Use along ladder stringers to maximize cable routing and management.

Nom. Height	Actual Height	Finish: Black Catalog No.	Finish: Gray Catalog No.
6"	8.3"	HLP06B	HLP06G
8"	10.4"	HLP08B	HLP08G
10"	12.4"	HLP10B	HLP10G



Foot Kit

Use to secure vertical ladder to floor.

Finish: Black powder coat

Catalog No. **HLRF**



T-Junction Splice Kit

Use to connect one section of ladder perpendicular to another.

Finish: Black powder coat

Catalog No. **HLTK**



Ceiling Mounting Kit

Use to hang ladder from ceiling. Recommended spacing between handers is 5'.

Finish: Black powder coat

Description	Catalog No.
Ceiling Mounting kit with 6' threaded rods	HLCMK
Brackets only	HLCF



HLCF

Butt Splice Kit



Use to splice two sections of ladder end to end.

Finish: Black powder coat

Catalog No. **HLBSK**

Swivel Splice Kit



Use to splice two sections of ladder at any angle.

Finish: Black powder coat

Catalog No. **HLSSK**

Wall Rack Mounting Kit



Use to join the top of an equipment rack to the wall.

Finish: Black powder coat

Catalog No. **HLWRK**

Vertical Wall Bracket



Use to secure ladder rack vertically to wall.

Finish: Black powder coat

Catalog No. **HLVWBK**

Protective End Caps



Use to dress ends of stringers and cable posts.

Finish: Black powder coat. Qty: 2

Catalog No. **HLECPK2**

J-Bolt Kit



Use to secure ladder to brackets. Length: 3".

Catalog No. **HLJB**



Hubbell Premise Wiring

HUBBELL INCORPORATED (Delaware)

14 Lord's Hill Road • Stonington, CT 06378-0901 • (860) 535-8326 • 800-626-0005

Fax: (860) 535-8328 • Internet site: <http://www.hubbell-premise.com>

Worldwide Locations

Hubbell Premise Wiring, Asia Pacific
 Hubbell Canada Inc.
 Hubbell Premise Wiring, Central America
 Hubbell Premise Wiring, China
 Hubbell Premise Wiring, Colombia
 Hubbell Premise Wiring, Europe
 Hubbell Int'l. Inc., Korea Branch

852-2836-7131
 905-839-1138
 506-309-4158
 8621-6309-0119
 571-245-8940
 44-01283 500500
 82-2-(0)2607-1363

Fax: 852-2836-7132
 Fax: 905-839-9108
 Fax: 506-260-1616
 Fax: 8621-6309-0122
 Fax: 571-340-0925
 Fax: 44-01283 500400
 Fax: 82-2-(0)2603-7386

Hubbell Premise Wiring, Latin America
 Hubbell de Mexico, S.A. de C.V.
 Hubbell Premise Wiring, Middle East
 Hubbell-Taian Co., Ltd., Taiwan
 Hubbell Premise Wiring, Turkey
 Hubbell Premise Wiring, Venezuela

305-408-4501
 (5255) 9151-9999
 971-4-393-4192
 886-2-2522-1862
 90-216-313-5016
 58-416-680-7453

Fax: 305-408-8201
 Fax: (5255) 9151-9989
 Fax: 971-4-393-4194
 Fax: 886-2-2522-1872
 Fax: 90-216-414-8148
 Fax: 58-281-274-7900