

- Weather-proof protection and cooling for network switches, PoE devices and equipment deployed outside facility
- Top mounted patch panel allows for efficient cable use and convenient patch cord installation
- Utilize shared accessories with REBOX®, QUADCAB® and IDF wall mount enclosures

FEATURES

- Active closed-loop cooling system to maintain equipment operating temperature range
- Keyed locking door compresses gasket to ensure lifetime weather rating
- Steel construction with a baked powder coat finish withstands outside environmental conditions

SPECIFICATIONS

- NEMA/EEMAC Types 4, 12 and 13
- 14 gauge steel
- ANSI 61 gray polyester powder coat
- 19" rack mount width
- Poured-in polyurethane door gasket

STANDARDS

- EIA/ECA 310-E
- UL and cUL
- NEMA 4/12/13

HUBBELL
REBOX

Industrial Enclosure with Cooling



Hubbell's Industrial REBOX® Enclosure with Cooling product offering allows deployment of network equipment outside of the data center while maintaining an appropriate temperature operating range. High quality manufacturing and installer friendly configurations ensure that equipment is safe from environmental factors and meet the many challenges of outside plant installations.

APPLICATIONS

- Parking garages
- Outdoor
- Roof top
- Fiber interconnect
- Security
- Campus



REBOX® VERTICAL ENCLOSURES

Requires: 1160 BTU air conditioner (IRAC1)
Includes: enclosure, 5U bracket, 4U patch panel bracket

Height	Width	Depth	Rack Units	Catalog No.
24"	24"	12"	9	IR221APG
36"	24"	12"	9	IR321APG
48"	24"	12"	9	IR421APG

STANDARD ENCLOSURES

Requires: 3000 BTU air conditioner (IRAC3)
Includes: enclosure, rail, 50 pack M6 cage nuts

Height	Width	Depth	Rack Units	Catalog No.
24"	24"	24"	12	IR222APG
36"	24"	24"	19	IR322APG

FIBER KIT ENCLOSURE

Requires: 2000 BTU air conditioner (IRAC2)
Contents: enclosure, 2U equipment bracket, fiber patch panel kit, 20A power receptacle kit

Height	Width	Depth	Rack Units	Catalog No.
24"	14"	16"	2	IR211AFK

AIR CONDITIONERS

Requires: 110V service
Includes: A/C unit, mounting brackets

BTU	Amp	Catalog No.
1160	4.3	IRAC1
2000	4	IRAC2
3000	6	IRAC3

FLOOR STANDING KIT


Includes: (2) floor standing supports

Height	Width	Depth	Catalog No.
18"	24"	12"	IRF1812
12"	24"	24"	IRF1224

ACCESSORIES

Description	Catalog No.
4U patch panel mounting bracket	REK19
5U equipment mounting bracket	REKZ
Cement anchors 4pk	HPWRRRA
Bonding busbar	REKGB

DIMENSIONS

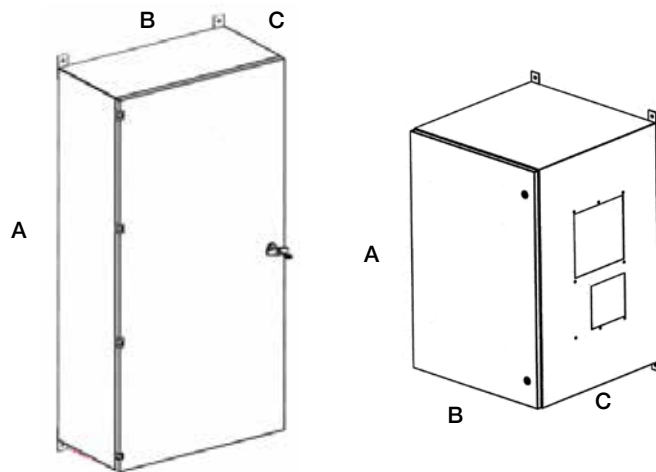

Enclosure	Catalog No.	A	B	C
Vertical	IR221APG	24"	24"	12"
	IR321APG	36"	24"	12"
	IR421APG	48"	24"	12"
Standard	IR222APG	24"	24"	24"
	IR322APG	36"	24"	24"
Fiber	IR211AFK	24"	14"	16"