

# HUBBELL® 350 FIBER OPTIC SPLICE CLOSURE


## UP TO 96 SINGLE FUSION SPLICES

### FEATURES AND APPLICATIONS:

- For all dielectric (AD) or armored (IG) fiber optic cables
- Up to 96 single fusion (4 x 24 splice trays) and 288 ribbon fibers (2 x 144 splice trays)
- For overhead or underground use
- 4 ports for butt, drop and lateral cable splices
- Waterproof design
- Split seal prevents trapped cables
- Fiber splices can be moved to larger closure without service interruption
- Lifting eye and flash valve
- Isolated grounds for each armored cable (IG closure)
- Includes diameter specific grommets - peel out grommets available for an additional charge
- Accepts cables from 0.250" (6mm) up to 0.625" (16mm)



*End plate color will be black instead of grey as shown.*

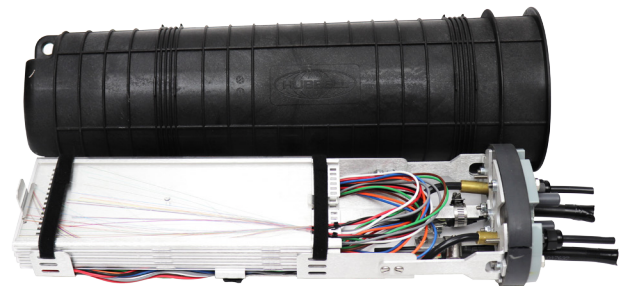

### CATALOG NO.

### DESCRIPTION

### WEIGHT

PSCA350S

DOME CLOSURE 350 ALL DIELECTRIC (AD)

5.3 lbs. (2.4kg)

PSCI350S

DOME CLOSURE 350 ISOLATED GROUND (IG)

5.7 lbs (2.6kg)

Hubbell Power Systems, Inc. | [hubbellpowersystems.com](http://hubbellpowersystems.com)

**HUBBELL®**  
Power Systems, Inc.

©Copyright 2018 Hubbell Incorporated. Because Hubbell has a policy of continuous product improvement, we reserve the right to change design and specifications without notice.



SF\_09\_155E