

HUBBELL® 570 GROMMET SPLICE CLOSURE


FOR USE WITH ALL DIELECTRIC AND ARMORED FIBER OPTIC CABLE

Maximum of 192 single or 576 mass fusion


FEATURES AND BENEFITS

- 6 ports
- Round grommets included for butt splice
- Optional peel out grommets available for an additional charge
- Soft Urethane seal
- Assembled in the USA
- Unsurpassed buffer tube storage
- Slotted ports to eliminate trapped cables and allows easy cable additions

570G ALL DIELECTRIC CLOSURE

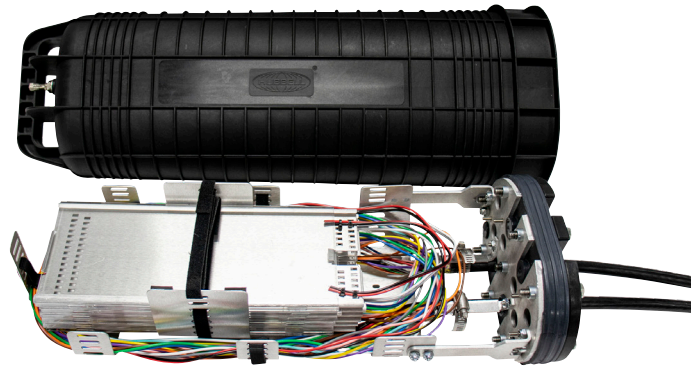

570G ISOLATED GROUND CLOSURE

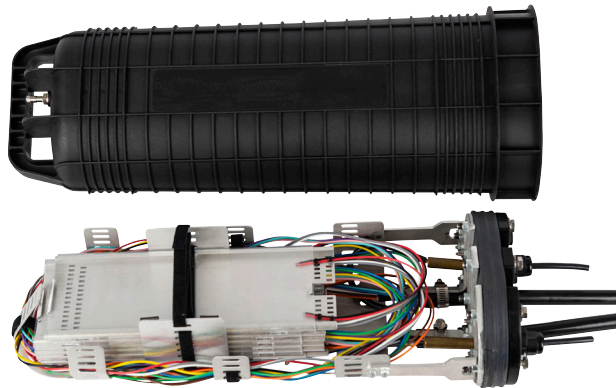

Catalog Number	Description	Weight
PSCA570SG	570 ALL DIELECTRIC ROUND GROMMETS	10 lb. (4.5Kg)
PSCI570SG	570 ISOLATED GROUND ROUND GROMMETS	11 lb. (5.0Kg)



hubbelpowersystems.com

For product inquiries, please contact your local sales representative or customer service representative.

©2019 Hubbell Incorporated.
Because Hubbell has a policy of continuous product improvement, we reserve the right to change design and specifications without notice.
Printed in the U.S.A. | SF_09_168E