
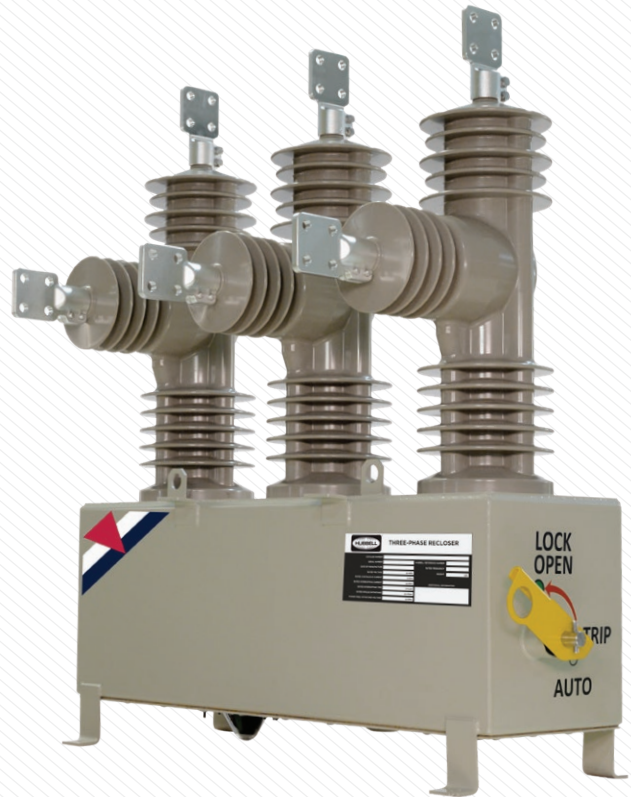


# LIBERTY™ HB SERIES THREE PHASE RECLOSER

## YOUR CHOICE FOR ADVANCED DISTRIBUTION AUTOMATION 3Ø SOLID DIELECTRIC SWITCHES

For advanced distribution automation switching applications, Hubbell Utility Solutions has you covered. The HPS LIBERTY™ three phase (3Ø) ganged recloser offering is a pole ready completely integrated solution.

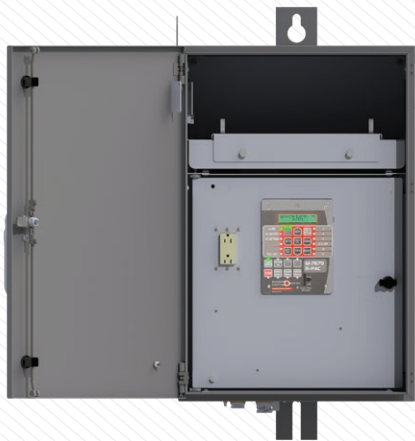

### ELECTRICAL SPECIFICATIONS:

Description	Hubbell 3Ø Ganged Recloser		
	15.5kV 16kA	27 kV 16kA	38kV 16kA
Rated Maximum Voltage (kV)	15.5	27	38
Rated Power Frequency (Hz)	50/60	50/60	50/60
Rated Continuous Current (A RMS)	630	800	800
Impulse Withstand Voltage (kV)	110	150	170
Short Circuit Interrupting Current (kA)	16	16	16
Rated Short Circuit Current - 3 second (kA)	16	16	16
Rated Peak Withstand Current, Asymmetrical (kA)	41.6	41.6	41.6
Rated Mechanical Operations	10,000 (Max. 30,000)		
Temperature (°C)	-40°C to +60°C		
Switching Performance Test Standard	IEEE / IEC 62271-111		






### SOLID-DIELECTRIC VACUUM BREAKER TECHNOLOGY

Vacuum interrupter technology encapsulated in hydrophobic cycloaliphatic epoxy material reduces the risk of insulation flashover, provides maximum performance for contaminated environments, and requires no maintenance.



### INTEGRATED SENSING

Six Voltage (3 source side and 3 load side) and Three Current Sensors for Advanced Automation & Switching Applications

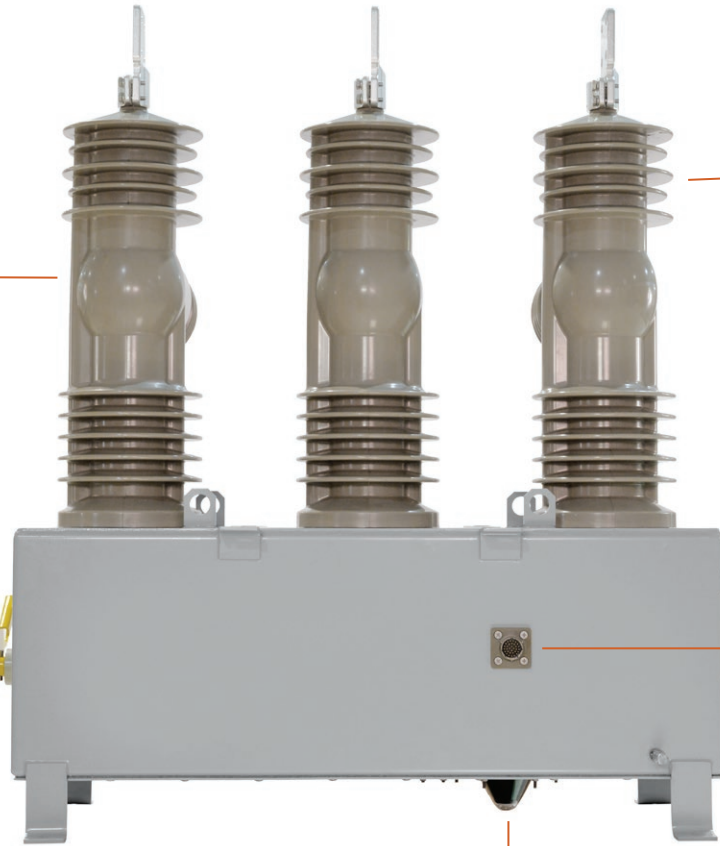

### OPERATIONAL & LOCKOUT HANDLES

For Operating Convenience and Maximum Safety



### SINGLE 32-PIN CONNECTOR

MIL spec twist-lock bayonet-style connector meets and exceeds the industry standard



### SEMAPHORE & MECHANICAL COUNTER

Highly Visible, Lineman Friendly Position Indication Semaphore

