

LGX Max[™] Series CS Cassettes

FIBERHUBB LGX Max Series Cassettes utilize the latest in ultra compact duplex connector technology to make ultra high density easily accessible.



FIBERHUBB LGX Max Series Cassettes with CS Connector technology allows 36 fiber ports in a single LGX cassette.

LGX Max Series Cassettes

Fiber Type	CS Ports (front)	Fibers (front)	MPO Ports (rear)	Catalog No.
OS2	18	36	3	OCCSSM
OM3/OM4	18	36	3	OCCSM34

Type A Polarity (straight through, pin 1 to pin 1)


COMPATIBILITY
FCR Rackmount Series
FTR 3 Across Series
OFPNL Series

CS Connector features easy to access pull tab for quick disconnect.



CS Connectors bring duplex availability to a more compact port size.

CS Duplex Connector LC Duplex Connector

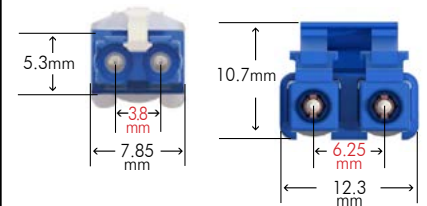

LGX Max CS to LC Duplex Plenum Patch Cords

	Color	1 meter	2 meter	3 meter	5 meter
OM3/OM4	Aqua	DFPCCSLCF1MM	DFPCCSLCF2MM	DFPCCSLCF3MM	DFPCCSLCF5MM
OS2	Yellow	DFPCCSLCS1SM	DFPCCSLCS2SM	DFPCCSLCS3SM	DFPCCSLCS5SM

LGX Max CS to CS Duplex Plenum Patch Cords

	Color	1 meter	2 meter	3 meter	5 meter
OM3/OM4	Aqua	DFPCCSCSF1MM	DFPCCSCSF2MM	DFPCCSCSF3MM	DFPCCSCSF5MM
OS2	Yellow	DFPCCSCSS1SM	DFPCCSCSS2SM	DFPCCSCSS3SM	DFPCCSCSS5SM



LGX Max™ Series SN Cassettes

FIBERHUBB LGX Max Series Cassettes utilize the latest in ultra compact duplex connector technology to make ultra high density easily accessible.

SN Connector technology allows 72 fiber ports in a single LGX cassette.




LGX Max Series Cassettes

Fiber Type	SN Ports (front)	Fibers (front)	MPO Ports (rear)	Catalog No.
OS2	36	72	6	OCSNSM
OM3/OM4	36	72	6	OCSNM34

Type A Polarity (straight through, pin 1 to pin 1)

COMPATIBILITY
FCR Rackmount Series
FTR 3 Across Series
FPR3SP
OFPNL Series

LGX Max SN to LC Duplex Plenum Patch Cords

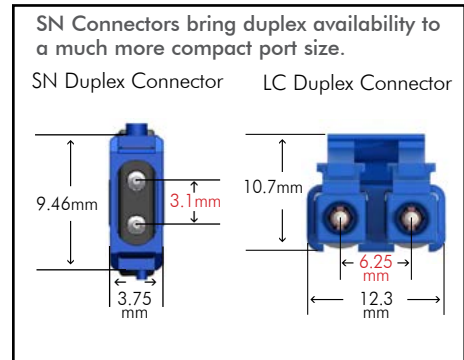

Quick push install and simple pull disconnect for easy access

	Color	1 meter	2 meter	3 meter	5 meter
OM3/OM4	Aqua	DFPCSNLCF1MM	DFPCSNLCF2MM	DFPCSNLCF3MM	DFPCSNLCF5MM
OS2	Yellow	DFPCSNLCS1SM	DFPCSNLCS2SM	DFPCSNLCS3SM	DFPCSNLCS5SM