


HUBBELL SystemOne

Recessed
4, 6 and 8 Inch
Fire-Rated
Poke-Throughs



Hubbell's SystemOne Recessed Fire-Rated Poke-Throughs (FRPT) enhances functionality providing increased power, data and audio visual capacity. Safety is improved with recessed connectivity, a low profile flange, and egress doors that hinge inwards. Building value is enhanced with plated finishes to match and blend with modern building décor.

Hubbell SystemOne Recessed FRPTs for 8" Core Hole Applications...

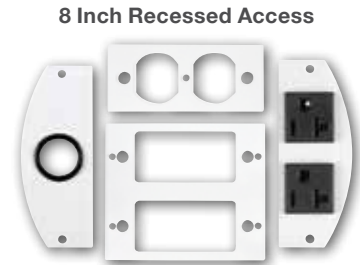

Center Sub-Plates
with Outer Sub-plates

High Capacity Multimedia

Sub-plate layout for the center three gangs of the eight inch FRPT allows for maximum audio visual capacity. The NEMA spacing allows the product flexibility to easily accept 3rd party products.

High Capacity Multimedia

Perimeter sub plates for the eight inch FRPT help compliment the audio visual or data in the center three gangs. Additionally these plates can be exchange for other low voltage compatible plates.

Fire-Rated Poke-Throughs 4
Sub-Plates, Covers and Accessories 5
One-Piece Units 10

Hubbell SystemOne Recessed FRPTs for 6" Core Hole Applications...



60/40 split
Sub-Plates

50/50 split
Sub-Plates

60/40 6" Sub-Plate Split
An Industry first, the 60/40 sub-plate layout allows for unmatched capacity with up to 12 keystone jacks and one 20A duplex.

Two duplexes with ample audio/video and data are achieved by using the 50/50 sub-plate layout. Additionally this layout will accommodate two Style Line® devices for GFCI, surge, etc. applications.

Fire-Rated Poke-Throughs 6
Sub-Plates, Covers and Accessories 7
One-Piece Units 11

50/50 6" Sub-Plate Split

Hubbell SystemOne Recessed FRPTs for 4" Core Hole Applications...



Quad Sub-Plate

Multi & Single Service
Sub-Plates

4" Quad Sub-Plate
The quad sub-plate can be wired on one circuit or two and includes 18 inch of stranded 12AWG wire.

4" 2X2 Sub-Plate
The 2x2 sub plates are available with Style Line® or traditional duplex openings and can accommodate up to two keystone jacks.

Fire-Rated Poke-Throughs 8
Sub-Plates, Covers and Accessories 9
One-Piece Units 12

Benefits and Enhancements

Safety

- Low profile flange, 0.150", is better than ADA requirements
- Hide-away egress door fold under cover while in use
- 180° opening of main door

Functionality

- Cables and connections are protected by recessed functionality
- Open architecture sub-plate design
- Dirt ingress reduced by egress door brushes
- Exceeds UL 514A Scrub Requirements with ScrubShield® technology
- Easy selection with common flange for all floor types



Value

- Enhance building décor with numerous finishes
- Increase durability and longevity with cast aluminum covers

8 Inch Sub-Plate Features

Center Plate Configurations

- Allows for three duplex receptacles or up to 18 data and or audio visual jacks
- Open architecture sub-plate design accommodates FSR®, Extron®, Crestron®, etc.
- NEMA spacing between devices
- All plates can be independently wired



Outer Plate Configurations

- Available in pre-wired 20A duplex receptacles or data/AV plates
- Multiple 20A duplex receptacles can be wired to a common circuit or independently

6 Inch Sub-Plate Features

60/40 Device Plate Combination

- Allows for a wide array of data and audio visual connectivity with a 20A duplex receptacle
- The two plates can be independently wired



50/50 Device Plate Combination

- Accommodates up to two 20A duplex receptacles with eight data or audio visual connections
- The two plates can be independently wired



4 Inch Sub-Plate Features

Plate Configurations

- Quad receptacle sub-plate, single or dual circuit wiring
- 2x2 sub plate for decorator or traditional receptacles plus two keystone jacks
- Since service decorator or traditional sub-plates




On-line Resources

- BIM models, customer drawings and technical specifications are available on www.hubbell-wiring.com

Extron® is a registered trademark of Extron Electronics.
Crestron® is a registered trademark of Crestron Electronics, Inc.
FSR® is a registered trademark of FSR Inc.

8 Inch Fire-Rated Poke-Through Fittings


- Step down installation
- Maintains concrete floor fire rating up to two hours
- Junction box standard
- For use in the City of Chicago, junction box NOT included

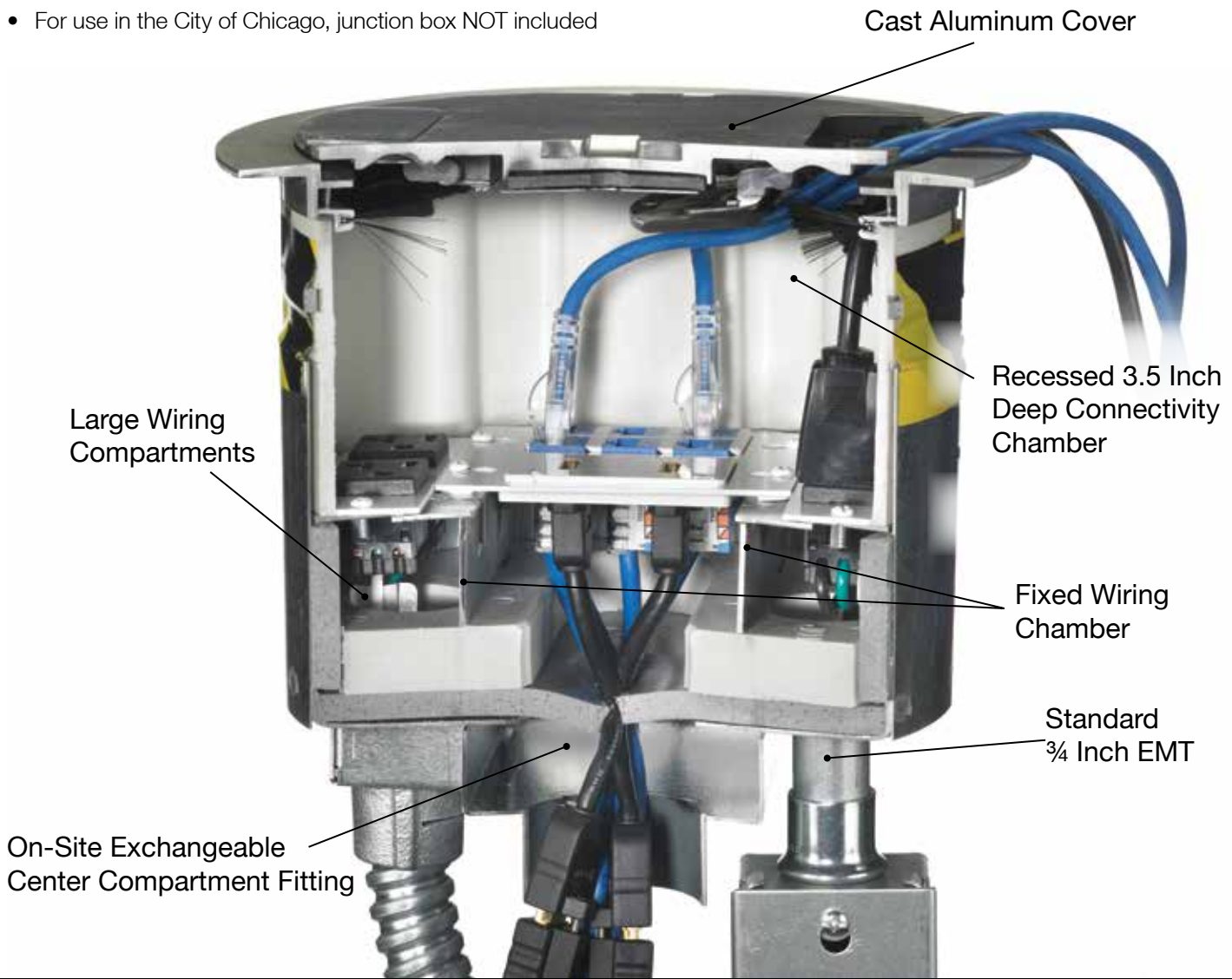

8 Inch Fire-Rated Poke-Through



| Description | Catalog Number |
|--|----------------------|
| 8 Inch Fire-Rated Poke-Through includes: (1) 3/4 inch power EMT plus (1) S1R8JNC1 with (1) 1 inch EMT and (1) 1 1/2 inch EMT. | S1R8PTFIT1 |
| 8 Inch Fire-Rated Poke-Through includes: (1) 3/4 inch power EMT plus (1) S1R8JNC2 with (2) 1 inch EMT. | S1R8PTFIT2 |
| 8 Inch Fire-Rated Poke-Through includes: (1) 3/4 inch power EMT plus (1) S1R8JNC3 with (1) 2 inch EMT. | S1R8PTFIT3 |
| 8 Inch Fire-Rated Poke-Through includes: (1) 3/4 inch power EMT plus (1) S1R8JNC1 with (2) 1 inch EMT and (1) 1 1/2 inch EMT. No junction box or flexible metal conduit. | S1R8PTFIT1CHI |
| 8 Inch Fire-Rated Poke-Through includes: (1) 3/4 inch power EMT plus (1) S1R8JNC2 with (2) 1 inch EMT. No junction box or flexible metal conduit. | S1R8PTFIT2CHI |
| 8 Inch Fire-Rated Poke-Through includes: (1) 3/4 inch power EMT plus (1) S1R8JNC3 with (1) 2 inch EMT. No junction box or flexible metal conduit. | S1R8PTFIT3CHI |

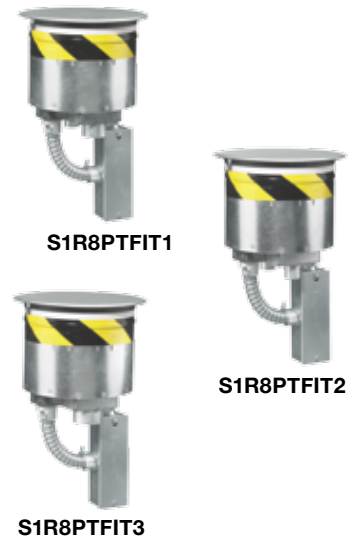









8 Inch Sub-Plates

Center Plate Configurations

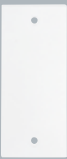


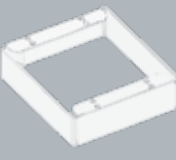

- Allows for 3 duplexes or up to 18 data/AV jacks. Other combinations possible
- Accepts third party AV devices (i.e. FSR®, Crestron®, Extron®)
- Standard NEMA spacing between devices



Center Sub-Plates - Single Gang

| Description | Catalog Number | Description | Catalog Number |
|-------------------------------------|--|---------------------------------------|--|
| Blank cover plate |  S1R8CSPB | (2) Extron® MAAP openings |  S1R8CSPC |
| (1) 1 unit Hubbell iSTATION opening |  S1R8CSPD | (1) 1.5 unit Hubbell iSTATION opening |  S1R8CSPE |
| (1) 1.60" Twist-Lock® opening |  S1R8CSPG | (1) duplex opening |  S1R8CSPI |
| (1) 1.40" Twist-Lock® opening |  S1R8CSPJ | (1) Style Line® Decorator opening |  S1R8CSPK |

Center Sub-Plates - Two and Three Gang

| | | | |
|--|--|--|--|
| Two-gang; (4) Extron® AAP openings |  S1R8CSPA | Two gang; 3 unit Hubbell iSTATION opening |  S1R8CSPL |
| Two gang; (2) Style Line® Decorator openings |  S1R8CSPM | Device depth extension collar (for use with 3rd party device up to 2.5" depth) |  S1R8CSPEXT |
| Three gang; blank cover plate |  S1R8CSPN | | |

Note: Rectangle sub-plates are for center compartment, crescent sub-plates are for outer compartments and are not inter-changeable.







Extron® is a registered trademark of Extron Electronics.
Crestron® is a registered trademark of Crestron Electronics, Inc.
FSR® is a registered trademark of FSR Inc.

Outer Plate Configurations

- Available in pre-wired duplexes or openings to accommodate third party AV Devices
- Multiple duplexes can be wired in the supplied junction box or independently



Outer Sub-Plates

| Description | Catalog Number | Description | Catalog Number |
|--------------------------------------|---|---|---|
| Blank cover plate |  S1R8PSPU | Single Extron® MAAP opening |  S1R8PSPV |
| Pull through with 1" bushing opening |  S1R8PSPW | Single Extron® MAAP opening |  S1R8PSPX |
| (1) 1 unit Hubbell iSTATION opening |  S1R8PSPY | Dual 20A pre-wired power cubes; One circuit |  S1R8PSPZ |

Recessed 8 Inch Cover

Single Piece 8 Inch FRPT Cover Assembly unit includes solid cast aluminum construction, carpet gasket and mounting hardware.



| Finish | Catalog Number |
|----------------------|-------------------|
| Brushed Aluminum | S1R8CVRALU |
| Black Powder Coat | S1R8CVRBLK |
| Brushed Brass Plated | S1R8CVRBRS |
| Bronze Plated Finish | S1R8CVRBRZ |
| Satin Nickel Plated | S1R8CVRNKL |



S1R8PPT



S1FRPTJB



S1R8JNC1



S1R8JNC2



S1R8JNC3

8 Inch Accessories




| Description | Catalog Number |
|--|-------------------|
| Pre-pour tube, includes hardware | S1R8PPT* |
| Abandonment plate, black finish | S1R8ADMTBK |
| Low voltage replacement divider | S1R8DIV |
| Power junction box, 27.0 cubic inches; (1) ¾ inch and (1) 1 inch EMT connector | S1FRPTJB |
| Replacement fitting box (1) 1½ inch & (1) 1 inch EMTs | S1R8JNC1 |
| (2) 1 inch EMTs | S1R8JNC2 |
| (1) 2 inch EMT | S1R8JNC3 |

* Not UL Listed.

6 Inch Fire-Rated Poke-Through Fittings

ScrubShield[®]
Complies with UL514A

- Step down installation
- Maintains concrete floor fire rating up to two hours
- Junction box standard
- Includes (1) 2 inch data/AV EMT and (1) 3/4 inch power EMT
- For use in the City of Chicago, junction box NOT included

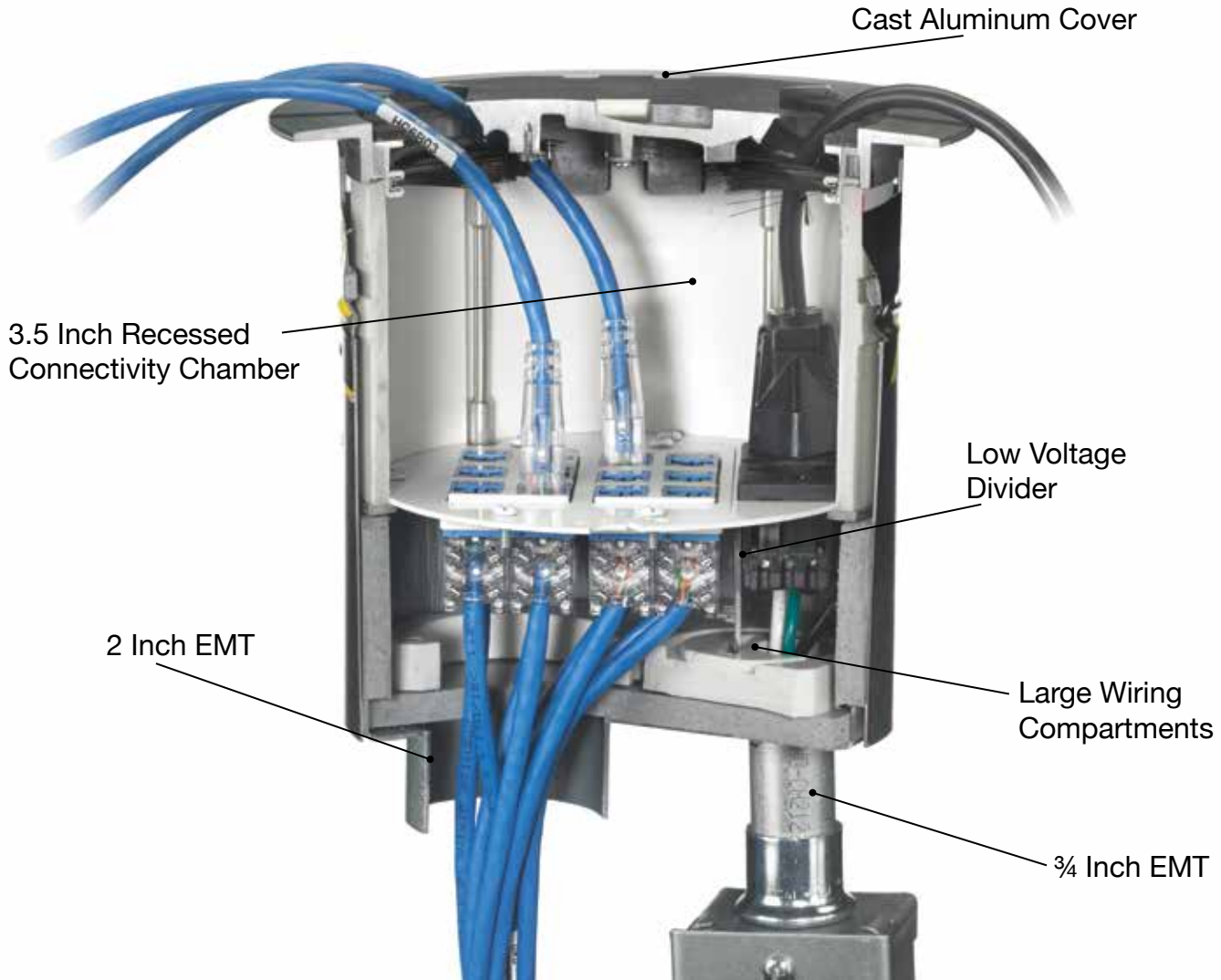

6 Inch Fire-Rated Poke-Through



| Description | Catalog Number |
|--|---------------------|
| 6 Inch Fire-Rated Poke-Through. | S1R6PTFIT |
| 6 Inch Fire-Rated Poke-Through; junction box NOT included. | S1R6PTFITCHI |







6 Inch Sub-Plates

60/40 Device Plate Combination



- Allows for up to twelve data/AV jacks plus a 20A duplex receptacle
- Two plates which can be wired independently



Left 60% Sub-Plates

| Description | Catalog Number | Description | Catalog Number |
|---|---|--|---|
| (1) Style Line® Decorator and (2) Extron® MAAP openings, left side only |  S1R6SPV | (1) Style Line® Decorator and (2) Extron® AAP openings, left side only |  S1R6SPX |
| (2) Style Line® Decorator openings, left side only |  S1R6SPW | (1) Style Line® Decorator and (2) 1.5 unit Hubbell iSTATION openings, left side only |  S1R6SPY |

Right 40% Sub-Plates
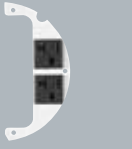
| | | | |
|---|--|---|--|
| (2) 20A pre-wired receptacles; 16 inch lead; one circuit, right side only |  S1R6SPZ | (2) 20A pre-wired receptacles; 25 foot lead; one circuit, right side only |  S1R6SPZ25 |
|---|--|---|--|

Recessed 6 Inch Cover

6 Inch Fire-Rated Poke-Through cover assembled unit includes solid cast aluminum construction, carpet gasket and mounting hardware.



| Finish | Catalog Number | Furniture Feed Option |
|----------------------|-------------------|-----------------------|
| Brushed Aluminum | S1R6CVRALU | S1R6FFCVRALU |
| Black Powder Coat | S1R6CVRBLK | S1R6FFCVRBLK |
| Brushed Brass Plated | S1R6CVRBRS | S1R6FFCVRBRS |
| Bronze Plated Finish | S1R6CVRBRZ | S1R6FFCVRBRZ |
| Satin Nickel Plated | S1R6CVRNKL | S1R6FFCVRNKL |

6 Inch Accessories



| Description | Catalog Number |
|--|---|
| Pre-pour tube, includes hardware | S1R6PPT* |
| Abandonment plate, black finish | S1R6ADMTBK |
| Low voltage replacement divider | S1R6DIV |
| Power junction box, 27.0 cubic inches; (1) ¾ inch and (1) 1 inch EMT connector | S1FRPTJB |
| Replacement furniture feed fitting | 2 Inch S1RFFFIT2 ¾ Inch S1RFFFIT075 |
| Replacement plugs | 2 Inch S1RPLUG2ALU ¾ Inch S1RPLUG075ALU Aluminum S1RPLUG2BLK S1RPLUG075BLK Black S1RPLUG2BRS S1RPLUG075BRS Brass S1RPLUG2BRZ S1RPLUG075BRZ Bronze S1RPLUG2NKL S1RPLUG075NKL Nickel |











* Not UL Listed.

50/50 Device Plate Combination






- Allows for up to eight Hubbell data jacks plus two 20A duplex receptacles
- Two plates which can be wired independently



Left 50% Sub-Plates

| Description | Catalog Number | Description | Catalog Number |
|--|---|--|---|
| (3) Extron® AAP plate openings, left side only |  S1R6SPA | Blank cover plate, left side only |  S1R6SPB |
| (5) Extron® MAAP plate openings, left side only |  S1R6SPC | (4) 1 unit Hubbell iSTATION openings, left side only |  S1R6SPD |
| (1) Style Line® Decorator and (2) Hubbell keystone openings, left side only |  S1R6SPE | (2) 1.5 unit Hubbell iSTATION openings, left side only |  S1R6SPF |
| (3) Extron® MAAP openings and (2) Hubbell keystone jack openings, left side only |  S1R6SPL | (1) Style Line® Decorator opening, left side only |  S1R6SPM |

Right 50% Sub-Plates

| | | | |
|---|---|--|---|
| (1) 1.60 inch opening for Twist-Lock®, right side only |  S1R6SPG | (4) 20A pre-wired receptacles; 16 Inch leads; one or two circuits, right side only |  S1R6SPH |
| (1) duplex device opening, right side only |  S1R6SPI | (1) 1.40 inch opening for simplex or Twist-Lock®, right side only |  S1R6SPJ |
| (1) Style Line® Decorator device opening, right side only |  S1R6SPK | | |


Note: Sub-plates can not be rotated to create additional layouts. When assembled, sub-plates can not overlap. Custom Plates available upon request and may be subject to minimum order quantity.

Extron® is a registered trademark of Extron Electronics.

4 Inch Fire-Rated Poke-Throughs

- Step down installation
- Maintains concrete floor fire rating up to two hours
- Junction box standard, 27 cubic inches
- (1) ¾ inch conduit for power and (2) ½ inch conduits for low voltage
- For use in the City of Chicago, junction box NOT included

ScrubShield[®]
Complies with UL514A

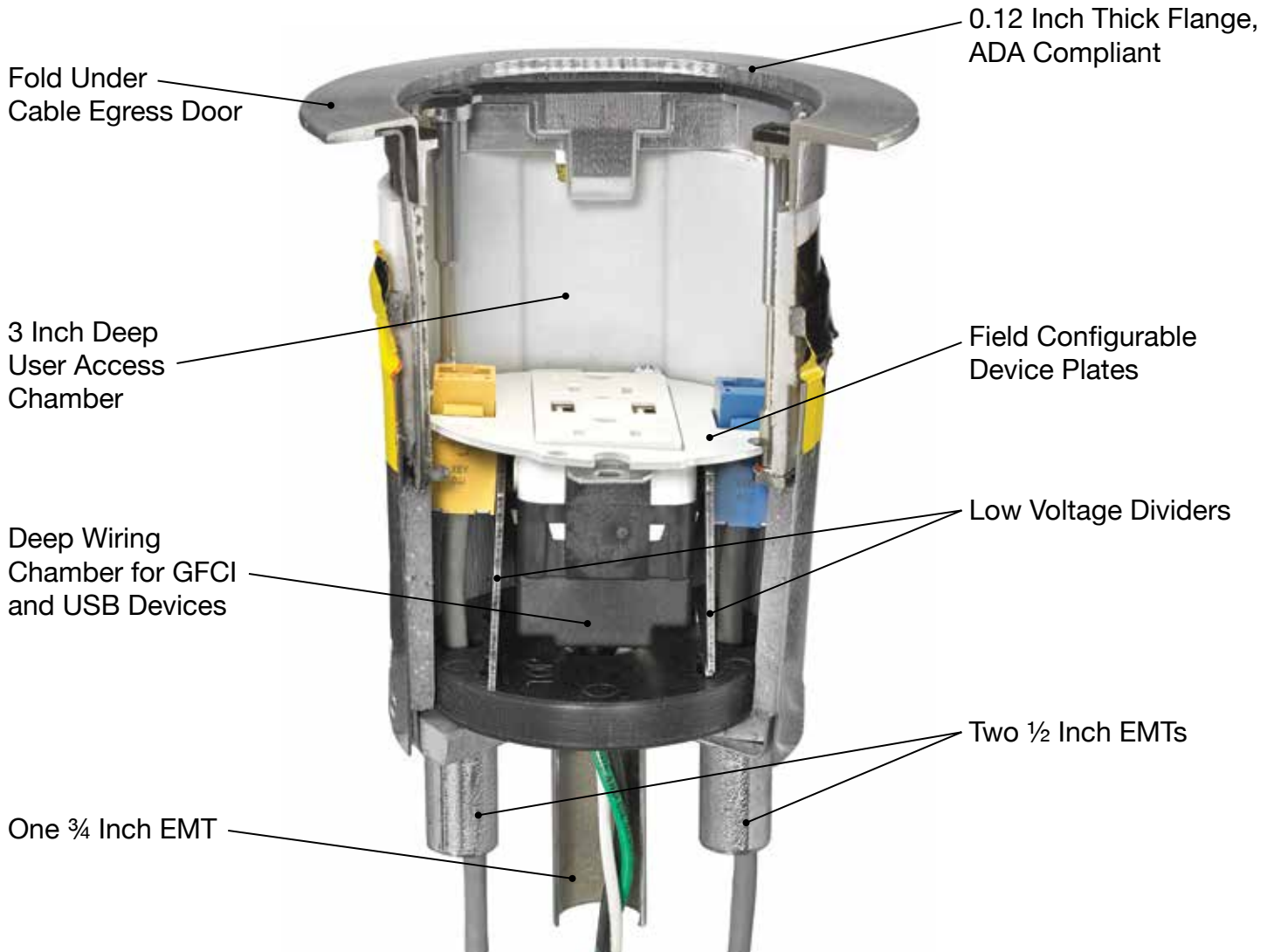

4 Inch Fire-Rated Poke-Through



| Description | Catalog Number |
|--|---------------------|
| 4 Inch FRPT includes: Junction box and low voltage dividers. | S1R4PTFIT |
| 4 Inch FRPT includes: Low voltage dividers, junction box NOT included. | S1R4PTFITCHI |
| 4 Inch FRPT includes: Quad sub-plate and junction box. | S1R4PTQUAD |



S1R4PTFIT
S1R4PTQUAD



S1R4PTFITCHI



4 Inch Covers and Device Plates

The 4 Inch recessed cover is available in a number of durable, yet beautiful finishes to match any décor. The flange height of 0.12 inch is ADA compliant and suitable for use on any floor finish. All covers are UL514A, scrubwater compliant.





Architectural Cover Finishes

| Description | Catalog Number |
|---|--|
| Brushed Aluminum Finish, Single fold under cable egress door. | S1R4CVRALU  |
| Plated Brushed Brass Finish, Single fold under cable egress door. | S1R4CVRBRS  |
| Plated Antique Bronze Finish, Single fold under cable egress door. | S1R4CVRBRZ  |
| Plated Satin Nickel Finish, Single fold under cable egress door. | S1R4CVRNKL  |

Note: COVER LOAD RATING: 1,000 LBS with 2x safety factor. Load applied through a 3" (76mm) mandrel in center of the cover. Static loads only.



Multi-Service Device Plates

| Description | Catalog Number |
|--|---|
| 2X2 Sub-plate with one duplex device opening and two keystone jack openings*. |  S1R4SP2X2DUPLEX |
| 2X2 Sub-plate with one Style Line® decorator device opening and two keystone jack openings*. |  S1R4SP2X2STYLE |

Note: *Go to www.hubbell-wiring.com for data jacks and frames.

For low light applications (i.e. under tables or podiums) consider using Hubbell's LED illuminated receptacles: HBL8200ILW 15A, LED or HBL8300ILW 20A, LED.



HBL8300ILW

4 Inch Accessories



| Description | Catalog Number |
|----------------------------------|-----------------|
| Pre-pour tube, includes hardware | S1R4PPT* |
| Low voltage replacement divider | S1R4DIV |

Note: *Not UL Listed.



S1R4PPT S1R4DIV






Powder Coated Cover Finishes

| Description | Catalog Number |
|---|--|
| Black Powder Coat Finish, Single fold under cable egress door. | S1R4CVRBLK  |
| Gray Powder Coat Finish, Single fold under cable egress door. | S1R4CVRGRY  |

Note: COVER LOAD RATING: 1,000 LBS with 2x safety factor. Load applied through a 3" (76mm) mandrel in center of the cover. Static loads only.



Single-Service Device Plates

| Description | Catalog Number |
|---|---|
| Four single 20A receptacles. Can be wired as single or two circuit with isolated ground capability, 24 inch wire leads. |  S1R4SPQUAD |
| One 1.60 inch opening for 20 or 30A Twist-Lock® receptacle. |  S1R4SPTWIST |
| One 1.40 inch opening for simplex receptacle. |  S1R4SPSIMPLEX |
| One duplex device opening for power or datacom* applications. |  S1R4SPDUPLEX |
| One Style Line® decorator device opening for power or datacom* applications. |  S1R4SPSTYLE |

Note: *Go to www.hubbell-wiring.com for data jacks and frames.



Recessed 8 Inch Core Hole, One-Piece Units

One-Piece Pre-Wired 8 Inch Fire-Rated Poke-Through

Assembled unit includes:

- (1) Hubbell SystemOne 8 inch floor fitting (S1R8PTFIT1)
- (4) 20A, pre-wired receptacles, 18 inch wire lead, two pieces (S1R8PSPZ)
- (1) Fitting connection box with 1 inch and 1½ inch EMT stubs (S1R8JNC1)
- (1) 8 inch flange and universal cover assembly (S1R8CVRxx)

Receptacles feature single circuit wiring



Finish

- Brushed Aluminum
- Black Powder Coat
- Brass Plated
- Bronze Plated (Oil rubbed)
- Nickel Plated

Catalog Number

- S1R8PTZZ1ALU**
- S1R8PTZZ1BLK**
- S1R8PTZZ1BRS**
- S1R8PTZZ1BRZ**
- S1R8PTZZ1NKL**



One-Piece 8 Inch Fire-Rated Poke-Through

Assembled unit includes:

- (1) Hubbell SystemOne 8 inch floor fitting (S1R8PTFIT1)
- (1) Fitting connection box with 1 inch and 1½ inch EMT stubs (S1R8JNC1)
- (1) 8 inch flange and universal cover assembly (S1R8CVRxx)



Finish

- Brushed Aluminum
- Black Powder Coat
- Brass Plated
- Bronze Plated (Oil rubbed)
- Nickel Plated

Catalog Number

 
- S1R8PT1ALU**
- S1R8PT1BLK**
- S1R8PT1BRS**
- S1R8PT1BRZ**
- S1R8PT1NKL**

One-Piece Pre-Wired 8 Inch Fire-Rated Poke-Through

Assembled unit includes:

- (1) Hubbell SystemOne 8 inch floor fitting (S1R8PTFIT2)
- (4) 20A, pre-wired receptacles, 18 inch wire lead, two pieces (S1R8PSPZ)
- (1) Fitting connection box with (2) 1 inch EMT stubs (S1R8JNC2)
- (1) 8 inch flange and universal cover assembly (S1R8CVRxx)

Receptacles feature single circuit wiring



Finish

- Brushed Aluminum
- Black Powder Coat
- Brass Plated
- Bronze Plated (Oil rubbed)
- Nickel Plated

Catalog Number

 
- S1R8PTZZ2ALU**
- S1R8PTZZ2BLK**
- S1R8PTZZ2BRS**
- S1R8PTZZ2BRZ**
- S1R8PTZZ2NKL**



One-Piece 8 Inch Fire-Rated Poke-Through

Assembled unit includes:

- (1) Hubbell SystemOne 8 inch floor fitting (S1R8PTFIT2)
- (1) Fitting connection box with (2) 1 inch EMT stubs (S1R8JNC2)
- (1) 8 inch flange and universal cover assembly (S1R8CVRxx)



Finish

- Brushed Aluminum
- Black Powder Coat
- Brass Plated
- Bronze Plated (Oil rubbed)
- Nickel Plated

Catalog Number

- S1R8PT2ALU**
- S1R8PT2BLK**
- S1R8PT2BRS**
- S1R8PT2BRZ**
- S1R8PT2NKL**

One-Piece Pre-Wired 8 Inch Fire-Rated Poke-Through for Data AV

Assembled unit includes:

- (1) Hubbell SystemOne 8 inch floor fitting (S1R8PTFIT3)
- (4) 20A, pre-wired receptacles, 18 inch wire lead, two pieces (S1R8PSPZ)
- (1) Fitting connection box with one 2 inch EMT stubs (S1R8JNC3)
- (1) 8 inch flange and universal cover assembly (S1R8CVRxx)

Receptacles feature single circuit wiring



Finish

- Brushed Aluminum
- Black Powder Coat
- Brass Plated
- Bronze Plated (Oil rubbed)
- Nickel Plated

Catalog Number

 
- S1R8PTZZ3ALU**
- S1R8PTZZ3BLK**
- S1R8PTZZ3BRS**
- S1R8PTZZ3BRZ**
- S1R8PTZZ3NKL**



One-Piece 8 Inch Fire-Rated Poke-Through

Assembled unit includes:

- (1) Hubbell SystemOne 8 inch floor fitting (S1R8PTFIT3)
- (1) Fitting connection box with one 2 inch EMT stub (S1R8JNC3)
- (1) 8 inch flange and universal cover assembly (S1R8CVRxx)



Finish

- Brushed Aluminum
- Black Powder Coat
- Brass Plated
- Bronze Plated (Oil rubbed)
- Nickel Plated

Catalog Number

- S1R8PT3ALU**
- S1R8PT3BLK**
- S1R8PT3BRS**
- S1R8PT3BRZ**
- S1R8PT3NKL**

Note: xx indicates finish options.



Recessed 6 Inch Core Hole, One-Piece Units

One-Piece Pre-Wired 60/40 Split 6 Inch Fire-Rated Poke-Through for Data AV

Assembled unit includes:

- (1) Hubbell SystemOne 6 inch floor fitting (S1R6PTFIT)
- (2) Decorator opening sub-plate (S1R6SPW)
- (2) 20A, pre-wired receptacle with 18 inch wire leads (S1R6SPZ)
- (1) 6 inch flange and universal cover assembly (S1R6CVRxx)

 
Receptacles feature single circuit wiring.

Finish

Brushed Aluminum
Black Powder Coat
Brass Plated
Bronze Plated (Oil rubbed)
Nickel Plated

Catalog Number

S1R6PTWZALU
S1R6PTWZBLK
S1R6PTWZBRS
S1R6PTWZBRZ
S1R6PTWZNKL



One-Piece Pre-Wired 50/50 Split 6 Inch Fire-Rated Poke-Through for Data AV

Assembled unit includes:

- (1) Hubbell SystemOne 6 inch floor fitting (S1R6PTFIT)
- (4) 1 Unit Hubbell iSTATION openings (S1R6SPD)
- (1) Decorator opening and (2) keystone openings (S1R6SPE)
- (4) 20A, pre-wired receptacles (S1R6SPH)
- (1) 6 inch flange and universal cover assembly (S1R6CVRxx)

Opening architecture Keystone openings accept Hubbell modular jacks and many others.

 
Receptacles feature single or two circuit wiring and isolated ground capability.

Finish

Brushed Aluminum
Black Powder Coat
Brass Plated
Bronze Plated (Oil rubbed)
Nickel Plated

Catalog Number

S1R6PTDEHALU
S1R6PTDEHBLK
S1R6PTDEHBRS
S1R6PTDEHBRZ
S1R6PTDEHNKL



One-Piece Pre-Wired 50/50 Split 6 Inch Fire-Rated Poke-Through for Third Party Devices

Assembled unit includes:

- (1) Hubbell SystemOne 6 inch floor fitting (S1R6PTFIT)
- (3) Extron® AAP openings (S1R6SPA)
- (5) Extron® MAPP openings (S1R6SPC)
- (1) Decorator opening and (2) Hubbell keystone openings (S1R6SPE)
- (4) 20A, pre-wired receptacles (S1R6SPH)
- (1) 6 inch flange and universal cover assembly (S1R6CVRxx)

Opening architecture Keystone openings accept Hubbell modular jacks and many others.

 
Receptacles feature single or two circuit wiring and isolated ground capability.

Finish

Brushed Aluminum
Black Powder Coat
Brass Plated
Bronze Plated (Oil rubbed)
Nickel Plated

Catalog Number

S1R6PTACEHALU
S1R6PTACEHBLK
S1R6PTACEHBRS
S1R6PTACEHBRZ
S1R6PTACEHNKL



One-Piece 6 Inch Fire-Rated Poke-Through with Finished Cover

Assembled unit includes:

- (1) Hubbell SystemOne 6 inch floor fitting (S1R6PTFIT)
- (1) 6 inch flange and universal cover assembly (S1R6CVRxx)

Finish

Brushed Aluminum
Black Powder Coat
Brass Plated
Bronze Plated (Oil rubbed)
Nickel Plated

Catalog Number

S1R6PTALU
S1R6PTBLK
S1R6PTBRS
S1R6PTBRZ
S1R6PTNKL



One-Piece 6 Inch Fire-Rated Poke-Through for Furniture Feed Applications

Assembled unit includes:

- (1) Hubbell SystemOne 6 inch floor fitting (S1R6PTFIT)
- (1) 6 inch furniture feed flange and cover assembly (S1R6FFCVRxx)
- (1) 2 inch conduit fitting (S1RFFFIT2)
- (1) ¼ inch conduit fitting (S1RFFFIT075)

Finish

Brushed Aluminum
Black Powder Coat
Brass Plated
Bronze Plated (Oil rubbed)
Nickel Plated

Catalog Number

S1R6PTFFALU
S1R6PTFFBLK
S1R6PTFFBRS
S1R6PTFFBRZ
S1R6PTFFNKL



Note: xx indicates finish options.

Extron® is a registered trademark of Extron Electronics.

Recessed 4 Inch Core Hole, One-Piece Units




One-Piece Pre-Wired, Quad Receptacle, Recessed Connectivity, Fire-Rated Poke-Through for Power Only

Assembled unit includes:

- (1) Hubbell SystemOne 4 inch recessed floor fitting (S1R4PTFIT)
- (1) Hubbell SystemOne 4 inch recessed activation cover (S1R4CVRxx)
- (1) Hubbell pre-wired quad receptacle with mounting plate (S1R4SPQUAD)
- (1) Hubbell Junction box (S1FRPTJB)

| Finish | Catalog Number |
|-----------------------|-----------------------|
| Brushed Aluminum | S1R4PTQUADALU |
| Brushed Brass Plated | S1R4PTQUADBRS |
| Antique Bronze Plated | S1R4PTQUADBRSZ |
| Satin Nickel Plated | S1R4PTQUADNKL |
| Black Powder Coat | S1R4PTQUADBLK |
| Gray Powder Coat | S1R4PTQUADGRY |

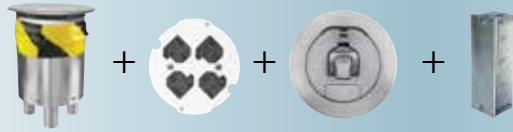

One-Piece, Fire-Rated Poke-Through, Recessed Connectivity

Assembled unit includes:

- (1) Hubbell SystemOne 4 inch recessed floor fitting (S1R4PTFIT)
- (1) Hubbell SystemOne 4 inch recessed activation cover (S1R4CVRxx)
- (1) Hubbell Junction box (S1FRPTJB)

| Finish | Catalog Number |
|-----------------------|------------------|
| Brushed Aluminum | S1R4PTALU |
| Brushed Brass Plated | S1R4PTBRS |
| Antique Bronze Plated | S1R4PTBRZ |
| Satin Nickel Plated | S1R4PTNKL |
| Black Powder Coat | S1R4PTBLK |
| Gray Powder Coat | S1R4PTGRY |



Note: xx indicates finish options.

Recommended Fire-Rated Poke-Through Size Chart

To avoid over or under utilizing the capacity of the fire-rated poke-through, first determine how many gangs of power, data and AV are required for the application. The matrix below will guide you to the correct poke-through size.

Example: 2 gangs of power, 1 gang of AV and 1-gang of data is required. Find the intersection for 2 power gangs with 2 data/AV gangs. The highlighted intersection defines the recommended FRPT.

| | | Recommended Fire-Rated Poke-Through Size | | | | | |
|-------------|---|--|------------------|---------------------|---------------|----|----|
| POWER GANGS | 5 | 8" | Exceeds capacity | | | | |
| | 4 | 8" | 8" | of Hubbell recessed | | | |
| | 3 | 6" | 8" | 8" | poke-throughs | | |
| | 2 | 6" | 6" | 8" | 8" | | |
| | 1 | 4" | 6" | 6" | 8" | 8" | 8" |
| | 0 | — | 4" | 6" | 8" | 8" | 8" |
| | | 0 | 1 | 2 | 3 | 4 | 5 |
| | | DATA AND AV GANGS | | | | | |

Design Solutions for:

- Commercial Office Space
- Retail
- Education
- Mass Transit Hubs



Tile

Terrazzo

Carpet

For Technical files, including BIM models, CAD files and Customer drawings, please visit www.hubbell-wiring.com under the Technical tab.

