

Hubbell Health Care Outlet Assembly (HCOA)

*Only UL listed power strip
approved by CMS for
patient and critical care
areas of a healthcare facility*



Healthcare | UL2930 HCOAs



Complies with UL60601-1 and UL60950-1



*The only UL
Listed HCOA
& Relocatable
Power Tap*

Healthcare Grade

Healthcare Facility Outlet Assemblies (HCOA) UL2930 Listed



Hubbell HCOA:


- UL2930 listed for patient care areas
- 15A and 20A 125V versions
- 6 ft. or 15 ft. cord length
- 12/3 AWG cord
- Surge protected models in all configurations
- Non-surge protected RPT models in all configurations
- 4 outlet models feature straight plugs



45° Angle Plug
(6 outlet 15A models only)

Green LED indicates surge protection working

12/3 SJT
15A and 20A Models

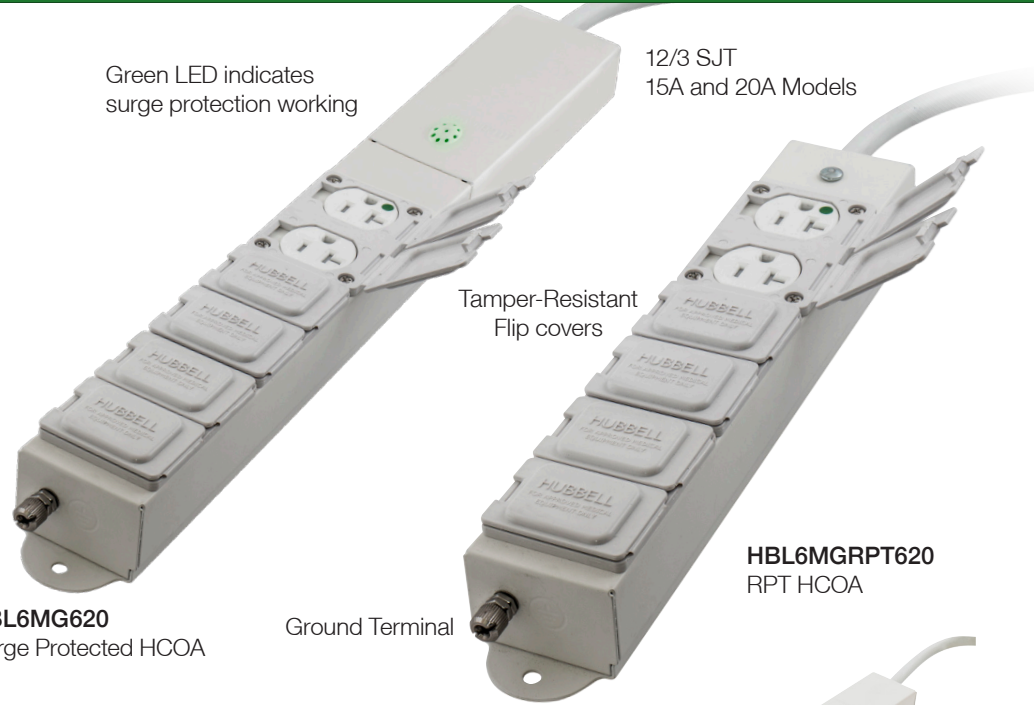

HBL6MG620
Surge Protected HCOA

Ground Terminal

HBL6MGRPT620
RPT HCOA

UL2930 Healthcare Outlet Assembly (HCOA)

| Description | Cord Length | Color | # of Outlets | 15 Amp | 20 Amp |
|--|-------------|-------|--------------|--------------------|----------------------|
| | | | | | |
| UL 2930 HCOA with L-N Surge Protection | 6 Ft. | White | 6 | HBL6MG6 | HBL6MG620 |
| | | | 4 | HBL4MG6 | HBL4MG620 |
| | 15 Ft. | White | 6 | HBL6MG15 | HBL6MG1520 |
| | | | 4 | HBL4MG15 | HBL4MG1520 |
| UL 2930 HCOA Relocatable Power Tap (RPT) | 6 Ft. | White | 6 | HBL6MGRPT6 | HBL6MGRPT620 |
| | | | 4 | HBL4MGRPT6 | HBL4MGRPT620 |
| | 15 Ft. | White | 6 | HBL6MGRPT15 | HBL6MGRPT1520 |
| | | | 4 | HBL4MGRPT15 | HBL4MGRPT1520 |



Hubbell HCOA Mounting Bracket

| Description | Color | Catalog Number |
|---|-------|------------------|
| Allows strips to be easily mounted to IV poles or other medical devices | Black | HBLHCOAMB |

UL2930 HCOA Specifications

| | HBL4MG6/15 HBL6MG6/15 | HBL4MG620/1520 HBL6MG620/1520 | HBL4MGRPT6/15 HBL6MGRPT6/15 | HBL4MGRPT620/1520 HBL6MGRPT620/1520 |
|----------------------------------|--|--|--|--|
| Electrical Specifications | | | | |
| Current | 15A | 20A | 15A | 20A |
| Voltage | 125V | 125V | 125V | 125V |
| Frequency | 60Hz | 60Hz | 60Hz | 60Hz |
| Surge Component | MOV | MOV | n/a | n/a |
| Performance | | | | |
| UL VPR L-N | | 600V | | |
| L-G, N-G | | n/a | | |
| EMI Noise Filtration: | -11 dB to -68 dB (10kHz to 100MHZ) | | | |
| In (Nominal Discharge Current) | | 3kA | | |
| MCOV | | 150V | n/a | n/a |
| Peak Current Rating L-N | | 30kA | | |
| Leakage Current: | | <.1mA | | |
| Total Joules (L-N) | | 550j | | |

Physical Specifications

| | |
|-------------------------------------|-----------------------|
| Cord | 12/3 SJT |
| Housing | 18G Galvanized Steel |
| Color | White Powder Coat |
| Receptacles | HG Tamper Resistant |
| Plug: | 15A HG 45° Angle |
| | 20A HG 90° Angle |
| LED (HBL4MG and HBL6MG Series only) | Green Power Indicator |

Dimensions

| | |
|-------------------------|--------------------------|
| HBL4MG Series: | HBL4MGRPT Series: |
| Length 11.90" (302.3mm) | Length 9.15" (232.4mm) |
| Width 2.22" (56.4mm) | Width 2.22" (56.4mm) |
| Depth 1.92" (48.7mm) | Depth 1.92" (48.7mm) |
| HBL6MG Series: | HBL6MGRPT Series: |
| Length 15.20" (386.1mm) | Length 11.90" (302.3mm) |
| Width 2.22" (56.4mm) | Width 2.22" (56.4mm) |
| Depth 1.92" (48.7mm) | Depth 1.92" (48.7mm) |

Environmental Specifications

| | |
|-----------------------|--------------------------------|
| Operating Temperature | -40°F to 160°F (-40°C to 70°C) |
|-----------------------|--------------------------------|

Certifications

UL 2930; UL File # E488399; RoHs Compliant; NFPA 99; ANSI/IEEE Category A (HBL4MG & HBL6MG Series Only)
Complies with UL 60601-1 and UL 60950-1