



Sleek and highly efficient, this reliable compact luminaire delivers a uniform photometric distribution and powerful performance of 130,000 maintenance free hours at 25°C.

An excellent temperature range of -50°C to +55°C makes the **Arran** a global lighting solution providing high output lighting at extreme temperatures.

The great versatility of this luminaire allows a variety of mounting options from pendant to stanchion covering a wide range of Industrial installations.

Mounting Options

- Floodlight
- Pendant
- Pole/Column
- High Bay

International Approvals

CE

Standard Specification

Arran LED Floodlight

Enclosure	Aluminium alloy with epoxy powder finish
Entry	2 x M20 cable entries
Termination	3 core 6mm ² max. conductor with looping
Installation	Stirrup mounting bracket
Control Gear	Electronic Driver
Colour Temperature (CCT)	5000K (Cool White)
Maintenance	M5 Slotted Screws
Ingress Protection	IP66
Surge Protection	4kV line to line, 6kV line to earth
Electrical Supply	120-277V AC 50/60Hz 127-250V DC

Chalmit®

**LED
SOLUTIONS**

For Harsh & Hazardous Locations



Features

- ◆ **Instant on** crisp white light output
- ◆ Highly **Energy Efficient**
- ◆ **130,000** maintenance free hours at 25°C
- ◆ **Lower power consumption** than HID lamps
- ◆ **Low temperature applications** to -50°C

Product design and specifications are subject to change without notice. Please check the Chalmit website for latest specifications.
www.chalmit.com


Std. Cat No.	Delivered Output	Power Consumption	Ambient °C	Weight
ARRI/06L/LE	5885 lm	53W	-50 to +55	13kg
ARRI/10L/LE	10489 lm	66W	-50 to +55	13kg
ARRI/11L/LE	11976 lm	81W	-50 to +55	13kg
ARRI/15L/LE	16880 lm	122W	-50 to +55	13kg

Options - Suffix to Catalogue No.

/M25	M25 Cable entries	/DM	DALI Dimmable Driver (15L T rating reduces to T5)
-------------	-------------------	------------	------------------------------------------------------

Accessories Accessories should be ordered separately

	Order Code
Wire Guard	SARR1-0001
Anti Glare Shield	SARR1-0002
Pole Mounting Bracket Assembly	S2400-0002

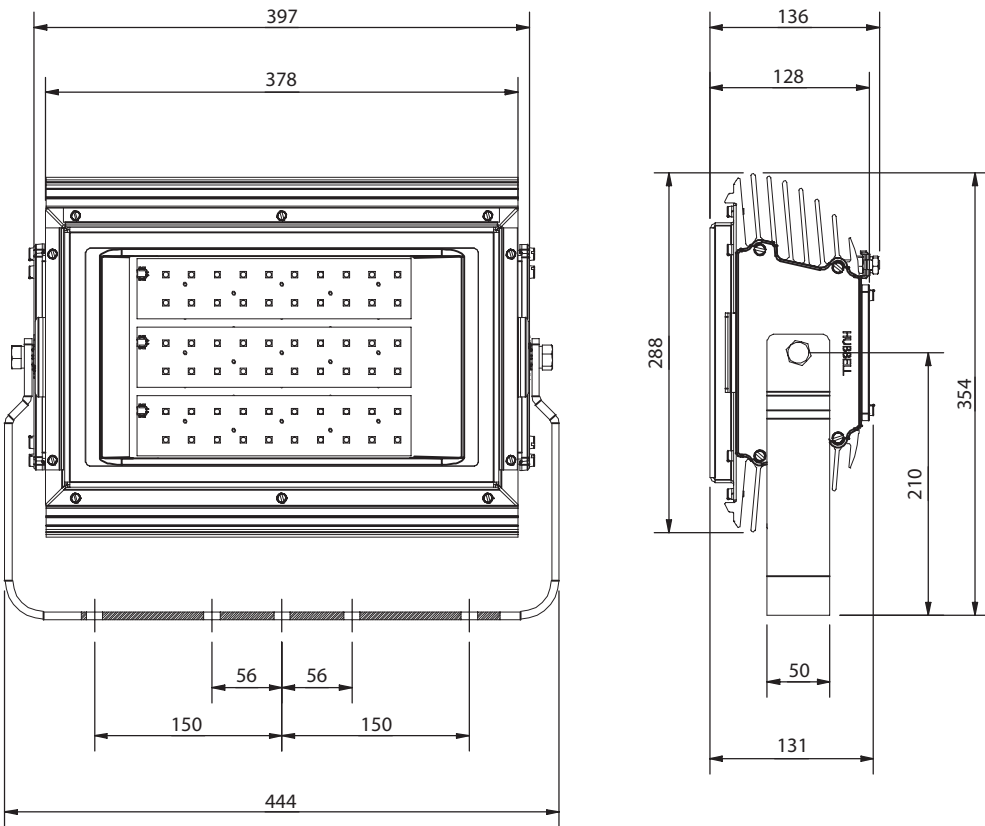

MADE IN BRITAIN



LED SOLUTIONS

For Harsh & Hazardous Locations



Harsh & Hazardous