


thermOweld's UL Listed Chemical Ground Rods are designed to be used in high resistivity soil conditions. When low resistance grounding is critical, this system fits the bill.

Our chemical ground rods are designed with a conductor attached 18" down from the top of the rod. It meets all UL 467 requirements. They come in two styles depending on your needs, vertical and horizontal L shaped and they come pre-filled. The Horizontal L-shaped Chemical ground rods are used when proper depth cannot be achieved due to soil conditions such as bedrock.

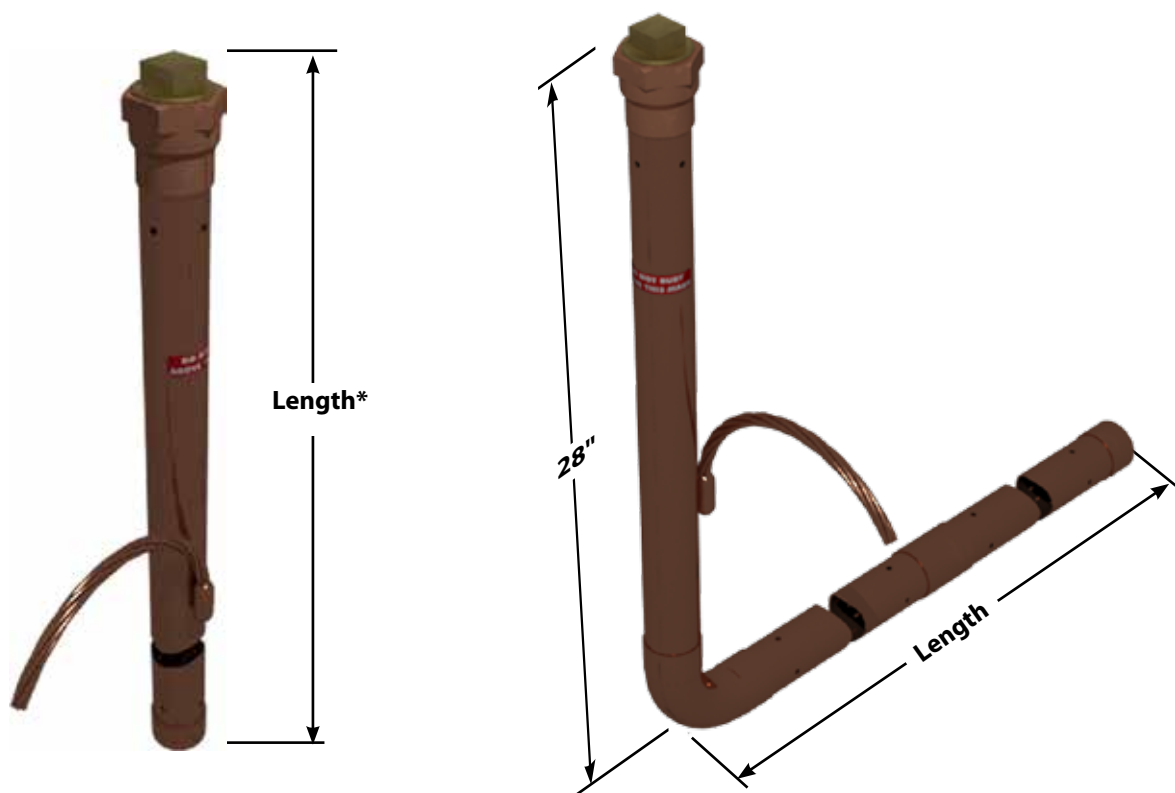

Vertical Chemical Ground Rods

Catalog Number	Length	Pigtail
38-6050-01	5'	5' - 4/0 STR
38-6050-02	10'	5' - #2 SOL (Tinned)
38-6050-03	10'	5' - 2/0 STR
38-6050-04	10'	5' - 4/0 STR
38-6050-05	20'	5' - #2 SOL (Tinned)
38-6050-06	20'	5' - 2/0 STR
38-6050-07	20'	5' - 4/0 STR

Other sizes and conductor types available.
Contact the factory for details.

Horizontal L Shaped Chemical Ground Rod

Catalog Number	Length	Pigtail
38-6051-02	2' X 10'	5' - #2 SOL (Tinned)
38-6051-03	2' X 10'	5' - 2/0 STR
38-6051-04	2' X 10'	5' - 4/0 STR
38-6051-05	2' X 20'	5' - #2 SOL (Tinned)
38-6051-06	2 X 20'	5' - 2/0 STR
38-6051-07	2' X 20'	5' - 4/0 STR


Other sizes and conductor types available.
Contact the factory for details.

99-5073-00 1/15


thermOweld®

UL LISTED CHEMICAL GROUND RODS

thermOweld's UL Listed Chemical Ground Rods kits give you everything you need to complete your installation. Our Pre-filled Chemical Ground Rod, Contact GF Ground Enhancement and our inspection well.

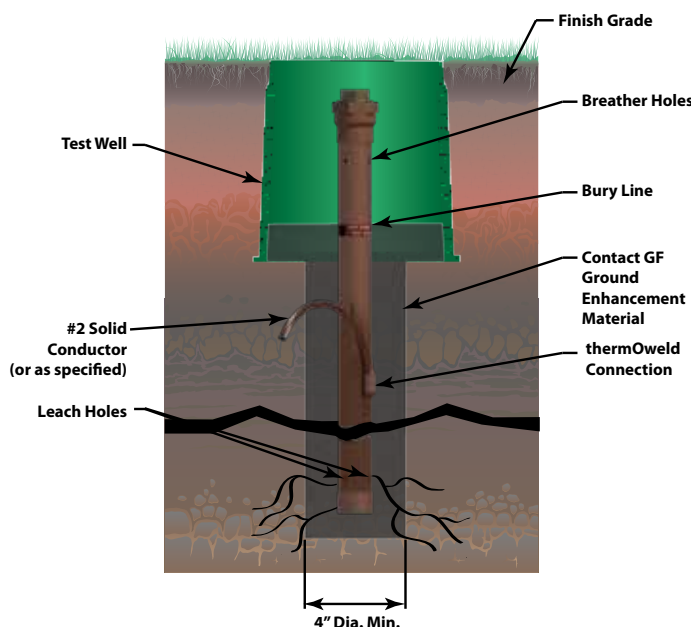

Vertical Installation

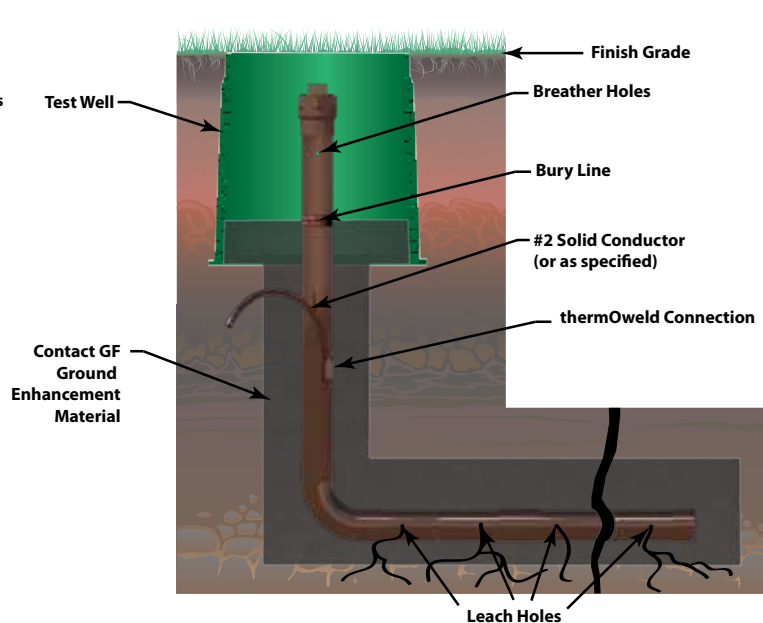

Horizontal L shape Installation

Vertical Chemical Ground Rod Kits



Inspection Well



Contact GF

Catalog Number	Length	Inspection Well	Contact GF 25# Bag	Pigtail
38-6050-31	5'	Yes	2	5' - 4/0 STR
38-6050-32	10'	Yes	4	5' - #2 SOL (Tinned)
38-6050-33	10'	Yes	4	5' - 2/0 STR
38-6050-34	10'	Yes	4	5' - 4/0 STR
38-6050-35	20'	Yes	8	5' - #2 SOL (Tinned)
38-6050-36	20'	Yes	8	5' - 2/0 STR
38-6050-37	20'	Yes	8	5' - 4/0 STR

Other sizes and conductor types available. Contact the factory for details.

Horizontal L Shaped Chemical Ground Rod Kits

Catalog Number	Length	Inspection Well	Contact GF 25# Bag	Pigtail
38-6051-32	2' X 10'	Yes	4	5' - #2 SOL (Tinned)
38-6051-33	2' X 10'	Yes	4	5' - 2/0 STR
38-6051-34	2' X 10'	Yes	4	5' - 4/0 STR
38-6051-35	2' X 20'	Yes	8	5' - #2 SOL (Tinned)
38-6051-36	2' X 20'	Yes	8	5' - 2/0 STR
38-6051-37	2' X 20'	Yes	8	5' - 4/0 STR

Other sizes and conductor types available. Contact the factory for details.

99-5073-00 1/15