




trade**SELECT**™

# CABLE TIES

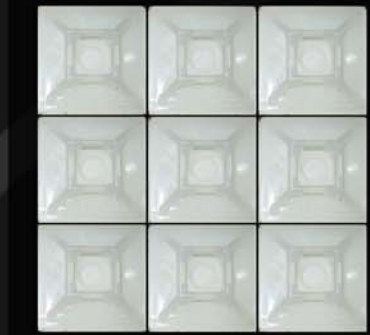

## Retail packaging - for an effective Plan-O-Gram

a) Small pack quantities of  
6, 8, 10, 20, 25, 40, 50



b) Bulk pack quantities of  
100, 500, 1000

c) Cannister



d) Case



- Extensive packaging sizes to meet different customer base;
- All packaging are Color Coded to quickly identify the different product categories
- UPC on each packaging



tradeSELECT™

## Product History

PRODUCT LINE	PRODUCT TYPE	LENGTH	WEATHER PROOF	PACK TYPE	PACK SIZE
<b>CT</b>	<b>S</b>	<b>4</b>	<b>W</b>	<b>P</b>	<b>20</b>
CT - Cable Ties		Length In inches rounded to 1 decimal place		P - Polybag B - Bulk Canister	
	<b>M</b> - Miniature (18 LBS)				
	<b>I</b> - Intermediate (40lbs)				
	<b>S</b> - Standard (50lbs)				
	<b>X</b> - Extra Heavy Duty (175lbs)				
	<b>H</b> - Mounting Head				
	<b>R</b> - Releasable				
	<b>V</b> - Hook and Loop				
	<b>TG</b> - Tie Gun				
	<b>MB</b> - Mounting Base Adhesive				

## Proper storage and usage of Nylon Cable Tie:

Our cable Ties are made of high quality Nylon 66 Resin. For best performance, the following are recommended :

- Ideal storage temperature is around 23°C, with humidity over 50%.
- Open the bag only when needed and seal back to keep the moisture.
- Avoid exposing the cable ties to direct sunlight, unless they are UV Weather Resistant
- Avoid storing cable ties next to heating objects such as heaters.

## Compliance :



Material: Nylon 6.6

Working temperature: Min. : -40°F / -40°C; Max.: 185°F / 85°C

Storage Temperature: Min. : 32°F / 0°C; Max.: 78.8°F / 26°C

Moisture: Min.: RH 50%; Max.: RH 65%

### Miniature Ties - 18 Lbs.



Cat. No.	Color	Length		Width		Diam Min.		Diam Max.		Pack	Master	UPC
		inch	mm	inch	mm	inch	mm	inch	mm	Qty	Pack	
		CTM4P40										
CTM4P100	Natural	4	100	0.10	2.5	0.12	3	0.79	20	100	10	626463041444
CTM4P1000										1000	5	626463041451
CTM4WP40										40	25	626463041468
CTM4WP100	UV Black	4	100	0.10	2.5	0.12	3	0.79	20	100	10	626463041475
CTM4WP1000										1000	5	626463041482

### Standard Ties - 50 Lbs.



4



Cat. No.	Color	Length		Width		Diam Min.		Diam Max.		Pack	Master	UPC
		inch	mm	inch	mm	inch	mm	inch	mm	Qty	Pack	
		CTS75P100	Natural	7.5	190	0.19	4.8	0.16	4	1.77	45	
CTS75P1000										1000	5	626463041512
CTS75WP20										20	25	626463041529
CTS75WP100	UV Black	7.5	190	0.19	4.8	0.16	4	1.77	45	100	10	626463041536
CTS75WP1000										1000	5	626463041543
CTS11P10										10	25	626463041550
CTS11P100	Natural	11	280	0.19	4.8	0.28	7	2.76	70	100	10	626463041567
CTS11P500										500	5	626463041574
CTS11WP10										10	25	626463041581
CTS11WP100	UV Black	11	280	0.19	4.8	0.28	7	2.76	70	100	10	626463041598
CTS11WP500										500	5	626463041604
CTS145P10										10	25	626463041611
CTS145P100	Natural	14.5	368	0.19	4.8	0.28	7	3.78	96	100	10	626463041628
CTS145P500										500	5	626463041635
CTS145WP10										10	25	626463041642
CTS145WP100	UV Black	14.5	368	0.19	4.8	0.28	7	3.78	96	100	10	626463041659
CTS145WP500										500	5	626463041666



tradeSELECT™

# CABLE TIES

**Material:** Nylon 6.6  
**Working temperature:** Min.: -40°F / -40°C; Max.: 185°F / 85°C  
**Storage Temperature:** Min.: 32°F / 0°C; Max.: 78.8°F / 26°C  
**Moisture:** Min.: RH 50%; Max.: RH 65%

## Extra Heavy Duty Ties - 175 Lbs.

Cat. No.	Color	Length		Width		Diam Min.		Diam Max.		Pack	Master	UPC
		inch	mm	inch	mm	inch	mm	inch	mm	Qty	Pack	
		CTX24P10	Natural	24	610	0.35	9	0.43	11	6.38	162	
CTX36P10	Natural	36	914	0.35	9	0.47	12	9.96	253	10	5	626463041680
CTX48P10	Natural	48	1219	0.35	9	0.47	12	13.50	342	10	5	626463041697



## Releasable Ties - 50 lbs.

Cat. No.	Color	Length		Width		Diam Min.		Diam Max.		Pack	Master	UPC
		inch	mm	inch	mm	inch	mm	inch	mm	Qty	Pack	
		CTR79P20	Natural	7.9	200	0.18	4.6	0.2	5	1.97	50	
CTR79WP20	UV Black	7.9	200	0.18	4.6	0.2	5	1.97	50	20	15	626463041710
CTR79WP50	UV Black	7.9	200	0.18	4.6	0.2	5	1.97	50	50	10	626463041727
CTR146P100	Natural	14.6	370	0.19	4.8	0.28	7	4.02	102	100	10	626463041734



## Mounting Head Ties

Cat. No.	Color	Length		Width		Diam Min.		Diam Max.		Tensile	Pack	Master	UPC
		inch	mm	inch	mm	inch	mm	inch	mm	strength	Qty	Pack	
		CTH87P10	Natural	8.7	221	0.17	4.2	0.2	5	2.05	52	50 lbs.	
CTH87P100	Natural	8.7	221	0.17	4.2	0.2	5	2.05	52	50 lbs.	100	10	626463041758
CTH67WP10	UV Black	6.7	171	0.15	3.7	0.2	5	1.46	37	40 lbs.	10	25	626463041765
CTH67WP100	UV Black	6.7	171	0.15	3.7	0.2	5	1.46	37	40 lbs.	100	10	626463041772
CTH118P25	Natural	11.8	300	0.19	4.8	0.28	7	3.11	79	50 lbs.	25	10	626463041789
CTH146P25	Natural	14.6	370	0.19	4.8	0.28	7	3.94	100	50 lbs.	25	10	626463041796



**Material:** Nylon 6.6

**Working temperature:** Min. : 32°F / 0°C; Max.: 122°F / 50°C

**Storage Temperature:** Min. : 32°F / 0°C; Max.: 86°F / 30°C

**Moisture:** Min.: RH 50%; Max.: RH 65%

## Hook and Loop Ties

 


Cat. No.	Color	Length		Width		Diam Min.		Diam Max.		Pack	Master	UPC
		inch	mm	inch	mm	inch	mm	inch	mm	Qty	Pack	
		CTV49P6	Various color	4.9	125	0.47	12	0.2	5	1.22	31	
CTV71P6	Various color	7	180	0.47	12	0.2	5	1.81	46	6	10	626463041857
CTV122P6	Various color	12.2	310	0.63	16	0.2	5	3.43	87	6	10	626463041864

## Mount pad self-adhesive

**Material:** Nylon 6.6

**Working temperature:** Min. : -22°F / -30°C; Max.: 185°F / 85°C



Cat. No.	Color	Length x Width		T		Height		Mount hole		Pack	Master	UPC
		inch	mm	inch	mm	inch	mm	inch	mm	Qty	Pack	
CTMB49P100	White	0.5 x 0.5	12.5 x 12.5	0.13	3.2	0.1	3.20	-	-	100	10	26463042120
CTMB1P100	White	1.1 x 1.1	28.6 x 28.6	0.21	5.5	0.2	5.33	0.20	5	100	10	626463041802
CTMB1P8	White	1.1 x 1.1	28.6 x 28.6	0.21	5.5	0.2	5.33	0.20	5	8	10	626463041819
CTMB1WP100	Black	1.1 x 1.1	28.6 x 28.6	0.21	5.5	0.2	5.33	0.20	5	100	10	626463041826
CTMB1WP8	Black	1.1 x 1.1	28.6 x 28.6	0.21	5.5	0.2	5.33	0.20	5	8	10	626463041833

## TIE GUN



Cat. No.	For Tie Width	Weight	Pack Qty	Master pack	UPC
CTTG6	2.5 ~ 5.0 mm	60 g	1	5	626463041925



tradeSELECT™

# CABLE TIES

**Material:** Nylon 6.6  
**Working temperature:** Min. : -40°F / -40°C; Max.: 185°F / 85°C  
**Storage Temperature:** Min. : 32°F / 0°C; Max.: 78.8°F / 26°C  
**Moisture:** Min.: RH 50%; Max.: RH 65%

## Cannisters

Cat. No.	Pack Qty	Master Pack	UPC
CTB150	150	6	626463041871



Qty per size	50	50	50
Color	Natural	Black	yellow
Length	4", 100mm	6", 150mm	8", 203mm
Tensile Strength	18 lbs.	40 lbs.	50 lbs.
Max. Bundle Dia.	0.79", 20mm	1.3", 33mm	1.85", 47mm



Cat. No.	Pack Qty	Master Pack	UPC
CTB300	300	6	626463041888



Qty per size	100	100	100
Color	Black	Natural	yellow
Length	4", 100mm	5.5", 142mm	4.75", 120mm
Tensile Strength	18 lbs.	40 lbs.	50 lbs.
Max. Bundle Dia.	0.79", 20mm	1.22", 31mm	0.94", 24mm



Cat. No.	Pack Qty	Master Pack	UPC
CTB500	500	6	626463041895



Qty per size	300	200
Color	100 green, 100 yellow, 100 red	natural
Length	4", 100mm	7.5", 190mm
Tensile Strength	18 lbs.	50 lbs.
Max. Bundle Dia.	0.79", 20mm	1.77", 45mm



Cat. No.	Pack Qty	Master Pack	UPC
CTB850	850	6	626463041901



Qty per size	500	50	300
Color	125 Green, 125 red 125 yellow, 125 black	200 nat, 100 black	natural
Length	4", 100mm	7.5", 190mm	11", 280mm
Tensile Strength	18 lbs.	50 lbs.	50 lbs.
Max. Bundle Dia.	0.79", 20mm	1.77", 45mm	2.75", 70mm



**HeadQuarter:**

870 Brock Road South

Pickering, ON

L1W 1Z8

Tel: 905-839-1138

Fax: 905-839-9108

**Office:**

4700 Amiens St.

Montreal, PQ

H1H 2H8

Tel: 514-322-3543

Fax: 514-322-1840

[www.HubbellOnline.com](http://www.HubbellOnline.com)



trade**SELECT**<sup>™</sup>