

## QuikTap™ Ground Rod Connector

Multi-functional irreversible grounding solution

Multi-functional irreversible ground rod connection supplied with wire exothermically welded to a coupling and ready for installation. The connection can be made using a ground rod driver to compress the coupling onto the ground rod, providing a convenient and safe irreversible connection. Quick and easy to install in the field without the need for a burn permit and reduces concerns regarding hazardous materials and critical equipment.



### Features & Benefits

- Irreversible connection — no maintenance
- No need to weld in the field
- No burn permit required
- Perfect for volatile or hazardous job sites
- Compatible with most ground rod types and configurations
- UL 467 Listed for Grounding and Bonding; Rated for Direct Burial in Earth or concrete
- Easy to install — Low Labor Cost

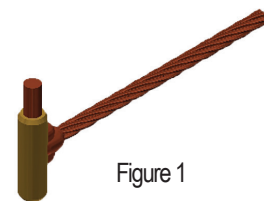


Figure 1  
QuikTap™ to 1 Rod

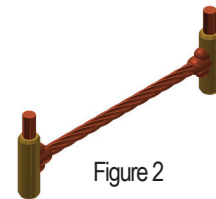


Figure 2  
QuikTap™ to 2 Rods

Catalog Number	Figure	Diameter Accommodated	Conductor Length	Conductor Size
38838505	1	5/8"	5 Feet	#8 Solid
38838510	1	5/8"	10 Feet	#8 Solid
38838515	1	5/8"	15 Feet	#8 Solid
38838520	1	5/8"	20 Feet	#8 Solid
38838530	1	5/8"	30 Feet	#8 Solid
38838540	1	5/8"	40 Feet	#8 Solid
38838550	1	5/8"	50 Feet	#8 Solid
38823905	1	5/8"	5 Feet	#6 Solid
38823910	1	5/8"	10 Feet	#6 Solid
38823915	1	5/8"	15 Feet	#6 Solid
38823920	1	5/8"	20 Feet	#6 Solid
38823930	1	5/8"	30 Feet	#6 Solid
38823940	1	5/8"	40 Feet	#6 Solid
38823950	1	5/8"	50 Feet	#6 Solid
38796405	1	5/8"	5 Feet	2/0 Stranded
38796410	1	5/8"	10 Feet	2/0 Stranded
38796415	1	5/8"	15 Feet	2/0 Stranded
38796420	1	5/8"	20 Feet	2/0 Stranded

Catalog Number	Figure	Diameter Accommodated	Conductor Length	Conductor Size
38796430	1	5/8"	30 Feet	2/0 Stranded
38796440	1	5/8"	40 Feet	2/0 Stranded
38796450	1	5/8"	50 Feet	2/0 Stranded
38796505	1	5/8"	5 Feet	4/0 Stranded
38796510	1	5/8"	10 Feet	4/0 Stranded
38796515	1	5/8"	15 Feet	4/0 Stranded
38796520	1	5/8"	20 Feet	4/0 Stranded
38796530	1	5/8"	30 Feet	4/0 Stranded
38796540	1	5/8"	40 Feet	4/0 Stranded
38796550	1	5/8"	50 Feet	4/0 Stranded
38796605	2	5/8"	5 Feet	2/0 Stranded
38796610	2	5/8"	10 Feet	2/0 Stranded
38796615	2	5/8"	15 Feet	2/0 Stranded
38796620	2	5/8"	20 Feet	2/0 Stranded
38796630	2	5/8"	30 Feet	2/0 Stranded
38796640	2	5/8"	40 Feet	2/0 Stranded
38796650	2	5/8"	50 Feet	2/0 Stranded
38796705	2	5/8"	5 Feet	4/0 Stranded

## QuikTap™ Ground Rod Connector

(continued)

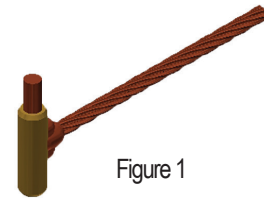


Figure 1  
QuikTap™ to 1 Rod


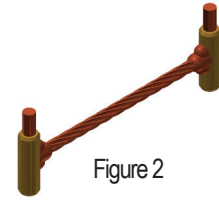


Figure 2  
QuikTap™ to 2 Rods

Catalog Number	Figure	Diameter Accommodated	Conductor Length	Conductor Size
38796710	2	5/8"	10 Feet	4/0 Stranded
38796715	2	5/8"	15 Feet	4/0 Stranded
38796720	2	5/8"	20 Feet	4/0 Stranded
38796730	2	5/8"	30 Feet	4/0 Stranded
38796740	2	5/8"	40 Feet	4/0 Stranded
38796750	2	5/8"	50 Feet	4/0 Stranded
38797005	1	3/4"	5 Feet	2/0 Stranded
38797010	1	3/4"	10 Feet	2/0 Stranded
38797015	1	3/4"	15 Feet	2/0 Stranded
38797020	1	3/4"	20 Feet	2/0 Stranded
38797030	1	3/4"	30 Feet	2/0 Stranded
38797040	1	3/4"	40 Feet	2/0 Stranded
38797050	1	3/4"	50 Feet	2/0 Stranded
38797105	1	3/4"	5 Feet	4/0 Stranded
38797110	1	3/4"	10 Feet	4/0 Stranded
38797115	1	3/4"	15 Feet	4/0 Stranded
38797120	1	3/4"	20 Feet	4/0 Stranded
38797130	1	3/4"	30 Feet	4/0 Stranded
38797140	1	3/4"	40 Feet	4/0 Stranded
38797150	1	3/4"	50 Feet	4/0 Stranded
38799200		QuikTap™ Driver Plate		
38824301		QuikTap™ Attachment Tool		



38799200 - QuikTap™ Driver Plate

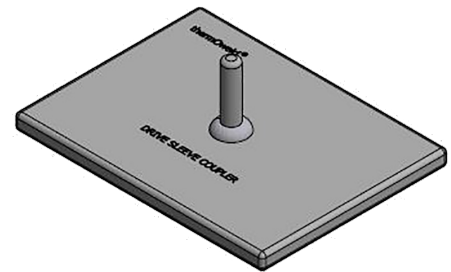

38824301 - QuikTap™ Attachment Tool