

BURNDY® TOOLS

PATRIOT® PAT444S
DIELESS C-HEAD
SERIES




Connecting Power to Your World®



BURNDY® PATRIOT® PAT444S SERIES

FEATURES & BENEFITS

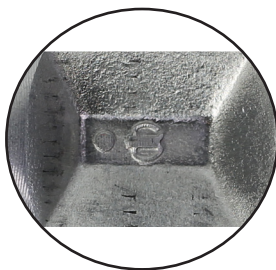

Unique Crimp Embossment



MODELS, SPECIFICATIONS & CAPACITIES

MODELS

PAT444SLI	Tool, 3Ah, 120V AC
PAT444SL5	Tool, 5Ah, 120V AC
PAT444SLCB	Tool, No Charger/Batteries

SPECIFICATIONS

Output Force	11 Tons
Tool Weight	16 lbs
Size	16.9" x 13.7" x 3.2"
Die Style	Dieless
Operating Voltage	18 V-DC Lithium-ion
Recharge Time	30 minutes (3.0Ah)
	45 minutes (5.0Ah)
Warranty	5 year limited warranty
	Lifetime warranty on INFINITY DRIVE®
	3 years on batteries and charger



Range Taking Capability: #4 AWG to 1000 kcmil



- Connections are UL Listed to 486A-486B on Copper & Aluminum terminals and splices
- Comply with ANSI C119.4 on YDS-RL and YDS-RLNI Splices (ACSR, AAC, AAAC, ACAR)
- Qualified for use on YCP-L Compression Pulling Heads

CRIMPING CAPACITIES	TERMINALS & SPLICES	HYPLUG™	FULL TENSION SPLICES
Copper	#4 AWG - 1000 kcmil	#4 AWG - 1000 kcmil	
Copper Flex	#4 AWG - 1000 kcmil	#2 AWG - 777 kcmil	
Aluminum	#4 AWG - 1000 kcmil	#4 AWG - 1000 kcmil	
ACSR, AAC, AAAC, ACAR			#4 AWG - 556.5 kcmil



TRUST THE BURNDY® ENGINEERED SYSTEM

**WHEN FACING THE UNPREDICTABLE,
YOU'RE NOT ALONE...**

 BURNDY HAS YOUR BACK!

**PROFESSIONAL GRADE
TOOLS YOU KNOW
TOOLS YOU TRUST**



Customer Service Department
7 Aviation Park Drive
Londonderry, NH 03053
1-800-346-4175
1-800-451-4956 (Technical Services)
1-603-647-5299 (International)

Canada
1-800-361-6975 (Quebec)
1-800-387-6487 (All other provinces)

Mexico
011-52-722-265-4400

Brazil
011-55-11-5515-7225

Tool Service Center
Littleton Industrial Park
Littleton, NH 03561
1-800-426-8720

www.burndy.com | 1-800-346-4175



Connecting Power to Your World®

