




Polyolefin Thin Wall Heat Shrink

Flexible, Flame Retardant, Multipurpose



Insulate connections easily with our broad range of heat shrink tubing

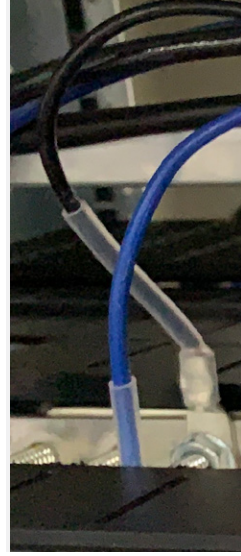

Type: HS-TP (*Heat Shrink - Thin Polyolefin*)

| Thin wall heat shrink tubing

+ Features & Benefits:

- Provides mechanical protection for terminal strain relief and wire bonding
- Material: Thin wall cross-linked polyolefin
- Ideal for industrial and automotive markets as well as for covering copper and aluminum tubular connectors
- Product is available in 6 inch and 4 foot precut multi packaged lengths and a variety of reel sizes, (1000, 500, 250, 200, 100, 50 & 25 ft)
- 2:1 shrink ratio for faster shrink recovery*
- -55°C to 135°C (-67°F to 275°F) Continuous Operating Temperature
- Shrink temperature of 90°C min.
- Rated up to 600 Volts
- Colors are flame retardant & UV resistant
- Resistant to common fluids and solvents



*Yellow/Green heat shrink has a 3:1 shrink ratio

+ Standards:

- ROHS compliant
- UL 224, 125°C (colors)
- CSA C22.2 No. 198.1, 125°C
- AMS.3636, 3637 and 3587
- UL/CSA approval applies to black and colors
- Approved to automotive OEM specifications

+ Typical Applications:

- Electrical Insulation of wire splices and terminals
- Strain Relief of wire terminations
- Protection against abrasion, fluids and environmental conditions



Heat Shrink Thin Wall Naming Convention


Product Family								
Heat	Shrink	Thin Wall Polyolefin	Color: BK: Black BL: Blue CL: Clear GR: Green OR: Orange RD: Red WH: White YL: Yellow YG: Yellow/Green MX: Mixed	Internal Diameter: 0047: 0.0047 (3/64") 0063: 0.063 (1/16") 0094: 0.094 (3/32") 0125: 0.125 (1/8") 0187: 0.187 (3/16") 0250: 0.250 (1/4") 0375: 0.375 (3/8") 0500: 0.500 (1/2") 0625: 0.625 (5/8") 0750: 0.750 (3/4") 1000: 1.000 (1") 1250: 1.250 (1-1/4") 1500: 1.500 (1-1/2") 2000: 2.000 (2") 3000: 3.000 (3") 4000: 4.000 (4")	Length: 6I: 6 Inch Lengths 4F: 4 Foot Lengths 1000F: 1000 Feet 500F: 500 Feet 250F: 250 Feet 200F: 200 Feet 100F: 100 Feet 50F: 50 Feet 25F: 25 Feet	Package Type: PK: Package RL: Reel	Number of Pieces in Multipack	Ordering Suffix: EA: Each
H	S	TP	BK	0047	4F	PK	25	EA
Example: "HSTPBK00474FPK25EA"								

Thin Wall Heat Shrink Wire Accommodates Matrix / 2:1 Shrink Ratio**

Nominal Size (Inch)	Nominal Size (Issued)	Recovery Size (Shrunk)	Wall Thickness (Supplied)	Copper Code* (Terminals & Splices)	Copper Flex* (Terminals & Splices)	Aluminum* (Terminals & Splices)
3/64"	0.047	0.023	0.016	-	-	-
1/16"	0.063	0.031	0.017	18 AWG	-	-
3/32"	0.094	0.047	0.020	18 - 16 AWG	-	-
1/8"	0.125	0.063	0.020	18 - 14 AWG	-	-
3/16"	0.187	0.093	0.020	18 - 12 AWG	-	-
1/4"	0.250	0.125	0.025	14 - 10 AWG	-	12 - 10 AWG
3/8"	0.375	0.187	0.025	8 - 6 AWG	14 - 5 AWG	12 - 8 AWG
1/2"	0.500	0.250	0.025	6 - 2 AWG	8 - 3 AWG	8 - 4 AWG
5/8"	0.625	0.313	0.030	2 - 2/0 AWG	3 - 1/0 AWG	4 - 1 AWG
3/4"	0.750	0.375	0.030	1 - 4/0 AWG	4 - 3/0 AWG	4 - 2/0 AWG
1"	1.000	0.500	0.035	2/0 AWG - 350 KCMIL	1/0 AWG - 250 KCMIL I,K,M, 262 DLO	2 AWG - 250 KCMIL
1-1/4"	1.250	0.625	0.035	250 - 500 KCMIL	4/0 AWG G,H,I,K,M, DLO To 350 KCMIL G,H,I,K,M, 373 DLO	3/0 AWG - 300 KCMIL
1-1/2"	1.500	0.750	0.040	350 - 750 KCMIL	250 KCMIL I,K,M, 262 DLO To 600 KCMIL G,H,I,K, 1470/24 DLO	3/0 AWG - 750 KCMIL
2"	2.000	1.000	0.045	600 - 1500 KCMIL	500 KCMIL G,H, 444 DLO To 750 KCMIL G,H, 777 DLO	300 - 1000 KCMIL
3"	3.000	1.500	0.050	1250 - 2000 KCMIL	-	1000 - 2000 KCMIL
4"	4.000	2.000	0.055	-	-	-

* Wires in the table are for reference and the installer should select the proper heat shrink size based on the OD of the wire insulation, terminal or splice being used.

** Excludes yellow/green (3:1 shrink ratio)

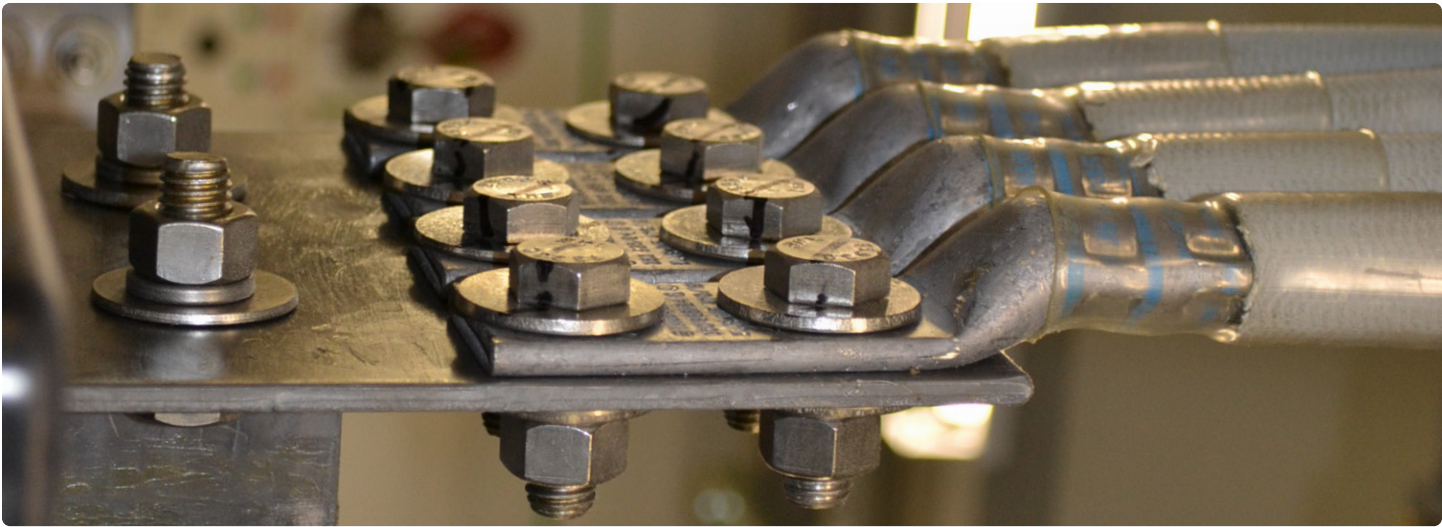

BURNDY® heat shrink packaging options & available reel sizes

Nominal Size	Colors									Package Options									
	Black	Blue	Clear	Green	Orange	Red	White	Yellow	Yellow/ Green*	6 Inch Lengths 25 Piece Packs	4 Ft Sticks	Ordering Increments	Reel Sizes Available (Feet)						
													1000*	500*	250*	200	100	50	25
3/64"	•	•	•	•	•	•	•	•	-	•	•	25	•	•	•	-	•	•	•
1/16"	•	•	•	•	•	•	•	•	-	•	•	25	•	•	•	-	•	•	•
3/32"	•	•	•	•	•	•	•	•	-	•	•	25	•	•	•	-	•	•	•
1/8"	•	•	•	•	•	•	•	•	•	•	•	25	•	•	•	-	•	•	•
3/16"	•	•	•	•	•	•	•	•	•	•	•	25	•	•	•	*	•	•	•
1/4"	•	•	•	•	•	•	•	•	•	•	•	25	-	•	•	-	•	•	•
3/8"	•	•	•	•	•	•	•	•	•	•	•	25	-	•	•	*	•	•	•
1/2"	•	•	•	•	•	•	•	•	•	•	•	25	-	-	-	•	•	•	•
5/8"	•	•	•	•	•	•	•	•	-	•	•	5	-	-	-	•	•	•	•
3/4"	•	•	•	•	•	•	•	•	•	•	•	5	-	-	-	-	•	•	•
1"	•	•	•	•	•	•	•	•	•	•	•	5	-	-	-	-	•	•	•
1-1/4"	•	•	•	•	•	•	•	•	-	-	•	5	-	-	-	-	•	•	•
1-1/2"	•	•	•	•	•	•	•	•	•	-	•	5	-	-	-	-	•	•	•
2"	•	•	•	•	•	•	•	•	-	-	•	5	-	-	-	-	•	•	•
3"	•	•	•	•	•	•	•	•	-	-	•	2	-	-	-	-	-	•	•
4"	•	•	•	•	•	•	•	•	-	-	•	2	-	-	-	-	-	•	•

* Yellow/Green not available in 1000 ft reels for 1/8" and 3/16" ID sizes & 500 and 250 ft reels are not available for 3/16" and 3/8" ID sizes
 * 200 Foot Reel available in yellow/green only for 3/16" & 3/8" ID Size



6 Inch Packs



4 Foot Sticks



Assorted Reel Sizes



HEAT GUN OPTIONS



MCHSG102218V

- Makita 18V LXT high temperature 1022°F heat gun kit
- Cordless, battery operated (battery not included)
- Fixed LED light to illuminate the work area
- Trigger switch with lock-on, lock-off functions
- Built in hook allows for hanging of tool
- Tool case & 4 nozzle accessories included



MHSG1202

- Makita variable temp. corded heat gun kit
- LCD digital display
- Push-button temp. control (122°F - 1202° F)
- Slide switch sets 3 air flow settings
- Rubberized handle & integrated rear stand
- Tool case & 4 nozzle accessories included



BHS1100

- Burndy multipurpose low-cost corded heat gun
- Electronic variable thermal control dial
- Temperature range from 250°F to 1100°F (121°C - 650°C)
- Two speed motor
- Built in safety stand
- Includes heat guard

Makita® and the Makita® Logo are trademarks of Makita USA

HS-TP Thin Wall Polyolefin Heat Shrink							
Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPMX00476IPK25	3/64"	0.047	0.023	0.016	600V	Multi-Pack (6" Lengths)	1
HSTPBK00476IPK25	3/64"	0.047	0.023	0.016	600V	Multi-Pack (6" Lengths)	1
HSTPBK00474FPK25EA	3/64"	0.047	0.023	0.016	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBK00471000FRL	3/64"	0.047	0.023	0.016	600V	1000 Foot Reel	1
HSTPBK0047500FRL	3/64"	0.047	0.023	0.016	600V	500 Foot Reel	1
HSTPBK0047250FRL	3/64"	0.047	0.023	0.016	600V	250 Foot Reel	1
HSTPBK0047100FRL	3/64"	0.047	0.023	0.016	600V	100 Foot Reel	1
HSTPBK004750FRL	3/64"	0.047	0.023	0.016	600V	50 Foot Reel	1
HSTPBK004725FRL	3/64"	0.047	0.023	0.016	600V	25 Foot Reel	1
HSTPBL00476IPK25	3/64"	0.047	0.023	0.016	600V	Multi-Pack (6" Lengths)	1
HSTPBL00474FPK25EA	3/64"	0.047	0.023	0.016	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBL00471000FRL	3/64"	0.047	0.023	0.016	600V	1000 Foot Reel	1
HSTPBL0047500FRL	3/64"	0.047	0.023	0.016	600V	500 Foot Reel	1
HSTPBL0047250FRL	3/64"	0.047	0.023	0.016	600V	250 Foot Reel	1
HSTPBL0047100FRL	3/64"	0.047	0.023	0.016	600V	100 Foot Reel	1
HSTPBL004750FRL	3/64"	0.047	0.023	0.016	600V	50 Foot Reel	1
HSTPBL004725FRL	3/64"	0.047	0.023	0.016	600V	25 Foot Reel	1
HSTPCL00476IPK25	3/64"	0.047	0.023	0.016	600V	Multi-Pack (6" Lengths)	1
HSTPCL00474FPK25EA	3/64"	0.047	0.023	0.016	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPCL00471000FRL	3/64"	0.047	0.023	0.016	600V	1000 Foot Reel	1
HSTPCL0047500FRL	3/64"	0.047	0.023	0.016	600V	500 Foot Reel	1
HSTPCL0047250FRL	3/64"	0.047	0.023	0.016	600V	250 Foot Reel	1
HSTPCL0047100FRL	3/64"	0.047	0.023	0.016	600V	100 Foot Reel	1
HSTPCL004750FRL	3/64"	0.047	0.023	0.016	600V	50 Foot Reel	1
HSTPCL004725FRL	3/64"	0.047	0.023	0.016	600V	25 Foot Reel	1
HSTPGR00476IPK25	3/64"	0.047	0.023	0.016	600V	Multi-Pack (6" Lengths)	1
HSTPGR00474FPK25EA	3/64"	0.047	0.023	0.016	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPGR00471000FRL	3/64"	0.047	0.023	0.016	600V	1000 Foot Reel	1
HSTPGR0047500FRL	3/64"	0.047	0.023	0.016	600V	500 Foot Reel	1
HSTPGR0047250FRL	3/64"	0.047	0.023	0.016	600V	250 Foot Reel	1
HSTPGR0047100FRL	3/64"	0.047	0.023	0.016	600V	100 Foot Reel	1
HSTPGR004750FRL	3/64"	0.047	0.023	0.016	600V	50 Foot Reel	1
HSTPGR004725FRL	3/64"	0.047	0.023	0.016	600V	25 Foot Reel	1
HSTPOR00476IPK25	3/64"	0.047	0.023	0.016	600V	Multi-Pack (6" Lengths)	1
HSTPOR00474FPK25EA	3/64"	0.047	0.023	0.016	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPOR00471000FRL	3/64"	0.047	0.023	0.016	600V	1000 Foot Reel	1
HSTPOR0047500FRL	3/64"	0.047	0.023	0.016	600V	500 Foot Reel	1
HSTPOR0047250FRL	3/64"	0.047	0.023	0.016	600V	250 Foot Reel	1
HSTPOR0047100FRL	3/64"	0.047	0.023	0.016	600V	100 Foot Reel	1
HSTPOR004750FRL	3/64"	0.047	0.023	0.016	600V	50 Foot Reel	1
HSTPOR004725FRL	3/64"	0.047	0.023	0.016	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
25 Piece Increments	25	25	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
25 Piece Increments	25	-	25	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
25 Piece Increments	25	-	-	25	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
25 Piece Increments	25	-	-	-	25	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
25 Piece Increments	25	-	-	-	-	25	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange

HS-TP Thin Wall Polyolefin Heat Shrink							
Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPRD00476IPK25	3/64"	0.047	0.023	0.016	600V	Multi-Pack (6" Lengths)	1
HSTPRD00474FPK25EA	3/64"	0.047	0.023	0.016	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPRD00471000FRL	3/64"	0.047	0.023	0.016	600V	1000 Foot Reel	1
HSTPRD0047500FRL	3/64"	0.047	0.023	0.016	600V	500 Foot Reel	1
HSTPRD0047250FRL	3/64"	0.047	0.023	0.016	600V	250 Foot Reel	1
HSTPRD0047100FRL	3/64"	0.047	0.023	0.016	600V	100 Foot Reel	1
HSTPRD004750FRL	3/64"	0.047	0.023	0.016	600V	50 Foot Reel	1
HSTPRD004725FRL	3/64"	0.047	0.023	0.016	600V	25 Foot Reel	1
HSTPWH00476IPK25	3/64"	0.047	0.023	0.016	600V	Multi-Pack (6" Lengths)	1
HSTPWH00474FPK25EA	3/64"	0.047	0.023	0.016	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPWH00471000FRL	3/64"	0.047	0.023	0.016	600V	1000 Foot Reel	1
HSTPWH0047500FRL	3/64"	0.047	0.023	0.016	600V	500 Foot Reel	1
HSTPWH0047250FRL	3/64"	0.047	0.023	0.016	600V	250 Foot Reel	1
HSTPWH0047100FRL	3/64"	0.047	0.023	0.016	600V	100 Foot Reel	1
HSTPWH004750FRL	3/64"	0.047	0.023	0.016	600V	50 Foot Reel	1
HSTPWH004725FRL	3/64"	0.047	0.023	0.016	600V	25 Foot Reel	1
HSTPYL00476IPK25	3/64"	0.047	0.023	0.016	600V	Multi-Pack (6" Lengths)	1
HSTPYL00474FPK25EA	3/64"	0.047	0.023	0.016	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPYL00471000FRL	3/64"	0.047	0.023	0.016	600V	1000 Foot Reel	1
HSTPYL0047500FRL	3/64"	0.047	0.023	0.016	600V	500 Foot Reel	1
HSTPYL0047250FRL	3/64"	0.047	0.023	0.016	600V	250 Foot Reel	1
HSTPYL0047100FRL	3/64"	0.047	0.023	0.016	600V	100 Foot Reel	1
HSTPYL004750FRL	3/64"	0.047	0.023	0.016	600V	50 Foot Reel	1
HSTPYL004725FRL	3/64"	0.047	0.023	0.016	600V	25 Foot Reel	1
HSTPMX00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1
HSTPBK00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1
HSTPBK00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBK00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1
HSTPBK0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1
HSTPBK0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1
HSTPBK0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1
HSTPBK006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1
HSTPBK006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1
HSTPBL00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1
HSTPBL00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBL00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1
HSTPBL0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1
HSTPBL0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1
HSTPBL0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1
HSTPBL006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1
HSTPBL006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1

[illegible]

HS-TP Thin Wall Polyolefin Heat Shrink

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPCL00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1
HSTPCL00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPCL00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1
HSTPCL0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1
HSTPCL0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1
HSTPCL0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1
HSTPCL006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1
HSTPCL006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1
HSTPGR00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1
HSTPGR00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPGR00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1
HSTPGR0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1
HSTPGR0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1
HSTPGR0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1
HSTPGR006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1
HSTPGR006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1
HS0063ORTP6IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1
HS0063ORTP4FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4' Lengths) Sold by Each	25
HS0063ORTP1000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1
HS0063ORTP500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1
HS0063ORTP250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1
HS0063ORTP100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1
HS0063ORTP50FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1
HS0063ORTP25FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1
HSTPRD00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1
HSTPRD00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPRD00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1
HSTPRD0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1
HSTPRD0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1
HSTPRD0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1
HSTPRD006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1
HSTPRD006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1
HSTPWH00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1
HSTPWH00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPWH00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1
HSTPWH0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1
HSTPWH0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1
HSTPWH0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1
HSTPWH006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1
HSTPWH006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1

		Quantity of Each Color									Color
Package Quantity	Total Pieces Per Pack	Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
25 Piece Increments	25	-	-	25	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
25 Piece Increments	25	-	-	-	25	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
25 Piece Increments	25	-	-	-	-	25	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
25 Piece Increments	25	-	-	-	-	-	25	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
25 Piece Increments	25	-	-	-	-	-	-	25	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White

HS-TP Thin Wall Polyolefin Heat Shrink							
Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPYL00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1
HSTPYL00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPYL00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1
HSTPYL0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1
HSTPYL0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1
HSTPYL0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1
HSTPYL006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1
HSTPYL006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1
HSTPMX00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPBK00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPBK00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBK00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1
HSTPBK0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1
HSTPBK0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1
HSTPBK0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1
HSTPBK009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1
HSTPBK009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1
HSTPBL00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPBL00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBL00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1
HSTPBL0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1
HSTPBL0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1
HSTPBL0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1
HSTPBL009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1
HSTPBL009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1
HSTPCL00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPCL00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPCL00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1
HSTPCL0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1
HSTPCL0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1
HSTPCL0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1
HSTPCL009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1
HSTPCL009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1
HSTPGR00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPGR00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPGR00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1
HSTPGR0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1
HSTPGR0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1
HSTPGR0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1
HSTPGR009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1
HSTPGR009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/ Green (YG)	
1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
25 Piece Increments	25	-	-	-	-	-	-	-	25	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
25 Piece Increments	25	25	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
25 Piece Increments	25	-	25	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
25 Piece Increments	25	-	-	25	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
25 Piece Increments	25	-	-	-	25	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green

HS-TP Thin Wall Polyolefin Heat Shrink

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPOR00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPOR00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPOR00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1
HSTPOR0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1
HSTPOR0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1
HSTPOR0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1
HSTPOR009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1
HSTPOR009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1
HSTPRD00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPRD00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPRD00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1
HSTPRD0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1
HSTPRD0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1
HSTPRD0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1
HSTPRD009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1
HSTPRD009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1
HSTPWH00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPWH00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPWH00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1
HSTPWH0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1
HSTPWH0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1
HSTPWH0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1
HSTPWH009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1
HSTPWH009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1
HSTPYL00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPYL00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPYL00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1
HSTPYL0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1
HSTPYL0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1
HSTPYL0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1
HSTPYL009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1
HSTPYL009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1
HSTPMX01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPBK01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPBK01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBK01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1
HSTPBK0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1
HSTPBK0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1
HSTPBK0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1
HSTPBK012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1
HSTPBK012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1

HS-TP Thin Wall Polyolefin Heat Shrink

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPBL01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPBL01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBL01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1
HSTPBL0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1
HSTPBL0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1
HSTPBL0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1
HSTPBL012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1
HSTPBL012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1
HSTPCL01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPCL01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPCL01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1
HSTPCL0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1
HSTPCL0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1
HSTPCL0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1
HSTPCL012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1
HSTPCL012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1
HSTPGR01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPGR01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPGR01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1
HSTPGR0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1
HSTPGR0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1
HSTPGR0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1
HSTPGR012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1
HSTPGR012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1
HSTPOR01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPOR01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPOR01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1
HSTPOR0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1
HSTPOR0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1
HSTPOR0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1
HSTPOR012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1
HSTPOR012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1
HSTPRD01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPRD01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPRD01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1
HSTPRD0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1
HSTPRD0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1
HSTPRD0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1
HSTPRD012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1
HSTPRD012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
25 Piece Increments	25	-	25	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
25 Piece Increments	25	-	-	25	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
25 Piece Increments	25	-	-	-	25	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
25 Piece Increments	25	-	-	-	-	25	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
25 Piece Increments	25	-	-	-	-	-	25	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red

HS-TP Thin Wall Polyolefin Heat Shrink							
Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPWH01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPWH01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPWH01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1
HSTPWH0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1
HSTPWH0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1
HSTPWH0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1
HSTPWH012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1
HSTPWH012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1
HSTPYL01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPYL01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPYL01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1
HSTPYL0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1
HSTPYL0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1
HSTPYL0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1
HSTPYL012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1
HSTPYG01256IPK25	1/8"	0.125	0.039	0.022	600V	Multi-Pack (6" Lengths)	1
HSTPYG01254FPK25EA	1/8"	0.125	0.039	0.022	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPYG0125500FRL	1/8"	0.125	0.039	0.022	600V	500 Foot Reel	1
HSTPYG0125250FRL	1/8"	0.125	0.039	0.022	600V	250 Foot Reel	1
HSTPYG0125100FRL	1/8"	0.125	0.039	0.022	600V	100 Foot Reel	1
HSTPYG012550FRL	1/8"	0.125	0.039	0.022	600V	50 Foot Reel	1
HSTPYG012525FRL	1/8"	0.125	0.039	0.022	600V	25 Foot Reel	1
HSTPMX01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPBK01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPBK01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBK01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1
HSTPBK0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1
HSTPBK0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1
HSTPBK0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1
HSTPBK018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1
HSTPBK018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1
HSTPBL01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPBL01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBL01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1
HSTPBL0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1
HSTPBL0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1
HSTPBL0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1
HSTPBL018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1
HSTPBL018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1
HSTPCL01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPCL01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPCL01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1
HSTPCL0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1
HSTPCL0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1
HSTPCL0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1
HSTPCL018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1
HSTPCL018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
25 Piece Increments	25	-	-	-	-	-	-	25	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
25 Piece Increments	25	-	-	-	-	-	-	-	25	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 pack of 25 pieces	25	-	-	-	-	-	-	-	-	25	Yellow/Green
25 Piece Increments	25	-	-	-	-	-	-	-	-	25	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
25 Piece Increments	25	25	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
25 Piece Increments	25	-	25	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
25 Piece Increments	25	-	-	25	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear

HS-TP Thin Wall Polyolefin Heat Shrink

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPGR01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPGR01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPGR01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1
HSTPGR0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1
HSTPGR0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1
HSTPGR0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1
HSTPGR018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1
HSTPGR018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1
HSTPOR01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPOR01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPOR01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1
HSTPOR0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1
HSTPOR0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1
HSTPOR0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1
HSTPOR018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1
HSTPOR018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1
HSTPRD01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPRD01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPRD01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1
HSTPRD0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1
HSTPRD0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1
HSTPRD0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1
HSTPRD018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1
HSTPRD018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1
HSTPWH01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPWH01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPWH01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1
HSTPWH0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1
HSTPWH0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1
HSTPWH0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1
HSTPWH018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1
HSTPWH018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1
HSTPYL01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1
HSTPYL01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPYL01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1
HSTPYL0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1
HSTPYL0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1
HSTPYL0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1
HSTPYL018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1
HSTPYL018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1
HSTPYG01876IPK25	3/16"	0.187	0.059	0.024	600V	Multi-Pack (6" Lengths)	1
HSTPYG01874FPK25EA	3/16"	0.187	0.059	0.024	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPYG0187200FRL	3/16"	0.187	0.059	0.024	600V	200 Foot Reel	1
HSTPYG0187100FRL	3/16"	0.187	0.059	0.024	600V	100 Foot Reel	1
HSTPYG018750FRL	3/16"	0.187	0.059	0.024	600V	50 Foot Reel	1
HSTPYG018725FRL	3/16"	0.187	0.059	0.024	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
25 Piece Increments	25	-	-	-	25	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
25 Piece Increments	25	-	-	-	-	25	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
25 Piece Increments	25	-	-	-	-	-	25	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
25 Piece Increments	25	-	-	-	-	-	-	25	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
25 Piece Increments	25	-	-	-	-	-	-	-	25	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 pack of 25 pieces	25	-	-	-	-	-	-	-	-	25	Yellow/Green
25 Piece Increments	25	-	-	-	-	-	-	-	-	25	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green

HS-TP Thin Wall Polyolefin Heat Shrink

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPMX02506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPBK02506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPBK02504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBK0250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1
HSTPBK0250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1
HSTPBK0250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1
HSTPBK025050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1
HSTPBK025025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1
HSTPBL02506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPBL02504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBL0250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1
HSTPBL0250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1
HSTPBL0250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1
HSTPBL025050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1
HSTPBL025025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1
HSTPCL02506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPCL02504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPCL0250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1
HSTPCL0250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1
HSTPCL0250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1
HSTPCL025050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1
HSTPCL025025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1
HSTPGR02506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPGR02504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPGR0250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1
HSTPGR0250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1
HSTPGR0250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1
HSTPGR025050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1
HSTPGR025025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1
HSTPOR02506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPOR02504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPOR0250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1
HSTPOR0250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1
HSTPOR0250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1
HSTPOR025050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1
HSTPOR025025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1
HSTPRD02506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPRD02504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPRD0250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1
HSTPRD0250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1
HSTPRD0250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1
HSTPRD025050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1
HSTPRD025025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
25 Piece Increments	25	25	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
25 Piece Increments	25	-	25	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
25 Piece Increments	25	-	-	25	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
25 Piece Increments	25	-	-	-	25	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
25 Piece Increments	25	-	-	-	-	25	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
25 Piece Increments	25	-	-	-	-	-	25	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red

HS-TP Thin Wall Polyolefin Heat Shrink

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPWH02506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPWH02504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPWH0250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1
HSTPWH0250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1
HSTPWH0250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1
HSTPWH025050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1
HSTPWH025025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1
HSTPYL02506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPYL02504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPYL0250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1
HSTPYL0250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1
HSTPYL0250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1
HSTPYL025050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1
HSTPYL025025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1
HSTPYG02506IPK25	1/4"	0.250	0.079	0.026	600V	Multi-Pack (6" Lengths)	1
HSTPYG02504FPK25EA	1/4"	0.250	0.079	0.026	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPYG0250500FRL	1/4"	0.250	0.079	0.026	600V	500 Foot Reel	1
HSTPYG0250250FRL	1/4"	0.250	0.079	0.026	600V	250 Foot Reel	1
HSTPYG0250100FRL	1/4"	0.250	0.079	0.026	600V	100 Foot Reel	1
HSTPYG025050FRL	1/4"	0.250	0.079	0.026	600V	50 Foot Reel	1
HSTPYG025025FRL	1/4"	0.250	0.079	0.026	600V	25 Foot Reel	1
HSTPMX03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPBK03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPBK03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBK0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1
HSTPBK0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1
HSTPBK0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1
HSTPBK037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1
HSTPBK037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1
HSTPBL03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPBL03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBL0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1
HSTPBL0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1
HSTPBL0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1
HSTPBL037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1
HSTPBL037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1
HSTPCL03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPCL03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPCL0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1
HSTPCL0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1
HSTPCL0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1
HSTPCL037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1
HSTPCL037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
25 Piece Increments	25	-	-	-	-	-	-	25	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
25 Piece Increments	25	-	-	-	-	-	-	-	25	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 pack of 25 pieces	25	-	-	-	-	-	-	-	-	25	Yellow/Green
25 Piece Increments	25	-	-	-	-	-	-	-	-	25	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
25 Piece Increments	25	25	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
25 Piece Increments	25	-	25	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
25 Piece Increments	25	-	-	25	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear

HS-TP Thin Wall Polyolefin Heat Shrink

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPGR03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPGR03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPGR0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1
HSTPGR0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1
HSTPGR0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1
HSTPGR037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1
HSTPGR037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1
HSTPOR03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPOR03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPOR0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1
HSTPOR0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1
HSTPOR0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1
HSTPOR037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1
HSTPOR037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1
HSTPRD03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPRD03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPRD0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1
HSTPRD0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1
HSTPRD0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1
HSTPRD037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1
HSTPRD037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1
HSTPWH03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPWH03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPWH0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1
HSTPWH0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1
HSTPWH0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1
HSTPWH037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1
HSTPWH037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1
HSTPYL03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPYL03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPYL0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1
HSTPYL0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1
HSTPYL0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1
HSTPYL037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1
HSTPYL037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1
HSTPYG03756IPK25	3/8"	0.375	0.118	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPYG03754FPK25EA	3/8"	0.375	0.118	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPYG0375200FRL	3/8"	0.375	0.118	0.030	600V	200 Foot Reel	1
HSTPYG0375100FRL	3/8"	0.375	0.118	0.030	600V	100 Foot Reel	1
HSTPYG037550FRL	3/8"	0.375	0.118	0.030	600V	50 Foot Reel	1
HSTPYG037525FRL	3/8"	0.375	0.118	0.030	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
25 Piece Increments	25	-	-	-	25	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
25 Piece Increments	25	-	-	-	-	25	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
25 Piece Increments	25	-	-	-	-	-	25	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
25 Piece Increments	25	-	-	-	-	-	-	25	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
25 Piece Increments	25	-	-	-	-	-	-	-	25	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 pack of 25 pieces	25	-	-	-	-	-	-	-	-	25	Yellow/Green
25 Piece Increments	25	-	-	-	-	-	-	-	-	25	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green

HS-TP Thin Wall Polyolefin Heat Shrink

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPMX05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPBK05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPBK05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBK0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1
HSTPBK0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1
HSTPBK050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1
HSTPBK050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1
HSTPBL05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPBL05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPBL0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1
HSTPBL0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1
HSTPBL050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1
HSTPBL050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1
HSTPCL05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPCL05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPCL0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1
HSTPCL0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1
HSTPCL050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1
HSTPCL050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1
HSTPGR05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPGR05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPGR0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1
HSTPGR0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1
HSTPGR050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1
HSTPGR050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1
HSTPOR05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPOR05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPOR0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1
HSTPOR0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1
HSTPOR050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1
HSTPOR050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1
HSTPRD05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPRD05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPRD0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1
HSTPRD0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1
HSTPRD050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1
HSTPRD050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1
HSTPWH05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPWH05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPWH0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1
HSTPWH0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1
HSTPWH050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1
HSTPWH050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
25 Piece Increments	25	25	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
25 Piece Increments	25	-	25	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
25 Piece Increments	25	-	-	25	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
25 Piece Increments	25	-	-	-	25	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
25 Piece Increments	25	-	-	-	-	25	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
25 Piece Increments	25	-	-	-	-	-	25	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
25 Piece Increments	25	-	-	-	-	-	-	25	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White

HS-TP Thin Wall Polyolefin Heat Shrink							
Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPYL05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1
HSTPYL05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPYL0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1
HSTPYL0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1
HSTPYL050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1
HSTPYL050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1
HSTPYG05006IPK25	1/2"	0.500	0.157	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPYG05004FPK25EA	1/2"	0.500	0.157	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	25
HSTPYG0500200FRL	1/2"	0.500	0.157	0.030	600V	200 Foot Reel	1
HSTPYG0500100FRL	1/2"	0.500	0.157	0.030	600V	100 Foot Reel	1
HSTPYG050050FRL	1/2"	0.500	0.157	0.030	600V	50 Foot Reel	1
HSTPYG050025FRL	1/2"	0.500	0.157	0.030	600V	25 Foot Reel	1
HSTPMX06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPBK06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPBK06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPBK0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1
HSTPBK0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1
HSTPBK062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1
HSTPBK062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1
HSTPBL06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPBL06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPBL0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1
HSTPBL0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1
HSTPBL062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1
HSTPBL062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1
HSTPCL06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPCL06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPCL0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1
HSTPCL0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1
HSTPCL062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1
HSTPCL062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1
HSTPGR06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPGR06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPGR0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1
HSTPGR0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1
HSTPGR062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1
HSTPGR062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1
HSTPOR06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPOR06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPOR0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1
HSTPOR0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1
HSTPOR062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1
HSTPOR062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
25 Piece Increments	25	-	-	-	-	-	-	-	25	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 pack of 25 pieces	25	-	-	-	-	-	-	-	-	25	Yellow/Green
25 Piece Increments	25	-	-	-	-	-	-	-	-	25	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
5 pieces in 1 pack	5	5	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
5 pieces in 1 pack	5	-	5	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
5 pieces in 1 pack	5	-	-	5	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
5 pieces in 1 pack	5	-	-	-	5	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
5 pieces in 1 pack	5	-	-	-	-	5	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange

HS-TP Thin Wall Polyolefin Heat Shrink

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPRD06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPRD06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPRD0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1
HSTPRD0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1
HSTPRD062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1
HSTPRD062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1
HSTPWH06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPWH06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPWH0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1
HSTPWH0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1
HSTPWH062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1
HSTPWH062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1
HSTPYL06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPYL06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPYL0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1
HSTPYL0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1
HSTPYL062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1
HSTPYL062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1
HSTPMX07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPBK07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPBK07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPBK0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1
HSTPBK075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1
HSTPBK075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1
HSTPBL07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPBL07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPBL0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1
HSTPBL075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1
HSTPBL075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1
HSTPCL07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPCL07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPCL0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1
HSTPCL075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1
HSTPCL075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1
HSTPGR07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPGR07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPGR0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1
HSTPGR075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1
HSTPGR075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1
HSTPOR07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPOR07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPOR0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1
HSTPOR075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1
HSTPOR075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
5 pieces in 1 pack	5	-	-	-	-	-	5	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
5 pieces in 1 pack	5	-	-	-	-	-	-	5	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
5 pieces in 1 pack	5	-	-	-	-	-	-	-	5	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
5 pieces in 1 pack	5	5	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
5 pieces in 1 pack	5	-	5	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
5 pieces in 1 pack	5	-	-	5	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
5 pieces in 1 pack	5	-	-	-	5	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
5 pieces in 1 pack	5	-	-	-	-	5	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange

HS-TP Thin Wall Polyolefin Heat Shrink							
Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPRD07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPRD07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPRD0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1
HSTPRD075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1
HSTPRD075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1
HSTPWH07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPWH07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPWH0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1
HSTPWH075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1
HSTPWH075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1
HSTPYL07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1
HSTPYL07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPYL0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1
HSTPYL075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1
HSTPYL075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1
HSTPYG07506IPK25	3/4"	0.750	0.236	0.033	600V	Multi-Pack (6" Lengths)	1
HSTPYG07504FPK5EA	3/4"	0.750	0.236	0.033	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPYG0750100FRL	3/4"	0.750	0.236	0.033	600V	100 Foot Reel	1
HSTPYG075050FRL	3/4"	0.750	0.236	0.033	600V	50 Foot Reel	1
HSTPYG075025FRL	3/4"	0.750	0.236	0.033	600V	25 Foot Reel	1
HSTPMX10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1
HSTPBK10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1
HSTPBK10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPBK1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1
HSTPBK100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1
HSTPBK100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1
HSTPBL10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1
HSTPBL10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPBL1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1
HSTPBL100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1
HSTPBL100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1
HSTPCL10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1
HSTPCL10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1
HSTPCL10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPCL1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1
HSTPCL100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1
HSTPCL100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1
HSTPGR10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1
HSTPGR10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPGR1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1
HSTPGR100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1
HSTPGR100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
5 pieces in 1 pack	5	-	-	-	-	-	5	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
5 pieces in 1 pack	5	-	-	-	-	-	-	5	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
5 pieces in 1 pack	5	-	-	-	-	-	-	-	5	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 pack of 25 pieces	25	-	-	-	-	-	-	-	-	25	Yellow/Green
5 pieces in 1 pack	5	-	-	-	-	-	-	-	-	5	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
5 pieces in 1 pack	5	5	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
5 pieces in 1 pack	5	-	5	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
1 pack of 5 pieces	5	-	-	5	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
100 Feet as 1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
50 Feet as 1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
25 Feet as 1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
5 pieces in 1 pack	5	-	-	-	5	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green

HS-TP Thin Wall Polyolefin Heat Shrink

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPOR10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1
HSTPOR10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPOR1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1
HSTPOR100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1
HSTPOR100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1
HSTPRD10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1
HSTPRD10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPRD1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1
HSTPRD100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1
HSTPRD100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1
HSTPWH10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1
HSTPWH10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPWH1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1
HSTPWH100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1
HSTPWH100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1
HSTPYL10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1
HSTPYL10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPYL1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1
HSTPYL100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1
HSTPYL100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1
HSTPYG10006IPK25	1"	1.000	0.315	0.039	600V	Multi-Pack (6" Lengths)	1
HSTPYG10004FPK5EA	1"	1.000	0.315	0.039	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPYG1000100FRL	1"	1.000	0.315	0.039	600V	100 Foot Reel	1
HSTPYG100050FRL	1"	1.000	0.315	0.039	600V	50 Foot Reel	1
HSTPYG100025FRL	1"	1.000	0.315	0.039	600V	25 Foot Reel	1
HSTPBK12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPBK1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1
HSTPBK125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1
HSTPBK125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1
HSTPBL12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPBL1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1
HSTPBL125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1
HSTPBL125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1
HSTPCL12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPCL1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1
HSTPCL125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1
HSTPCL125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1
HSTPGR12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPGR1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1
HSTPGR125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1
HSTPGR125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
5 pieces in 1 pack	5	-	-	-	-	5	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
5 pieces in 1 pack	5	-	-	-	-	-	5	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
5 pieces in 1 pack	5	-	-	-	-	-	-	5	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
5 pieces in 1 pack	5	-	-	-	-	-	-	-	5	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 pack of 25 pieces	25	-	-	-	-	-	-	-	-	25	Yellow/Green
5 pieces in 1 pack	5	-	-	-	-	-	-	-	-	5	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
5 pieces in 1 pack	5	5	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
5 pieces in 1 pack	5	-	5	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
5 pieces in 1 pack	5	-	-	5	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
5 pieces in 1 pack	5	-	-	-	5	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green

HS-TP Thin Wall Polyolefin Heat Shrink

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPOR12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPOR1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1
HSTPOR125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1
HSTPOR125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1
HSTPGR12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPGR1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1
HSTPGR125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1
HSTPGR125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1
HSTPRD12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPRD1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1
HSTPRD125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1
HSTPRD125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1
HSTPWH12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPWH1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1
HSTPWH125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1
HSTPWH125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1
HS1250YLTP4FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5
HS1250YLTP100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1
HS1250YLTP50FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1
HS1250YLTP25FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1
HSTPBK15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPBK1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1
HSTPBK150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1
HSTPBK150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1
HSTPBL15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPBL1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1
HSTPBL150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1
HSTPBL150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1
HSTPCL15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPCL1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1
HSTPCL150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1
HSTPCL150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1
HSTPGR15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPGR1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1
HSTPGR150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1
HSTPGR150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1
HSTPOR15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPOR1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1
HSTPOR150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1
HSTPOR150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1
HSTPRD15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPRD1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1
HSTPRD150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1
HSTPRD150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
5 pieces in 1 pack	5	-	-	-	-	5	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
5 pieces in 1 pack	5	-	-	-	5	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
5 pieces in 1 pack	5	-	-	-	-	-	5	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
5 pieces in 1 pack	5	-	-	-	-	-	-	5	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
5 pieces in 1 pack	5	-	-	-	-	-	-	-	5	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
5 pieces in 1 pack	5	5	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
5 pieces in 1 pack	5	-	5	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
5 pieces in 1 pack	5	-	-	5	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
5 pieces in 1 pack	5	-	-	-	5	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
5 pieces in 1 pack	5	-	-	-	-	5	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
5 pieces in 1 pack	5	-	-	-	-	-	5	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red

HS-TP Thin Wall Polyolefin Heat Shrink							
Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPWH15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPWH1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1
HSTPWH150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1
HSTPWH150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1
HSTPYL15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPYL1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1
HSTPYL150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1
HSTPYL150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1
HSTPYG15004FPK5EA	1-1/2"	1.500	0.512	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPYG1500100FRL	1-1/2"	1.500	0.512	0.045	600V	100 Foot Reel	1
HSTPYG150050FRL	1-1/2"	1.500	0.512	0.045	600V	50 Foot Reel	1
HSTPYG150025FRL	1-1/2"	1.500	0.512	0.045	600V	25 Foot Reel	1
HSTPBK20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPBK2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1
HSTPBK200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1
HSTPBK200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1
HSTPBL20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPBL2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1
HSTPBL200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1
HSTPBL200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1
HSTPCL20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPCL2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1
HSTPCL200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1
HSTPCL200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1
HSTPGR20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPGR2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1
HSTPGR200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1
HSTPGR200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1
HSTPOR20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPOR2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1
HSTPOR200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1
HSTPOR200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1
HSTPRD20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPRD2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1
HSTPRD200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1
HSTPRD200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1
HSTPWH20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPWH2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1
HSTPWH200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1
HSTPWH200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1
HSTPYL20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5
HSTPYL2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1
HSTPYL200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1
HSTPYL200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1
HSTPBK30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPBK300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1
HSTPBK300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1
HSTPBL30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPBL300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1
HSTPBL300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
5 pieces in 1 pack	5	-	-	-	-	-	-	5	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
5 pieces in 1 pack	5	-	-	-	-	-	-	-	5	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
5 pieces in 1 pack	5	-	-	-	-	-	-	-	-	5	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
5 pieces in 1 pack	5	5	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
5 pieces in 1 pack	5	-	5	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
5 pieces in 1 pack	5	-	-	5	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
5 pieces in 1 pack	5	-	-	-	5	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
5 pieces in 1 pack	5	-	-	-	-	5	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
5 pieces in 1 pack	5	-	-	-	-	-	5	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
5 pieces in 1 pack	5	-	-	-	-	-	-	5	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
5 pieces in 1 pack	5	-	-	-	-	-	-	-	5	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
2 pieces in 1 pack	2	2	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
2 pieces in 1 pack	2	-	2	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue

HS-TP Thin Wall Polyolefin Heat Shrink

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min. Order Quantity
HSTPCL30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPCL300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1
HSTPCL300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1
HSTPGR30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPGR300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1
HSTPGR300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1
HSTPOR30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPOR300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1
HSTPOR300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1
HSTPRD30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPRD300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1
HSTPRD300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1
HSTPWH30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPWH300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1
HSTPWH300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1
HSTPYL30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPYL300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1
HSTPYL300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1
HSTPBK40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPBK400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1
HSTPBK400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1
HSTPBL40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPBL400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1
HSTPBL400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1
HSTPCL40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPCL400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1
HSTPCL400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1
HSTPGR40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPGR400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1
HSTPGR400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1
HSTPOR40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPOR400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1
HSTPOR400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1
HSTPRD40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPRD400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1
HSTPRD400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1
HSTPWH40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPWH400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1
HSTPWH400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1
HSTPYL40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2
HSTPYL400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1
HSTPYL400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1

Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Color
		Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
2 pieces in 1 pack	2	-	-	2	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
2 pieces in 1 pack	2	-	-	-	2	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
2 pieces in 1 pack	2	-	-	-	-	2	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
2 pieces in 1 pack	2	-	-	-	-	-	2	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
2 pieces in 1 pack	2	-	-	-	-	-	-	2	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
2 pieces in 1 pack	2	-	-	-	-	-	-	-	2	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
2 pieces in 1 pack	2	2	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
1 Reel	1	1	-	-	-	-	-	-	-	-	Black
2 pieces in 1 pack	2	-	2	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
2 pieces in 1 pack	2	-	-	2	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
2 pieces in 1 pack	2	-	-	-	2	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
1 Reel	1	-	-	-	1	-	-	-	-	-	Green
2 pieces in 1 pack	2	-	-	-	-	2	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
2 pieces in 1 pack	2	-	-	-	-	-	2	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
1 Reel	1	-	-	-	-	-	1	-	-	-	Red
2 pieces in 1 pack	2	-	-	-	-	-	-	2	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
1 Reel	1	-	-	-	-	-	-	1	-	-	White
2 pieces in 1 pack	2	-	-	-	-	-	-	-	2	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow



hubbell.com/burndy/en

Contact a Sales Representative for Ordering Details



A proud member of the Hubbell family.

www.hubbell.com/burndy | Customer Service 1-800-346-4175
International 603-647-5299 | Canada 1-800-465-7051

©2023 Burndy. All rights reserved.
Hubbell and the Hubbell logo are registered trademarks
or trademarks of Hubbell Incorporated.
All other trademarks are the property of their respective owners.

LI-BURC-Mult-BR-EN-00576