

NEW PATRIOT® PAT444S

VERSATILE 11-TON DIELESS C-HEAD




Connections are UL Listed to
UL 486A-486B on Copper & Aluminum
terminals and splices;

Also, comply with
ANSI C119.4 on YDS-RL Splices
(ACSR, ACC, AAC, ACAR)
Other BURNDY splice families
coming soon!

Features & Benefits

- New C-Head Style for easy access and increased flexibility
- Dieless System with Range Taking Capability
- For Use On:
 - #4 AWG - 1000 kcmil Copper & Aluminum;
 - #4 AWG - 556.6 kcmil ACSR, AAC, AAAC, ACAR
(Full Tension Overhead Splices)
- 355° Head rotation
- Ergonomically balanced
- **Multi-Ah Capability: EP Enhanced Power** labeled tools accept 2.0Ah to 6.0Ah 18V Makita Lithium-ion batteries
- 3.0Ah and 5.0Ah versions available
- Kits come complete with 2 batteries, charger, lanyard and polymer carrying case

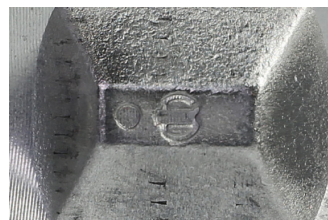

Unique 444S Crimp
Embossment

Customer Service 1-800-346-4175 | Tool Service Center 1-800-426-8720 | Technical Services 1-800-451-4956 | www.burndy.com



Connecting Power to Your World®

