

Not a Chip off the Old Block!


VERSIPOLE™ Configurable Power Distribution Blocks Product Line Expansion

Features & Benefits


- 600 Volt Rated
- Listed to UL1953 (File #E74460)
- Rated for use with both code and flex conductor without requiring ferrules
- AL9CU dual rated for use with copper and aluminum conductors
- Range taking conductor ports will accommodate wire sizes up to 535 DLO and can support up to 5 primary conductors (run side) and up to 24 taps for secondary circuits (tap side)
- High Short-Circuit Current Rating up to 100kA with proper fusing
- Bases and side barriers are made of glass-reinforced nylon 6/6 for extra durability and excellent insulating properties; these carry a UL94 flammability rating of V0

Markets


- Commercial
- Industrial
- Construction
- MRO

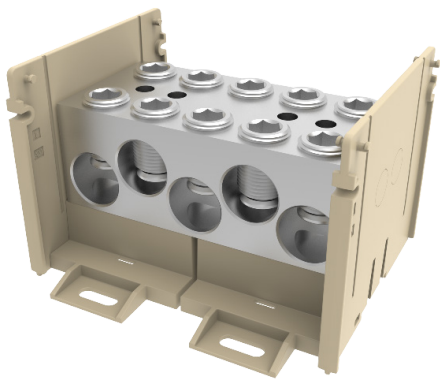

Double-Wide

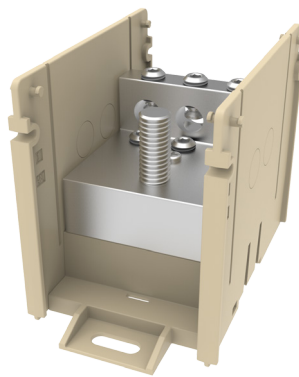

Box-to-Stud

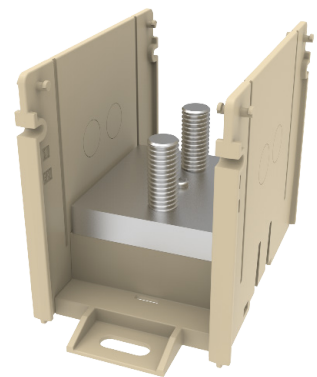

Stud-to-Stud

Customer Service 1-800-346-4175 | Tool Service Center 1-800-426-8720 | Technical Services 1-800-451-4956 | www.burndy.com