


PRODUCT BULLETIN

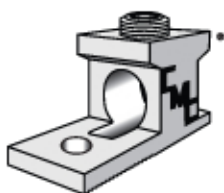

**CONNECTOR
MANUFACTURING
COMPANY**

SUBMERSIBLE EXTENDED SPLICE



TYPE **ESC** Mechanical Underground Cable Repair Splice

- Dual rated connector for aluminum or copper conductors.
- Cable repair made easy - only a 5/16 Hex Wrench is needed to install this mechanical splice.
- Insulation is electrical grade PVC.
- Boots are watertight EPDM rubber.
- Repairs 350 kcmil down to #6 wire sizes.
- For installation CMC recommends the use of an insulated Allen Wrench.

Connector Manufacturing Company

3501 Symmes Road

Hamilton, Ohio 45015-1369


Phone: 513-860-4455

Fax: 800-846-0787

www.cmclugs.com




PRODUCT BULLETIN

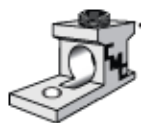

**CONNECTOR
MANUFACTURING
COMPANY**

SUBMERSIBLE EXTENDED SPLICE

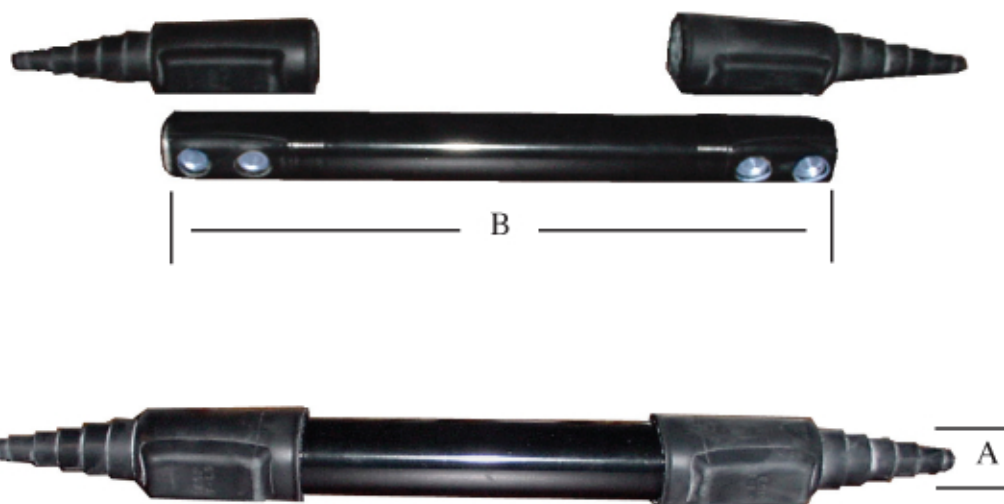

Catalog Number	Conductor Range	Hex	A Inches	B Inches
	AWG			
ESC350-121	350-6	5/16	1.38	12

Note: Standard length is 12 inches. Available in 6 inch increments up to 48 inches. Includes watertight EPDM insulating sleeve.