
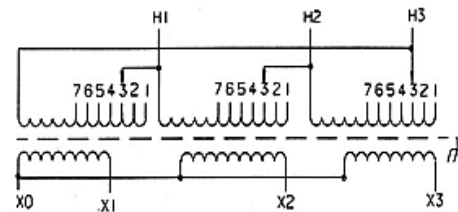



REVISIONS

NOTES:

1. Dry Type
2. Class AA
3. Ventilated
4. Paint - #61 ANSI

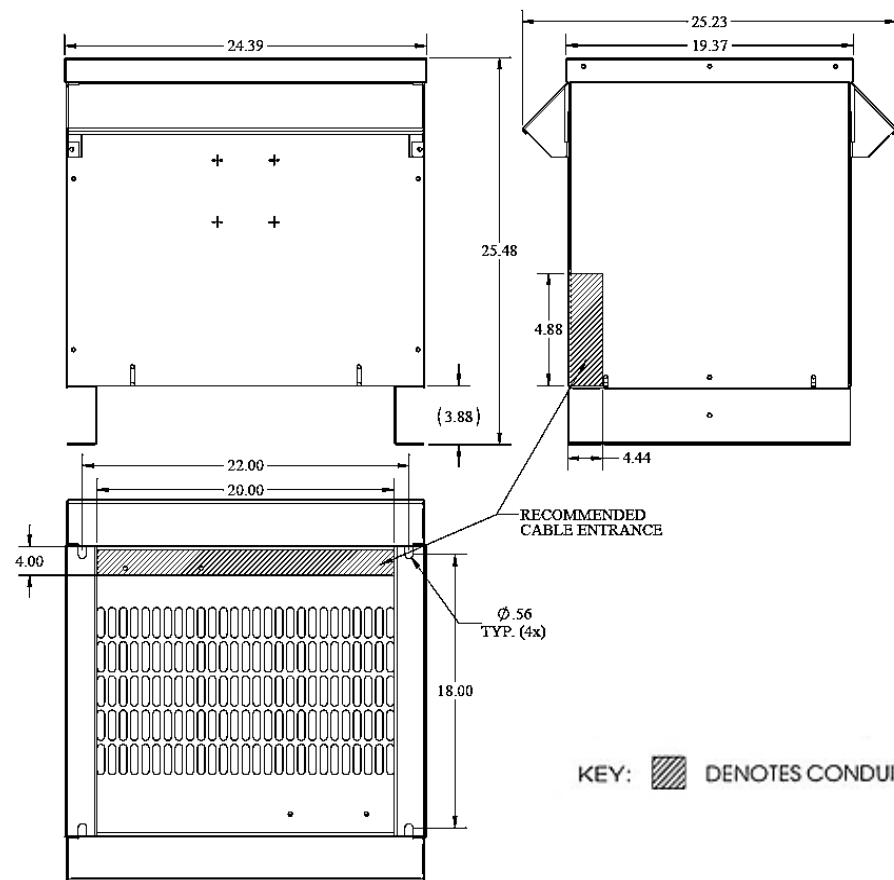

PRIMARY VOLTS	%	CONNECT LEADS TO TAP NO.
504	105	1
492	102.5	2
480	100	3
468	97.5	4
456	95	5
444	92.5	6
432	90	7

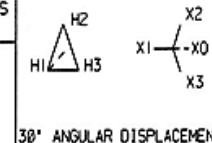

PRIMARY LINES TO H1-H2-H3
SECONDARY LINES TO X0-X1-X2-X3

KEY: DENOTES CONDUIT AREAS

NOTE: PRIMARY AND SECONDARY BUS AREA IN FRONT OF CASE.



KVA	CATALOG NUMBER	VOLTAGE		K-FACTOR	WEIGHT	PHASE	FREQUENCY
		HIGH	LOW				
30	T3030K0013BK13SF	480Δ	208Y/120	13	500 Lbs	3φ	60Hz
Temp Rise:	115°C	TYPICAL PERFORMANCE DATA				Typical Efficiency @ 35%	
Insulation:	220°C					Regulation @ 100% PF	Standards:
NEMA ST20 Standard:	45 dB	Approvals:	DOE-2016	Impedance:	Enclosure:	3R	100% Load (Typ) Load Losses (I ² R)
Electrostatic Shield:	YES					Total Load Losses:	

DATE: 25-Jan-16

TYPE NO:

CASE 2

Meets US DOE 2016 Efficiency