



BRYANT® Metal Raceway

HBL500 and HBL750 Series Raceway

HBL500 Series	Length	Color	Catalog Number
Single Channel	5 Ft.	Ivory	HBL5005IV
Single Channel	10 Ft.	Ivory	HBL50010IV
Single Channel	10 Ft.	White	HBL50010W

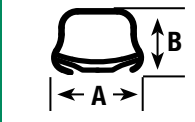

A: .76" (19.3)
B: .53" (13.5)

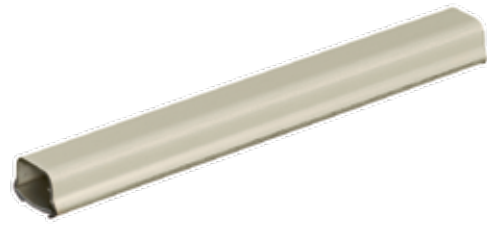

HBL750 Series	Length	Color	Catalog Number
Single Channel	5 Ft.	Ivory	HBL7505IV
Single Channel	10 Ft.	Ivory	HBL75010IV
Single Channel	10 Ft.	White	HBL75010W



A: .76" (19.3)
B: .85" (21.6)



Note: Suffix IV for Ivory,
W for White.

Switch and Receptacle Boxes

Switch & Receptacle Box	Shallow Switch & Receptacle Box	Deep Switch & Receptacle Box	Extra Deep Switch & Receptacle Box
1 Gang HBL5748IV HBL5748W 2 Gang HBL57482IV HBL57482W 3 Gang HBL57483IV HBL57483W 4 Gang HBL57484IV 5 Gang HBL57485IV 6 Gang HBL57486IV	1 Gang HBL5747IV HBL5747W 2 Gang HBL57472IV HBL57472W 3 Gang HBL57473IV	1 Gang HBL5744SIV HBL5744SW 2 Gang HBL5744S2IV HBL5744S2W 3-Gang HBL5744S3IV	1 Gang HBL5744IV HBL5744W 2 Gang HBL57442IV HBL57442W 3 Gang HBL57443IV

Specialty Boxes

Extension Box	Utility Box	Blank Extension Box	Combination Switch & Receptacle Box	Distribution Box	Alarm Device Box	Extra Deep Alarm Device Box
HBL5751IV (Depth 1.375") HBL5751W (Depth 1.375") HBL5751AIV (Depth 1.75") HBL5751AW (Depth 1.75")	HBL57242IV HBL57242W	HBL5760IV	HBL5745IV HBL5745W	HBL5735IV	HBL5752IV (Ivory) HBL5752R (Red)	HBL5753IV (Ivory) HBL5753R (Red)

Round Boxes

Blank Cover	Extension Box with Open Base	Fixture Box with Solid Base	Fanbox with Solid Base	Round Box for Audible Alarms
HBL5736IV HBL5736W	HBL5737IV (Dia. 4 3/8") HBL5737W (Dia. 4 3/8") HBL5737AIV (Dia. 5 1/2") HBL5737AW (Dia. 5 1/2") HBL5739AIV (Dia. 6 3/8")	HBL5738IV (Dia. 4 3/8") HBL5738W (Dia. 4 3/8") HBL5738AIV (Dia. 5 1/2") HBL5738AW (Dia. 5 1/2") HBL5739IV (Dia. 6 3/8") HBL5739W (Dia. 6 3/8")	HBL5738AFIV HBL5738AFW	HBL5739AABIV HBL5739AABW

Tools and Accessories

Cutter	Replacement Blade	Bender	Ivory Touch-Up Pen
HBL500 Series HBL605CUT HBL750 Series HBL607CUT	HBL605K HBL607K	HBL600B HBL600B	HBLIWEP HBLIWEP

Fittings


Series	90° Flat Elbow	45° Flat Elbow	Internal Elbow	External Elbow	Bushing	Mounting Strap	Connection Cover	Wiremold® to Bryant Transition Fitting
HBL500 HBL750	HBL511IV HBL511W HBL711IV HBL711W	HBL512IV HBL712IV	HBL517IV HBL517W HBL717IV HBL717W	HBL518IV HBL518W HBL718IV HBL718W	HBL502B HBL702B	HBL504IV HBL704IV HBL704W	HBL506IV HBL706IV HBL706W	HBL500TFIV HBL750TFIV
Series	Tee Fitting	Internal Twisted Elbow (Left)	Internal Twisted Elbow (Right)	Corner Box	Elbow Box Connector	Elbow Conduit Connector		
HBL500/HBL750	HBL5715IV HBL5715W	HBL5711LHIV HBL5711LHW	HBL5711RHIV HBL5711RHW	HBL5719IV HBL5719W	HBL5783IV	HBL5784IV		
Series	Adjustable Offset Connector	Entrance End Connector	Combination Connector	Armored Cable Connector	Box Connector Male	Box Connector Female		
HBL500/HBL750	HBL5786IV HBL5786W	HBL5786AIV HBL5786AW	HBL5785IV HBL5785W	HBL5790B	HBL5781 (1/2") HBL5781A (3/4")	HBL5782C (1/2") HBL5782A (3/4")		
Series	Ground Clamp	Ground Clamp	Coupling	Support Clip	Flexible Section			
HBL500/HBL750	HBL5709	HBL5709GC	HBL5701C	HBL5703IV HBL5703W	HBL5700FIV HBL5700FW			

HBL2000 Series Raceway


Color	5 Ft. Base & Cover
Ivory	HBL2000BCIV
Gray	HBL2000BCGY

Color	5 Ft. Base
Ivory	HBL2000B5IV
Gray	HBL2000B5GY

Color	5 Ft. Cover
Ivory	HBL2000CIV
Gray	HBL2000CGY

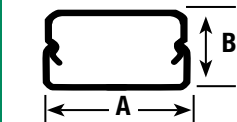

A: 1.31" (33.28)
B: .83" (21.1)

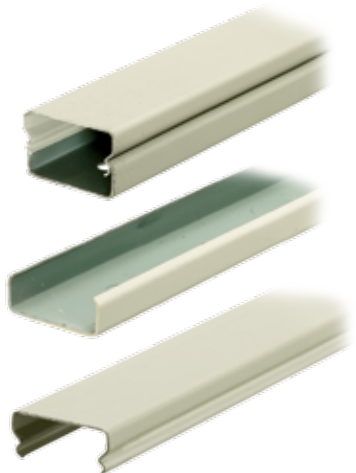

Device Boxes

Color	1-Gang Device Box	2-Gang Device Box
Ivory	HBL2048IV	HBL20482IV
Gray	HBL2048GY	HBL20482GY


Tools and Accessories

Cutter	Replacement Blade	Touch-Up Pen
HBL620C	HBL620BCK	HBLIWEP (Ivory) HBLGWEP (Gray)

Fittings

Color	90° Flat Elbow	Tee Fitting	External Corner Coupling	Internal Corner Coupling	Cover Clip	Entrance End Fitting	Large Capacity Entrance End Fitting	Blank End Fitting
Ivory Gray	HBL2011IV HBL2011GY	HBL2015IV HBL2015GY	HBL2018CIV HBL2018CGY	HBL2017TC (Galvanized Steel)	HBL2006IV HBL2006GY	HBL2010A2IV HBL2010A2GY	HBL2010A3IV HBL2010A3GY	HBL2010BIV HBL2010BGY
Color	Flush Plate Adaptor	Side Reducing Connector	Wiremold® to Bryant Transition Fitting	Wire Clip	Coupling	Supporting Clip	Ground Clamp	
Ivory Gray	HBL2051HIV HBL2051HGY	HBL2089IV	HBL2000TFIV HBL2000TFGY	HBL2000WCA (Galvanized Steel)	HBL2001C (Galvanized Steel)	HBL2003SC (Galvanized Steel)	HBL2009GC (Galvanized Steel)	

Metal PlugTrak®

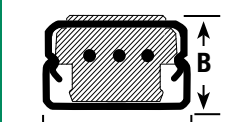

A: 1.31" (33.28)
B: .83" (21.1)

Each PlugTrak® is supplied with (2) HBL2010BIV or (2) HBL2010BGY blank end fittings and (1) HBL2001C coupling. Outlets match raceway color.

*For Tamper-Resistant, add the suffix TR. For example: HBL20GB306IVTR



3 Ft. Metal PlugTrak®

Ivory	Gray	Amp	Circuits	# Single Receptacle	Recept. Spacing	Available in Tamper-Resistant*
HBL20GB306IV	HBL20GB306GY	15	Single	6	6"	✓
HBL20IG306IV	HBL20IG306GY	15	IG/Single	6	6"	
HBL24GB306IV	HBL24GB306GY	20	Single	6	6"	✓

5 Ft. Metal PlugTrak®

Ivory	Gray	Amp	Circuits	# Single Receptacle	Recept. Spacing	Available in Tamper-Resistant*
HBL20GB506IV	HBL20GB506GY	15	Single	10	6"	
HBL20GB512IV	HBL20GB512GY	15	Single	5	12"	✓
HBL20GBA512IV	HBL20GBA512GY	15	Two	5	12"	
HBL20IG512IV	HBL20IG512GY	15	IG/Single	5	12"	
HBL24GB506IV	HBL24GB506GY	20	Single	10	6"	
HBL24GB512IV	HBL24GB512GY	20	Single	5	12"	✓
HBL24GBA512IV	HBL24GBA512GY	20	Two	5	12"	

6 Ft. Metal PlugTrak®

Ivory	Gray	Amp	Circuits	# Single Receptacle	Receptacle Spacing
HBL20GB606IV	HBL20GB606GY	15	Single	12	6"
HBL20GB609IV	HBL20GB609GY	15	Single	8	9"
HBL20GB612IV	HBL20GB612GY	15	Single	6	12"
HBL20GB618IV	HBL20GB618GY	15	Single	4	18"
HBL20GBA609IV	HBL20GBA609GY	15	Two	8	9"
HBL20GBA612IV	HBL20GBA612GY	15	Two	6	12"
HBL20GBA618IV	HBL20GBA618GY	15	Two	4	18"
HBL20IG606IV	HBL20IG606GY	15	IG/Single	12	6"
HBL24GB606IV	HBL24GB606GY	20	Single	12	6"
HBL24GB612IV	HBL24GB612GY	20	Single	6	12"
HBL24GB618IV	HBL24GB618GY	20	Single	4	18"
HBL24GBA612IV	HBL24GBA612GY	20	Two	6	12"
HBL24GBA618IV	HBL24GBA618GY	20	Two	4	18"

Painted Steel Plates

Gang	Color	Switch	Duplex	Rectangular	Blank	Single Receptacle (1.41 I.D.)
One-Gang	Almond Gray	SP1AL SP1G	SP8AL SP8G	PHPS1AL PHPS1G	SP14AL SP14G	SP7AL SP7G
Two-Gang	Almond Gray	SP2AL SP2G	SP82AL SP82G	PHPS2AL PHPS2G	SP24AL SP24G	—
Three-Gang	Almond	SP3AL	SP83AL	PHPS3AL	SP34AL	—
Four-Gang	Almond	SP4AL	—	PHPS4AL	—	—
Five-Gang	Almond	SP5AL	—	PHPS5AL	—	—
Six-Gang	Almond	SP6AL	—	PHPS6AL	—	—

Combination Plates

Description	Color	Catalog #	Description	Color	Catalog #
One Switch, One Duplex	Almond Gray	SP18AL SP18G	One Switch, One Rectangular	Almond Gray	PJS126AL PJS126G
Two Switch, One Duplex	Almond Gray	SP28AL SP28G	Two Switch, One Rectangular	Gray	PJS226G

Communication Outlet Plates

Description	Color	Catalog Number
One-Gang, Two-Port Decorator Frame	Almond Gray White	NS612AL NS612GY NS612W
One-Gang, Three-Port Decorator Frame	Almond Gray White	NS613AL NS613GY NS613W
One-Gang, Four-Port Decorator Frame	Almond Gray White	NS614AL NS614GY NS614W
One-Gang, Six-Port Decorator Frame	Almond Gray White	NS616AL NS616GY NS616W
One-Gang Adapter, .406" Dia. Hole	Almond Gray White	NS621AL NS621GY NS621W
One-Gang Adapter, Blank	Almond Gray White	NS620AL NS620GY NS620W

Comm/Data and Audio/Video

Bryant's Audio/Video Connectors allow custom creation of multimedia outlets and workstations while maintaining a decorative look. For more information related to Bryant's broad offering of accessory jacks, please contact Bryant Customer Service at 800-323-2792.