



LARGE CAPACITY BOX w/STUD MOUNT BRACKET



260H



UL US LISTED
Outlet Box
731A

Application

Large capacity boxes used for audio, video, data and power applications. Provides ample space for Cat 6A and fiber optical cable bends. Stud mounting bracket for quick and easy installation included. Far side support to accommodate various stud wall depths. Extra large knockouts for pulling pre-terminated cables.

Features

- 4-11/16" square, 3-1/4" deep box
- Accepts standard 4-11/16" square covers
- "H" bracket for mounting to metal or wood studs
- Far-Side Box Support for stud size up to 6 inches
- Includes knockouts - 1/2" through 2"
- Three pre-installed ground screws
- Raised ground screw surface
- Accepts UL Listed Voltage Partition - Cat. No. 981
- cULus Listed

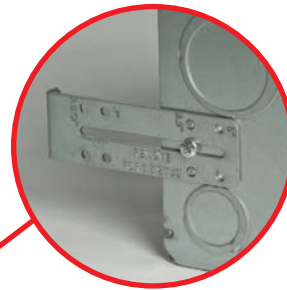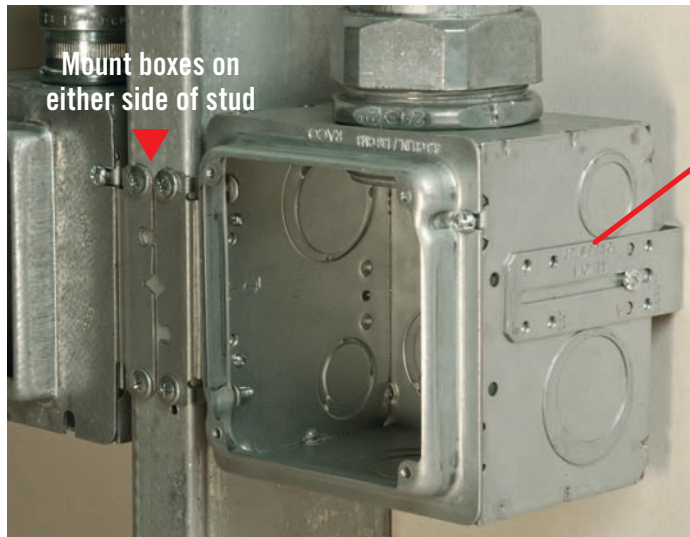

Robust Far-side support - 3-5/8" to 6" metal and wood studs



Catalog No.	Description	Carton Qty.	Cu. In. Capacity	Knockouts Sides	Knockouts Back	Unit Carton 1 of 5
260H	Contractor Pack	10	66.0	2, 1/2"-3/4" TKO; 2, 1" 1-1/4" TKO; 2, 1" - 2" Conc. KO	2, 3/4" - 1 TKO; 2, 1/2"	50050169500502



As Shipped



Far-side support adjusted and bracket installed



Use standard 4-11/16" covers and large KO for data outlet applications



Use with adapter ring for professional looking installation of fire alarm notification appliances



Use standard 4-11/16" sq. covers and 981 partition for power and data in same box



Mount box and run conduit before mud ring is attached



UL Listed Voltage Partition

Catalog No. 981 -

Compatible with raised covers:

1/2", 3/4", and 1-1/4"

Compatible with raised covers:

260, 260H, and 263. Available in

Contractor Packs/25 pcs.