

Government Education Facility Maintenance

Hubbell Wiring Device-Kellems and Hubbell Lighting, Inc. have the power and lighting control solutions for :

- ✓ Governments Facilities
- ✓ Local & State Municipalities
- ✓ K-12 Schools
- ✓ Colleges and Universities

We offer a full range of products for efficient maintenance and retrofit solutions including:

HUBBELL® Wiring Device-Kellems

- ✓ Wiring Devices
- ✓ Occupancy Sensors
- ✓ Voice-Data-Video

HUBBELL Lighting

- ✓ Indoor & Outdoor Lighting
- ✓ Sports Lighting
- ✓ Life Safety Lighting

Hubbell has provided quality, innovative solutions to the government and educational markets for over 100 years.



Industrial Grade Receptacles		HBL® Extra Heavy Duty Spec. Grade		Hubbell-PRO® Heavy Duty Specification Grade					
									
		Flush, Nylon Face, Back and Side Wired		Finder Groove Face Back and Side Wired		Smooth, Nylon Face Back and Side Wired		Isolated Ground Finder Groove Face	
NEMA	Color	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
15A 125V 	Brown Ivory White Orange	HBL5262 HBL5262I HBL5262W —	0736064 0736071 0736078 —	5262B 5262I 5262W —	0731908 0731912 0731919 —	5252AB 5252AI 5252AW —	0731853 0731856 0731860 —	— CR5252IGI CR5252IGW CR5252IG	— 0732748 0732750 0732745
20A 125V 	Brown Ivory White Orange	HBL5362 HBL5362I HBL5362W —	0736169 0736177 0736185 —	5362B 5362I 5362W —	0731932 0731939 0731945 —	5352AB 5352AI 5352AW —	0731923 0731926 0731930 —	— CR5352IGI CR5352IGW CR5352IG	— 0732770 0732772 0732766

Commercial Grade Receptacles		Commercial Specification Grade				USB Charger Receptacle		GFCI	
									
		Smooth, Nylon Face Side Wired Only		Isolated Ground Smooth Face, Side Wired Only		Tamper-Resistant Receptacle, 2 USB Type 2.0 Ports, 3A 5V DC		Flush Nylon Face, Back and Side Wired, Self-Grounding Staple	
NEMA	Color	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell/Bryant	Fastenal
15A 125V 	Brown Gray Ivory White Orange	CR15 CR15GRY CR15I CR15WHI —	0732650 0732663 0732669 0732687 —	— — — — IG15CR	— — — — —	USB15X2 USB15X2GY USB15X2I USB15X2W —	0774434 0774439 0774435 0774436 —	GF15LA GF15GYLA GF15ILA GF15WLA —	0733608 0733595 0733601 0733630 —
20A 125V 	Brown Gray Ivory White Orange	CR20 CR20GRY CR20I CR20WHI —	0732697 0732710 0732716 0732734 —	— — — — IG20CR	— — — — —	USB20X2 USB20X2GY USB20X2I USB20X2W —	0774440 0774445 0774441 0774442 —	GF20LA GF20GYLA GF20ILA GF20WLA —	0733661 0733649 0733655 0733683 —

4-PLEX Receptacles		4-PLEX® Spec. Grade		Accessories			
							
		Heavy Duty Impact Housing		4-Plex Adapter Plates for 1 and 2-Gang		4-Plex Portable Box 4-Inch Sq. Box with Cord Grip	
NEMA	Color	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
15A 125V 	Brown Gray Ivory White	HBL415 HBL415GY HBL415I HBL415W	0735548 0735550 0735555 0735558	HBL4AP HBL4APGY HBL4API HBL4APW	0735915 0735917 0735918 0735921	— — HBL4PBI —	— — 0735933 —
20A 125V 	Brown Gray Ivory White	HBL420 HBL420GY HBL420I HBL420W	0735562 0735585 0735593 0735610	HBL4AP HBL4APGY HBL4API HBL4APW	0735915 0735917 0735918 0735921	— — HBL4PBI —	— — 0735933 —

Industrial Grade Switches 120-277V AC		HBL® Extra Heavy Duty Specification Grade, Back and Side Wired							
		Single-Pole		Double Pole		Three Way		Four Way	
Amperage	Color	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
15A	Brown Ivory White	HBL1201	0734276	HBL1202	0734284	HBL1203	0734287	HBL1204	0734293
		HBL1201I	0734278	HBL1202I	0734285	HBL1203I	0734289	HBL1204I	0734295
		HBL1201W	0734283	—	—	HBL1203W	0777600	HBL1204W	0777625
20A	Brown Ivory White	HBL1221	0734300	HBL1222	0734316	HBL1223	0734324	HBL1224	0734337
		HBL1221I	0734304	HBL1222I	0734318	HBL1223I	0734327	HBL1224I	0734340
		HBL1221W	0734315	HBL1202W	0734323	HBL1223W	0734336	HBL1224W	0734345

Industrial Grade Locking Switches 120-277V AC		HBL® Extra Heavy Duty Locking Switches, Back and Side Wired							
		Single-Pole		Double Pole		Three Way		Four Way	
Amperage	Key Guide	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
Locking Fork Key (Replacement Key HBL1209-Fastenal # 0734297)									
15A	Black	HBL1201L	0734280	HBL1202L	#N/A	HBL1203L	0734291	HBL1204L	#N/A
20A	Black	HBL1221L	0734308	HBL1222L	0734319	HBL1223L	0734330	HBL1224L	0734341
Locking Barrel Key (Replacement Key HBL1209RKL-Fastenal # 0734928)									
20A	Chrome	HBL1221RKL	0734314	HBL1222RKL	#N/A	HBL1223RKL	0734335	HBL1224RKL	#N/A

Industrial Grade Switches 120-277V AC		Hubbell-PRO® Heavy Duty Specification Grade, Back and Side Wired							
		Single-Pole		Double Pole		Three Way		Four Way	
Amperage	Color	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
15A	Brown Ivory White	1201B	0731711	—	—	1203B	0731717	—	—
		1201I	0731714	—	—	1203I	0731720	—	—
		1201W	0731716	—	—	1203W	0731722	—	—
20A	Brown Ivory White	1221B	0731723	1222B	0731730	1223B	0731736	1224B	0731742
		1221I	0731726	1222I	0731733	1223I	0731739	1224I	0731745
		1221W	0731728	1222W	0731735	1223W	0731741	1224W	0731748

Commercial Grade Switches 120-277V AC		Commercial Specification Grade, Back and Side Wired							
		Single-Pole		Double Pole		Three Way		Four Way	
Amperage	Color	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
15A	Brown Ivory White	CSB115	0732918	CSB215	0732934	CSB315	0732950	CSB415	0732966
		CSB115I	0732921	CSB215I	0732937	CSB315I	0732953	CSB415I	0732969
		CSB115W	0732924	CSB215W	0732940	CSB315W	0732956	CSB415W	0732972
20A	Brown Ivory White	CSB120	0732925	CSB220	0732941	CSB320	0732957	CSB420	0732973
		CSB120I	0732929	CSB220I	0732945	CSB320I	0732961	CSB420I	0732977
		CSB120W	0732933	CSB220W	0732949	CSB320W	0732965	CSB420W	0732981

Straight Blade Plugs and Connectors

Insulgrip®

Valise®

Watertight



NEMA	Device	Black & White Nylon .230"-.720" (5.8-18.3)		Yellow Nylon .220"-.660" (5.6-16.8)		Black Nylon .220"-.660" (5.6-16.8)		Yellow Thermoplastic Elastomer	
		Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
15A 125V  2-Pole 3-Wire	Plug Connector Angled Plug Flanged Inlet Flanged Receptacle	HBL5266C HBL5269C HBL5266CA HBL5279C HBL5278C	0736082 0736086 0736083 0736091 0736089	HBL5965VY HBL5969VY	0736380 0736388	HBL5965VBLK HBL5969VBLK	0736378 0736386	14W47H 15W47H	0747822 0747827
20A 125V  2-Pole 3-Wire	Plug Connector Angled Plug Flanged Inlet Flanged Receptacle	HBL5366C HBL5369C HBL5366CA HBL5379C HBL5378C	0736193 0736195 0736194 0736201 0736200	HBL5364VY HBL5369VY	0736191 0736198	HBL5364VBK HBL5369VBK	0736189 0736387	14W33H 15W33H	0747821 0747826

Twist-Lock® Locking Plugs and Connectors

Insulgrip®



NEMA	Device	Black & White Nylon		NEMA	Device	Black & White Nylon	
		Hubbell	Fastenal			Hubbell	Fastenal
15A 125V  2-Pole 3-Wire	Plug Connector Receptacle Flanged Inlet Flanged Receptacle	HBL4720C HBL4729C HBL4710 HBL4716C HBL4715C	0735803 0735809 0735766 0735791 0735785	30A 125V  2-Pole 3-Wire	Plug Connector Receptacle Flanged Inlet Flanged Receptacle	HBL2611 HBL2613 HBL2610 HBL2615 HBL2616	0734971 0734978 0734965 0734984 0734987
20A 125V  2-Pole 3-Wire	Plug Connector Receptacle Flanged Inlet Flanged Receptacle	HBL2311 HBL2313 HBL2310 HBL2315 HBL2316	0734713 0734720 0734707 0734726 0734728	30A 250V  2-Pole 3-Wire	Plug Connector Receptacle Flanged Inlet Flanged Receptacle	HBL2621 HBL2623 HBL2620 HBL2625 HBL2626	0734995 0735003 0734989 0735010 0735013
20A 250V  2-Pole 3-Wire	Plug Connector Receptacle Flanged Inlet Flanged Receptacle	HBL2321 HBL2323 HBL2320 HBL2325 HBL2326	0734736 0734743 0734729 0734749 0734751	30A 125/250V  3-Pole 4-Wire	Plug Connector Receptacle Flanged Inlet Flanged Receptacle	HBL2711 HBL2713 HBL2710 HBL2715 HBL2716	0735060 0735064 0735054 0735068 0735071
20A 3Ø 250V  3-Pole 4-Wire	Plug Connector Receptacle Flanged Inlet Flanged Receptacle	HBL2421 HBL2423 HBL2420 HBL2425 HBL2426	0734840 0734843 0734833 0734845 0734847	30A 3Ø 250V  2-Pole 3-Wire	Plug Connector Receptacle Flanged Inlet Flanged Receptacle	HBL2721 HBL2723 HBL2720 HBL2725 HBL2726	0735078 0735081 0735072 0735084 0735086
20A 3Ø 480V  3-Pole 4-Wire	Plug Connector Receptacle Flanged Inlet Flanged Receptacle	HBL2431 HBL2433 HBL2430 HBL2435 HBL2436	0734857 0734862 0734849 0734865 0734867	30A 3Ø 480V  2-Pole 3-Wire	Plug Connector Receptacle Flanged Inlet Flanged Receptacle	HBL2731 HBL2733 HBL2730 HBL2735 HBL2736	0735093 0735096 0735087 0735099 0735101

H-MOSS® Wall Switch Occupancy Sensors		Adaptive Technology							
		Single Circuit				Dual Circuit			
		Manual/Auto Control 1 Button		Auto Control No Button		Manual/Auto Control 2 Buttons		Auto Control No Button	
	Color	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
Dual (ultrasonic & PIR) 1000 sq. ft. coverage with photocell, 800W Incandescent, 1000W Fluorescent at 120V AC, 1800W Fluorescent at 277V AC, 50/60Hz.	Ivory White Gray	AD1277I1	0732024	AD1277I1N	0732025	AD1277I2	0732026	AD1277I2N	0732027
		AD1277W1	0732032	AD1277W1N	0732033	AD1277W2	0732034	AD1277W2N	0732035
		AD1277GY1	0732020	AD1277GY1N	0732021	AD1277GY2	0732022	AD1277GY2N	0732023
Ultrasonic 400 sq. ft. coverage with photocell, 800W Incandescent, 1000W Fluorescent at 120V AC, 1800W Fluorescent at 277V AC, 50/60Hz.	Ivory White Gray	AU1277I1	0732140	AU1277I1N	0732141	AU1277I2	0732142	AU1277I2N	0732143
		AU1277W1	0732148	AU1277W1N	0732149	AU1277W2	0732150	AU1277W2N	0732151
		AU1277GY1	0732136	AU1277GY1N	0732137	AU1277GY2	0732138	AU1277GY2N	0732139
Passive Infrared (PIR) 1000 sq. ft. coverage with photocell, 800W Incandescent, 1000W Fluorescent at 120V AC, 1800W Fluorescent at 277V AC, 50/60Hz.	Ivory White Gray	AP1277I1	0732140	AP1277I1N	0732068	AP1277I2	0732069	AP1277I2N	0732070
		AP1277W1	0732148	AP1277W1N	0732076	AP1277W2	0732077	AP1277W2N	0732078
		AP1277GY1	0732063	AP1277GY1N	0732064	AP1277GY2	0732065	AP1277GY2N	0732066

H-MOSS® Wall Switch Occupancy Sensors		Passive Infrared Wall Switches							
		Standard				With Neutral			
		Standard		With Nightlight		Standard		With Nightlight	
	Color	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
Adaptive auto-adjusting; selectable manual/auto- on operation; dual-voltage 120/277V; 3-way capable; 1200 sq. ft. coverage	Gray Ivory Lt. Almond White	ATP2000GY	**	ATP2000NGY	**	—	—	—	—
		ATP2000I	**	ATP2000NI	**	ATP2004I	**	ATP2004NI	**
		ATP2000LA	**	ATP2000NLA	**	—	—	—	—
		ATP2000W	**	ATP2000NW	**	ATP2004W	**	ATP2004NW	**
Manual adjusting; selectable manual/auto- on operation; dual-voltage 120/277V; 3-way capable 1200 sq. ft. coverage	Gray Ivory Lt. Almond White	WS2000GY	**	WS2000NGY	**	—	—	—	—
		WS2000I	**	WS2000NI	**	WS2004I	**	WS2004NI	**
		WS2000LA	**	WS2000NLA	**	—	—	—	—
		WS2000W	**	WS2000NW	**	WS2004W	**	WS2004NW	**
Manual adjusting; auto-on operation; 120V AC only; 1200 sq. ft. coverage	Ivory White	WS1000I	**	WS1000NI	**				
		WS1000W	**	WS1000NW	**				
Manual adjusting; Manual-on operation; 120V AC only; 1200 sq. ft. coverage	Ivory White	WS1001I	**	WS1001NI	**				
		WS1001W	**	WS1001NW	**				

**Check www.fastenal.com

LED Combo Exit Sign and Emergency Lights

LED Combo Exit/Emergency Lights



Description	Color	Standard		Remote Capacity		Compact Design High Impact Housing Full Range Lamp Positioning	
		Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
LED Combo Exit/Emergency Light, Universal Face, NiCad Battery (C-series); Lithium Iron Phosphate Battery (E-Series), Damp Listed	White/Red	CCR	0775085	CCRRC	0775086	EVCURWD	**

LED Exit Lights

LED Emergency Exit Lights



Description		Standard NiCAD Battery		Remote Capacity NiCAD Battery		Wall, Ceiling Or End Mount Nickel Metal Hydride Battery	
		Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
LED Emergency Exit Lights, Universal Face, 120 or 277VAC	White/Red Black/Red White/Green	CER — —	** — —	CERRC — —	** — —	EVEURW EVEURB EVEUGW	** ** **

LED Emergency Lights

LED Emergency Exit Lights



Description		Damp Listed, LED Fully Adjustable Heads		5.4W Sealed Beam PAR36 Lamp Heads		5.4W Sealed Beam PAR36 Lamp Heads, Damp Listed	
		Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
LED Emergency Exit Lights, Universal Face, 120 or 277VAC	White	CU2	0775087	EZ-2	0745653	EZ-2-D	0745654

Compact Architectural LED Emergency Lights

Compact LED Emergency Lights



Description		Standard		Remote Capacity	
		Hubbell	Fastenal	Hubbell	Fastenal
120/277VAC input, Damp Location Listed, Includes NiMH Battery, Wall or Ceiling Mount	White Black	EV2D	0775090	EV4D EV4DB	0775093 0775094

Compact Architectural LED Emergency Lights

Compact LED Emergency Lights



Description		Indoor Double head		Indoor Single head		Decorative Single head		Decorate Double head	
		Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal		
120/277VAC input, Damp Location Listed, Includes NiMH Battery, Wall or Ceiling Mount, Fully Aimable	White	CIRD	**	CIRS	**	EVOSW	**	EVODW	**

**Check www.fastenal.com

Compact LED Wall Packs		Compact LED Energy Efficient Architectural Wallpacks					
Description	Color	120-277V,					
		16.4w Equal to 70w MH,HPS or 42w CFL		29w Equal to 150w MH,HPS or 84w CFL		42.3w Equal to 150w+ MH,HPS or 84w CFL	
		Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
80-85% Energy Savings, Mounting Height up to 15 feet	Dark Bronze	LNC7LU5K31	0775214	LNC212LU5K31	0775216	LNC218LU5K31	**

LED Wall Packs		LED Energy Efficient Wallpacks					
Description	Color	Glass Refractor 69w, 120-277V Equal to 250w MH, HPS		Polycarbonate Refractor 69w, 120-277V Equals 250w MH, HPS		Glass Refractor 35w, 120-277V Equals 250w MH, HPS	
		Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
60-70% Energy Savings Mounting heights 15-18 feet	Dark Bronze	PGM330LU5KBZ	0775221	PVL330LU5KBZ	0775223	PGM330LU5K035BZ	0775220

Photocontrols	Photocontrols							
								
Voltage	Photo Control Button Type		Weatherproof Twist-Lock® Photocell		Receptacle-Remote Twist-Lock® Cell w/ Bracket		Shorting Cap Twist-Lock® Mount	
	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal	Hubbell	Fastenal
120 208, 240, 277	PBT1 PBT234	0775211 0775212	— —	— —	— —	— —	— —	— —
120-277 480	— —	— —	PTL8 PTL5	0775210 **	— —	— —	— —	— —
120-480	—	—	—	—	PRR	**	—	—
NA	—	—	—	—	—	—	PSC	0775209

**Check www.fastenal.com

Literature Support

Hubbell offers an extensive literature library for product support. Downloadable PDFs are available online.

Hubbell Wiring Device-Kellems

Online Virtual Catalog

Find what you need on the Hubbell Wiring Device-Kellems website, www.hubbell-wiring.com. The online virtual catalog allows you to print, search and download PDFs anytime, anywhere.

Online Technical Support


Search our knowledge base for the answer to your technical questions regarding Hubbell products, or submit a new question to Technical Support. Browse the customer drawing library by part number or product family. Drawings are available in PDF and DWG format. Our Twist-Lock® selector tool is also available as a downloadable app.

Hubbell Lighting, Inc.

Electronic Product Selection Guide

The e-PSG Web App, www.hubbelllighting.com/resources/epsg_web/, provides Lighting PDF files of each product's catalog page and user-editable product spec sheets. The web app also organizes direct links to each product's web page where users can download IES photometric files. The applications are also available for download to your PC, tablet, or smart phone.

Available Hubbell Literature

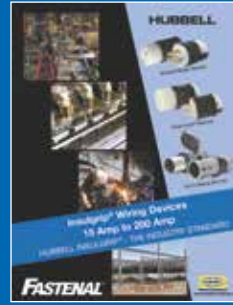

Insulgrip Brochure
#9702886



Safety Guide
#9702819



USB Charger Receptacle
#9704213

Website Support

The Hubbell brand websites feature quick links to Hubbell's government oriented products, virtual and downloadable PDF catalogs, resources, support and ordering tools. The websites also offer extensive literature libraries and strategic market landing pages.



www.hubbell-wiring.com



www.hubbelllighting.com

Online Resources

Visit the Hubbell-Fastenal Bin Stocking Website for a one-stop online resource.

- Presentations
- Facility eTours
- Plan-O-Grams
- Products Listings
- Key Literature and more...

<http://www.hubbell-wiring.com/fmiprogram>



HUBBELL®
Wiring Device-Kellems

COMPASS™
Products by Hubbell Lighting, Inc.

DUALITE

HUBBELL
Outdoor Lighting



FASTENAL®

HOW DO YOU PREFER TO BUY?

LOCAL STORE / PERSONAL SERVICE / INVENTORY SOLUTIONS / FASTENAL.COM