



MBULLETTLED SERIES

LED bullet is versatile, compact floodlight for landscape, accent, pole, column, facade and small area illumination



Mounting Versatility

6.75" stake with 8" SO cord for landscape application also included

Versatile compact LED floodlight perfect for a variety of applications including: landscape, accent, pole/column, facade and small area illumination. Stake or threaded mounting plus adjustable knuckle provides mounting flexibility. Durable die-cast design with corrosion resistant powder coat paint finish for years of maintenance free illumination.

Features and Benefits:

- Capable of replacing 50w or 70w HID, 100w incandescent or 84w CFL luminaires
- Competitively priced and stocked for availability
- Mounting versatility:
 - 7" stake with 8" SO cord
 - 1/2" 14 NPT threaded mounting box for box or pipe mounting
- Listed to UL1598 for use in wet locations
- NEMA 3R




Performance Data

Series Number	Equivalency	Lumens Delivered	Voltage	System Watts	Lumens Per Watt	CCT/CRI
MBUL-1L3K-1	up to 70w or 84w CFL	1115	120V	13.2	84.5	3000K/83






Performance

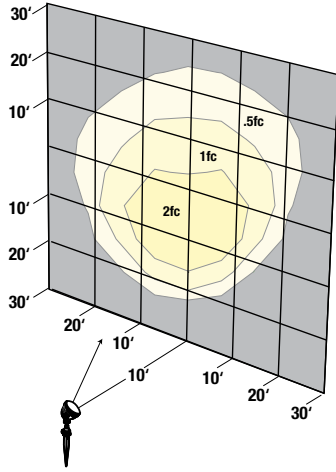


45 Tilt 10' Set Back

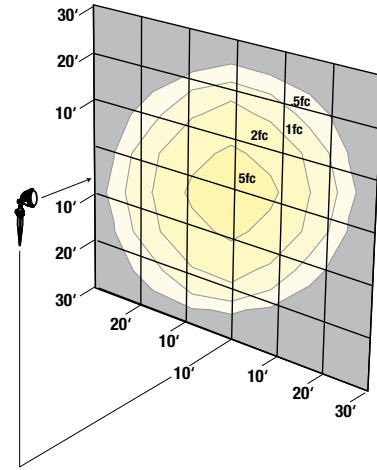

Straight on 10' Set Back

Dimensions

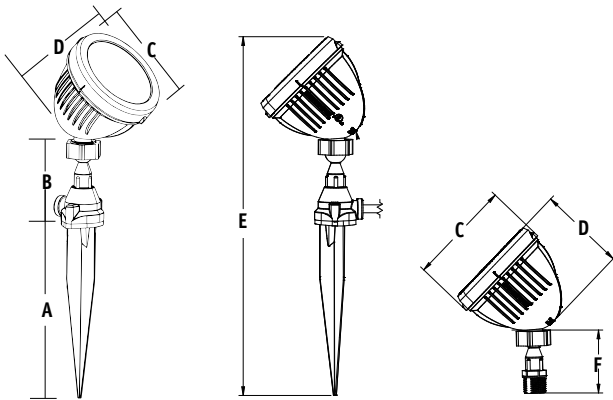

A	B	C	D	E	F
6.75"	2.875"	3.26"	3.9"	13.53"	2.37"
171 mm	73 mm	82 mm	99 mm	343 mm	60 mm

