

## ORDERING INFORMATION




DDL-9L1  
DDL-9LU

DDL-140L-1

DDL-56L-4K-1

Catalog Number	Mount	Wattage	Drive Current	Voltage	Color Temperature	Lumens	LPW
DDL-9L1	Arm/Wall/Surface	40	1280mA	120V	5000K	3437	86
DDL-9LU	Arm/Wall/Surface	40	1280mA	120V-277V	5000K	3437	86
DDL-56L-4K-1-NA	Arm not included	30	150mA	120V	4000K	2906	97
DDL-140L-1	Arm included	43.5	92mA	120V	5000K	5279	121

## DIMENSIONS


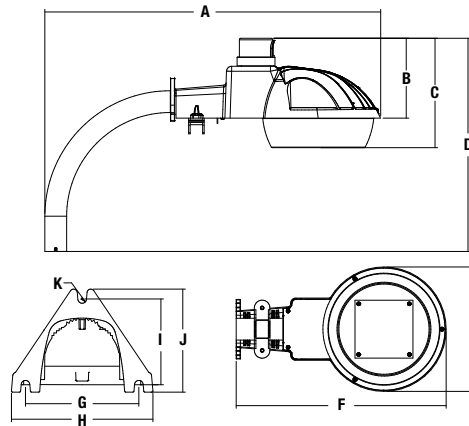


A	B	C	D	E	F
29.72"	6"	8.25"	16.19"	9.45"	16"
754 mm	152 mm	209 mm	411 mm	240 mm	406 mm
G	H	I	J	K	WEIGHT
3.62"	4.52"	2.74"	3.29"	.138"	6.8 LBS.
92 mm	115 mm	69 mm	84 mm	3.5 mm	3.08 KG


EPA = 0.5




## LED MULTI-PURPOSE DUSK-TO-DAWN LUMINAIRE

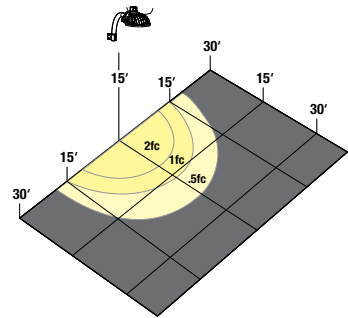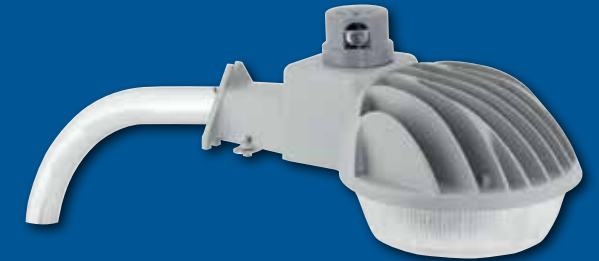

Symmetric LED lens

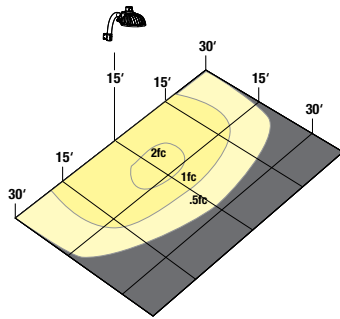

Asymmetric LED lens

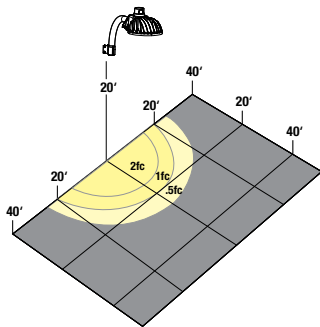

DDL-140L-1 at 20'

Full line of LED products visit: [www.hubbelloutdoor.com](http://www.hubbelloutdoor.com)

FOR MORE INFORMATION ABOUT THE FULL LINE OF LED PRODUCTS:

Hubbell Lighting Inc. Distinguished Lighting Brands



Alera Lighting  
Architectural Area Lighting  
Columbia Lighting  
Compass Products  
Devine Lighting  
Dual-Lite  
Hubbell Building Automation  
Hubbell Outdoor Lighting

Hubbell Industrial Lighting  
Kim Lighting  
Kurt Versen  
Litecontrol  
Prescolite  
Spaulding Lighting  
Sportsliter Solutions  
Sternier Lighting Systems

United States  
Hubbell Lighting, Inc.  
701 Millennium Boulevard  
Greenville, SC 29607  
864-678-1000

Canada  
Hubbell Canada  
870 Brock Road  
Pickering, Ontario L1W 1Z8  
[www.hubbell-canada.com](http://www.hubbell-canada.com)

Mexico  
Hubbell De Mexico, S.A. DE CV  
Av. Insurgentes Sur # 1228, 8th Floor  
Col. Tlacoquemecatl del Valle • 03200 Mexico, D.F.  
[www.hubbell.com.mx](http://www.hubbell.com.mx)

Due to our continued efforts to improve our products, product specifications are subject to change without notice.

HOL0077 POD 4.15



# LED MULTI-PURPOSE DUSK-TO-DAWN LUMINAIRE

Hubbell Outdoor Lighting's LED multi-purpose dusk-to-dawn luminaire series features multiple lumens and distributions, zero uplight performance and versatile mounting options in a single SKU. Stylish and rugged, this energy saving luminaire is designed to solve your security lighting needs.




## Key Features & Benefits

- Rugged die-cast aluminum housing with textured gray powder paint provides corrosion resistance and clean finish
- Symmetric LED lens installed standard; Field rotatable asymmetric LED lens included (DDL-9L only)
- 2900 to 5200 lumens with up to 121 lumens per watt efficacy
- Zero uplight for environmentally friendly installations
- 120V twist-lock style photocontrol included
- IDA approved Dark-Sky friendly fixture (without acrylic refractor)
- Prismatic acrylic refractor included for security applications and glare comfort




IDA approved without lens

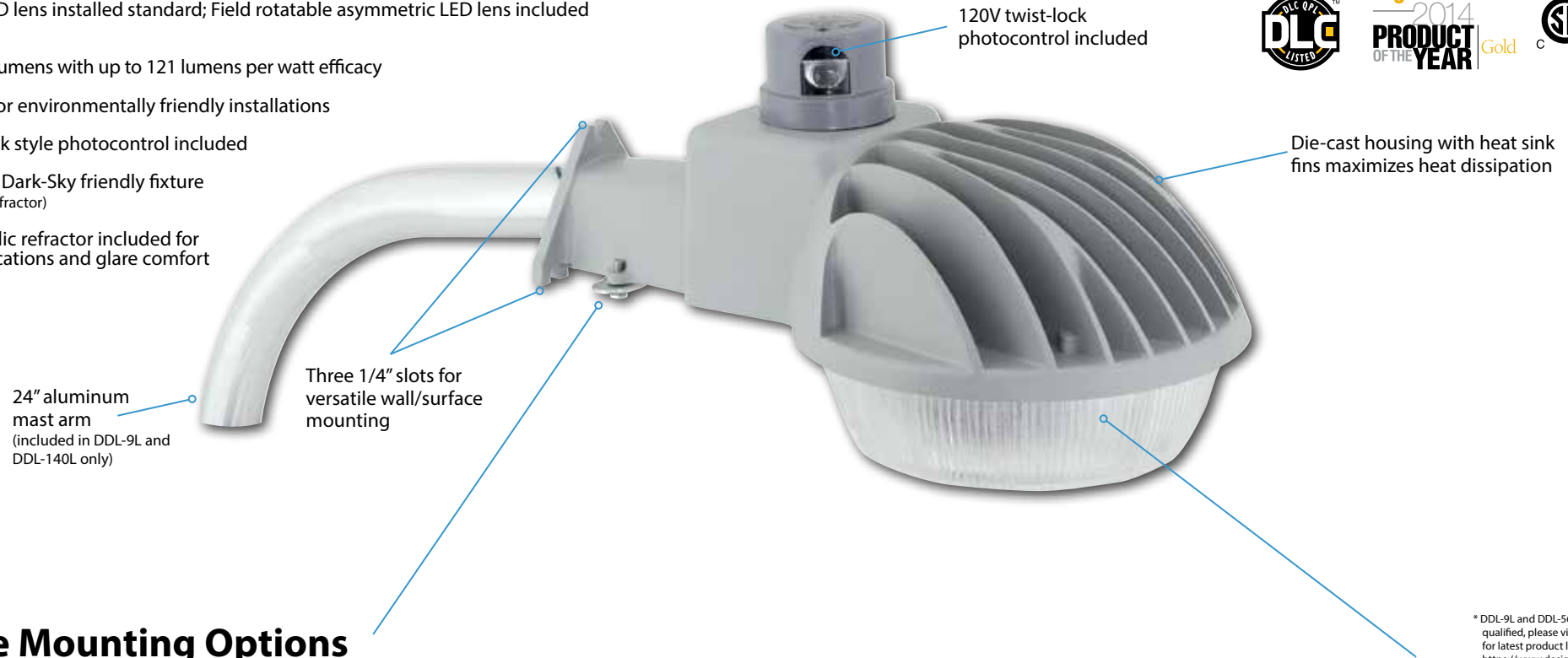


\* DDL-9L and DDL-56 DesignLights Consortium qualified, please visit DesignLights Consortium\* for latest product listings: <https://www.designlights.org/QPL>


## Versatile Mounting Options

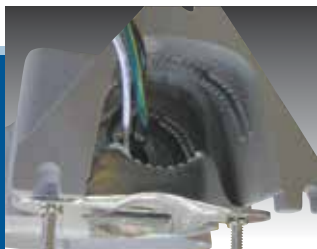

Dual rows of cast serrated teeth ensure positive grip on mast arm, preventing loosening or twisting due to continuous vibration

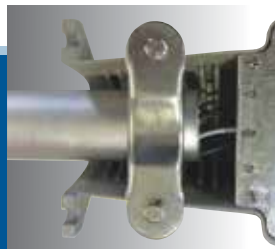

Bottom view of corrosion resistant steel mast arm clamp

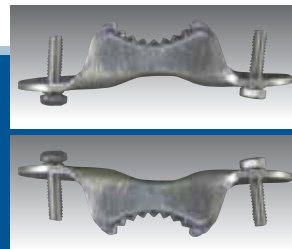

Corrosion resistant steel mast arm clamp is reversible accommodating either 2-3/8" or 1-5/8" OD arms



Mast arm clamp easily adjusts to 1-5/8" OD arms with two 3/8" bolts




Reversible clamp easily adjusts to 2-3/8" OD arms with two 3/8" bolts



Molded orientation marker for rotatable asymmetric lens, align lens with "house" icon for desired light direction



Asymmetric

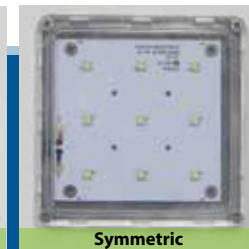

Symmetric

Symmetric lens installed as standard. Rotatable asymmetric lens included with DDL-9L – easily exchangeable by removing four phillips head screws. Lenses are field rotatable in 90° increments.