


 







BUILDING MOUNT

selection guide

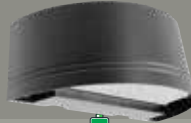

Mounting Height											HID/CFL Replacement	
15 Feet and up	 LNC4	 TRAVERSE								 WGH-225L	400w 250w HID	
12-15 Feet	 LNC3	 SG2	 TRP2	 RDI2	 QSP2				 PGM3	 PVL3	 WGH-110L	250w 150w HID
10-12 Feet	 LNC2	 SG1	 TRP1	 RDI1	 GSP1				 LNC2-P	 WGH-81L	150w 70w HID	
Up to 10 Feet	 LNC										 NRG-356LU	42w 26w CFL

See reverse side for fixture data

 = Battery Back up

Building Mount Selection Guide

Luminaire	Mounting Height Range	Mounting Height Spacing	Delivered Lumens	System Watts	LPW	HID Equivalency	Approximate Energy Savings	# LEDs	CCT	# of Drivers	Voltage Range	DLC Listing	Battery Backup	Photocell	Occupancy Sensor	SiteSync
Traverse	15' - 25'	4 - 6 X	3,300 - 15,000	27 - 136w	Up to 125	150 - 400w+	75 - 80%	24 - 60	3K/4K/5K	1 - 2	120 - 480V	Standard & Premium	36L Only	Button	Yes	Yes
LitePak LNC4	15' - 25'	4 - 6 X	4,500 - 14,800	40 - 170w	Up to 115	175 - 400w+	65 - 75%	36 / 44	3K/4K/5K	2	120 - 480V	Standard & Premium	36L Only	Button and 7-Pin Receptacle	Yes	Yes
WGH-225L	15' - 25'	3 - 4 X	11,800 - 12,800	102 - 110w	Up to 120	400w	75 - 80%	225	4K/5K	1	120 - 480V	Standard	No	Button	No	No
TRP2/RDI2/QSP2	12 - 20'	4 - 6 X	3,700 - 10,800	28 - 87w	Up to 145	150 - 400w	75 - 80%	24 / 32	3K/4K/5K	1 - 2	120 - 480V	Standard & Premium	Yes	Button	Yes	Yes
TRP2/RDI2 Low Glare	10 - 20'	3 - 4 X	3,000 - 9,000	21 - 62w	Up to 155	150 - 250w	75 - 80%	180	3K/4K/5K	1 - 2	120 - 480V	Standard & Premium	No	Button	Yes	Yes
Sling SG2	12 - 20'	3 - 4 X	5,500 - 8,100	50 - 80w	Up to 110	175 - 250w	70%	3	3K/4K/5K	1	120 - 480V	Standard & Premium	Yes	Button	Yes	Yes
PGM3	10 - 20'	3 - 4 X	4,200 - 8,100	32 - 72w	Up to 130	150 - 250w	75 - 80%	180	3K/4K/5K	1 - 2	120 - 480V	Standard	350mA Only	Button	Yes	No
LitePak LNC3	10 - 20'	4 - 6 X	3,000 - 7,600	28 - 83w	Up to 115	150 - 250w	70 - 80%	24	3K/4K/5K	1 - 2	120 - 480V	Standard & Premium	Yes	Button and 7-Pin Receptacle	Yes	Yes
LMC	10 - 20'	4 - 6 X	3,800 - 7,300	35 - 70w	Up to 115	150 - 250w	70 - 80%	30	3K/4K/5K	1 - 2	120 - 480V	Standard	Yes	Button	Yes	No
PVL3	10 - 20'	3 - 4 X	3,500 - 6,800	32 - 72w	Up to 110	150 - 250w	75 - 80%	180	3K/4K/5K	1 - 2	120 - 480V	No	350mA Only	Button	Yes	No
WGH-110L	10 - 20'	3 - 4 X	6,200 - 6,400	54w	Up to 120	250w	75 - 80%	110	4K/5K	1	120 - 277V	Standard	No	Button	No	No
LitePack LNC2	8 - 15'	4 - 6 X	1,600 - 4,300	14 - 42w	Up to 120	70 - 175w	75 - 80%	9 - 18	3K/4K/5K	1 - 2	120 - 480V	Standard & Premium	Yes	Button	Yes	Yes
LNC2 Prismatic	8 - 15'	4 - 5 X	1,600 - 4,000	13 - 37w	Up to 130	70 - 175w	75 - 80%	1	3K/4K/5K	1	120 - 480V	Standard & Premium	Yes	Button	Yes	Yes
WGH-81L	8 - 15'	3 - 4 X	2,900 - 3,300	32w	Up to 105	150w	80%	1	4K/5K	1	120 - 277V	Standard	No	Button	No	No
Sling SG1	8 - 15'	3 - 4 X	2,200 - 3,300	21 - 29w	Up to 115	100 - 150w	80%	2	3K/4K/5K	1	120 - 277V	Standard & Premium	No	Button	No	No
TRP1/RDI1/QSP1	8 - 15'	4 - 6 X	1,500 - 3,000	14 - 28w	Up to 120	70 - 150w	75 - 80%	12	3K/4K/5K	1	120 - 277V	Standard & Premium	Yes	Button	Yes	No
LitePak LNC	8 - 12'	3 - 5 X	1,000 - 2,000	13 - 22w	Up to 95	50 - 100w	75 - 80%	5 - 9	3K/4K/5K	1	120 - 277V	Standard	No	Button	No	No
NRG356	8 - 10'	2 - 3 X	1,800	17w	Up to 110	70w	75%	56	4K/5K	1	120 - 277V	No	No	Button	No	No