
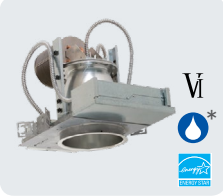
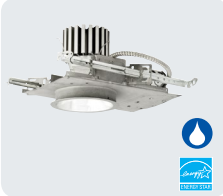





# CEILING HEIGHT CROSSOVER



LED Families						
CEILING HEIGHT	Architektür	LF Series	LifeFrame Commercial	LiteBoxPlus+	LiteBox	LEGACY
60' & Above (>10,000 Lumens)	MD8 16L MD8 12L					 400W MH
40'-60' (5000-9000 Lumens)	MD8 8L MD6 9L MD6 7L		LCHL 60L			 320W MH 250W MH
30'-40' (3000-5000 Lumens)	MD6 5L		LCHL 45L			 100W MH 250W MH 70W MH
20'-30' (2000-3000 Lumens)	MD8 4L	LF6ML 30L LF6SL 20L	LC6ML 30L LC6ML 24L			 42/57W CFL Twin 26W CFL
10'-20' (1000-2000 Lumens)	D2LED 15L D2LED 12L A2LED 12L AB2LED 12L	LF6SL 15L LF6SL 11L	LC6SL 18L LC6SL 14L LC6SL 10L LC4SL 18L LC4SL 14L LC4SL 10L	LBP 15L LBP 11L	LB6LEDA 10L LBSLEDA 10L LBSQLEDA 10L	 26/32W CFL
10' & under (<900 Lumens)	D2LED 9L D2LED 7L (WW) A2LED 9L A2LED 7L AB2LED 9L AB2LED 7L			LBP 08L	LB6A 7L LBEB6A 7L LB4A 6L LBEB4A 6L LBS5LEDA 6L LBSQ5LEDA6L	 18W CFL 75W INC

PRODUCT IMAGE	CATALOG #	APERTURE	DELIVERED LUMENS	SYSTEM WATTS	EQUIVALENCY	LPW	CCT	VOLTAGE	DIMMING
<b>D2Series</b> 	D2LED-2D9LED 9L D2LED-2D9LED 12L D2LED-2D9LED 15L	2" Round	921 1227 1631	12.6 15.7 21.1	50W MR16 75W MR16 100W MR16	73 78 77	2700K 3000K 3500K 4000K	120 or 277	Standard: 0-10V 10%  Optional: 0-10V 0.1%; HDM 1%
	A2LED-2A9LED 7L A2LED-2A9LED 9L A2LED-2A9LED 12L	2" Round Adjustable	702 905 1218	11.6 14.3 19.2	50W MR16 50W MR16 75W MR16	61 63 63			
	AB2LED-2AB9LED 7L AB2LED-2AB9LED 9L AB2LED-2AB9LED 12L	2" Round Adjustable	720 931 1241	13.8 17.8 22.4	50W MR16 50W MR16 75W MR16	52 52 55			
	MD8LED 4L	8" Round	4097	38.8	70W CFL 70W MH	105.6			
	MD8LED 8L		8094	78.1	500W T4 150W MH	103.6			
	MD8LED 12L		12095	117.5	500W T4 250W MH	102.9			
<b>MEGALUM</b> 	MD8LED 16L		15920	156.1	320W MH 400W MH	102	2700K 3000K 3500K 4000K	120 or 277	Standard: 0-10V 10%  Optional: 0-10V 0.1%; Leading Edge HDM 1%
	MD6LED 5L	6" Round	5148**	73	400W T4 100W MH	70			
	MD6LED 7L		7410**	103	500W T4 150W MH	72			
	MD6LED 9L		9710**	137	400W T4 100W MH	71			
	LF8SL-8LFSL 11L	8" Round	1038	14	26W CFL				
	LF8SL- 8LFSL 15L		1406	19	32W CFL				
<b>LifeFrame LED</b> 	LF8SL- 8LFSL 20L		1853	26	42W CFL (2) 26W CFL				
	LF8ML- 8LFML 30L	6" Round & Square	2484	36	50W MH 70W CFL		3000K 3500K 4000K	120/277	Standard: 0-10V 10%  Optional: EcoSystem 1%; Leading Edge 1% 0-10V 1% DMX 0.1%
	LF6SL- 6LFSL 11L		1054	14	26W CFL	75			
	LF6SL- 6LFSL 15L		1413	19	32W CFL	74			
	LF6SL- 6LFSL 20L		1860	26	42W CFL (2) 26W CFL	71			
	LF6ML- 6LFML 30L		2500	36	50W MH 70W CFL	69			
	LF4SL- 4LFSL 11L	4" Round & Square	994	14	26W CFL	71			
	LF4SL- 4LFSL 15L		1323	19	32W CFL	70			
	LF4SL- 4LFSL 20L		1698	26	42W CFL (2) 26W CFL	65			
	LF4ML- 4LFML 30L				50W MH 70W CFL	66			
			2393	36					

# prescolite CEILING HEIGHT CROSSOVER

PRODUCT IMAGE	CATALOG #	APERTURE	DELIVERED LUMENS	SYSTEM WATTS	EQUIVALENCY	LPW	CCT	VOLTAGE	DIMMING
<div>LiteFrame Commercial</div> <div></div>	LC4SL 4LCSL10L	4" Round	1062	13.3	26W CFL	79.8	2700K 3000K 3500K 4000K	120V or 277V	Optional: 0-10V 10% 0-10V 1%
	LC4SL 4LCSL14L		1443	17.7	32W CFL	81.5			
	LC4SL 4LCSL18L		1865	22.3	42W CFL (2) 26W CFL	83.6			
	LC6SL 6LCSL10L	6" Round	1107	17	26W CFL	65			
	LC6SL 6LCSL14L		1424	21	32W CFL	66			
	LC6SL 6LCSL18L		1797	26	42W CFL (2) 26W CFL	69			
	LC6ML 6LCML24L*		2375	33	57W CFL	73			
	LC6ML 6LCML30L*		2993	42	50W MH 70W CFL	72			
	LC6HL 6LCHL45L*		4655	52	400W T4 100W MH	2700K 3000K 3500K 4000K 5000K			
	LC6HL 6LCHL60L*	6071	68	500W T4 150W MH					
	LC8SL 8LCSL10L	8" Round	1216	15	26W CFL	2700K 3000K 3500K 4000K 5000K			
	LC8SL 8LCSL14L		1594	20	32W CFL				
LC8SL 8LCSL18L	1958		25	42W CFL (2) 26W CFL					
LC8ML 8LCML24L*	2625		32	57W CFL					
LC8ML 8LCML30L*	3256		40	50W MH 70W CFL					
LC8HL 8LCHL45L*	4599		52	70W CFL					
LC8HL 8LCHL60L*	6026	68	100W MH						
<div>LiteBoxPlus+</div> <div></div>	LBP6-6LBP8L	6" Round	808	10	26W CFL	78	2700K 3000K 3500K 4000K	120V-277V	Standard 0-10V 5% Triac/ELV
	LBP6-6LBP11L		1050	12	32W CFL	80			
	LBP6-6LBP15L		1539	20		76			
<div>LiteBox</div> <div></div>	LB4A6L LBEB4A6L	4"/6" Round and Eyeball	600	9	50W R20 65W BR30 18W CFL 26W CFL	67	3000K 3500K	120V	Triac/ELV
	LB6A7L LBEB6A7L		700	10		70			
	LB6LEDA10L	6" Downlight	1038	12		87			
	LBS5LED6 LBSQ5LED6L	5" Surface Mount Round or Square	623 679	13 10	65W BR30	49			
	LBSLEDA10L LBSQLEDA10L	7" Surface Mount Round or Square	1032	17	36W CFL	63			



WET LOCATION



WET LOCATION WITH LENS



ENERGY STAR



Variable Intensity Technology

\* ENERGY STAR not available

\*\*Delivered Lumens are effected by beam distribution chosen.