

HOME
STYLE
LIGHTING™

HOME COLLECTION 2021

HOMESTYLE-LTG.COM

HS21007-09
Brushed Nickel p.6



HS21007-125
Bronze p.6



HS21008-09
Brushed Nickel p.6



HS21008-125
Bronze p.6



HS21009-09
Brushed Nickel p.6



HS21009-125
Bronze p.6



HS31021-09
Brushed Nickel p.6



HS31021-125
Bronze p.6



HS31000-125
Bronze p.5



HS31000-09
Brushed Nickel p.5



HS31000-30
White p.5



HS31001-09
Brushed Nickel p.5



HS31001-125
Bronze p.5



HS31001-30
White p.5



HS31002-09
Brushed Nickel p.5



HS31002-30
White p.5



HS41009-09
Brushed Nickel p.4



HS41009-125
Bronze p.4



HS41002-09
Brushed Nickel p.3



HS41004-09
Brushed Nickel p.3



HS41005-09
Brushed Nickel p.3



HS41007-09
Brushed Nickel p.4



HS41008-09
Brushed Nickel p.4



HS41008-125
Brushed Nickel p.4



HS71001-31

Black

p.8

HS71001-125

Bronze

p.8

HS71003-31

Black

p.9

HS71003-125

Bronze

p.9

HS71006-31

Black

p.7

HS71006-125

Bronze

p.7



HS71007-31

Black

p.7

HS71007-125

Bronze

p.7

HS71008-31

Black

p.7

HS71008-125

Bronze

p.7

HS71010-31

Black

p.9

HS71010-125

Bronze

p.9



HS71011-31

Black

p.9

HS71011-125

Bronze

p.9

HS71012-31

Black

p.8

HS71013-31

Black

p.8

HS71014-31

Black

p.8

HS71017-31

Black

p.8



HS21011-01

White Glass

p.4

HS99000-01

Glass Shade

p.10

HS99001-01

Glass Shade

p.10

HS99003-01

Glass Shade

p.10

HS99009-09

Brushed Nickel

p.10

HS99009-125

Bronze

p.10



RECESSED TRIMS

410W
White

p.11



601A
White

p.12



610W
White

p.12



620B
Black

p.12



620W
White

p.12



650W
White

p.12



690W
White

p.12



HS4-WH-30K9
White

p.11



HS56-WH-30K9
White

p.11



HS56CA-WH-30K9
White

p.11



RECESSED HOUSINGS

C4ICAT

p.11



C4T

p.11



C5LED

p.11



C6ICAT

p.12



CHANDELIERS

HS41002-09 Brushed Nickel
22-1/4" dia., 15-1/2" ht.
Overall ht. w/chain 91".
Three Medium base lamps,
each 100w max.



HS41004-09 Brushed Nickel
26-1/4" dia., 18-1/8" ht.
Overall ht. w/chain 94".
Five Medium base lamps,
each 100w max.



HS41005-09 Brushed Nickel
24-1/4" dia., 19" ht.
Overall ht. w/chain 94".
Five Medium base lamps,
each 100w max.



PENDANT, FOYER & SCONCE

HS41008-09 Brushed Nickel
HS41008-125 Bronze
 7-1/2" dia., 6-3/8" ht.
 Overall ht. w/stem 63-3/4".
 One Medium base lamp,
 100w max.

HS41009-09 Brushed Nickel
HS41009-125 Bronze
 16" dia., 9-3/4" ht.
 Overall ht. w/chain 83-1/4".
 One Medium base lamp,
 60w max.

HS41007-09 Brushed Nickel
 16" dia., 19-1/8" ht.
 Overall ht. w/chain 92-1/4".
 Two Medium base lamps,
 each 100w max.

HS21011-01 White Glass
 13-1/8" W., 5-1/4" ht.
 Extends 6-1/2".
 One Medium base lamp,
 100w max.



HS41008-09



HS41008-125



HS41009-09



HS41009-125



HS41007-09



HS21011-01

Brushed Nickel
hardwareBronze
hardwareWhite
hardware

CLOSE-TO-CEILING

HS31000-09 Brushed Nickel
HS31000-30 White
HS31000-125 Bronze
7-1/4" dia., 4-5/8" ht.
One Medium base lamp,
60w max.



HS31000-09



HS31000-30

HS31001-09 Brushed Nickel
HS31001-30 White
HS31001-125 Bronze
9-3/8" dia., 5-1/8" ht.
Two Medium base lamps,
each 60w max.



HS31000-125



HS31001-09

HS31002-09 Brushed Nickel
HS31002-30 White
5-7/8" dia., 7-1/8" ht.
One Medium base lamp,
60w max.



HS31001-30



HS31001-125



HS31002-09



HS31002-30

BATH

HS21007-09 Brushed Nickel
HS21007-125 Bronze
 4-5/8" W., 9-1/2" ht.
 Extends 7-1/2".
 One Medium base lamp,
 60w max.



HS21007-09



HS21007-125

HS21008-09 Brushed Nickel
HS21008-125 Bronze
 18" W., 8" ht.
 Extends 7-1/2".
 Two Medium base lamps,
 each 60w max.



HS21008-09



HS21008-125

HS21009-09 Brushed Nickel
HS21009-125 Bronze
 24" W., 8" ht.
 Extends 7-1/2".
 Three Medium base lamps,
 each 60w max.



HS21009-09



HS21009-125

HS31021-09 Brushed Nickel
HS31021-125 Bronze
 30" W., 8" ht.
 Extends 7-1/2".
 Four medium base lamps,
 each 60w max.



HS31021-09



HS31021-125

OUTDOOR

HS71006-31 Black
HS71006-125 Bronze
6" W., 14-1/4" ht.
Extends 8".
One Medium base lamp,
100w max.



HS71006-31



HS71006-125

HS71007-31 Black
HS71007-125 Bronze
7-1/4" W., 15-5/8" ht.
Extends 9-5/8".
One Medium base lamp,
100w max.



HS71007-31



HS71007-125

HS71008-31 Black
HS71008-125 Bronze
7-1/4" W., 15-5/8" ht.
Extends 9-5/8".
One Medium base lamp,
100w max.



HS71008-31



HS71008-125

OUTDOOR

HS71001-31 Black
HS71001-125 Bronze
 4-3/4" W., 8" ht.
 Extends 5-5/8".
 One Medium base lamp,
 100w max.



HS71001-31



HS71001-125

HS71012-31 Black
 5-3/4" W., 9-1/2" ht.
 Extends 6-1/4".
 One Medium base lamp,
 100w max.



HS71012-31

HS71013-31 Black
 8" W., 12-3/4" ht.
 Extends 7-1/4".
 One Medium base lamp,
 100w max.



HS71013-31

HS71014-31 Black
 10 3/4" W., 6" ht.
 Two Candelabra base lamps,
 each 60w max.



HS71014-31

HS71017-31 Black
 5-3/4" W., 8-5/8" ht.
 Extends 4-3/8". H/CTR 5".
 One Medium base lamp,
 60w max.



HS71017-31

OUTDOOR

HS71003-31 Black
HS71003-125 Bronze
7" W., 12-1/4" ht.
Extends 6-7/8".
One medium base lamp,
100w max.



HS71003-31



HS71003-125

HS71010-31 Black
HS71010-125 Bronze
9-1/8" dia., 4-1/8" ht.
One medium base lamp,
60w max.



HS71010-31



HS71010-125

HS71011-31 Black
HS71011-125 Bronze
11-1/2" dia., 4-7/8" ht.
Two medium base lamps,
each 60w max.



HS71011-31



HS71011-125

ACCESSORIES

HS99000-01 Glass shade
7-1/2" dia.
Replacement shade for
chandeliers and mini-pendants.



HS99000-01

HS99001-01 Glass shade
16" dia.
Replacement shade for
foyer fixture.



HS99001-01

HS99003-01 Glass shade
5-1/2" dia.
Replacement shade for
bath brackets.




HS99003-01

HS99009-09 Brushed Nickel
HS99009-125 Bronze
6 ft. of 9-gauge chain for use with
chandeliers and pendants.



HS99009-09

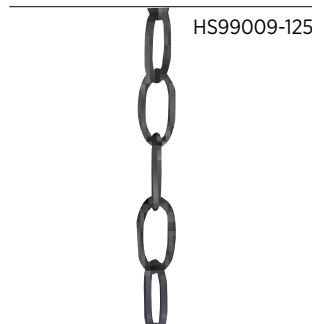

HS99009-125

RECESSED

C4ICAT
4" IC Airtight Incandescent Housing



410W
50W PAR20/R20
White Baffle



HS4-WH-30K9
9W
700 Lumens
3000K, 90CRI
White Baffle
Wet Location Listed



C4T
4" Non-IC Incandescent Housing



410W
50W PAR20/R20
White Baffle



HS4-WH-30K9
9W
700 Lumens
3000K, 90CRI
White Baffle
Wet Location Listed



C5LED
5" IC Airtight LED Housing



HS56-WH-30K9
10W
760 Lumens
3000K, 90CRI
White Baffle
Wet Location Listed



C5LED
5" IC Airtight LED Housing



HS56CA-WH-30K9
10W
760 Lumens
3000K, 90CRI
White Baffle
Wet Location Listed



RECESSED

C6ICAT

6" IC Airtight Incandescent Housing



601A

40W A19
Flush Albalite
Lens
Wet location



610W

60W PAR30,
65W BR30
White Half Baffle



620B

75W PAR30/
PAR38, 65W
BR30, 90W
BR40
Black Full
Baffle



620W

75W PAR30/
PAR38, 65W
BR30, 90W
BR40
White Full
Baffle



650W

75W PAR30,
65W BR30
White Eyeball



690W

60W PAR30,
65W BR30
White Open
Ring




HS56-WH-30K9

10W
760 Lumens
3000K, 90CRI
White Baffle
Wet Location Listed


LED




C4T

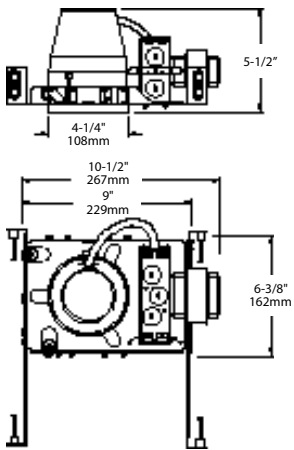


C4ICAT

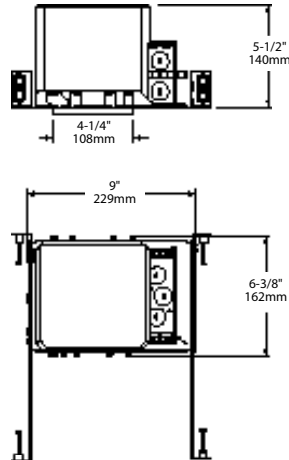

C5LED

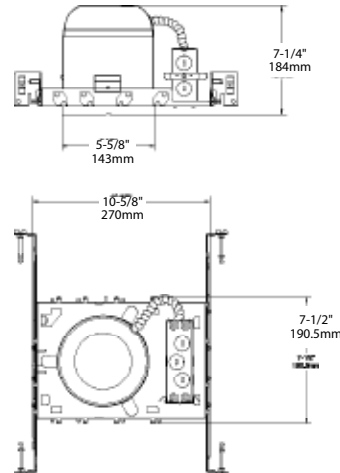

C6ICAT

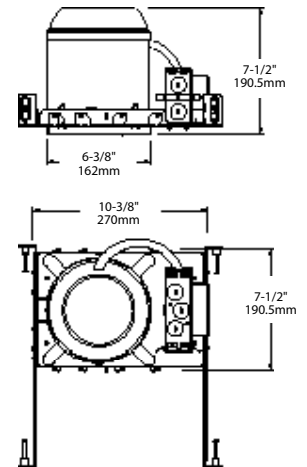

HomeStyle Lighting's recessed product line offers the best mix of value and availability. All of our recessed products have passed rigid testing to ensure compliance to safety standards.

- Residential or light commercial
- Discretionary distributor sales or contractor job business

PRODUCT INDEX

PRODUCT #	PAGE
-----------	------

HS21007.....	6
HS21008	6
HS21009	6
HS21011.....	4
HS31000	5
HS31001.....	5
HS31002	5
HS31021	6
HS41002	3
HS41004	3
HS41005	3
HS41007	4
HS41008	4
HS41009	4
HS71001.....	8
HS71003	9
HS71006	7
HS71007.....	7
HS71008	7
HS71010	9
HS71011.....	9
HS71012	8
HS71013	8
HS71014	8
HS71017	8
HS99000.....	10
HS99001	10
HS99003.....	10
HS99009.....	10

RECESSED TRIMS

410W	11
601A	12
610W	12
620B.....	12
620W.....	12
650W.....	12
690W.....	12
HS4-WH-30K9	11
HS56-WH-30K9.....	11
HS56CA-WH-30K9	11

RECESSED HOUSINGS

C4ICAT.....	11
C4T.....	11
C5LED	11
C6ICAT.....	12

HOME STYLE LIGHTING™

HomeStyle Lighting features a full line of decorative, affordable luminaires for a variety of residential and light commercial projects. Chandeliers, pendants, recessed, close-to-ceiling, outdoor and bath lighting are all included in the HomeStyle Lighting collection to offer a complete selection of products. Browse among the classic styles that are available at a great value, and see for yourself how you can use HomeStyle Lighting for your next residential or light commercial project.



701 Millennium Boulevard - Greenville, SC 29607
www.homestyle-ltg.com