



COMMERCIAL PRODUCT CATALOG 2020





See
Yourself
Here.

Lighting helps tell a story as well as being an integral part of the modern commercial environment. From providing functional light that improves well-being and efficiency, to bringing beautiful style to interior and exterior applications, let Progress Lighting be your guide in illuminating these spaces into special places.

Table of Contents

Site Lighting	16	Building Interior	52
Area Lighting	18	Linear	54
Low Level/Pathway	26	Undercabinet	56
		Recessed Downlighting	60
		Surface Mount Downlighting	66
		Steps, Corridors & Wall Lights	69
		DFS Series	70
		Close-to-Ceiling	78
		Sconces	95
		Bath	98
		Pendants	113
Building Exterior	28		
Flood Lighting	30		
Wall/Surface	31		
Outdoor	32		
		Ceiling Fans	126
Egress	46		
Exit	48		
Emergency	50	Index	144





A Complete Solution for Commercial Projects

Progress Lighting offers a wide selection of light commercial and commercial luminaires that work together to provide unique solutions for various applications, including multi-family, hospitality, assisted living, workplace environments and many others.

Our collection of proven lighting designs is diverse and versatile, with style and function for any type of space. We offer more than 100 new integrated LED options that present numerous benefits over traditional sources, such as energy savings, increased light and color output, easy installation and low maintenance.

We understand that multi-use projects require both interior and exterior lighting solutions that meet the specific needs of each area. We have interior lighting in the latest style trends, such as decorative fixtures for the bath and vanity, kitchen and living areas, as well as exterior fixtures that consider security, pedestrian safety, maintenance and site lighting needs.

For more than 100 years, Progress Lighting has been a leading provider of reliable commercial fixtures that represent aesthetics, performance, innovation and value. Our complete lighting solutions meet or exceed individual project needs, every time.

Area Lighting

PCAPAB SERIES Bronze	p.18	PCPA SERIES Black, Bronze, Grey	p.18	PCPTS SERIES Black, Bronze	p.19
--------------------------------	------	---	------	--------------------------------------	------



PCPTD SERIES Black, Bronze	p.19	PCAD SERIES Black, Bronze	p.20	PCAD SERIES Black, Bronze, Green	p.21
--------------------------------------	------	-------------------------------------	------	--	------



POLES AND DECORATIVE ARMS Multiple Options	p.22
--	------



Low Level Pathway

BOLLARDS Black, Bronze	p.20	STEP LIGHTS LED Multiple Finishes	p.26	STEP LIGHTS LED Multiple Finishes	p.26	STEP LIGHTS LED Multiple Finishes	p.26
----------------------------------	------	---	------	---	------	---	------



STEP LIGHTS LED Multiple Finishes	p.26	INTEGRATED LED LOW VOLTAGE Black	p.27	INTEGRATED LED LOW VOLTAGE Black	p.27	INTEGRATED LED LOW VOLTAGE Black	p.27
---	------	--	------	--	------	--	------



INTEGRATED LED LOW VOLTAGE Black, Brushed Nickel	p.27	INTEGRATED LED LOW VOLTAGE Antique Bronze, Black	p.27	INTEGRATED LED LOW VOLTAGE Black	p.27	INTEGRATED LED LOW VOLTAGE Black	p.27
--	------	--	------	--	------	--	------



INTEGRATED LED LOW VOLTAGE Black	p.27	ACCESSORIES Black	p.27
--	------	-----------------------------	------



Wall/ Surface & Outdoor

PCOWC SERIES Bronze	COMMERCIAL WALL PACK Bronze	COMMERCIAL WALL PACK Bronze	ALUMINUM CYLINDERS LED Multiple Finishes
p.31	p.31	p.31	p.32



ALUMINUM SQUARES LED Multiple Finishes	CYLINDER ACCESSORIES Multiple Finishes	BROOKSIDE LED Multiple Finishes	DISTRICT LED Multiple Finishes
p.34	p.34	p.35	p.35



CEDAR SPRINGS Multiple Finishes	CEDAR SPRINGS WALL Multiple Finishes	BELL LED Multiple Finishes	ENDORSE LED Antique Bronze, Black
p.36	p.37	p.38	p.38



WESTPORT LED Antique Bronze, Black	BULKHEADS LED Black, White	STRATA LED Multiple Finishes	CORNICE LED Multiple Finishes
p.39	p.40	p.41	p.41



Wall/ Surface & Outdoor

Z-1030 LED Black, Metallic Grey	Z-1010 LED Multiple Finishes	Z-1020 LED Architectural Bronze, Black	VALERA LED Multiple Finishes
p.42	p.42	p.43	p.43



Z-1070 LED Multiple Finishes	Z-1080 LED Black, Metallic Grey	Z-1090 LED Black, Metallic Grey	Z-1060 LED Black
p.44	p.44	p.45	p.45



Flood Lighting

COMMERCIAL FLOODLIGHT Bronze	COMMERCIAL FLOODLIGHT Bronze	COMMERCIAL CANOPY Bronze
p.30	p.30	p.30



Egress

EXIT SIGN White- Green, Red	COMBO EXIT/ EMERGENCY White- Green, Red	ALUMINUM EXIT SIGN Brushed Aluminum	WET LOCATION EXIT SIGN White - Green, Red	EDGE-LIT EMERGENCY EXIT Brushed Aluminum
p.48	p.48	p.48	p.49	p.49



Linear

RECESSED PERFORMANCE White	LOW PROFILE WRAPAROUND White	STAIRWELL LUMINAIRE White	LINEAR VAPOR TIGHT White	LOW PROFILE LENS STRIP White
p.54	p.54	p.54	p.54	p.55



LINEAR CLOUD LED White	WRAP & STRIP LED White	SURFACE MOUNT LINEAR LED Multiple Finishes
p.55	p.55	p.56



Undercabinet

PUCK LED Multiple Finishes	UNDERCABINET LED Antique Bronze, White	TAPE LED Multiple Lengths	TAPE LED CONNECTORS Black	TAPE LED ACCESORIES Multiple Options
p.56	p.57	p.58	p.59	p.59



Recessed Downlighting

EDGELIT RECESSED LED Multiple Finishes	EDGELIT ACCESSORIES Multiple Options	4" LED HOUSING Multiple Options	4" LED ROUND TRIM Multiple Finishes	4" LED EYEBALL Multiple Finishes
p.60	p.61	p.62	p.62	p.62



5" RECESSED LED HOUSING Multiple Options	5" LED ROUND TRIM Multiple Finishes	5" LED EYEBALL TRIM Multiple Finishes	5" RECESSED HOUSING Remodel Shallow	SHOWER TRIM White
p.63	p.63	p.63	p.64	p.64



STEP BAFFLE White	EYEBALL White	6" RECESSED LED HOUSING New Construction	6" LED TRIM 1000 LUMENS White	6" LED TRIMS Multiple Finishes
p.64	p.64	p.65	p.65	p.65



Surface Mount Downlighting

EVERLUME™ ROUND SURFACE MOUNT LED White p.66	EVERLUME™ ROUND TRIM ACCESSORIES Multiple Finishes p.67	ROUND SURFACE MOUNT LED White p.68	EMBLEM SURFACE MOUNT LED Bronze, White p.68	INTRINSIC SURFACE MOUNT LED White p.68
--	---	--	---	--



DECORATIVE SURFACE MOUNT LED Multiple Finishes p.69	RETROFIT RECESSED ACCESSORIES Multiple Options p.69
---	---



DFS Series

DFS SERIES SQUARE DRUM Multiple Finishes p.72	DFS SERIES ROUND DRUM Multiple Finishes p.73	DFS SERIES DOUBLE LAYER Multiple Finishes p.74	DFS SERIES INNER STEP Multiple Finishes p.74	DFS SERIES DOME-IN-SHADE Multiple Finishes p.75
---	--	--	--	---



DFS SERIES TAPERED SHADE Multiple Finishes p.75	DFS SERIES HALF CYLINDER Multiple Finishes p.76	DFS SERIES HOURGLASS Multiple Finishes p.76	DFS SERIES CONCAVE Multiple Finishes p.77	DFS SERIES VERICAL SWEEP Multiple Finishes p.77
---	---	---	---	---



Close-to-Ceiling

DFS SERIES DOUBLE SQUARE Multiple Finishes p.77	APOGEE LED Multiple Finishes p.78	WEAVER LED Multiple Finishes p.80	BEYOND LED Brushed Nickel p.80	SURFACE MOUNT LED Multiple Finishes p.81
---	---	---	--	--



HELM LED Multiple Finishes p.82	FRESNEL LED Multiple Finishes p.82	BEZEL LED Multiple Finishes p.83	FINESSE LED Multiple Finishes p.84	MINGLE LED Multiple Finishes p.85
---	--	--	--	---



INSPIRE LED Multiple Finishes p.86	DOMED LED Multiple Finishes p.86	PORTAL LED Multiple Finishes p.87	GATHER LED Multiple Finishes p.87	FLUSH MOUNTS LED Multiple Finishes p.88
--	--	---	---	---



SQUARE ALABASTER GLASS LED Multiple Finishes p.90	SQUARE LINEN GLASS LED Multiple Finishes p.90	CLOUD + DRUM LED Black, White p.91	MAIER DC LED Multiple Finishes p.92	OPAL-LINEN LED Multiple Finishes p.93
---	---	--	---	---














MILFORD LED Black p.93	LINEN LED Brushed Nickel p.94	6" FITTER LED Brushed Nickel, White p.94
----------------------------------	---	--
















Sconces/Bath

FRAME LED Multiple Finishes p. 95, 102	TRUSS LED Multiple Finishes p.95, 102	APOGEE LED Multiple Finishes p.95	ECLIPSE LED Multiple Finishes p.96	INSPIRE LED Multiple Finishes p.96
				
ANSON LED Architectural Bronze p.96	LED SCONCES Multiple Options p.97	LED SCONCES Multiple Finishes p.97	PONDER LED Multiple Finishes p.98	CAPELLI LED Polished Chrome p.98
				
MITER LED Brushed Nickel p.99	CONCOURSE LED Brushed Nickel p.99	COLONNADE LED Multiple Finishes p.100	BEAM LED Multiple Finishes p.101	PLANCK LED Brushed Nickel p.101
				
PARALLEL LED Multiple Finishes p.103	BLANCO LED Multiple Finishes p.104	ACE LED Multiple Finishes p.105	PHASE 1.1 LED Brushed Nickel p.106	PHASE 1.2 LED Brushed Nickel p.106
				
PHASE 2.1 LED Brushed Nickel p.107	PHASE 2.1 LED Brushed Nickel p.107	BATH LED Brushed Nickel p.108	CLOUD LED Opal White p.109	CAPTARENT Mirrored p.110
				

Pendants

MARKOR PENDANT Multiple Options p.113	ROUND CANOPY Multiple Finishes p.114	LINEAR CANOPY Multiple Finishes p.115	PLANCK LED Multiple Finishes p.117	CONCOURSE LED Brushed Nickel p.118
				
FRESNEL LENS LED Multiple Finishes p.119	BROOKSIDE LED Brushed Nickel p.120	BEAKER LED Polished Chrome p.120	DOME LED Multiple Finishes p.121	GLOBE LED Multiple Finishes p.122
				
PRISMATIC GLASS LED Brushed Nickel p.123	NEAT LED Multiple Finishes p.123	AVANT LED Multiple Finishes p.124	SIMPLE LED Multiple Finishes p.124	PURE LED Brushed Nickel p.125
				
WAREHOUSE PENDANT LED Multiple Finishes p.125				
				

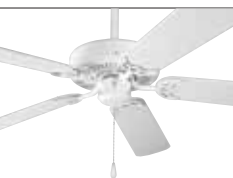Ceiling Fans

VAST Multiple Finishes p.128	SANFORD Multiple Finishes p.130	GAZE Multiple Finishes p.131	ORIOLE Multiple Finishes p.132	SOAR Multiple Finishes p.133
				
GUST Multiple Finishes p.134	KUDOS Multiple Finishes p.135	52" SIGNATURE FAN Multiple Finishes p.136	TREVINA II 52" Multiple Finishes p.138	SIGNATURE PLUS II Multiple Finishes p.139
				
52" BUILDER FAN Multiple Finishes p.140	42" BUILDER FAN Multiple Finishes p.141	52" PATIO FAN Multiple Finishes p.142		
				





Site Lighting

UNIFORM ILLUMINATION FOR OUTDOOR
COMMERCIAL SPACES

Our selection of site lighting and accessories provides consistent illumination for parking lots, walkways, building grounds, common and other outdoor areas for increased safety, including LED area lights for additional control and energy savings.

PCPAB Series

Economy Series Parking/Site Luminaire

The PCPAB series is designed to provide efficient illumination for parking and area lighting applications, utilizing high power LEDs. The PCPAB is offered in 10,000, 16,000 and 30,000 lumen versions. All models standard as 4000K CCT.

Series	Wattage	Lumens	Distribution	Finish	CCT/CRI
PCPAB	80LED - 80W	10000	2 - Type 2	BZ - Bronze	4000K/80CRI
	140LED - 140W	16000	3 - Type 3		
	240LED - 240W	30000	4 - Type 4		
			5 - Type 5		



Ships within 5 days



PCPA Series

Performance Series Parking/Site Luminaire


The PCPAS and PCPAL series are designed to provide high performance illumination for parking and area lighting applications, utilizing high power LEDs. The PSPAS is offered in 5,000 to 9,000 lumen versions. The PSPAL is offered in 15,000 to 27,000 lumen versions. All models standard as 4000K CCT.

Series	Wattage	Lumens	Distribution	Finish	Options
PCPAS - Parking/Area Small	55LED - 55W*	5900-6260	2 - Type 2	BZ - Bronze	Blank
PCPAL - Parking/Area Large	80LED - 80W*	8800-9400	3 - Type 3	BL - Black GY - Gray	P - Photocell
	135LED - 135W**	15500-18000	4 - Type 4		BC - Backlight Control
	180LED - 180W**	19800-22650	4W - Type 4 Wide		
	235LED - 235W**	23800-27400	5R - Type 5 Rectangle 5W - Type 5 Round		



*Small only

**Large only

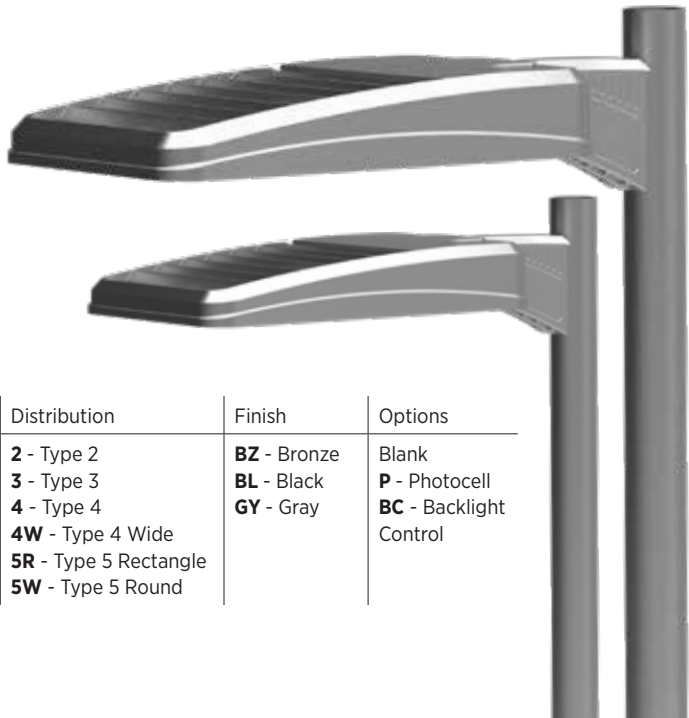

Post Top Shade

Decorative Post Top Shade Luminaire

The PCPTS series is ideal for parking, area and pedestrian lighting applications. The full top shade design provides the benefit of full cut-off. Luminaire is offered in 2,600 to 10,500 lumen versions. All models standard as 4000K CCT.

Series	Wattage	Lumens	Distribution	Finish	Options
PCPTS	27LED - 27W	2600-2950	2 - Type 2	BZ - Bronze BL - Black	Blank
	55LED - 55W	4900-5470	3 - Type 3		PC120 - 120V Photocell
	80LED - 80W	7400-8200	4 - Type 4		PC277 - 277V Photocell
	110LED - 110W	9800-10900	4W - Type 4 Wide		BC - Backlight Control
			5R - Type 5 Rectangle 5W - Type 5 Round		

Size: 25-1/2" W., 24-1/4" ht.



Post Top Designer

Designer Post Top Luminaire

The PCPTD series offers decorative and contemporary aesthetics, and is ideal for area and pedestrian lighting applications. Luminaire is offered in 4,500 to 11,500 lumen versions. All models standard as 4000K CCT.

Series	Wattage	Lumens	Distribution	Finish	Options
PCPTD	55LED - 55W	4600-4750	3 - Type 3	BZ - Bronze BL - Black	Blank
	80LED - 80W	6900-7100	4 - Type 4		PC120 - 120V Photocell
	110LED - 110W	9250-9500	5 - Type 5		PC277 - 277V Photocell

Size: 18-7/16" W., 36" ht.



Post Top Globe

Globe Post Top Luminaire

The PCPTG series offers a traditional globe design ideal for area and pedestrian lighting applications. Luminaire is offered in 2,000 to 4,500 lumen versions. All models standard as 4000K CCT.

Series	Wattage	Lumens	Distribution	Finish	Options
PCPTG	27LED - 27W	2350-2800 4220-4675	3 - Type 3	BZ - Bronze	Blank PC120 - 120V Photocell PC277 - 277V Photocell
	55LED - 55W		4 - Type 4	BL - Black	
			5 - Type 5		

Size: 16-3/5" W., 25" ht.



Bollards

Provides ideal low level lighting for sidewalks, courtyards, and pedestrian walkways. Available in round or square, and offers both asymmetric and symmetric distribution options. All models standard as 4000K CCT. Turtle friendly amber option available.

Series	Wattage	Lumens	Finish
PCBOR - Bollard Round	ASY - 27w LED	650 - 940 1440 - 1780 314, 590 NM	BZ - Bronze
PCBOS - Bollard Square	SYM - 41w LED		BL - Black
	SYMAMB - 20w LED		

Size: Round - 6.75" sq., 42" ht. Square - 7" dia., 42" ht.



PCBOR

PCBOS

PCAD Series

Designer Series Parking/Site Luminaire

The PCADS and PCADL series are designed for parking and area lighting applications utilizing high power LEDs, while providing contemporary aesthetics. The PSADS/PCADL is offered in 6,000 to 12,500 lumen versions.



Series	Wattage	Lumens	Color Temp	Distribution	Finish	Options
PCADS - Designer Small PCADL - Designer Large	55LED - 55W 80LED - 80W 110LED - 110W *	6000-6450 9000-9700 12000-12900	3K - 3000K, 70CRI 4K - 4000K, 70CRI	2 - Type 2 3 - Type 3 4 - Type 4 4W - Type 4 Wide 5R - Type 5 Rectangle 5W - Type 5 Round	BZ - Bronze BL - Black GN - Green	Blank PC120 - 120V Photocell PC277 - 277V Photocell BC - Backlight Control




*Large only


Decorative Arms

Series	Profile	Shaft Sizes	Arrangement	Mounting
AA-25	W - Wall Mount	4 - 4"	A - Wall (single)	P - Pendant
AA-39	S - Smooth	5 - 5"	B - Single	T - Tenon
AA-44	F - Fluted		C - Double	
AA-52				


AA-25

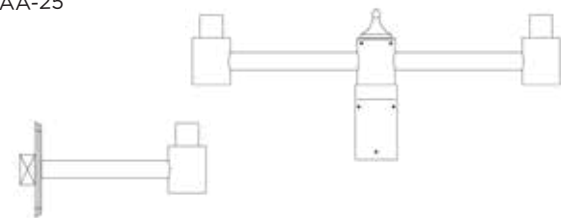


AA-39

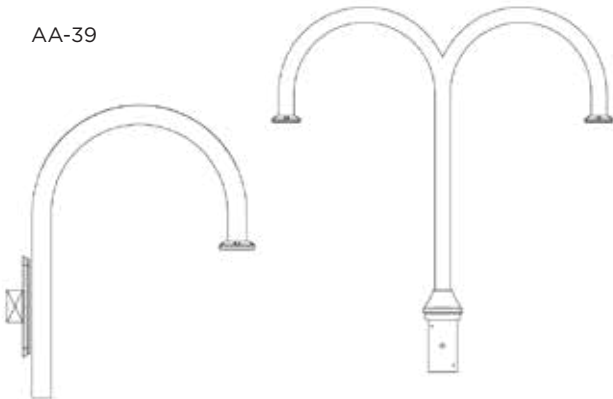

AA-44

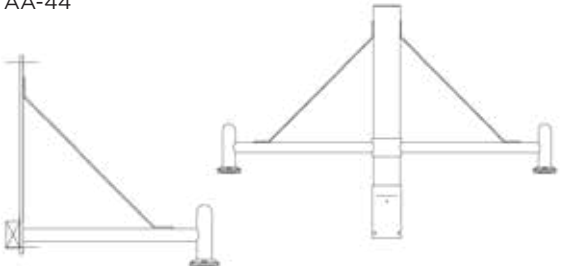

AA-52

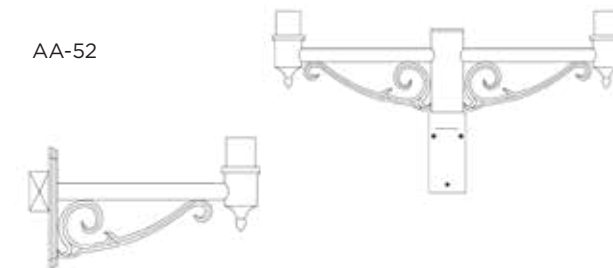

Poles

Constructed with exacting standards both our aluminum and steel products meet strict guidelines for quality, strength and finish durability. Protecting your investment for years is our Lektrocote® powder paint finish, available in bronze, black and textured green. From shaft cutting through finishing, quality control inspections are conducted throughout a highly automated process.



RSS-P



SSS-P



FLAK



CEAK



CENA

Steel Products

Series	Construction	Shaft Sizes	Wall Thickness	Lengths
SSS-P	Square Straight Steel	4", 5"	.125", .188"	10 – 30 ft
RSS-P	Round Straight Steel	4", 4.5", 5"	.125", .188"	10 – 25 ft

Aluminum Products - Anchor Base

Series	Construction	Shaft Sizes	Wall Thickness	Lengths
SSA-P	Square Straight Aluminum	4", 5"	.125", .188"	8 - 25 ft
RSA-P	Round Straight Aluminum	3", 4", 4.5", 5"	.125", .188", .250"	8 – 25 ft
RSA-P-F	Round Straight Aluminum Fluted	4", 5"	.188"	8 – 24 ft
RTA-P	Round Tapered Aluminum	4", 5"	.125"	10 – 20 ft

Aluminum Products - Direct Burial

Series	Construction	Shaft Sizes	Wall Thickness	Lengths
RSA-P-DBE-S	Round Straight Aluminum Smooth	3", 4", 5"	.125", .188", .250"	8 - 16 ft
RSA-P-DBE-F	Round Straight Aluminum Fluted	3", 4", 5"	.125", .188"	8 - 16 ft

Aluminum Products - Decorative


Series	Construction	Shaft Sizes	Wall Thickness	Lengths
RSA-P-CENA-S	Round Straight Aluminum Smooth	4"	.125", .188", .250"	10 – 24 ft
RSA-P-CENA-F	Round Straight Aluminum Fluted	4"	.188"	10 – 24 ft
RSA-P-CEAK-S	Round Straight Aluminum Smooth	4"	.125", .188", .250"	10 – 24 ft
RSA-P-CEAK-F	Round Straight Aluminum Fluted	4"	.188"	10 – 24 ft
RSA-P-FLAK-S	Round Straight Aluminum Smooth	4"	.125", .188", .250"	10 – 24 ft
RSA-P-FLAK-F	Round Straight Aluminum Fluted	4"	.188"	10 – 24 ft

Composite Poles

Composite construction allows for durability, impact resistance, corrosion resistance and low maintenance. Light weight allows for labor and time savings, oftentimes without use of heavy equipment, while maintaining structural integrity, allowing for resistance of wind loads up to 180 mph. Ideal applications include residential, multi-family, hotel/motel, assisted living, and light commercial.


Composite Products

Series	Construction	Shaft	Lengths
RTC-P-XX-SM	Round Tapered Fiberglass	Smooth	10 – 25 ft
RTC-P-XX-FL	Round Tapered Fiberglass	Fluted	10 – 25 ft

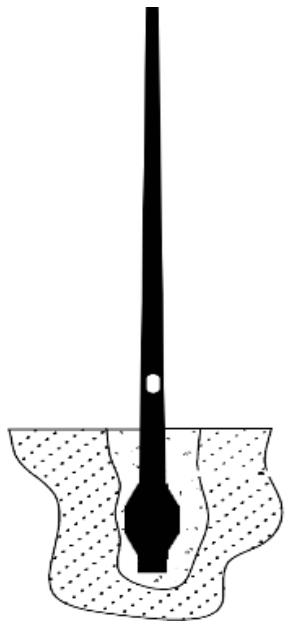


Distribution Types


Our offering of area and post-top luminaires allow for options for distribution types. These distribution options range from types 2-5, and each type provides a different performance. Below is each type explained in detail to provide a better understanding of luminaire type performance.

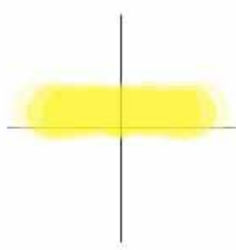


Type 2 – A long, narrow distribution of light, commonly used for roadway and entrance lighting.

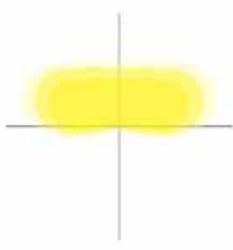

Type 3 – A forward distribution of light, commonly used for parking areas and general roadway lighting.

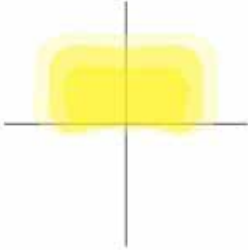


Type 4 – A forward distribution of light, commonly used for parking areas and area illumination from wall mounting.

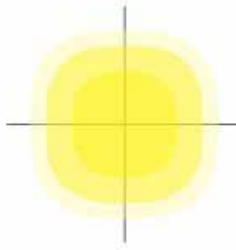


Type 5 – A circular or square distribution of light that has near equal intensity in all directions. Generally used in centers of parking areas.

ASCE7-05 Wind Map

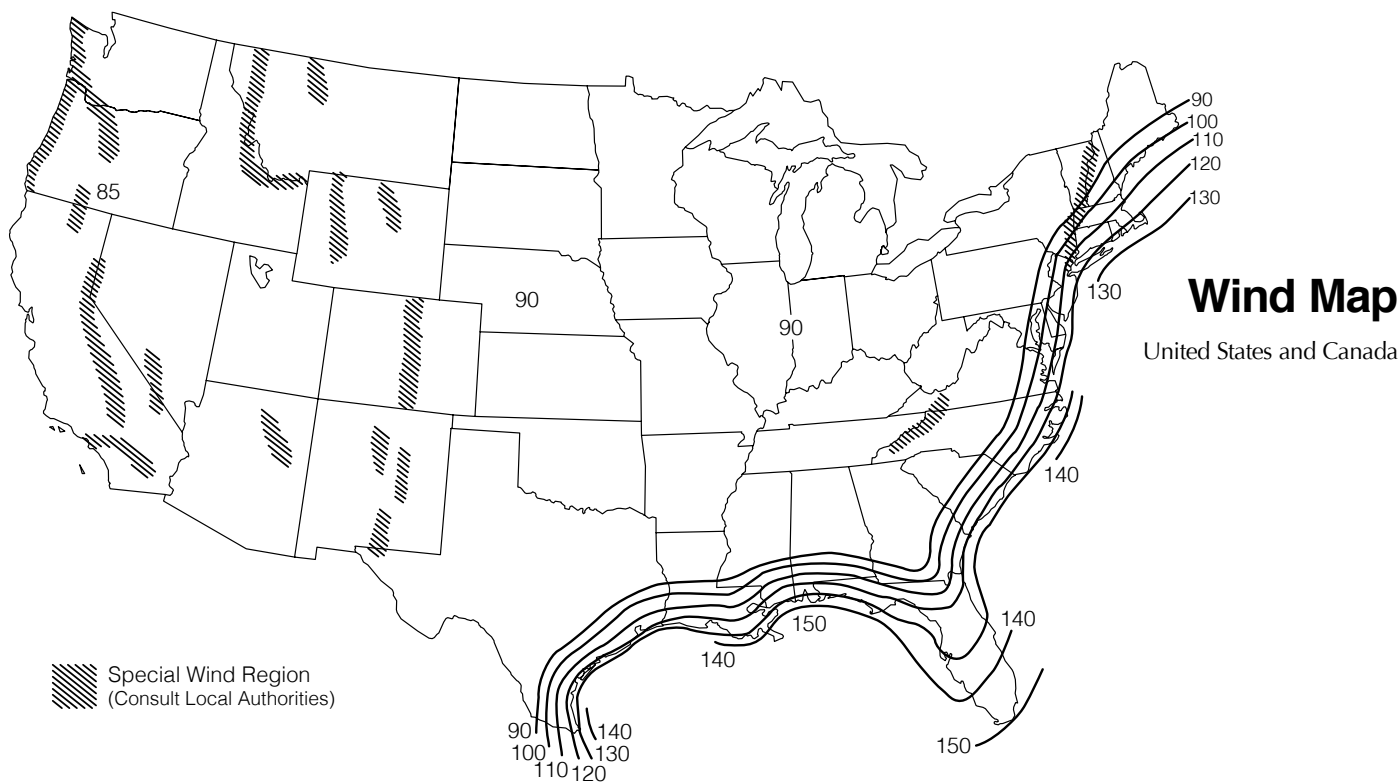

Florida Region Wind Map

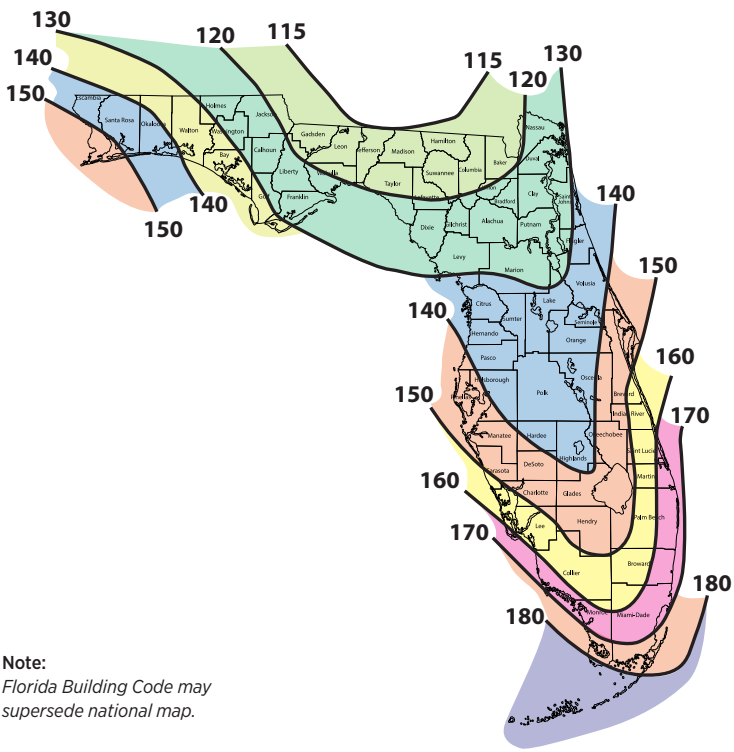

Wind Map Notes

- Values are based on 50 year mean recurrence interval 30’ above grade.
- Hawaii has an 105 mph wind velocity.
- Puerto Rico has a 125 mph wind velocity.
- Caution must be exercised in determining wind velocities in special wind areas such as:
 - Mountainous Regions
 - Areas surrounding the Great Lakes or other large bodies of water or open land.
 - Areas subject to extreme wind conditions, such as hurricanes, typhoons, cyclones, and tornadoes.
 - Areas adjacent to airports.
 - Any specific area with a known or suspected abnormally high intermittent wind condition caused by geography, adjacent structures, or other specific local conditions that may not be recorded in National Weather Service records.
- Allowable pole EPA for jobsite wind conditions must be equal to or greater than fixture EPA. Responsibility lies with the specifier for correct pole selection based on ASCE7-05 wind map and job location.
- The Wind Map is intended only as a general guide. Always consult local authorities to determine maximum wind velocities, gusting and unique wind conditions for each specific application.

Caution

- Wind speeds and listed EPAs are for ground mounted installations. Poles mounted on structures (such as bridges and buildings) must consider vibration and coefficient of height factors beyond this general guide. Consult AASHTO standards.
- Extreme Wind Events: Hurricanes, Typhoons, Cyclones, or Tornadoes expose poles to flying debris, wind shear, and other unpredictable aerodynamic forces not indicated by the wind velocity ratings.
- Pole Strength Limited Warranty: Standard, unmodified Progress Commercial Lighting Poles installed as recommended, undamaged by corrosion, or lack of maintenance, shall withstand steady wind conditions on each pole’s Allowable Pole EPA chart. Installation of poles without luminaries, or attachment of any unauthorized accessories to poles shall void this warranty.

EPA Information

All allowable pole and fixture EPAs (Fixture Area x Drag Factor) are derived from the AASHTO standard (American Association of State Highway and Transportation Officials). Responsibility lies with the specifier for correct pole selection based on local codes and standards for the job location.

To obtain more information on AASHTO Standards for Lighting Equipment contact:
 American Association of State Highway and Transportation Officials
 444 N. Capitol Street, NW, Suite 249
 Washington, DC 20001
 202 624-5800
www.aashto.org

AASHTO standards used are found in the following publications:
 I-LTS-4 “Standard Specification for Structural Support for Highway Signs, Luminaries and Traffic Signals,” (2001).

Important

Do not erect poles without luminaries in place. Any accessories attached to pole, or other modifications will compromise pole strength and may result in pole failure.

Maintenance

A regularly scheduled maintenance program must be established to insure the protective paint coating is intact, corrosion or structural damage has not occurred, and anchor bolt nuts are tight. Failure to do so could lead to pole collapse and personal injury.

Step Lights LED

Product No.	Finish	Size	Source	Input
P6827-0930K P6827-2030K P6827-3030K P6827-3130K	Brushed Nickel Antique Bronze White Black	5-1/4" W., 3-1/2" ht.	5w LED module, 100 lumens, 22 lumens/watt	120V

P6827-2030K



P6827-3030K



P6827-3130K



P6827-0930K

Product No.	Finish	Size	Source	Input
P6828-0930K P6828-2030K P6828-3030K P6828-3130K	Brushed Nickel Antique Bronze White Black	3-1/2" W., 5-1/4" ht.	5w LED module, 100 lumens, 22 lumens/watt	120V

P6828-2030K



P6828-3030K



P6828-3130K



P6828-0930K

Product No.	Finish	Size	Source	Input
P6829-0930K P6829-2030K P6829-3030K P6829-3130K	Brushed Nickel Antique Bronze White Black	2-7/8" W., 4-1/2" ht.	5w LED module, 84 lumens, 18 lumens/watt	120V

P6829-2030K



P6829-3030K



P6829-3130K



P6829-0930K

Product No.	Finish	Size	Source	Input
P6832-0930K P6832-2030K P6832-3030K P6832-3130K	Brushed Nickel Antique Bronze White Black	4-1/2" W., 2-7/8" ht.	4.5w LED module 65 lumens, 14 lumens/watt	120V

P6832-2030K



P6832-3030K



P6832-3130K



P6832-0930K

Integrated LED Low Voltage

Product No.	Finish	Size	Source	Input
P5246-31	Black	5-3/8" W., 2-3/8" ht.	1 LED, 1.5w	12V
P5295-31		5" dia., 4" ht.	1 LED, 3w	
P5296-31		4-1/8" dia., 2-1/4" ht.	3 LEDs, 1.5w	
P5299-31		4-1/2" dia., 6-5/8" ht.	1 LED, 3w	
P5245-20 P5245-31	Antique Bronze Black	6-1/2" dia., 20-3/4" ht.	1 LED, 1.5w	
P5247-09 P5247-31	Brushed Nickel Black	2-5/8" dia., 24" ht.	1 LED, 1.5w	
P5297-31	Black	7" dia., 16-1/2" ht.	1 LED, 1.5w	
P5298-31	Black	5-1/8" dia., 17-1/2" ht.	1 LED, 1.5w	



P5246-31



P5295-31



P5296-31



P5247-09



P5247-31



P5245-20



P5245-31



P5298-31



P5297-31



P5299-31

Outdoor Transformers

LED Low Voltage Transformer

Product No.	Finish	Description	Size
P8270-31	Black	LED transformer	120V
P8618-31	Black	Ground stake	8-3/4"



P8618-31



P8270-31




Building Exterior

BENEFICIAL LIGHTING SOLUTIONS FOR A
WELL-DESIGNED COMMERCIAL EXTERIOR

Our comprehensive line of exterior solutions includes site/area lighting, landscape lighting, entryway, egress and more lighting options to give your business a competitive edge by improving property values and reducing utility costs.

Commercial Floodlights

Product No.	Finish	Size	Source	Input
PCOEF-30LED-4K-KM-BZ PCOEF-30LED-4K-YM-BZ	Bronze	7-1/4" W., 7" ht., 1-1/2" D.	27w LED, 5000K, 2040 lumens	120 - 277V, 50 or 60 Hz 
PCOEF-50LED-4K-KM-BZ PCOEF-50LED-4K-YM-BZ		8-1/2" W., 8" ht., 1-7/8" D.	53w LED, 5000K, 4825 lumens	
PCOLF-15LED-3K-KM-BZ		3" W., 5-1/4" ht., 4-1/4" D.	14w LED, 3000K, 1495 lumens	



PCOEF-30LED-4K-YM-BZ
Shown as yoke mount.
Knuckle mount also available.





PCOEF-50LED-4K-YM-BZ
Shown as yoke mount.
Knuckle mount also available.



PCOLF-15LED
Shown with canopy mount accessory.
Accessories sold separately.

Commercial Canopy

Product No.	Finish	Size	Source	Input
PCOCY-45LED-5K-BZ	Bronze	10" L., 10" W., 3-5/8" ht.	45w LED, 5000K, 80CRI, 4700 lumens	120 - 277V, 50 or 60 Hz  
PCOCY-80LED-5K-BZ		14" L., 14" W., 4" ht.	80w LED, 5000K, 80CRI, 9660 lumens	





PCOCY-45LED-5K-BZ



PCOCY-80LED-5K-BZ

PCOWC SERIES Wall Pack

Full cutoff distribution with no uplight. Turtle friendly amber option available (AMB).

Product No.	Finish	Size	Source	Input
PCOWC-20LED-20	Bronze	8.22" W., 5.25" ht., 4.81" dia.	18w LED, 4000K, 1421 lumens	120 - 277V, 50 or 60 Hz  
PCOWC-30LED-20		10.25" W., 5.6" ht., 6.25" dia.	29w LED, 4000K, 2246 lumens	
PCOWC-45LED-20			45w LED, 4000K, 3096 lumens	
PCOWC-45LED-20-AMB		10.25" W., 5.6" ht., 6.25" dia.	32w LED, 590 NM	
PCOWC-20LED-28	White	8.22" W., 5.25" ht., 4.81" dia.	18w LED, 4000K, 1421 lumens	
PCOWC-30LED-28		10.25" W., 5.6" ht., 6.25" dia.	29w LED, 4000K, 2246 lumens	
PCOWC-45LED-28			45w LED, 4000K, 3096 lumens	
PCOWC-20LED-82	Metallic Gray	8.22" W., 5.25" ht., 4.81" dia.	18w LED, 4000K, 1421 lumens	
PCOWC-30LED-82		10.25" W., 5.6" ht., 6.25" dia.	29w LED, 4000K, 2246 lumens	
PCOWC-45LED-82			45w LED, 4000K, 3096 lumens	

*Turtle Friendly ONLY
PCOWC-45LED-20AMB



PCOWC-20LED-20





PCOWC-45LED-20



PCOWC-30LED-20

Commercial Wall Pack

Product No.	Finish	Size	Source	Input
PCOWP-30LED-4K-BZ	Bronze	14-3/8" W., 9-1/4" ht., 7-3/8" D.	30w LED, 4000K, 80CRI, 351 lumens	120 - 277V, 50 or 60 Hz  
PCOWP-60LED-4K-BZ		8-9/16" W., 8-9/16" ht., 9-3/4" D.	60w LED, 4000K, 80CRI, 6700 lumens	
PCOWF-50LED-4K-BZ		14" W., 8-1/4" ht., 8-1/4" D.	50w LED, 4000K, 80CRI, 6350 lumens, full cutoff distribution with no uplight	



PCOWP-30LED-4K-BZ



PCOWF-50LED-4K-BZ







PCOWP-60LED-4K-BZ

Aluminum Cylinders LED

Sleek, cylindrical forms in elegant finish selections. Die-cast aluminum wall brackets and heavy-duty aluminum framing. Fade and chip-resistant. UL listed for wet locations when used with lens cover. Dark Sky compliant for down light only. 90+ CRI.

3" Aluminum Cylinders LED

Product No.	Finish	Description	Size	Source	Input
P563000-020-30K P563000-030-30K P563000-143-30K P563000-147-30K	Antique Bronze White Graphite Satin Nickel	One-light down For wet locations	5-1/2" W., 5-5/8" ht.	One 12w integrated LED, 3000K, 90CRI 900 delivered lumens	120V    
P563001-020-30K P563001-030-30K P563001-143-30K P563001-147-30K	Antique Bronze White Graphite Satin Nickel	Two-light down For wet locations	5-1/2" W., 8-1/4" ht.	Two 24w integrated LED, 3000K, 90CRI 1800 delivered lumens	



P563000-020-30K



P563000-030-30K



P563000-143-30K



P563000-147-30K



P563001-020-30K



P563001-030-30K






P563001-143-30K




P563001-147-30K

5" Aluminum Cylinders LED

Product No.	Finish	Size	Source	Input
P5674-20/30K P5674-30/30K P5674-31/30K P5674-82/30K	Bronze White Black Metallic Gray	5" W., 7-1/4" ht. Extends 8". H/CTR 2-1/2".	One 17w integrated LED, 3000K, 90CRI 531 delivered lumens up/down	120V   <i>*Dark Sky ONLY P5674 & P5774</i>
P5675-20/30K P5675-30/30K P5675-31/30K P5675-82/30K	Bronze White Black Metallic Gray	5" W., 14" ht. Extends 8". H/CTR 7".	Two 17w integrated LED, 3000K, 90CRI 1025 delivered lumens up/down	
P5774-20/30K P5774-30/30K P5774-31/30K P5774-82/30K	Bronze White Black Metallic Gray	5" W., 6-1/2" ht.	One 17w integrated LED, 3000K, 90CRI 764 delivered lumens	



P5675-20/30K



P5675-82/30K



P5774-20/30K



P5774-31/30K



P5774-30/30K



P5674-31/30K






P5674-20/30K




P5674-82/30K

6" Aluminum Cylinders LED


Product No.	Finish	Size	Source	Input
P5641-20/30K P5641-30/30K P5641-31/30K P5641-82/30K	Bronze White Black Metallic Gray	6" W., 12" ht. Extends 8-7/8". H/CTR 4-1/2".	One 29w integrated LED, 3000K, 90CRI 1800 delivered lumens up/down	120V   <i>*Dark Sky ONLY P5641 & P5741</i>
P5642-20/30K P5642-30/30K P5642-31/30K P5642-82/30K	Bronze White Black Metallic Gray	6" W., 18" ht. Extends 8-7/8". H/CTR 8".	Two 29w integrated LED, 3000K, 90CRI 2566 delivered lumens	
P5741-20/30K P5741-30/30K P5741-31/30K P5741-82/30K	Bronze White Black Metallic Gray	6" dia., 12" ht.	One 29w integrated LED, 3000K, 90CRI 1800 delivered lumens	




P5741-31/30K




P5741-30/30K



P5641-31/30K




P5641-82/30K



P5642-20/30K

Aluminum Squares LED

Heavy-duty aluminum construction, die-cast aluminum wall bracket. UL listed for wet locations. Powder coat for chipping and fading resistance. Dark Sky compliant for down light only. 90+ CRI.

Product No.	Finish	Size	Source	Input
P5643-20-30K P5643-30-30K P5643-31-30K P5643-82-30K	Bronze White Black Metallic Gray	6" W., 12" ht. Extends 8-7/8". H/CTR 4-1/2".	One 29w integrated LED, 3000K, 90CRI 1800 delivered lumens	120V  <i>*Dark Sky ONLY P5643</i>
P5644-20-30K P5644-30-30K P5644-31-30K P5644-82-30K	Bronze White Black Metallic Gray	6" W., 12" ht. Extends 8-7/8". H/CTR 8".	Two 29w integrated LED, 3000K, 90CRI 1800 delivered lumens. up/down	



P5644-20-30K



P5644-30-30K



P5644-31-30K



P5644-82-30K



P5643-20-30K



P5643-30-30K



P5643-31-30K



P5643-82-30K

Cylinder Accessories

Product No.	Finish	Description	Size
P8741-20 P8741-30 P8741-31	Antique Bronze White Black	Pendant kit adapts P5741 ceiling fixture to 6", 12" or 18" stem mounting. Includes canopy, hang-straight swivel, 6" and 12" sections with coupling.	
P860045-031 P860045-030	Black White	Round cylinder cover. Water proof version.	6" dia., 4/5" ht.
P860046-031 P860046-030	Black White	Round cylinder cover. Water proof version.	5" dia.
P860047-031 P860047-030	Black White	Square cylinder cover. Water proof version.	6" wd., 7/9" ht. Extends 6" dp.



P860045-031




P860046-031



P860045-030




P860046-030

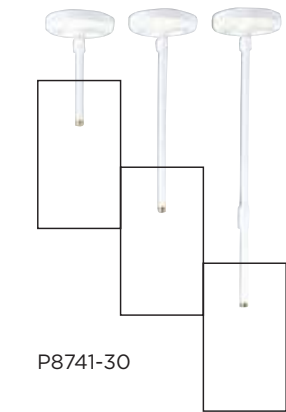

P8741-30



 


P860047-030



P860047-031

Brookside LED

Get inspired from vintage undertones and train station styling with this energy efficient outdoor lantern collection. Available in aluminum with Gilded Iron finish, solid brass with Antique Nickel finish or Solid Copper that ages to a patina finish. Dark Sky compliant.

Product No.	Finish	Size	Source	Input
P5723-1430K9 P5723-7130K9 P5723-8130K9	Copper Gilded Iron Antique Nickel	12" W., 12-1/4" ht. Extends 13-1/4". H/CTR 6-7/8"	One 17w LED module, 3000K, 90CRI 1211 source lumens	120V   



P5723-1430K9






P5723-7130K9



P5723-8130K9

District LED

The outdoor lanterns from the District Collection features a metal shade that offers an industrial-inspired design. The versatile vintage form can be used in outdoor applications. Dark Sky compliant.

Product No.	Finish	Size	Source	Input
P5622-2030K9 P5622-8230K9	Antique Bronze Metallic Gray	8" W., 8-1/4" ht. Extends 10-1/4". H/CTR 4-1/8".	One 9w LED module, 3000K, 90CRI 623 source lumens	120V   
P5623-2030K9 P5623-8230K9	Antique Bronze Metallic Gray	12" W., 10-1/2" ht. Extends 13-1/4". H/CTR 5".		



P5622-2030K9



P5622-8230K9




P5623-2030K9



P5623-8230K9

Cedar Springs

A fun take on the traditional warehouse shade, the Cedar Springs Collection features a signature gooseneck arm and a smooth, simple, metal shade. This modern collection provides excellent task lighting for reading a book in your bedroom or illuminating a doorway in your home. Dark Sky Compliant.

Product No.	Finish	Size	Source
P550070-030 P550070-031 P550070-039 P550070-079 P550070-082 P550070-091	White Black Red Pistachio Metallic Gray Navy	13-1/4" dia., 9-1/2" ht.	One medium base lamp, 100w max. 



P550070-030



P550070-031



P550070-039




P550070-079



P550070-082



P550070-091

Product No.	Finish	Size	Source
P560091-030 P560091-031 P560091-039 P560091-079 P560091-082 P560091-091	White Black Red Pistachio Metallic Gray Navy	13-1/4" W., 11-1/4" ht. Extends 21-5/8". H/CTR 7-1/4".	One medium base lamp, 100w max. 



P560091-030



P560091-031



P560091-039



P560091-079






P560091-082



P560091-091

Bell LED

Featuring nautical undertones, the Bell outdoor collection offers cage lights reminiscent of industrial architecture. Ideal for use in both interior and exterior settings, this LED fixture is available in convertible ceiling/pendant and wall mount options.

Product No.	Finish	Size	Source	Input
P5676-2030K9 P5676-13630K9	Antique Bronze Textured Graphite	5-1/2" W., 10-5/8" ht. Extends 7-3/8". H/CTR 3".	One 9w LED module, 3000K, 90CRI 623 lumens	120V   






P5676-2030K9



P5676-13630K9

Endorse LED

Endorse celebrates the traditional form of a gas-powered coach light with illumination from a modern LED source. A die-cast aluminum, powder coated frame creates an intriguing visual effect with clear beveled glass.

Product No.	Finish	Size	Source	Input
P6058-3130K9	Black	6-3/4" W., 12" ht. Extends 7-5/8". H/CTR 3-1/4".	One 9w LED module, 3000K, 90CRI 623 lumens	120V   
P6056-3130K9	Black	8-3/4" W., 14-3/4" ht. Extends 9-3/4". H/CTR 4".		
P6057-3130K9	Black	10-3/4" W., 17-3/4" ht. Extends 11-3/4". H/CTR 4".		
P6426-3130K9	Black	Fits 3" post (sold separately) 3" W., 21" ht.		



P6056-3130K9



P6057-3130K9






P6058-3130K9



P6426-3130K9

Westport LED

Westport LED offers traditional styling to complement a variety of home décor options. A durable, die-cast aluminum frame cradles a softly diffused, seeded glass shade.

Product No.	Finish	Size	Source	Input
P5862-2030K9 P5862-3130K9	Antique Bronze Black	6-7/8" W., 10-1/4" ht. Extends 8-3/8". H/CTR 3-1/8".	One 9w LED module, 3000K, 90CRI 623 source lumens	120V   
P5863-2030K9 P5863-3130K9	Antique Bronze Black	9" W., 12-7/8" ht. Extends 10-3/8". H/CTR 3-3/4"		
P5864-2030K9 P5864-3130K9	Antique Bronze Black	11" W., 15-3/8" ht. Extends 12-7/8". H/CTR 4".	One 17w LED module, 3000K, 90CRI 1211 source lumens	



P5862-2030K9



P5862-3130K9



P5863-2030K9



P5863-3130K9






P5864-3130K9



P5864-2030K9

Bulkheads LED

Robust and energy efficient, LED bulkheads are a general-purpose luminaire. Comprised of a die-cast aluminum frame and polycarbonate diffuser. Fixtures are impact resistant and offer various mounting options and can be widely adopted for indoor and outdoor applications.

Product No.	Finish	Size	Source	Input
P3647-3030K9 P3647-3130K9	White Black	6-1/2" W., 10-1/2" ht. Extends 4-3/8". H/CTR 5-1/4".	One 9w LED module, 3000k, 90CRI 623 source lumens	120V   
P3648-3030K9 P3648-3130K9	White Black	9-1/2" W., 4-3/8" ht. H/CTR 4-3/4".	One 17w LED module, 3000k, 90CRI 623 source lumens	
P3649-3030K9 P3649-3130K9	White Black	6-1/2" W., 10-1/2" ht. Extends 4-1/2". H/CTR 5-1/4".	One 9w LED module, 3000k, 90CRI 623 source lumens	
P3650-3030K9 P3650-3130K9	White Black	9-1/2" W., 4-1/2" ht. H/CTR 4-3/4".	One 9w LED module, 3000k, 90CRI 623 source lumens	



P3647-3030K9
shown wall-mounted



P3647-3130K9
shown ceiling-mounted



P3648-3130K9
shown wall-mounted



P3648-3030K9
shown ceiling-mounted



P3649-3130K9
shown wall-mounted



P3649-3030K9
shown ceiling-mounted






P3650-3130K9
shown wall-mounted



P3650-3030K9
shown ceiling-mounted

Strata LED

The Strata features a modern, low profile design ideal for residential and multifamily applications. Energy efficient and functional, wall mounted, can be installed indoor and outdoor.

Product No.	Finish	Size	Source	Input
P560090-020-30K P560090-030-30K P560090-031-30K P560090-082-30K	Antique Bronze White Black Metallic Gray	6-5/8" W., 5-1/2" ht.	12w integrated LED, 3000K, 90CRI, 825 delivered lumens.	120V   



P560090-030-30K



P560090-082-30K







P560090-031-30K



P560090-020-30K

Cornice LED

Modern geometric outdoor LED sconces are designed to complement a range of residential and commercial architectural styles. ADA compliant. Available in Black, Antique Bronze and Metallic Gray finishes. Dark Sky compliant.

Product No.	Finish	Size	Source	Input
P5634-2030K9 P5634-3130K9 P5634-8230K9	Bronze Black Metallic Gray	5-1/4" W., 4-3/4" ht. Extends 4". H/CTR 2-3/8".	One 9w LED module, 3000K, 623 lumens ADA	120V    
P5635-2030K9 P5635-3130K9 P5635-8230K9	Bronze Black Metallic Gray	6-1/8" W., 5" ht. Extends 4". H/CTR 2-3/8".	One 9w LED module, 3000K, 623 lumens ADA	



P5634-2030K9



P5634-3130K9



P5634-8230K9



P5635-2030K9





P5635-3130K9



P5635-8230K9

Z-1030 LED





A modern outdoor LED sconce with an architectural-inspired open linear frame and clear glass diffuser. Finished in Black, White, Metallic Gray or Antique Bronze.

Product No.	Finish	Size	Source	Input
P560051-020-30 P560051-030-30 P560051-031-30 P560051-082-30	Antique Bronze White Black Metallic Gray	5-1/8" W., 12" ht. Extends 5-3/4". H/CTR 2-1/4".	One 9w LED module, 3000K, 90CRI 624 source lumens	120V  
P560056-020-30 P560056-030-30 P560056-031-30 P560056-082-30	Antique Bronze White Black Metallic Gray	5-1/8" W., 20" ht. Extends 5-3/4". H/CTR 2-1/4".		



Z-1010 LED




A modern outdoor sconce with an open linear frame and seeded glass diffuser. Finished in Black, Satin White and Architectural Bronze.

Product No.	Finish	Size	Source	Input
P560029-031-30 P560029-129-30	Black Architectural Bronze	7-1/2" W., 16" ht. Extends 4". H/CTR 4-1/4".	One 9w LED module, 3000K, 90CRI 624 source lumens	120V    



Z-1020 LED




A modern outdoor sconce with white glass shade is suspended in a curved frame that serves as a reflector when illuminated. Finished in Black or Architectural Bronze.

Product No.	Finish	Size	Source	Input
P560030-031-30 P560030-129-30	Black Architectural Bronze	7-1/2" W., 13-1/2" ht. Extends 4-3/4". H/CTR 11-1/8".	One 9w LED module, 3000K, 90CRI 670 source lumens	120V   



Valera LED




Transform outdoor settings with a bold, straightforward style. Double linear details finished in Brushed Nickel or Antique Bronze over a white acrylic diffuser. Die-cast aluminum construction. T24 applies to outdoor installation only.


Product No.	Finish	Size	Source	Input
P5800-12930K9	Brushed Nickel Architectural Bronze	5-5/8" W., 8" ht. Extends 4". H/CTR 4". ADA	One 9w LED module, 3000K, 90CRI 623 source lumens	120V   
P5801-12930K9	Brushed Nickel Architectural Bronze	8-5/8" W., 11" ht. Extends 4". H/CTR 5-1/2". ADA	One 17w LED module, 3000K, 90CRI 1211 source lumens	
P5806-0930K9 P5806-12930K9	Brushed Nickel Architectural Bronze	5-5/8" W., 16" ht. Extends 4". H/CTR 8". ADA	Two 9w LED modules, 3000K, 90CRI 623 source lumens	




Z-1070 LED

Tranquility is yours with the Z-10170 Collection, whose sleek rectangular back plate hold a curved etched glass shade trimmed top and bottom with minimalist metal caps.


Product No.	Finish	Size	Source	Input
P560208-031-30 P560208-082-30	Black Metallic Gray	6" W., 12-9/16" ht. Extends 3-3/4". H/CTR 6-1/4".	11w integrated LED, 3000K, 90CRI, 528 delivered lumens.	120V   
P560209-031-30 P560209-082-30	Black Metallic Gray	6" W., 23-1/8" ht., wire 6". Extends 3-3/4". H/CTR 11-9/16".	22w integrated LED, 3000K, 90CRI, 1019 delivered lumens.	




P560208-031-30



P560208-082-30



P560209-031-30



P560209-082-30

Z-1080 LED

Smooth, elongated frames hold a simple shade banded top and bottom, exuding the modern attitude that is a hallmark of the Z-1080 collection.

Product No.	Finish	Size	Source	Input
P560210-031-30 P560210-082-30	Black Metallic Gray	5" W., 13" ht. Extends 3". H/CTR 6-1/2".	11w integrated LED, 3000K, 90CRI, 415 delivered lumens.	120V   
P560211-031-30 P560211-082-30	Black Metallic Gray	5" W., 23-1/2" ht. Extends 3". H/CTR 11-3/4".	22w integrated LED, 3000K, 90CRI, 847 delivered lumens.	



P560210-031-30



P560210-082-30



P560211-031-30



P560211-082-30

Z-1060 LED

Get even more of the home décor compliments you love with the classic Z-1060 Collection. A minimalist, yet welcoming cylinder-shaped, etched opal glass shade hangs from a handsome black ceiling plate. This collection is perfect for casting a welcoming glow near an entryway or for guiding guests and family down a hallway.

Product No.	Finish	Size	Source	Input
P550071-031-30	Black	4-1/2" dia., 4-3/8" ht., wire 6".	9w Module LED, 3000K, 90CRI, 624 source lumens	120V   
P560072-031-30	Black	4-1/2" W., 4-1/2" ht. Extends 4-3/4". H/CTR 2-1/4".	One 9w LED module, 3000K, 90CRI, 624 source lumens.	
P560073-031-30	Black	4-1/2" W., 4-1/2" ht. Extends 4-3/4". H/CTR 2-1/4".	One 9w LED module, 3000K, 90CRI, 624 source lumens.	



P560072-031-30







P560073-031-30



P550071-031-30

Z-1090 LED

An elongated frame and clean, crisp lines are the hallmarks of the Z-1090 Collection. A modern take on an open-cage design is manifested by a rectangular silhouette with an open bottom through which a stunning glow shines.

Product No.	Finish	Size	Source	Input
P560137-028-30 P560137-031-30	Satin White Black	4-1/2" W., 16" ht., wire 6". Extends 4-3/8". H/CTR 2-1/2".	9w Module LED, 3000K, 90CRI, 624 source lumens.	120V   
				
P560137-031-031 P560137-028-30				



Egress Lighting

HIGHLY SPECIFIABLE SOLUTIONS OFFERING
ENERGY SAVINGS BENEFITS AND SUPERIOR
PERFORMANCE

Our selection of life safety and emergency egress products is specifically designed for improved performance, energy savings and longer service life for light commercial and residential emergency lighting needs.

Exit Sign

The PETPE Series offers quality and value with a compact and attractive LED based emergency exit. The white housing is made of high impact UL flame rated thermoplastic. Snap together canopy, housing, removable chevrons for quick and easy installation. Universal single or double-face. Remote capacity option will run 4 PERHC Series single remote Source-heads or 2 double PERHC remotes.

Product No.	Finish	Size	Source	Input
PETPE-UR-30	White/Red	11.6" W., 7.2" ht., 2" dia.	LED	120 or 277VAC
PETPE-UR-30-RC Remote Capacity				
PETPE-UG-30	White/ Green			
PETPE-UG-30-RC Remote Capacity				



PETPE-UR-30-RC



PETPE-UG-30-RC

Combo Exit/Emergency

The PECUE Series offers quality and value with a compact and attractive LED based combination emergency exit. The white housing and Source-heads are made of high impact UL flame rated thermoplastic. Snap together canopy, housing, removable chevrons for quick and easy installation. Universal single or double-face. Remote capacity unit will run 4 PERHC Series single remote Source-heads or 2 double PERHC remotes.

Product No.	Finish	Size	Source	Input
PECUE-UG-30	White/ Red	18" W., 7.2" ht. 2" dia.	LED	120 or 277VAC
PECUE-UG-30-RC Remote Capacity				
PECUE-UR-30	White/ Green			
PECUE-UR-30-RC Remote Capacity				



PECUE-UR-30



PECUE-UG-30

Aluminum Exit Sign

The PEALE Series offers quality and value with a compact and attractive Thin Die-Cast aluminum Exit sign. Exit face illumination by low energy, long-life red or green ultra bright LED's. The Exit face-plate is brushed aluminum with black edges and 6" letters with a red or green diffuser. Single-face models can be wall, end or ceiling mounted. Double-face models are end or ceiling mounted only. Includes canopy, universal mounting plate and a battery for emergency operation. Test switch and AC-on indicator are located at bottom center. Directional indication made by knock-out chevrons.

Product No.	Finish	Side / Color	Size	Source	Input
PEALE-DG-EM-16	Brushed Aluminum	Double / Green	11.6" W., 7.75" ht., .875" dia.	LED	120 or 277VAC
PEALE-DR-EM-16		Double / Red			
PEALE-SG-EM-16		Single / Green			
PEALE-SR-EM-16		Single / Red			



PEALE-SG-EM-16



PEALE-SG-EM-16

Wet Location Exit Sign

The PEWLE Series offers quality and value with a wet location rated emergency Exit sign. Housing and face-plate made from impact resistant UV stabilized polycarbonate. Housing is corrosion resistant and face-plate is fully gasketed. Exit face illumination by low energy, long-life red or green ultra bright LED's. The Exit letters measure 6" with a red or green diffuser. Single-face models can be wall mounted by use of molded-in template, end or ceiling mounted. Double-face models are end or ceiling mounted only. Includes canopy and universal mounting plate. Water-proof test switch and AC-on indicator located at Exit bottom. Directional indication made by place-able chevrons. Conduit entry KO's located in top and side housing, with conduit fitting included.

Product No.	Finish	Side / Color	Size	Source	Input
PEWLE-SR-30	White	Single / Red	12.5" W., 9.3" ht., 2.5" dia.	LED	120 or 277VAC
PEWLE-DR-30		Double / Red			
PEWLE-SG-30		Single / Green			
PEWLE-DG-30		Double / Green			



PEWLE-SR-30



PEWLE-SG-30

Edge-Lit Emergency Exit

The PEESE/PEERE Series offers quality and value with an Edge-Lit based emergency exit. The PEESE/PEERE is ideal for architectural applications and offers surface and recessed mounting options. The acrylic panels are ultrasonically welded and taped at the edges to maximize illumination and visibility. The Exit panel can be ratcheted to various angles for mounting to angled surfaces. The housing finish and trim-plate is brushed aluminum. Recessed mount model comes with a full recessed box complete with integrated caddy-bar assembly. Surface mount model has a clam-shell design for easy installation and access to internal circuitry. Canopy and mounting hardware included. All models are for emergency operation complete with a NiCad battery, status LED and Push-to-Test switch.

Product No.	Finish	Side / Color	Mount	Size	Source	Input
PEESE-DG-16	Brushed Aluminum	Double / Green	Surface	13.3" W., 11" ht., 4.25" dia.	LED	120 or 277VAC
PEESE-DR-16		Double / Red				
PEESE-SG-16		Single / Green				
PEESE-SR-16		Single / Red				

Product No.	Finish	Side / Color	Mount	Size	Source	Input
PEERE-DG-16	Brushed Aluminum	Double / Green	Recessed	16.88" W., 11.13" ht., 5.5" dia.	LED	120 or 277VAC
PEERE-DR-16		Double / Red				
PEERE-SG-16		Single / Green				
PEERE-SR-16		Single / Red				



PEESE-SR-16
Surface Mount



PEERE-SR-16 Recessed Ceiling
Mount Shown



Wall Mount Shown

Emergency Light

The PE2EU Series offers quality and value with a compact and attractive LED based emergency light. The white housing and Source-heads are fully adjustable and glare-free. Snap together design for quick and easy installation with option of Wall or Ceiling mount. Remote capacity unit will run a double-head remote or 2 single-head remotes of the PERHC Series.

Product No.	Finish	Size	Source	Input
PE2EU-30	White	9" W., 4" ht., 2.75" dia.	LED	120 or 277VAC
PE2EU-30-RC Remote Capacity				



PE2EU-30

Indoor/Outdoor Remote Heads

The PERHC Series offers quality and value with a compact and attractive LED based remote emergency light. Source-heads are fully adjustable and glare-free. The remote Source are driven by the Progress remote capacity Exit combo or Emergency Light. The Outdoor Remote Source-heads are fully gasketed and weatherproof to ensure operation in wet environments. Must be used with PETPE, PE2EU, and PECUE remote capacity models.

Product No.	Finish		Size	Source
PERHC-SG-ID-30	White	Indoor	4.6" W., 4.6" ht., 2.6" dia.	Single LED
PERHC-DB-ID-30			6.7" W., 4.7" ht., 2.5" dia.	Double LED
PERHC-SG-OD-30		Outdoor	4.5" W., 4.5" ht., 6.7" dia.	Single LED
PERHC-DB-OD-30			7.4" W., 4.5" ht., 5.6" dia.	Double LED



PERHC-SG-ID-30



PERHC-DB-OD-30

Normally On/Off Outdoor Emergency

The PEOEU Series offers LED performance in “normally on” AC and emergency lighting modes. The unit has a prismatic polycarbonate refractor with a durable die-cast aluminum housing available with durable powder coated finish in dark bronze, nickel or white. The housing is fully sealed and gasketed. It is designed for wall mounting with a universal K/O pattern in the back-plate for installation to most standard size junction boxes. Illumination is provided by 2 high power LEDs driven at 3 watts each. LED color at 5500K.

Series	Description	Finish	Size	Source	Input
PEOEU-EM-20	Emergency Battery	Bronze	6.54" W., 10.47" ht., 3.78" dia.	LED, 223 lumens in AC mode, 5000K, 261 lumens in battery mode	120 or 277VAC, 50 or 60 Hz
PEOEU-EM-20-HTR	Emergency Battery w/ heater option	Bronze			



PEOEU-EM-20-HTR

Wet Location Emergency Light

The PE2WL offers LED performance and value with a compact and attractive wet location LED based emergency light. The gray housing is made of corrosion resistant UV stabilized polycarbonate. Source-head consists of metalized high-performance reflector and 15 ultra-bright LED’s with tempered glass lens. Includes external mounting brackets for ease of installation. The PE2WL has adequate capacity to run 1 each PEWLH double head or 2 PEWLH single-head remotes at 9.6 VDC for 90 minutes.

Product No.	Finish	Size	Source	Input
PE2WL-82	Metallic Grey	8" W., 12.2" ht.	LED	120 or 277V AC input

Product No.	Description	Finish	Size
PEWLH-SG-82 PEWLH-DB-82	Single Head	Metallic Grey	7" ht., 4.25" W., 4.5" dia.
	Double Head		7" ht., 10" W., 4.5" dia.



PEWLH-SG-82



PE2WL-82




Building Interior

MAINTAIN OR IMPROVE THE QUALITY OF LIGHT IN ANY ENVIRONMENT


Our high-performance energy solutions for conference rooms, lobbies, restrooms, hallways and other spaces can dramatically reduce energy costs while positively impacting the value and marketability of your commercial real estate.

Recessed Performance

Product No.	Size	Source	Input
PCICT-LED-22-30K	23-7/8" L., 4" ht., 23-7/8" W.	32w LED, 3000K, 3600 Lumens	120 - 277V, 50 or 60 Hz 
PCICT-LED-22-35K		32w LED, 3500K, 3700 Lumens	
PCICT-LED-22-40K		32w LED, 4000K, 3750 Lumens	
PCICT-LED-24-30K	47-7/8" L., 4" ht., 23-7/8" W.	40w LED, 3000K, 4770 Lumens	
PCICT-LED-24-35K		40w LED, 3500K, 4900 Lumens	
PCICT-LED-24-40K		39w LED, 4000K, 4990 Lumens	



Low Profile Wraparound

Product No.	Size	Source	Input
PCIAW-LED-2-35K	24" L., 9" ht., 3-1/16" W.	18w LED, 3500K, 2000 Lumens	120 - 277V, 50 or 60 Hz 
PCIAW-LED-2-40K		18w LED, 4000K, 2000 Lumens	
PCIAW-LED-4-35K	48" L., 9" ht., 3-1/16" W.	38w LED, 3500K, 4000 Lumens	
PCIAW-LED-4-40K		38w LED, 4000K, 4000 Lumens	



Stairwell Luminaire

Product No.	Size	Source	Input
PCISW-LED-4-35K	54" L., 4" ht., 6" W.	52w LED, 3500K, 5000 Lumens	120 - 277V, 50 or 60 Hz




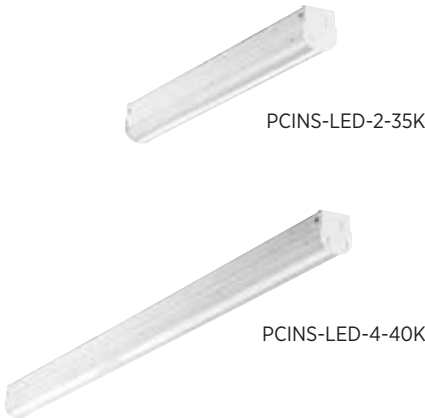
Linear Vapor Tight

Product No.	Size	Source	Input
PCIVT-LED-4-35K	51-3/4" L., 3-7/8" ht., 4-1/2" W.	37w LED, 3500K, 4000 Lumens	120 - 277V, 50 or 60 Hz





Low Profile Lens Strip


Product No.	Size	Source	Input
PCINS-LED-2-35K	24" L., 2-5/16" ht., 2-3/4" W.	18w LED, 3500K, 2000 Lumens	120 - 277V, 50 or 60 Hz 
PCINS-LED-2-40K		18w LED, 4000K, 2000 Lumens	
PCINS-LED-4-35K	48" L., 2-5/16" ht., 2-3/4" W.	40w LED, 3500K, 4000 Lumens	
PCINS-LED-4-40K		40w LED, 4000K, 4000 Lumens	





Linear Cloud LED

White contoured shallow acrylic cloud lens in LED offers both form and function.

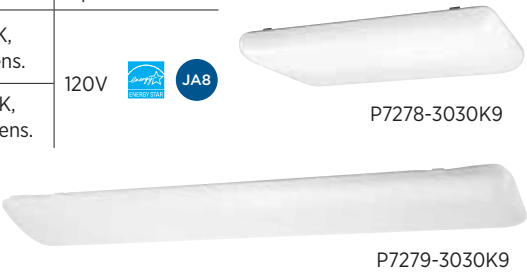Product No.	Finish	Size	Source	Input
P7278-3030K9	White	26" L., 10-1/4" W., 3-1/4" ht.	27w integrated LED, 3000K, 90CRI, 1974 delivered lumens.	120V  
P7279-3030K9	White	51" L., 11-3/4" W., 4-3/4" ht.	40w integrated LED, 3000K, 90CRI, 2908 delivered lumens.	





Wrap & Strip LED

Product No.	Finish	Size	Source	Input
P730000-030-30	White	23-11/16" L., 2-1/4" W., 2-3/8" ht.	21w integrated LED, 3000K, 90CRI, 1600 lumens.	120V  
P730001-030-30	White	47-1/4" W., 2-1/4" W., 2-3/8" ht.	36w LED, 3000, 90CRI, 90CRI, 3200 lumens.	
P730011-030-30	White	23-3/4" L., 6-3/16" W., 3" ht.	21w integrated LED, 3000K, 90CRI, 1700 lumens.	
P730012-030	White	47-3/8" L., 6-3/16" W., 3" ht.	36w integrated LED, 3000K, 90CRI, 3400 lumens.	



Surface Mount Linear LED

Thin geometric-styled metal end caps and acrylic shade offer a modern impact.

Product No.	Finish	Size	Source	Input
P7258-0930K9 P7258-17430K9	Brushed Nickel Urban Bronze	48-1/2" L., 11-13/16" W., 4-1/2" ht.	53w integrated LED, 3000K, 90CRI, 3559 delivered lumens.	120V  



P7258-0930K9





P7258-17430K9

Puck LED

The HIDE-a-LITE™ Puck LED provides an ideal solution for many applications. The low profile design provides versatility to allow installations inside a cabinet, under a cabinet and above a cabinet to provide up light. The HIDE-a-LITE™ Puck LED offers a quick and simple mounting installation and SPT-2 wire can be used for direct wiring. Energy Star Listed and meets CA T24 JA8-2016 requirements. The HIDE-a-LITE™ Pucks LED can be dimmed down to 10% with many Forward Phase (Triac) and Electronic Low Voltage (ELV) dimmers.




Product No.	Finish	Size	Source	Input
P700005-020-30 P700005-028-30	Antique Bronze Satin White	3" dia., 1" ht.	3w integrated LED 3000K, 90CRI 120V LED, 140 delivered lumens Damp location listed.	120V  
P860031-020 P860031-028	Antique Bronze Satin White	36" Direct Wire Cable (when used with P8740)	N/A	120V
P860029-020 P860029-028	Antique Bronze Satin White	50' 18 AWG SPT-2 Cable	N/A	
P860030-020 P860030-028	Antique Bronze Satin White	100' 18 AWG SPT-2 Cable	N/A	
P8740-20 P8740-30	Bronze White	3-1/4" W., 1" ht., 3-1/2" L.	N/A	



P700005-020-30



P700005-028-30

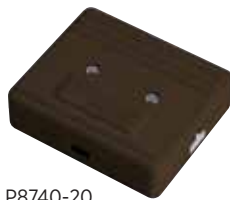

P8740-20



P8740-30



P860031-020



P860031-028



P860029-020
P860030-020





P860029-028
P860030-028

Linear Undercabinet LED

The HIDE-A-LITE™ Linear undercabinet series provides the ideal solution for residential and light commercial applications. The luminaire is constructed from an aluminum housing and features a lens designed to optimize light distribution, ensuring for proper illumination of the work space below. The HIDE-A-LITE™ linear undercabinet utilizes a through hole mounting method to allow for an easy installation. The luminaire can be direct wired, removing the need for separate cords. Two armored cable fittings are included with the product for applications requiring the use of armored cable. An on/off switch is located on the front of the luminaire, allowing for easy access when used as a task light. The energy efficient LEDs can be dimmed down to 10% with many forward phase (TRIAC) and electronic low voltage (ELV) dimmers.



Product No.	Finish	Size	Source	Input
P7000000-020-30 P7000000-028-30	Antique Bronze White	9" L., 3-1/4" W., 1-1/8" ht.	One 4.5w integrated LED, 3000K, 90CRI, 300 delivered lumens.	120V  
P7000001-020-30 P7000001-028-30	Antique Bronze White	11-1/2" L., 3-1/4" W., 1-1/8" ht.	One 7.5w integrated LED, 3000K, 90CRI, 500 delivered lumens.	
P7000002-020-30 P7000002-028-30	Antique Bronze White	17-1/2" L., 3-1/4" W., 1-1/8" ht.	One 12.5w integrated LED, 3000K, 90CRI, 815 delivered lumens.	
P7000003-020-30 P7000003-028-30	Antique Bronze White	23-1/2" L., 3-1/4" W., 1-1/8" ht.	One 15.5w integrated LED, 3000K, 90CRI, 980 delivered lumens.	
P7000004-020-30 P7000004-028-30	Antique Bronze White	35-1/2" L., 3-1/4" W., 1-1/8" ht.	One 20w integrated LED, 3000K, 90CRI, 1500 delivered lumens.	



P7000003-028-30



P7000001-028-30



P7000000-028-30



P7000004-028-30



P7000002-028-30



P7000003-020-30



P7000001-020-30



P7000000-020-30



P7000004-020-30



P7000002-020-30

Tape Undercabinet System LED

LED Tape provides lighting to enhance aesthetics, while also aiding in tasks around the home. Common applications for LED Tape include; undercabinet lighting in kitchens to add illumination to work surfaces, highlighting back splashes in kitchens or bathroom areas and adding toe kick lighting at the bases of cabinets for dramatic and functional lighting.



LED Tape Lighting

Product No.	Size	Source
P700008-000-27	12" L., 3/8" W., 1/8" ht.	2700K
P700008-000-30	12" L., 3/8" W., 1/8" ht.	3000K
P700009-000-27	60" L., 3/8" W., 1/8" ht.	2700K
P700009-000-30	60" L., 3/8" W., 1/8" ht.	3000K
P700010-000-27	240" L., 3/8" W., 1/8" ht.	2700K
P700010-000-30	240" L., 3/8" W., 1/8" ht.	3000K

- LED FEATURES**
- Field cuttable at every 4" to end of run.
 - cETLus listed damp location.
 - 300 lumens per foot and consumes 4.2 watts per foot (71 lumens/w).
 - 90CRI, 50,000 hr. life.
 - 5 year warranty.



P700008-000-27



P700009-000-27
P700010-000-27

Transformer

Product No.	finish	Size	Source
P700020-031	Black	Max length of tape 60" 8-3/16" L., 2" W., 1-3/4" ht.	25W
P700021-031	Black	Max length of tape 120" 8-3/16" L., 2" W., 1-3/4" ht	40W
P700023-031	Black	Max length of tape 240" 9-3/16" L., 3-3/8" W., 1-15/16" ht.	80W

- PRODUCT FEATURES**
- Maximum operating temperature -20° C to +40° C.
 - Enclosure provided.
 - Wire nuts and additional hardware included.



P700020-000
P700021-000
P700023-000

Additional System Connectors

Product No.	Finish	Size	Notes
P700011-000	Black	2" L., 5/8" W., 1/4" ht.	Connect tape sections (P700008, P700009, P700010)
P700012-000	Black	12" L., 5/8" W., 1/4" ht.	
P700013-000	Black	18" L., 5/8" W., 1/4" ht.	
P700014-000	Black	36" L., 5/8" W., 1/4" ht.	
P700015-000	Black	72" L., 5/8" W., 1/4" ht.	
P700016-000	Black	2-1/16" L., 2-1/16" W., 1/6" ht.	90° connector for connecting sections of tape (P700008, P700009, P700010) on corners.
P700017-000	Black	3-3/16" L., 3-3/16" W., 1/4" ht.	Three-way Y connector for connecting sections of tape (P700008, P700009, P700010)
P700022-000	Black	60" L., 5/8" W., 1/4" ht.	N/A



P700011-000



P700013-000



P700015-000



P700017-000



P700012-000



P700014-000



P700016-000



P700022-000

Mounting Clips/ Additional Accesories


Product No.	Size	Notes
P700018-000	1-1/8" L., 1/4" W., 1/8" ht.	Pack of 10 clips/screws for straight runs for added support (2 clips per foot recommended)
P700019-000	1/2" L., 1/2" W., 1/4" ht.	End caps to terminate run of LED tape. For use when tape has been cut at end of run. Sold in sets of 10.
P7024-31	1" L., 2" W., 5/8" ht.	N/A



P700018-000



P700019-000

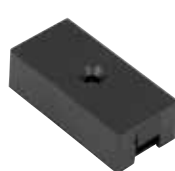



P7024-31

Edgelit Recessed LED

The LED edgelit recessed downlight combines a slim, low profile design with innovative technology, aesthetics, functionality and affordability. A separate recessed housing or junction box is not required for installation. The wet location listing allows for the product to be used in many applications, including showers. The low profile downlight is ideal for many residential, multi-family, commercial and hospitality applications. The detachable driver box can be removed from the fixture and mounted remotely when installing into shallow ceiling applications. The energy efficient design provides up to a 75% energy savings and up to 50,000 hours of LED life. The edgelit recessed luminaire can be dimmed down to 10%, flicker free, and is compatible with many forward phase (TRIAC) and electronic low voltage (ELV) dimmers.

- TRIM FEATURES
- Features a detachable driver box, which can be mounted remotely for shallow ceiling installations.
 - White polycarbonate lens controls direct glare from LEDs.
 - No housing or J-box required for installation.
 - Wet location listed.
 - 120V input voltage.
 - Dimmable to 10% with many Triac or ELV dimmers.
 - IC rated and Air-Tight.
 - Energy efficient design provides up to a 75% energy savings and up to 54,000 hours of LED life.
 - Energy Star and Title 24 JA8-2016 listed.

Product No.	Finish	Size	Source	Input
P800004-009-30 P800004-020-30 P800004-028-30 P800004-031-30	Brushed Nickel Antique Bronze White Black	5" W., 3" ht.	9.5w integrated LED, 3000K, 90CRI, 550 lumens.	120V  
P800005-009-30 P800005-020-30 P800005-028-30 P800005-031-30	Brushed Nickel Antique Bronze White Black	7" W., 3" ht.	13w integrated LED, 3000K, 90CRI, 800 lumens.	



P800004-009-30



P800004-020-30



P800004-028-30



P800004-031-30



P800005-009-30



P800005-020-30




P800005-028-30



P800005-031-30



P800005-028-30
back view shown with
junction box attached

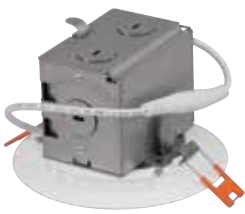

P800004-028-30
back view shown with
junction box attached

Edgelit Recessed Accessories

Progress lighting has released two new accessories for the Edgelit Recessed fixtures. P860040-028 - 18" extender cable allows for the junction box to be remote and mounted further away from the fixture. P860044 - rough in accessory allows for Edge Lit recessed fixtures to be used in new construction installations. This accessory ensures a mounting location after the dry wall is installed and can be used when building codes require that the luminaire is supported from the building structure

18" CABLE WITH TERMINALS
P860040-028 Satin White
18" L., 1/2" dia.



P860040-028

P860040-028
18" Cable with Terminals

Junction Box
(Included with P800004
and P800005)

Edgelit Recessed
(P800004 or P800005)

EDGELIT RECESSED
ROUGH-IN ACCESSORY
P860044-001 Unfinished
20" W., 9" ht.



P860044-001

P860044-001
Edgelit Recessed
Rough-in Plate

Edgelit Recessed
(P800004 or P800005)

4" Recessed LED

LED Housings

For complete fixture, order housing with trim.



New Construction Non-IC with LED Quick Connect

P830-LED
Ceiling opening: 4-1/2"
Plaster frame: 7-7/8" x 10-3/4"
Recessed depth: 5-1/2"
Pryouts: 1/2" and 3/4"


- P830-LED HOUSING FEATURES**
- Integral quick link connector mates with P8080 and P8046 series LED trims.



New Construction Air-Tight IC with LED Quick Connect

P831-LED
Ceiling opening: 4-1/2"
Plaster frame: 8-3/8" x 13"
Recessed depth: 7-1/2"

- P831-LED HOUSING FEATURES**
- Integral quick link connector mates with P8080 and P8046 series LED trims.

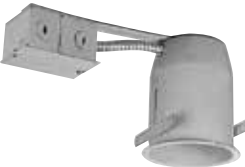


Remodel Non-IC with LED Quick Connect

P832-LED
Ceiling opening: 4-1/4"
Recessed depth: 5-1/2"
Pryouts: 1/2"

- P832-LED HOUSING FEATURES**
- Retrofit version of P830-LED for use in existing ceilings.

4" LED Round Trim

Flicker free dimming down to 10% with many Triac or forward phase dimmers. Flicker rate less than 30%.

Product No.	Finish	Source	Input
P8080-09-30K P8080-20-30K P8080-28-30K P8080-31-30K	Brushed Nickel Antique Bronze White Black	9.5w integrated LED, 3000K, 90CRI, 630 lumens.	120V 



P8080-09-30K



P8080-20-30K



P8080-28-30K




P8080-31-30K

P8080 & P8046 TRIM FEATURES

- The trim is equipped with both Edison base adapter and quick link connector allowing easy installation in many standard medium based socket recessed housings and Progress LED recessed housings.
- A polycarbonate diffused lens reduces glare and pixilation from LEDs.
- Trim uses friction springs for easy installation into recessed housings.
- cCSAus Listed for Wet Locations, Energy Star.
- Flicker free dimming down to 10% with many Triac or ELV dimmers.
- Suitable for use in IC and Non IC applications.
- LEDs are 3000K, CRI 90+ and rated for 50,000 hours.

4" LED Eyeball Trim

Flicker free dimming down to 10% with many Triac or forward phase dimmers. Flicker rate less than 30%.

Product No.	Finish	Source	Input
P8046-09-30K P8046-20-30K P8046-28-30K P8046-31-30K	Brushed Nickel Antique Bronze White Black	9.5w integrated LED, 3000K, 90CRI, 630 lumens.	120V 



P8046-09-30K



P8046-20-30K



P8046-28-30K



P8046-31-30K

5" Recessed LED

LED Housings

For complete fixture, order housing with trim.



New Construction Air-Tight IC with LED Quick Connect

P84-LED
Ceiling opening: 5-1/4"
Plaster frame: 7-7/8" x 10-3/4"
Recessed depth: 5-1/2"
Pryouts: 1/2" and 3/4"

- P84-LED HOUSING FEATURES**
- Integral quick connectors mate with P8061 and P8176 series.




Remodel Air-Tight IC with LED Quick Connect

P1841-LED
Ceiling opening: 5-1/2"
Recessed depth: 5-3/8"
Pryouts: 1/2"

- P1841-LED HOUSING FEATURES**
- Rated for direct contact with insulated ceiling.
 - Adjustable housing to accommodate ceiling thickness 1/2" to 1-1/2" .
 - Meets ASTM-E283 air flow requirements.

5" LED Round Trim

Flicker free dimming down to 10% with many Triac or forward phase dimmers. Flicker rate less than 30%.

Product No.	Finish	Source	Input
P8061-09-30K P8061-20-30K P8061-28-30K P8061-31-30K	Brushed Nickel Antique Bronze White Black	10.5w integrated LED, 3000K, 90CRI, 700 lumens.	120V 



P8061-09-30K



P8061-20-30K



P8061-28-30K




P8061-31-30K

P8061 & P8176 TRIM FEATURES

- Frosted polycarbonate lens controls direct glare from LEDs.
- cULus listed for wet locations.
- Lumen output and distribution comparable to 65w BR30 incandescent lamp.
- CRI is 90+ rivaling CFL.
- Suitable for use in IC or NON-IC applications.
- 50,000 hours life based on 70% lumen maintenance (TM-21).

5" LED Eyeball Trim

Flicker free dimming down to 10% with many Triac or forward phase dimmers. Flicker rate less than 30%.

Product No.	Finish	Source	Input
P8176-09-30K P8176-20-30K P8176-28-30K P8176-31-30K	Brushed Nickel Antique Bronze White Black	10.5w integrated LED, 3000K, 90CRI, 670 lumens.	120V 



P8176-09-30K



P8176-20-30K



P8176-28-30K



P8176-31-30K

5" Recessed

Shallow Remodel Housing

For complete fixture, order housing with trim.



Remodel Air-Tight IC with E26 Socket

P1841-ICAT

Ceiling opening: 5-1/2"
Recessed depth: 5-3/8"
Pryouts: 1/2"

P1841-ICAT HOUSING FEATURES

- Rated for direct contact with insulated ceiling.
- Meets ASTM-E283 air flow requirements.
- Adjustable housing to accommodate ceiling thickness 1/2" to 1-1/2".
- Use with compatible items only.



IC Trim

6-1/2" outside diameter. Can also be used with P851-ICAT.



SHALLOW STEP BAFFLE
P8475-28 Satin White
Damp location listed.
Lamp: PAR30/R30, 50w max.
Compatible with **P851-ICAT** and **P1841-ICAT**.



SHOWER TRIM
P867WL-28 White
Wet location listed when used with an outdoor rated PAR30 lamp. 50w PAR30*
**WL trims require use with outdoor rated PAR lamps*



EYEBALL
P876-28 White
75w PAR30

LED IC Trims

All fixtures:



LED ROUND
P8061-09-30K Brushed Nickel
10.5w integrated LED, 3000K, 90CRI, 700 lumens.



LED ROUND
P8061-20-30K Antique Bronze
10.5w integrated LED, 3000K, 90CRI, 700 lumens.



LED ROUND
P8061-28-30K White
10.5w integrated LED, 3000K, 90CRI, 700 lumens.



LED ROUND
P8061-31-30K Black
10.5w integrated LED, 3000K, 90CRI, 700 lumens.



LED EYEBALL
P8176-09-30K Brushed Nickel
10.5w integrated LED, 3000K, 90CRI, 670 lumens.



LED EYEBALL
P8176-20-30K Antique Bronze
10.5w integrated LED, 3000K, 90CRI, 670 lumens.



LED EYEBALL
P8176-28-30K White
10.5w integrated LED, 3000K, 90CRI, 670 lumens.



LED EYEBALL
P8176-31-30K Black
10.5w integrated LED, 3000K, 90CRI, 670 lumens.

6" Recessed LED

LED Housing New Construction

For complete fixture, order housing with trim.



New Construction Air-Tight IC & Non-IC with LED Quick Connect

P87-LED

Ceiling opening: 6-7/8" dia.
Plaster frame: 7-7/8" x 10-3/4"
Recessed depth: 7-1/2"
Pryouts: 1/2" & 3/4"

P87-LED HOUSING FEATURES

- Integral quick connect mates with P8071 and P8076 series LED trims.

6" LED Trim 1000 Lumens

Flicker free dimming down to 10% with many Triac or forward phase dimmers. Flicker rate less than 30%.

Product No.	Finish	Source	Input
P8071-28/30K-L10-STR2-30K	White	12w integrated LED, 3000K, 80 CRI, 1000 lumens	120V
P8071-28/35K-L10-STR2-30K	White	12w integrated LED, 3500K, 80 CRI, 1000 lumens	



P8071-28/30K-L10-STR2



P8071-28/35K-L10-STR2



Includes Edison base socket and Quick-Link connector

6" LED Round Trim

Flicker free dimming with Triac or forward phase dimmers. Flicker rate less than 30%.

Product No.	Finish	Source	Input
P8071-09-30K P8071-20-30K P8071-28-30K P8071-31-30K	Brushed Nickel Antique Bronze White Black	10.5w integrated LED, 3000K, 90CRI, 725 lumens.	120V



P8071-09-30K



P8071-20-30K



P8071-28-30K



P8071-31-30K

6" LED Eyeball Trim

Flicker free dimming down to 10% with many Triac or forward phase dimmers. Flicker rate less than 30%.

Product No.	Finish	Source	Input
P8076-09-30K P8076-20-30K P8076-28-30K P8076-31-30K	Brushed Nickel Antique Bronze White Black	10.5w integrated LED, 3000K, 90CRI, 700 lumens.	120V



P8076-09-30K



P8076-20-30K





P8076-28-30K



P8076-31-30K

Everlume™ Round Surface Mount LED

Edgelit technology creates a large glare free and evenly illuminated surface for a variety of applications for both residential and commercial applications. Offering a low profile design, LED Everlume™ Round Surface Mount is available in a White finish. The integrated driver does not recess into junction box, allowing for easy installation into 4" octagonal, 4" round PVC and 4-1/2" ceiling pan junction boxes. Wet location listed and offers a 50,000-hour LED life.

Product No.	Finish	Size	Source	Input
P810024-030-30	White	7" dia., 1-1/8" ht.	15w integrated LED 3000K, 90CRI, 1000 lumens.	120V  
P810015-030-30		11" dia., 1-1/8" ht.	17w integrated LED 3000K, 90CRI, 1300 lumens.	
P810016-030-30		14" dia., 1-1/8" ht.	19.5w integrated LED 3000K, 90CRI, 1700 lumens.	
P810017-030-30		18" dia., 1-1/8" ht.	23w integrated LED 3000K, 90CRI, 2100 lumens.	
P810018-030-30		5" dia., 1-1/8" ht.	12w integrated LED 3000K, 90CRI, 800 lumens.	

- LED FEATURES**
- Wet location listed.
 - Flicker-free dimming with many Triac and ELV dimmers.
 - 120v input voltage.
 - 50,000 hour life.





Everlume™ Round Trim Accessories

You'll never have to sacrifice function for style with our Everlume™ Round Trim Accessories. This collection offers a variety of finishes and trim ring sizes to best fit your unique design needs. Each trim ring is easy to install in both residential and commercial settings.

Product No.	Finish	Size
P860048-009 P860048-020 P860048-031	Brushed Nickel Antique Bronze Black	5" dia., 1-1/8" ht.
P860049-009 P860049-020 P860049-031	Brushed Nickel Antique Bronze Black	7" dia., 1-1/8" ht.
P860050-009 P860050-020 P860050-031	Brushed Nickel Antique Bronze Black	11" dia., 1-1/8" ht.
P860050-009 P860050-020 P860050-031	Brushed Nickel Antique Bronze Black	14" dia., 1-1/8" ht.
P860050-009 P860050-020 P860050-031	Brushed Nickel Antique Bronze Black	18" dia., 1-1/8" ht.



Round Surface Mount LED



Product No.	Finish	Size	Source	Input
P8222-28-30K	White	7-1/4" dia., 1-1/4" ht.	17w integrated LED, 3000K, 90CRI 1170 lumens	120V  



P8222-28-30K
Triac/ELV dimming

Emblem Surface Mount LED

Easy installation and a sleek, modern lighting aesthetic are offered by our Emblem Surface Mount LED Collection. An excellent choice for general ambient lighting, each polished design features a smooth, slightly tapered trim ring surrounding a single, integrated LED light source. Enjoy the unmatched level of glare control offered by the fixture’s diffused polycarbonate lens that also hides any unwanted LED pixelation. Each light fixture is home to an integrated AC LED light engine that seamlessly installs to a variety of ceiling pan junction boxes to give you added flexibility when it comes to creating your design vision. The surface mount provides unparalleled longevity with its, 50,000-hour LED life span and 80% energy savings.

Product No.	Finish	Size	Source	Input
P810027-020-30 P810027-028-30	Bronze White	5-1/2" dia., 1-7/8" ht.	12.5w integrated LED, 3000K, 90CRI, 750 lumens.	120V  
P810014-020-30 P810014-028-30	Bronze White	7-1/4" dia., 1-3/8" ht.	15.5w integrated LED, 3000K, 90CRI, 1080 lumens.	

- LED FEATURES**
- Wet location listed.
 - 120v input voltage.
 - 60 Lumens per watt.
 - Flicker-free dimming with many Triac and ELV dimmers.
 - 50,000 hour life.



P810027-020-30



P810027-028-30





P810014-020-30K



P810014-028-30

Intrinsic Surface Mount LED

Elevate your design vision with just the flip of a switch with our Intrinsic Surface Mount LED Collection. The simple, classic design of these light fixtures can easily be installed into a variety of style applications in both residential and commercial settings. We offer two different sizes of surface mounts, both coated in a crisp white finish, to meet your unique design needs. Each smooth trim ring surrounds an integrated LED light fixture ready to emit general ambient lighting wherever it calls home in your design plan.

Product No.	Finish	Size	Source	Input
P810012-028-30	White	5-1/2" dia., 1" ht.	12w integrated LED, 3000K, 90CRI, 600 lumens.	120V  
P810013-028-30	White	7-1/2" dia., 1-3/16" ht.	15.5w integrated LED, 3000K, 90CRI, 1000 lumens.	

- LED FEATURES**
- Wet location listed.
 - 120v input voltage.
 - 60 Lumens per watt.
 - Flicker-free dimming with many Triac and ELV dimmers.
 - 50,000 hour life.




P810012-028-30



P810013-028-30K

Decorative Surface Mount LED

Flicker free dimming down to 10% with many Triac or forward phase dimmers. Flicker rate less than 30%.

Product No.	Finish	Size	Source	Input
P8247-09-30K	Brushed Nickel Antique Bronze White Black	5-1/2" dia., 1-1/2" ht.	90CRI, 690 lumens, 66 lumens per watt	120V  
P8147-09-30K	Brushed Nickel	7-1/4" dia., 2-3/4" ht.	10.5w integrated LED, 3000K, 90CRI, 690 lumens, 66 lumens per watt.	



P8247-09-30K
Triac/ELV dimming



P8147-09-30K
Triac/ELV dimming

Retrofit Recessed Accessories

The P8147 and P8247 surface mounts require an accessory mounting option for recessed housings.

Product No.	Description
P8595-01	Recessed mounting accessory for P8147 and P8222 series. Allows for installation in 6" housings. Edison base adapter included.
P8596-01	Recessed mounting accessory for P8247 series. Allows for installation in 4" housings. Edison base adapter included.



P8595-01



P8596-01

Indoor Steplights LED

The mini-steplights are ideal for indoor residential applications. Energy efficient steplights include both vertical and horizontal louvers and are available in four finishes.

Product No.	Finish	Size	Source
P660003-009-30K P660003-020-30K P660003-028-30K P660003-031-30K	Brushed Nickel Antique Bronze White Black	2-3/4" W., 4-1/2" ht.	1w LED, 3000K, 90CRI, 12 lumens.



P660003-009-30K



P660003-020-30K



P660003-028-30K



P660003-031-30K



DFS Series

DECORATIVE FABRIC SHADES

Introducing a new family of ceiling, cable pendant, and wall mount decorative fabric/acrylic diffusers. The DFS Series combines modern aesthetics and quality performance by offering endless choices of size, shape and material finish. With the possibility for custom sizes and finishes, this offering is sure to meet every design need. Ideal for hospitality, multi-family, commercial, and residential applications.

DFS Series

Simple to order. Specify shape, shade finish, cross-grid, and canopy finish options.

Pendant Shapes



Round



Square



Double Layer



Cross Grid Finishes:
Black, Bronze,
Natural Oak,
Nickel, White.



Inner Step



Dome-In-Shade



Tapered



White



Nickel

Canopy Options

Sconce Shapes



Half Cylinder



Hour Glass



Concave

 


Vertical Sweep



Double Square

Pendant and Sconce Shade Finishes



Acrylic White



Black Linen



Beige Linen



Grey Linen



White Linen

DFS Series

The DFS Series is a family offering of ceiling, cable pendant, and wall mount decorative fabric/acrylic diffusers. The DFS Series combines modern aesthetics and quality performance by offering endless choices of size, shape and material finish. With the possibility for custom sizes and finishes. Ideal for hospitality, multi-family, commercial, and residential applications.

Surface/Pendant Shade - Square Drum

Series	Mounting	Shape	Size	Shade Finish	Wattage	Voltage	CRI / CCT	Canopy Finish
PCDFS	SM Surface Mount	SQ Square Drum	12 12" 15 15" 19 19"	WTL White Linen BGL Beige Linen BKL Black Linen GYL Gray Linen LWT Laminated White Linen LBG Laminated Beige Linen FAW Full Acrylic White	17 17W 25 25W 32 32W	120V 120V/60Hz	930 90CRI/ 3000K	Blank (surface) WT White BN Nickel
	CM Cable Mount							



PCDFS-CM-SQ-12-WTL
shown with canopy



PCDFS-SM-SQ-12-WTL



PCDFS-SM-SQ-12-BKL



PCDFS-SM-SQ-15-WTL



PCDFS-SM-SQ-15-GYL



PCDFS-SM-SQ-19-WTL



PCDFS-SM-SQ-15-GYL

Surface/Pendant Shade - Round Drum

Series	Mounting	Shape	Size	Shade Finish	Wattage	Voltage	CRI / CCT	Canopy Finish	Grid Options
PCDFS	SM Surface Mount	RD Round Drum	12 12" 15 15" 19 19"	WTL White Linen BGL Beige Linen BKL Black Linen GYL Gray Linen LWT Laminated White Linen LBG Laminated Beige Linen FAW Full Acrylic White FAWNT Acrylic White w/ top & bottom nickel trim	17 17W 25 25W 32 32W	120V 120V/60Hz	930 90CRI/ 3000K	Blank (surface) WT White BN Nickel	GBL Trim Black GBZ Trim Bronze GNI Trim Nickel GOF Trim Oak GWT Trim White
	CM Cable Mount								



PCDFS-CM-RD-12-WTL
shown with canopy



PCDFS-SM-RD-12-WTL



PCDFS-SM-RD-15-WTL



PCDFS-SM-RD-19-WTL



PCDFS-SM-RD-15-FAW



PCDFS-SM-RD-15-GYL-BNC



PCDFS-SM-RD-15-BGL



PCDFS-SM-RD-15-BGL



PCDFS-SM-RD-12-WTL-GOF



PCDFS-SM-RD-12-WTL-GNI



PCDFS-SM-RD-12-WTL-GWT



PCDFS-SM-RD-12-WTL-GBL



PCDFS-SM-RD-12-WTL-GBZ

DFS Series

Surface/Pendant Shade - Double Layer

Series	Mounting	Shape	Size	Shade Finish	Wattage	Voltage	CRI / CCT	Canopy Finish
PCDFS	SM Surface Mount	DL Double Layer	16 16" 18 18" 23 -23"	WTL White Linen	17 17W 25 25W 32 32W	120V 120V/60Hz	930 90CRI/ 3000K	Blank (surface)
	CM Cable Mount			BGL Beige Linen				WT White
				BKL Black Linen				BN Nickel
				GYL Gray Linen				
				LWT Laminated White Linen				
				LBG Laminated Beige Linen				
				FAW Full Acrylic White				



PCDFS-CM-DD-12-FAW
shown with canopy



PCDFS-SM-DD-12-FAW



PCDFS-SM-DD-18-FAW



PCDFS-SM-DD-23-WTL

Surface/Pendant Shade - Dome-in-Shade

Series	Mounting	Shape	Size	Shade Finish	Wattage	Voltage	CRI / CCT	Canopy Finish
PCDFS	SM Surface Mount	DS Dome-in-Shade	14 14" 16 16" 20 20"	WTL White Linen	17 17W 25 25W 32 32W	120V 120V/60Hz	930 90CRI/ 3000K	Blank (surface)
	CM Cable Mount			BGL Beige Linen				WT White
				BKL Black Linen				BN Nickel
				GYL Gray Linen				
				LWT Laminated White Linen				
				LBG Laminated Beige Linen				
				FAW Full Acrylic White				



PCDFS-CM-DS-16-GYL
shown with canopy



PCDFS-SM-DS-16-GYL



PCDFS-SM-DS-16-WTL



PCDFS-SM-DS-20-WTL

Surface/Pendant Shade - Inner Step

Series	Mounting	Shape	Size	Shade Finish	Wattage	Voltage	CRI / CCT	Canopy Finish
PCDFS	SM Surface Mount	IS Inner Step	12 12" 15 15" 19 19"	WTL White Linen	17 17W 25 25W 32 32W	120V 120V/60Hz	930 90CRI/ 3000K	Blank (surface)
	CM Cable Mount			BGL Beige Linen				WT White
	BKL Black Linen			BN Nickel				
	GYL Gray Linen							
	LWT Laminated White Linen							
	LBG Laminated Beige Linen							
	FAW Full Acrylic White							



PCDFS-CM-IS-12-WTL
shown with canopy



PCDFS-SM-IS-12-WTL



PCDFS-SM-IS-15-WTL



PCDFS-SM-IS-15-FAW



PCDFS-SM-IS-15-GYL



PCDFS-SM-IS-15-BGL



PCDFS-SM-IS-15-BKL



PCDFS-SM-IS-19-WTL

Surface/Pendant Shade - Tapered Shade

Series	Mounting	Shape	Size	Shade Finish	Wattage	Voltage	CRI / CCT	Canopy Finish
PCDFS	CM Cable Mount	TS Tapered Shade	20 12" x 20" tapered 24 15" x 24" tapered	WTL White Linen	17 17W 25 25W	120V 120V/60Hz	930 90CRI/ 3000K	WT White BN Nickel 
				BGL Beige Linen				
				BKL Black Linen				
				GYL Gray Linen				
				LWT Laminated White Linen				
				LBG Laminated Beige Linen				



PCDFS-CM-TS-BGL



PCDFS-CM-TS-GYL



PCDFS-CM-TS-WTL

DFS Series

Surface/Pendant Shade - Half Cylinder

Series	Mounting	Shape	Shade Finish	Wattage	Voltage	CRI / CCT
PCDFW	WM Wall Mount	HCS Half Cylinder Small HCL Half Cylinder Large	WTL White Linen	17 17W	120V 120V/60Hz	930 90CRI/ 3000K
			BGL Beige Linen			
			BKL Black Linen			
			GYL Gray Linen			
			LWT Laminated White Linen			
			LBG Laminated Beige Linen			
			FAW Full Acrylic White			
			FAWNT Acrylic White w/ top & bottom nickel trim			



PCDFW-WM-HCS-BGL



PCDFW-WM-HCL-GYL



PCDFW-WM-HCL-WTL



PCDFW-WM-HCL-BGI



PCDFW-WM-HCS-BGL-FAW



PCDFW-WM-HCS-WTL

Surface/Pendant Shade - Hourglass

Series	Mounting	Shape	Shade Finish	Wattage	Voltage	CRI / CCT
PCDFW	WM Wall Mount	HG Hourglass	WTL White Linen	17 17W	120V 120V/60Hz	930 90CRI/ 3000K
			BGL Beige Linen			
			BKL Black Linen			
			GYL Gray Linen			
			LWT Laminated White Linen			
			LBG Laminated Beige Linen			



PCDFW-WM-HG-BGL



PCDFW-WM-HG-WTL



PCDFW-WM-HG-WTL
Horizontal

Surface/Pendant Shade - Concave

Series	Mounting	Shape	Shade Finish	Wattage	Voltage	CRI / CCT
PCDFW	WM Wall Mount	CC Concave	WTL White Linen	17 17W	120V 120V/60Hz	930 90CRI/ 3000K
			BGL Beige Linen			
			BKL Black Linen			
			GYL Gray Linen			
			LWT Laminated White Linen			
			LBG Laminated Beige Linen			



PCDFW-WM-CC-WTL

Surface/Pendant Shade - Vertical Sweep

Series	Mounting	Shape	Shade Finish	Wattage	Voltage	CRI / CCT
PCDFW	WM Wall Mount	VS Vertical Sweep	WTL White Linen	17 17W	120V 120V/60Hz	930 90CRI/ 3000K
			BGL Beige Linen			
			BKL Black Linen			
			GYL Gray Linen			
			LWT Laminated White Linen			
			LBG Laminated Beige Linen			



PCDFW-WM-VS-GYL



PCDFW-WM-VS-WTL

Surface/Pendant Shade - Double Square

Series	Mounting	Shape	Trim Finish	Wattage	Voltage	CRI / CCT
PCDFW	WM Wall Mount	DSS Double Square	NI - Nickel	17 17W	120V 120V/60Hz	930 90CRI/ 3000K
			BZ - Bronze			





PCDFW-WM-DS-WTL

Apogee LED

Flushmount and semi-flush fixtures with etched white glass and universal input. Designed and ideal for residential and commercial applications, Apogee features a clean profile and a generous scale. The simple and elegant frame is finished in Architectural Bronze or Brushed Nickel. 0-10V dimming.

LED Flush

Product No.	Finish	Size	Source	Input
P350070-009-30 P350070-129-30	Brushed Nickel Architectural Bronze	15" dia., 3-11/16" ht.	30w integrated LED, 3000K, 90CRI, 1660 lumens	120 - 277V  
P350071-009-30 P350071-129-30	Brushed Nickel Architectural Bronze	21" dia., 4-1/2" ht.	45w integrated LED, 3000K, 90CRI, 2550 lumens	
P350072-009-30 P350072-129-30	Brushed Nickel Architectural Bronze	27" dia., 5-3/8" ht.	71w integrated LED, 3000K, 90CRI, 3850 lumens	



P350070-009-30



P350070-129-30



P350071-009-30



P350071-129-30



P350072-009-30





P350072-129-30

Apogee LED

Hanging and ceiling mount hardware included. 0-10V dimming.

LED Semi-Flush/Pendant

Product No.	Finish	Size	Source	Input
P350064-009-30 P350064-129-30	Brushed Nickel Architectural Bronze	15" dia., 10-3/4" ht. Overall ht. w/ chain 85-1/4"; wire 15'	30w integrated LED, 3000K, 90CRI, 1855 lumens	120 - 277V  
P350065-009-30 P350065-129-30	Brushed Nickel Architectural Bronze	21" dia., 14-1/2" ht. Overall ht. w/ chain 92"; wire 15'	45w integrated LED, 3000K, 90CRI, 2765 lumens	
P350066-009-30 P350066-129-30	Brushed Nickel Architectural Bronze	27" dia., 20-5/8" ht. Overall ht. w/ chain 98"; wire 15'	71w integrated LED, 3000K, 90CRI, 4215 lumens	



P350064-009-30
Shown as
semi-flush



P350064-129-30
Shown as
pendant



P350065-009-30
Shown as
pendant



P350065-129-30
Shown as semi-flush




P350066-009-30
Shown as
semi-flush



P350066-129-30
Shown as
pendant

Weaver LED

The Weaver collection combines linen drum shades with a Linen glass diffuser to offer a warm feel ideal for residential applications, including kitchens and laundry rooms, as well as light commercial environments. ELV dimming

Product No.	Finish	Size	Source	Input
P3610-0930K9 P3610-2030K9	Brushed Nickel Antique Bronze	10" dia., 3-1/2" ht.	One 17w LED module, 3000K, 90CRI, 1211 source lumens/module	120V 
P3611-0930K9 P3611-2030K9	Brushed Nickel Antique Bronze	16" dia., 4" ht.	Two 17w LED modules, 3000K, 90CRI, 1211 source lumens/module	
P3612-0930K9 P3612-2030K9	Brushed Nickel Antique Bronze	22" dia., 4-1/2" ht.	Three 17w LED modules, 3000K, 90CRI, 1211 source lumens/module	



P3612-0930K9



P3611-0930K9



P3610-0930K9



P3612-2030K9




P3611-2030K9



P3610-2030K9

Beyond LED

The Beyond collection offers a variety of distinctive, modern designs with updated casual flair. Available in round or square styles, the assortment features options with textures glass, metal overlays, or geometric acrylic diffusers. ELV dimming.

Product No.	Finish	Size	Source	Input
P2308-0930K9	Brushed Nickel	12" dia., 2-3/4" ht.	One 17w LED module, 3000K, 90CRI, 1211 lumens	120V 



P2308-0930K9

Surface Mount LED

White acrylic diffuser for kitchen, bath, laundry, workshop or family area. All Triac or ELV dimming except P7251 - Triac (120) 0-10V dimming.

Product No.	Finish	Size	Source	Input
P7249-0930K9 P7249-17430K9	Brushed Nickel Urban Bronze	10-3/8" dia., 3-1/2" ht.	21.7W integrated LED, 3000K, 90CRI, 1027 lumens	120V
P7250-0930K9 P7250-17430K9	Brushed Nickel Urban Bronze	17-3/4" dia., 4-3/4" ht.	30W integrated LED, 3000K, 90CRI, 1765 lumens	120V
P7251-0930K9 P7251-17430K9	Brushed Nickel Urban Bronze	32-1/2" L., 18" W., 4-3/4" ht.	39W integrated LED, 3000K, 90CRI, 2649 lumens	120- 277V
P7253-0930K9 P7253-17430K9	Brushed Nickel Urban Bronze	14" dia., 3-3/4" ht.	22W integrated LED, 3000K, 90CRI, 1184 lumens	120V



P7249-0930K9



P7253-0930K9



P7250-0930K9



P7249-17430K9





P7250-17430K9



P7251-17430K9

Helm LED

Square acrylic diffuser on an architectural square frame. Ceiling or wall mount. ELV Dimming.

Product No.	Finish	Size	Source	Input
P3447-0930K9 P3447-2030K9	Brushed Nickel Antique Bronze	11" sq., 3-3/4" ht.	One 17w LED module, 3000K, 90CRI, 1211 source lumens/module	120V  
P3448-0930K9 P3448-2030K9	Brushed Nickel Antique Bronze	14" sq., 3-3/4" ht.	Two 17w LED modules, 3000K, 90CRI, 1211 source lumens/module	
P3449-0930K9 P3449-2030K9	Brushed Nickel Antique Bronze	18" sq., 3-3/4" ht	Three 17w LED modules, 3000K, 90CRI, 1211 source lumens/module	



P3447-0930K9



P3447-2030K9



P3448-0930K9



P3449-2030K9





P3449-0930K9



P3448-2030K9

Fresnel LED

Industrial styling with a nautical-inspired Fresnel glass lens offers both form and function. ELV dimming.

Product No.	Finish	Size	Source	Input
P350113-009-30 P350113-015-30 P350113-108-30	Brushed Nickel Polished Chrome Oil Rubbed Bronze	12-3/4" dia., 4-1/2" ht.	One 17w LED module, 3000K, 90CRI, 1276 source lumens.	120V  



P350113-009-30





P350113-015-30



P350113-108-30

Bezel LED

Sleek and slim in appearance with etched white glass shade offering a pleasant glow from the bottom and sides.

Product No.	Finish	Size	Source	Input
P350085-009-30 P350085-015-30 P350085-020-30	Brushed Nickel Polished Chrome Antique Bronze	10-1/2" dia., 3-1/2" ht.	One 17w LED module, 3000K, 90CRI, 1276 source lumens.	120V  
P350086-009-30 P350086-015-30 P350086-020-30	Brushed Nickel Polished Chrome Antique Bronze	13" dia., 3-7/8" ht.	One 25w LED module, 3000K, 90CRI, 1770 source lumens.	
P350087-009-30 P350087-015-30 P350087-020-30	Brushed Nickel Polished Chrome Antique Bronze	16" dia., 4-3/4" ht.	One 26w LED module, 3000K, 90CRI, 1770 source lumens.	



P350085-015-30



P350085-009-30



P350085-020-30



P350086-015-30



P350086-009-30



P350086-020-30



P350087-015-30





P350087-009-30



P350087-020-30


Finesse LED

The beautifully graphic cage frame closes in a circular pattern around an etched opal glass shade.

Product No.	Finish	Size	Source	Input
P350089-078-30 P350089-121-30 P350089-143-30	Vintage Gold Metallic Silver Graphite	15" dia., 4-1/2" ht.	One 17w LED module, 3000K, 90CRI, 1452 source lumens.	120V  



P350089-078-30

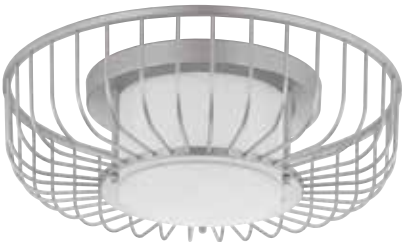


P350089-121-30



P350089-143-30

Mingle LED

Decorative metal frame that highlights concentric circular shapes. Brushed Nickel has etched parchment glass diffuser. Antique Bronze has natural parchment and glass. ELV dimming.

Product No.	Finish	Size	Source	Input
P2318-0930K9 P2318-2030K9	Brushed Nickel Antique Bronze	11" dia., 5-7/8" ht.	One 17w LED module, 3000K, 90CRI, 1211 lumens	120V 
P2320-0930K9 P2320-2030K9	Brushed Nickel Antique Bronze	14" dia., 10-1/2" ht.		
P2330-0930K9	Brushed Nickel	14" dia., 10-1/2" ht.		
P2332-0930K9	Brushed Nickel	14" dia., 10-1/2" ht.		



P2318-0930K9



P2318-2030K9



P2330-0930K9



P2320-0930K9





P2320-2030K9



P2332-0930K9

Inspire LED

Traditional forms are freshened with flowing lines and LED lamping.

Product No.	Finish	Size	Source	Input
P350134-009-30 P350134-143-30	Brushed Nickel Antique Bronze	13" dia., 10-5/8" ht.	One 17w LED module, 3000K, 90CRI, 1452 source lumens.	120V  
P350135-009-30 P350135-143-30	Brushed Nickel Antique Bronze	13" dia., 6" ht.	One 17w LED module, 3000K, 90CRI, 1452 source lumens.	



P350135-143-30



P350134-143-30




P350135-009-30



P350134-009-30

Dome LED

A domed, linen finish glass diffuser is discreetly supported from metal fittings and encloses an energy-efficient light source.
NOTE: This fixture is not dimmable.

Product No.	Finish	Size	Source	Input
P350055-009-30	Brushed Nickel	12" dia., 4-1/4" ht.	20w integrated LED, 3000K, 90CRI, 1000 lumens	120V 
P350056-009-30	Brushed Nickel	16" dia., 4-1/2" ht.	24w integrated LED, 3000K, 90CRI, 1144 lumens	




P350055-009-30



P350056-009-30

Portal LED

A series of flush mounts adorned with industrial-inspired accents and etched glass. ELV dimming.

Product No.	Finish	Size	Source	Input
P3631-0930K9 P3631-1530K9	Brushed Nickel Polished Chrome	9" dia., 2-1/2" ht.	One 17w LED module, 3000K, 90CRI, 1211 lumens	120V 
P3632-0930K9 P3632-1530K9	Brushed Nickel Polished Chrome	13" dia., 2-1/2" ht.	One 29w LED module, 3000K, 90CRI, 2197 lumens	
P3658-0930K9 P3658-2030K9	Brushed Nickel Antique Bronze	11" dia., 3-7/8" ht.	One 17w LED module, 3000K, 90CRI, 1211 lumens	



P3631-1530K9



P3631-0930K9



P3658-0930K9



P3632-1530K9





P3632-0930K9



P3658-2030K9

Gather LED

Sleek frame features updated styling and elegant etched glass shades.

Product No.	Finish	Size	Source	Input
P350088-009-30 P350088-015-30 P350088-020-30	Brushed Nickel Polished Chrome Antique Bronze	Hanging and ceiling mount hardware included. 12-7/8" dia., 10-3/8" ht.,	Overall ht. w/chain 50", wire 10'. One 17w LED module, 3000K, 90CRI, 1276 source lumens.	120V  



P350088-015-30
shown as hanging





P350088-009-30
shown as hanging



P350088-020-30
shown as hanging

Flush Mounts LED

Etched glass dominates a traditional design with its distinctive and sculptural bowl paired with a metal frame.

Product No.	Finish	Size	Source	Input
P350131-009-30 P350131-015-30 P350131-020-30	Brushed Nickel Polished Chrome Antique Bronze	15-1/2" dia., 5-1/4" ht.	One 25w LED module, 3000K, 90CRI, 1770 source lumens.	120V  
P350100-009-30 P350100-015-30 P350100-020-30	Brushed Nickel Polished Chrome Antique Bronze	11" dia., 4-1/4" ht.	One 17w LED module, 3000K, 90CRI, 1276 source lumens.	
P350101-009-30 P350101-015-30 P350101-020-30	Brushed Nickel Polished Chrome Antique Bronze	13-1/2" dia., 4-1/2": ht.	One 25w LED module, 3000K, 90CRI, 1770 source lumens.	



P350100-009-30



P350100-015-30



P350100-020-30



P350101-009-30



P350101-015-30



P350101-020-30



P350131-009-30





P350131-015-30



P350131-020-30

Flush Mounts LED

Flush mount series featuring an etched glass bowl. Triac or ELV dimming.

Product No.	Finish	Size	Source	Input
P350051-009-30 P350051-020-30	Brushed Nickel Antique Bronze	11" dia., 4-3/16" ht.	One 17w LED module, 3000K, 90CRI, 1452 lumens	120V  
P350052-009-30 P350052-020-30	Brushed Nickel Antique Bronze	12-9/16" dia., 4-1/2" ht.	One 25w LED module, 3000K, 90CRI, 2015 lumens	
P350053-009-30 P350053-020-30	Brushed Nickel Antique Bronze	11" dia., 4" ht.	One 17w LED module, 3000K, 90CRI, 1452 lumens	
P350054-009-30 P350054-020-30	Brushed Nickel Antique Bronze	13-1/4" dia., 4-3/4" ht.	One 25w LED module, 3000K, 90CRI, 2015 lumens	



P350051-009-30



P350051-020-30



P350053-009-30



P350053-020-30



P350052-009-30



P350052-020-30





P350054-009-30



P350054-020-30

Square Alabaster Glass LED



Flush mount with swirl pattern or alabaster glass. Triac or ELV dimming.


Product No.	Finish	Size	Source	Input
P350019-009-30 P350019-020-30	Brushed Nickel Antique Bronze	9-1/2" sq., 4-3/8" ht.	One 17w LED module, 3000K, 90CRI, 1452 source lumens	120V  
P350020-009-30 P350020-020-30	Brushed Nickel Antique Bronze	11-3/8" sq., 5" ht.	One 25w LED module, 3000K, 90CRI, 2015 source lumens	



Square Linen Glass LED


Classic square linen glass bowl is trimmed with architecturally detailed metal.

Product No.	Finish	Size	Source	Input
P350023-009-30 P350023-020-30	Brushed Nickel Antique Bronze	9-1/2" sq., 4-3/8" ht.	One 17w LED module, 3000K, 90CRI, 1452 source lumens.	120V  
P350024-009-30 P350024-020-30	Brushed Nickel Antique Bronze	11-1/2" sq., 4-7/8" ht.	One 25w LED module, 3000K, 90CRI, 2015 source lumens.	

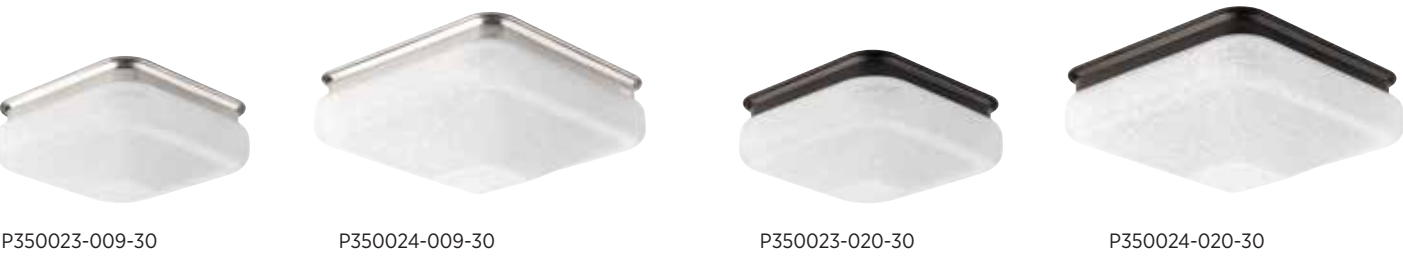

Cloud + Drum LED



Choose either a classic white round diffuser or cloud-like diffuser.

Product No.	Finish	Size	Source	Input
P730002-030-30	White	13-5/8" W., 4" ht.	22.5w integrated LED, 3000K, 90CRI, 2025 delivered lumens.	120V  
P730003-030-30	White	17" W., 4" ht.	28w integrated LED, 3000K, 90CRI, 2520 delivered lumens.	
P730005-030-30 P730005-031-30	White Black	11" W., 4" ht.	21w integrated LED, 3000K, 90CRI, 1680 delivered lumens.	
P730006-030-30	White	13-5/8" W., 4" ht.	22.5w integrated LED, 3000K, 90CRI, 1845 delivered lumens.	
P730007-030-30	White	17" W., 4" ht.	28w integrated LED, 3000K, 90CRI, 2548 delivered lumens.	
P730008-030-30	White	11" W., 4" ht.	21w integrated LED, 3000K, 90CRI, 1575 delivered lumens.	
P810025-030-30	White	11" dia., 3-1/2" ht.	15w integrated LED, 3000, 90CRI, 1152 delivered lumens.	
P810026-030-30	White	13-3/4" dia., 3-3/4" ht.	20w integrated LED, 3000, 90CRI, 1431 delivered lumens.	



Maier DC LED

Simplicity rules with a white opal acrylic diffuser held by double-banded metal trim.

Product No.	Finish	Size	Source	Input
P350076-009-30 P350076-020-30 P350076-030-30	Brushed Nickel Antique Bronze White	9-1/16" dia., 4-5/16" ht.	20.5w integrated LED, 3000K, 90CRI, 1354 delivered lumens.	120V  
P350077-009-30 P350077-020-30 P350077-030-30	Brushed Nickel Antique Bronze White	14" dia., 4-3/4" ht.	26w integrated LED, 3000K, 90CRI, 2016 delivered lumens.	
P350078-009-30 P350078-020-30 P350078-030-30	Brushed Nickel Antique Bronze White	18" dia., 5-1/4" ht.	28.5w integrated LED, 3000K, 90CRI, 2064 delivered lumens.	



P350076-020-30



P350076-030-30



P350076-009-30



P350077-020-30



P350077-030-30



P350077-009-30



P350078-020-30





P350078-030-30



P350078-009-30

Opal-Linen LED

Opal glass shade paired with a linen-textured diffuser and architecturally detailed metal trim.

Product No.	Finish	Size	Source	Input
P350081-009-30 P350081-020-30	Brushed Nickel Antique Bronze	12" dia., 4-3/4" ht.	One 17w LED module, 3000K, 90CRI, 1452 source lumens.	120V  
P350082-009-30 P350082-020-30	Brushed Nickel Antique Bronze	15" dia., 5" ht.	One 25w LED module, 3000K, 90CRI, 2015 source lumens.	



P350081-009-30



P350081-020-30





P350082-009-30



P350082-020-30

Milford LED

Octagonal aluminum metal frame surrounds white etched glass.

Product No.	Finish	Size	Source	Input
P3665-3130K9	Black	8-5/8" dia., 4-1/8" ht.	One 17w LED module, 3000K, 90CRI, 1211 source lumens.	120V  
P3673-3130K9	Black	10-5/8" dia., 4-7/8" ht.		





P3665-3130K9



P3673-3130K9

Linen LED

White linen glass bowl trimmed with metal banding and punctuated with a metal knob.

Product No.	Finish	Size	Source	Input
P350005-009-30	Brushed Nickel	11" dia., 4-5/8" ht.	21w integrated LED, 3000K, 90CRI, 921 delivered lumens.	120V  
P350006-009-30	Brushed Nickel	13" dia., 5-3/8": ht.	21w integrated LED, 3000K, 90CRI, 1152 delivered lumens.	
P350007-009-30	Brushed Nickel	15" dia., 5-7/8" ht.	28w integrated LED, 3000K, 90CRI, 1389 delivered lumens.	
P350008-009-30	Brushed Nickel	19" dia., 7-1/8" ht.	30w integrated LED, 3000K, 90CRI, 1984 delivered lumens.	



P350005-009-30



P350006-009-30




P350007-009-30



P350008-009-30

6" Fitter LED

Opal glass diffuser. ELV dimming.

Product No.	Finish	Size	Source	Input
P3408-0930K9 P3408-3030K9	Brushed Nickel White	7-1/2" dia., 4-3/8" ht.	One 17w LED module, 3000K, 90CRI, 1211 source lumens	120V 
P3412-0930K9	Brushed Nickel	11-1/2" dia., 5-3/4" ht.	One 29w LED module, 3000K, 90CRI, 2197 source lumens	




P3408-0930K9



P3408-3030K9

Frame LED

Modern architectural styling frames an integrated LED source and circular etched opal glass. For increased design options, fixtures can be installed horizontally or vertically. ELV dimming.


Product No.	Finish	Size	Source	Input
P2781-0930K9	Brushed Nickel Architectural Bronze	4-3/4" W., 12" ht. Extends 3-1/2". H/CTR 2-3/8".	15w integrated LED, 3000K, 90CRI, 738 lumens	120V 



P2781-0930K9

Truss LED

A tubular design pairs with a geometric back plate and mesh accents to create Truss – a fixture than can be mounted horizontally or vertically. Circular etched opal glass. ELV dimming

Product No.	Finish	Size	Source	Input
P2834-0930K9 P2834-12930K9	Brushed Nickel Architectural Bronze	4-3/4" W., 13" ht. Extends 3-7/8". H/CTR 2-3/8".	32w integrated LED, 3000K, 90CRI, 737 delivered lumens	120V 
P2839-0930K9 P2839-12930K9	Brushed Nickel Architectural Bronze	22-1/2" W., 4-3/4" ht. Extends 3-7/8". H/CTR 2-3/8".	37w integrated LED, 3000K, 90CRI, 1222 delivered lumens	



P2834-12930K9



P2839-0930K9






P2834-0930K9
shown vertically



P2839-12930K9
shown vertically

Apogee LED

Tiered metal banded trim holds a half-circle etched glass shade. 0-10V dimming

Product No.	Finish	Size	Source	Input
P710036-009-30 P710036-129-30	Brushed Nickel Architectural Bronze	15" W., 7-1/2" ht. Extends or depth 3-11/16"	20w integrated, 3000K, 90CRI, 940 delivered lumens	120-277V   






P710036-009-30



P710036-129-30

Eclipse LED

Lunar-eclipse inspired halfcircle metal frame accented by satin white glass. 0-10V dimming

Product No.	Finish	Size	Source	Input
P710090-009-30 P710090-031-30	Brushed Nickel Black	15-1/2" W., 7-1/2" ht., wire 6". Extends 4". H/CTR 3".	One 17w LED module, 3000K, 90CRI, 1276 source lumens.	120-277V   






P710090-031-30



P710090-009-30

Inspire LED

Gently curving form is accented with a fabric shade.

Product No.	Finish	Size	Source	Input
P710071-030-30 P710071-159-30	Summer Linen Off White Linen	6-1/4" W., 9" ht., Extends 3-1/8".	One 9w LED module, 3000K, 90CRI, 624 source lumens.	120V   





P710071-030-30



P710071-159-30

Anson LED

ADA wall lantern with polycarbonate diffuser and stainless steel frame. Triac or ELV dimming



Product No.	Finish	Size	Source	Input
P560001-129-30	Architectural Bronze	10" Sq., 3" ht. Extends 3".	One 17w LED module, 3000K, 90CRI, 1211 lumens	120V  



P560001-129-30

LED Sconces

ADA sconces with white acrylic or glass* diffuser. ELV dimming.

Product No.	Finish	Size	Source	Input
P7083-0930K9	Brushed Nickel	8-7/8" W., 10-5/8" ht. Extends 4". H/CTR 5-3/8".	One 17w LED module, 3000K, 90CRI, 1211 source lumens	120V  
P7085-0930K9	Brushed Nickel	9-1/2" W., 10-5/8" ht. Extends 3-3/4". H/CTR 10-3/8".		
P7088-0930K9	Brushed Nickel	8" W., 10-5/8" ht. Extends 3-7/8". H/CTR 5-3/8".		
P7092-0930K9	Brushed Nickel	8" W., 10-3/4" ht. Extends 4". H/CTR 5-1/2".		
P7093-3030K9	White	11-1/4" W., 11-5/16" ht. Extends 3-1/2". H/CTR 5-5/8".		
P7105-0930K9	Brushed Nickel	12-7/8" W., 10" ht. Extends 3-1/2". H/CTR 6-3/8".		



P7083-0930K9



P7085-0930K9



P7088-0930K9



P7092-0930K9*



P7093-3030K9*
Shown with Brushed Nickel finial



P7093-3030K9*
Shown with Bronze finial






P7093-3030K9*
Shown with White finial



P7105-0930K9*

LED Sconces

An elegant white linen shade that is open on the top and bottom diffuses light efficiently. Ideal for vanity and hospitality applications. Triac or ELV dimming.

Product No.	Finish	Size	Source	Input
P710010-009-30 P710010-129-30	Brushed Nickel Architectural Bronze	6-3/4" W., 12" ht. Extends 4". H/CTR 6".	One 9w LED module, 3000K, 90CRI, 624 source lumens	120V   






P710010-009-30



P710010-129-30

Ponder LED

Ponder vanity fixtures with prismatic glass shades offer a sleek, industrial-inspired appearance. Etched prismatic glass is framed within a die cast bezel to enhance visual interest in Urban Industrial or Farmhouse-style interiors.

Product No.	Finish	Size	Source	Input
P300091-020-30 P300091-143-30	Architectural Bronze Graphite	16-1/8 W., 4-5/8" ht. Extends 3-5/8". H/CTR 2-3/8".	Two 9w LED modules, 3000K, 90CRI, 670 source lumens per module.	120V   
P300092-020-30 P300092-143-30	Architectural Bronze Graphite	25-3/8" W., 4-5/8" ht. Extends 3-5/8". H/CTR 2-3/8".	Three 9w LED modules, 3000K, 90CRI, 670 source lumens per module.	



P300092-020-30



P300091-020-30



P300092-143-30





P300091-143-30

Capelli LED

Inspired by the beauty of frozen ice forms, Capelli LED sconces feature intriguing glass layers resulting in a sophisticated form. The integrated LED technology runs across the length of the fixture, allowing the illumination to showcase the unique effects of the handmade work of art. The backplate and knob details are finished in Chrome.

All fixtures can be installed horizontally or vertically.

Product No.	Finish	Size	Source	Input
P300054-015-30	Polished Chrome	24" W., 4-3/4" ht. Extends 3-3/4". H/CTR 2-3/8".	36w integrated LED, 3000K, 90CRI, 2600 delivered lumens.	120V  
P300055-015-30	Polished Chrome	33" W., 4-3/4" ht. Extends 3-3/4". H/CTR 2-3/8".	53w integrated LED, 3000K, 90CRI, 3850 delivered lumens.	
P710062-015-30	Polished Chrome	4-3/4" W., 12" ht. Extends 3-3/4". H/CTR 2-3/8".	16w integrated LED, 3000K, 90CRI, 1125 delivered lumens.	



P710062-015-30





P300055-015-30



P300054-015-30

Miter LED

The Miter LED wall sconce highlights a beautiful layered effect to enhance a variety of interior areas. Each clear beveled glass panel is hand cut and positioned together, creating visual interest that extend to the corners. To complete the form, a backplate and linear accents frame the glass in a Brushed Nickel finish. An integrated LED source provides a variety of energy and cost savings benefits.

Product No.	Finish	Size	Source	Input
P300152-009-30	Brushed Nickel	24" W., 5" ht. Extends 3-7/8". H/CTR 2-1/2".	36w integrated LED, 3000K, 90CRI, 1975 delivered lumens.	120V  
P300153-009-30	Brushed Nickel	34-1/8" W., 5" ht. Extends 3-7/8". H/CTR 2-1/2".	53w integrated LED, 3000K, 90CRI, 2825 delivered lumens	
P7100161-009-30	Brushed Nickel	5" W., 12-1/4" ht. Extends 3-7/8". H/CTR 6-1/8".	16w integrated LED, 3000K, 90CRI, 825 delivered lumens	



P300153-009-30



P300152-009-30





P710061-009-30

Concourse LED

Architectural details and a full size canopy are key elements in Concourse LED vanity fixtures. A dual tone reflector frames the canopy to provide a mirror like effect. Etched opal glass is paired with Brushed Nickel and polished stainless accents in this versatile cylindrical fixture.

All fixtures can be installed horizontally or vertically.

Product No.	Finish	Size	Source	Input
P300093-009-30	Brushed Nickel	24" W., 4-3/4" ht. Extends 3-1/2". H/CTR 2-3/8".	One 37w LED module, 3000K, 90CRI, 2191 delivered lumens.	120V  
P300094-009-30	Brushed Nickel	36" W., 4-3/4" ht. Extends 3-1/2". H/CTR 2-3/8".	One 53w LED module, 3000K, 90CRI, 2969 delivered lumens.	





P300093-009-30




P300094-009-30

Colonnade LED

Tubular etched glass shades pop against geometric backplate to create Colonnade, an LED bath collection. Available in one, two, three and four-light options. Modern style and continuous illumination are ideal for a variety of bath settings – including Mid-Century and Luxe.

Product No.	Finish	Size	Source	Input
P300185-009-30 P300185-015-30	Brushed Nickel Polished Chrome	4-3/4" W., 7-1/2" ht. Extends 3-7/8". H/CTR 3-7/8".	9.5w integrated LED, 3000K, 90CRI, 500 delivered lumens.	120V  
P300186-009-30 P300186-015-30	Brushed Nickel Polished Chrome	13-1/4" W., 7-1/2" ht. Extends 3-7/8". H/CTR 3-7/8".	19w integrated LED, 3000K, 90CRI, 1000 delivered lumens.	
P300187-009-30 P300187-015-30	Brushed Nickel Polished Chrome	22" W., 7-1/2" ht. Extends 3-7/8". H/CTR 3-7/8".	28.5w integrated LED, 3000K, 90CRI, 1500 delivered lumens.	
P300188-009-30 P300188-015-30	Brushed Nickel Polished Chrome	31-3/8" W., 7-1/2" ht. Extends 3-7/8". H/CTR 3-7/8".	38w integrated LED, 3000K, 90CRI, 2000 delivered lumens.	

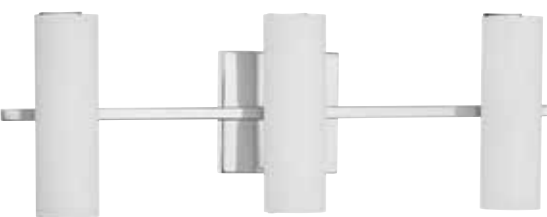

P300187-015-30



P300186-015-30



P300188-015-30



P300185-015-30



P300187-009-30



P300186-009-30





P300188-009-30



P300185-009-30

Beam LED

Beam LED vanity and sconces feature a squared, tubular opal glass diffuser paired with a simple, modern metal canopy. An integrated LED source provides a variety of energy and cost savings benefits. Suitable for residential and commercial applications.

Product No.	Finish	Size	Source	Input
P300182-129-30 P300182-009-30 P300182-015-30	Architectural Bronze Brushed Nickel Polished Chrome	Installs horizontal or vertical. 22-1/4" W., 4-3/4" ht. Extends 3". H/CTR 2-3/8".	36w integrated LED, 3000K, 90CRI, 2200 delivered lumens.	120V  
P710049-129-30 P710049-009-30 P710049-015-30	Architectural Bronze Brushed Nickel Polished Chrome	4-3/4" W., 10-1/2" ht. Extends 3-1/4". H/CTR 8-3/8".	16w integrated LED, 3000K, 90CRI, 1000 delivered lumens.	



P300182-129-30



P300182-009-30



P300182-015-30



P710049-015-30





P710049-129-30



P710049-009-30

Planck LED

Planck LED wall fixtures use indirect illumination to provide a dramatic architectural feature to any space. A brushed metal beam sports a sleek chrome accent to add visual interest to the minimalist form. Suitable for residential or commercial applications.

Product No.	Finish	Size	Source	Input
P710051-009-30	Brushed Nickel	4-3/4" W., 16" ht. Extends 3". H/CTR 12-5/8".	16w integrated LED, 3000K, 90CRI, 600 delivered lumens.	120V  
P710052-009-30	Brushed Nickel	24" W., 4-3/4" ht. Extends 3". H/CTR 2-3/8".	32w integrated LED, 3000K, 90CRI, 1100 delivered lumens	




P710052-009-30



P710051-009-30
Installs horizontal
or vertical

Frame LED

Modern architectural styling frames an integrated LED source and circular etched opal glass. For increased design options, fixtures can be installed horizontally or vertically. ELV Dimming.

Product No.	Finish	Size	Source	Input
P2781-0930K9	Brushed Nickel	4-3/4" W., 12" ht. Extends 3-1/2". H/CTR 2-3/8".	15w integrated LED, 3000K, 90CRI, 738 delivered lumens	120V 
P2782-0930K9	Brushed Nickel	24" W., 4-3/4" ht. Extends 3-1/2". H/CTR 2-3/8".	35w integrated LED, 3000K, 90CRI, 1659 delivered lumens	




P2781-0930K9



P2782-0930K9

Truss

A tubular design pairs with a geometric back plate and mesh accents to create Truss – a fixture than can be mounted horizontally or vertically. Circular etched opal glass. ELV Dimming

Product No.	Finish	Size	Source	Input
P2834-0930K9 P2834-12930K9	Brushed Nickel Architectural Bronze	4-3/4" W., 13" ht. Extends 3-7/8". H/CTR 2-3/8".	32w integrated LED, 3000K, 90CRI, 737 delivered lumens	120V 
P2839-0930K9 P2839-12930K9	Brushed Nickel Architectural Bronze	22-1/2" W., 4-3/4" ht. Extends 3-7/8". H/CTR 2-3/8".	37w integrated LED, 3000K, 90 CRI, 1222 delivered lumens.	



P2834-0930K9



P2834-12930K9





P2839-0930K9



P2839-12930K9

Parallel LED

The sophisticated, modern style of the Parallel Collection features crisp, tubular, opal glass diffusers, each paired with a simple modern metal backplate for an understated, elegant design.

Product No.	Finish	Size	Source	Input
P300183-009-30 P300183-129-30 P300183-012-30 P300183-015-30	Brushed Nickel Architectural Bronze Satin Brass Polished Chrome	Installs horizontal or vertical. 22-3/8" W., 4-3/4" ht. Extends 2-3/4". H/CTR 2-3/8".	36w integrated LED, 3000K, 90CRI, 2166 delivered lumens.	120V  
P300184-009-30 P300184-129-30 P300184-012-30 P300184-015-30	Brushed Nickel Architectural Bronze Satin Brass Polished Chrome	Installs horizontal or vertical. 32" W., 4-3/4" ht. Extends 2-3/4". H/CTR 2-3/8".	53w integrated LED, 3000K, 90CRI, 2872 delivered lumens.	
P710050-009-30 P710050-012-30 P710050-015-30 P710050-129-30	Brushed Nickel Architectural Bronze Satin Brass Polished Chrome	4-3/4" W., 11" ht. Extends 2-3/4". H/CTR 7-1/2".	16w integrated LED, 3000K, 90CRI, 930 delivered lumens.	



P300184-009-30



P300183-012-30



P300183-009-30



P300184-012-30



P300184-129-30



P300183-015-30



P300183-129-30



P300184-015-30



P710050-009-30



P710050-015-30





P710050-129-30



P710050-012-30

Blanco LED



The Blanco Collection highlights classic forms with crisp, contemporary updates. Offered in a variety of metal finishes, each fixture features a thin, horizontal cylinder shade for a clean, linear design. Blanco LED is ideal for modern and transitional settings.

Product No.	Finish	Size	Source	Input
P300150-009-30 P300150-012-30 P300150-031-30 P300150-150-30	Faux White Marble Brushed Nickel Satin Brass Matte Black	Installs horizontal or vertical. 22-1/4" W., 4-3/4" ht. Extends 3-5/8". H/CTR 2-3/8".	36w integrated LED, 3000K, 90CRI, 1942 delivered lumens.	120V  
P300151-009-30 P300151-012-30 P300151-031-30 P300151-150-30	Faux White Marble Brushed Nickel Satin Brass Matte Black	Installs horizontal or vertical. 32-3/8" W., 4-3/4" ht. Extends 3-3/4". H/CTR 2-3/8".	53w integrated LED, 3000K, 90CRI, 2768 delivered lumens.	
P710047-009-30 P710047-012-30 P710047-031-30 P710047-150-30	Faux White Marble Brushed Nickel Satin Brass Matte Black	Installs horizontal or vertical. 32-3/8" W., 4-3/4" ht. Extends 3-3/4". H/CTR 2-3/8".	53w integrated LED, 3000K, 90CRI, 2768 delivered lumens.	



Ace LED




Modern wall fixtures with geometric etched glass shades. ELV dimming

Product No.	Finish	Size	Source	Input
P2142-1530K9 P2142-2030K9	Polished Chrome Antique Bronze	7" W., 4-3/4" ht. Extends 4". H/CTR 2-3/4".	One 9w LED module, 3000K, 90CRI, 623 source lumens/module	120V  
P2143-1530K9 P2143-2030K9	Polished Chrome Antique Bronze	15-1/2" W., 4-3/4" ht. Extends 4". H/CTR 2-3/8".	Two 9w LED modules, 3000K, 90CRI, 623 source lumens/module	
P2144-1530K9 P2144-2030K9	Polished Chrome Antique Bronze	24" W., 4-3/4" ht. Extends 4". H/CTR 2-3/8".	Three 9w LED modules, 3000K, 90CRI, 623 source lumens/module	
P2145-1530K9 P2145-2030K9	Polished Chrome Antique Bronze	32-1/2" W., 4-3/4" ht. Extends 4". H/CTR 2-3/8".	Four 9w LED modules, 3000K, 90CRI, 623 source lumens/module	



Phase 1.1 LED



Featuring a cylindrical acrylic diffuser and a simple rectangular backplate, Phase 1.1 offers a variety of lengths to accommodate residential, light commercial and multi-family applications. An integrated LED source provides uniform illumination, as well as energy and cost savings benefits.


Product No.	Finish	Size	Source	Input
P300223-009-30	Brushed Nickel	24" W., 4-3/4" ht. Extends 4". H/CTR 2-3/8".	22w integrated LED, 3000K, 90CRI, 1675 delivered lumens.	120V   
P300224-009-30	Brushed Nickel	36" W., 4-3/4" ht. Extends 4". H/CTR 2-3/8".	33w integrated LED, 3000K, 90CRI, 2600 delivered lumens.	
P300225-009-30	Brushed Nickel	48" W., 4-3/4" ht. Extends 4". H/CTR 2-3/8".	42w integrated LED, 3000K, 90CRI, 3500 delivered lumens.	



Phase 1.2 LED




A classic form with contemporary updates, this elongated acrylic shade comes with decorative accents. Both a faux stone option and white geometric decorative diffuser are included to further customize the fixture. An integrated LED source provides uniform illumination, as well as energy and cost savings benefits.

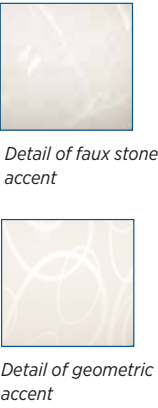Product No.	Finish	Size	Source	Input
P300205-009-30	Brushed Nickel	24" W., 4-3/4" ht. Extends 4-1/2". H/CTR 2-3/8".	22w integrated LED, 3000K, 90CRI, 1575 delivered lumens.	120V  
P300206-009-30	Brushed Nickel	36" W., 4-3/4" ht. Extends 4-1/2". H/CTR 2-3/8".	33w integrated LED, 3000K, 90CRI, 2475 delivered lumens.	
P300207-009-30	Brushed Nickel	48" W., 4-3/4" ht. Extends 4-1/2". H/CTR 2-3/8".	42w integrated LED, 3000K, 90CRI, 3400 delivered lumens.	



Phase 2.1 LED




Phase 2.1 features an acrylic lens that provides even illumination. This specially designed linear fixture delivers ambient light to surfaces free of shadows. Phase 2.1 is a perfect addition to modern applications. An integrated LED source provides energy and cost savings benefits.

Product No.	Finish	Size	Source	Input
P300208-009-30	Brushed Nickel	24" W., 4-3/4" ht. Extends 3-1/2". H/CTR 2-3/8".	23w integrated LED, 3000K, 90CRI, 1600 delivered lumens.	120V   
P300209-009-30	Brushed Nickel	36" W., 4-3/4" ht. Extends 3-1/2". H/CTR 2-3/8".	34w integrated LED, 3000K, 90CRI, 2450 delivered lumens.	
P300225-009-30	Brushed Nickel	48" W., 4-3/4" ht. Extends 3-1/2". H/CTR 2-3/8".	44w integrated LED, 3000K, 90CRI, 3300 delivered lumens.	



Phase 2.2 LED



Phase 2.2 features an acrylic shade framed by architectural accents in Brushed Nickel complete the design to deliver ambient light to surfaces free of shadows. Ideal for residential, commercial and multi-family applications. An integrated LED source provides energy and cost savings benefits.


Product No.	Finish	Size	Source	Input
P300211-009-30	Brushed Nickel	24" W., 4-3/4" ht. Extends 4". H/CTR 2-3/8".	23w integrated LED, 3000K, 90CRI, 1550 delivered lumens.	120V   
P300212-009-30	Brushed Nickel	36" W., 4-3/4" ht. Extends 4". H/CTR 2-3/8".	34w integrated LED, 3000K, 90CRI, 2400 delivered lumens.	
P300213-009-30	Brushed Nickel	48" W., 4-3/4" ht. Extends 4". H/CTR 2-3/8".	44w integrated LED, 3000K, 90CRI, 3250 delivered lumens.	



Bath LED

The Bath LED Collection offers a taste of subtle sophistication to any design. Beautiful Brushed Nickel bands cap each end of the shades for a clean, modern aesthetic.

Product No.	Finish	Size	Source	Input
P300243-009-30	Brushed Nickel	24" W., 6" ht. Extends 4-1/4".	23W integrated LED, 3000K, 90CRI, 1798 delivered lumens.	120V  
P300244-009-30	Brushed Nickel	48" W., 6" ht. Extends 4-1/4".	37W integrated LED, 3000K, 90CRI, 3040 delivered lumens.	

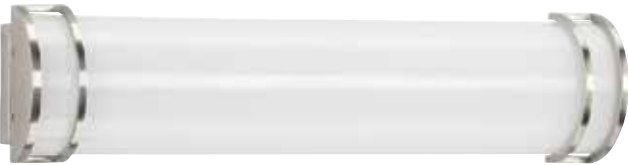



P300243-009-30



P300244-009-30

Cloud LED

The Cloud LED Collection features crisp opal white shades. Each shade is shaped into a linear tube design with a seamless aesthetic. The shades are offered in two different sizes to offer you versatility when it comes to fulfilling your design vision. This product includes a unique feature that allows the user to select color temperature. Fixture is integrated with and internal switch, allowing the user to select CCT options from 3000K, 4000K, or 5000K.

Product No.	Finish	Size	Source	Input
P300239-060-CS	Opal White	26-3/8" L., 6-1/8" W., ht. 4-5/8".	23w integrated LED, CCT selectable (3000K, 4000K, 5000K), 90CRI, 2124 delivered lumens.	120V  
P300240-060-CS	Opal White	38-1/4" L., 6-1/8" W., ht. 4-5/8".	32w integrated LED, CCT selectable (3000K, 4000K, 5000K), 90CRI, 2760 delivered lumens.	




P300239-060-CS



P300239-060-CS

Captarent


80+ CRI

Product No.	Finish	Size	Source	Input	
PCIM1-2543-830-U	Mirrored	24-3/4" W., 43" ht., Extends 2-3/8". ADA	25W Integrated LED, 1140 nominal lumens	120 - 277V 	
PCIM1-2543-835-U					
PCIM1-2543-840-U					
PCIM1-3143-830-U		31-3/4" W., 43" ht., Extends 2-3/8". ADA	36W Integrated LED, 1650 nominal lumens		
PCIM1-3143-835-U					
PCIM1-3143-840-U					
PCIM1-3743-830-U		37-3/4" W., 43" ht., Extends 2-3/8". ADA	36W Integrated LED, 1690 nominal lumens		
PCIM1-3743-835-U					
PCIM1-3743-840-U					

LED FEATURES

- Architecturally designed to provide soft, pleasing illumination
- Perimeter etched panels are indirectly backlit to provide uniform illumination
- Available in three sizes: 25"x43", 31"x43" and 37"x43"
- 80+ or 90+ CRI; Available in 3000K, 3500K, and 4000K color temperature options
- Universal (120-277) voltage, 0-10V dimming capable
- Mirror edges have brushed, radius treatment for consistency in appearance
- Easy installation of metal housing; simple, hanging attachment of mirror to housing.

90+ CRI

Product No.	Finish	Size	Source	Input
PCIM1-2543-930-U	Mirrored	24-3/4" W., 43" ht., Extends 2-3/8". ADA	25W Integrated LED, 1140 nominal lumens	120 - 277V 
PCIM1-3143-930-U		31-3/4" W., 43" ht., Extends 2-3/8". ADA	36W Integrated LED, 1650 nominal lumens	
PCIM1-3743-930-U		37-3/4" W., 43" ht., Extends 2-3/8". ADA	36W Integrated LED, 1690 nominal lumens	



PCIM1-3143-840-U
Featuring Ace



Captarent LED Illuminated Mirror

The Captarent LED illuminated mirror provides a clean, architecturally pleasing solution for illuminating the vanity that is ideal for multi-family, hospitality, assisted living and residential applications. The indirect, backlit solution delivers soft illumination that is well-suited for facial rendering.



Perimeter etched panels are indirectly backlit to provide soft illumination for rendering facial features.



All models are ADA compliant and simple to install.



Mirror edges have a brushed, radius treatment for consistency in appearance.



The housing comes with a standard antimicrobial paint finish to inhibit the growth of microbes.



Available in four sizes and in three different light color temperatures.



Standard 0-10V dimming.



Featuring Markor Pendant and Arch Wall Sconces

Markor Pendant System & Ordering

Simple to order. Specify two separate pieces – shade and stem kit of your choice.

Step 1: Choose a fabric



Black Parchment Paper



Beige Silken Fabric



Summer Linen



Khaki



Harvest Linen

Step 2: Select a shade size

10" DRUM SHADES
P8828-30 Summer Linen



16" DRUM SHADE
P8822-01 Black Parchment Paper
P8823-01 Beige Silken Fabric
P8829-30 Summer Linen
P8829-56 Khaki
P8829-59 Harvest Linen



22" DRUM SHADES
P8824-01 Black Parchment Paper
P8825-01 Beige Silken Fabric
P8830-30 Summer Linen
P8830-56 Khaki
P8830-59 Harvest Linen



Step 3: Select a stem kit

Shades and pendant kits are sold separately.
10" shade can be used only with pendant kit P5198.
16" and 22" shades can be used with pendant kit P5198 or P5199.

ONE-LIGHT STEM KIT
P5198-09 Brushed Nickel
P5198-20 Antique Bronze
P5198-12 Satin Brass
P5198-31 Black
1-5/8" dia., 5-5/8" ht. Overall ht. w/stem and lamps 66"; wire 10'. One medium base lamp, 100w max.

ONE-LIGHT LED STEM KIT
P5198-0930K9 Brushed Nickel
5-3/4" dia., 5-3/8" ht. Overall ht. w/stem and lamps 62"; wire 10'. One 17w LED module 3000K, 90CRI, 1211 source lumens.



THREE-LIGHT STEM KIT
P5199-09 Brushed Nickel
P5199-20 Antique Bronze
P5199-12 Satin Brass
P5199-31 Black
Three-light pendant kit for use with 16" and 22" Markor shades. 4-3/4" dia., 6-1/4" ht. Overall ht. w/stem and lamps 64"; wire 10'. Three medium base lamps, each 100w max.



Round Canopy

The round accessory accommodates 3 fixtures and is available in Brushed Nickel, Antique Bronze and Graphite finishes.

Product No.	Finish	Size
P8403-09 P8403-20 P8403-143	Brushed Nickel Antique Bronze Graphite	15-1/2" dia., 1-3/8" ht.



P8403-09



P8403-20



P8403-143

Round canopy can be used for three pendants. Refer to website for details.



Linear Canopy

Progress Lighting's canopy accessory offers a convenient way to mount groupings of pendants. The linear option can hold either 2 or 3 pendants. Available in Brushed Nickel, Antique Bronze and Graphite finishes.

Product No.	Finish	Size
P8404-09 P8404-20 P8404-143	Brushed Nickel Antique Bronze Graphite	See website for additional details. 4-1/4" W., 23-1/4" L., 11/16" ht.
P860004-009 P860004-020 P860004-143	Brushed Nickel Antique Bronze Graphite	See website for additional details. 4-1/4" W., 59-5/8" L., 1" ht.
P860005-009 P860005-143 P860005-020	Brushed Nickel Antique Bronze Graphite	See website for additional details. 8-1/8" W., 39-5/8" L., 1" ht.



P860004-009



P860004-143



P860004-020



P860005-143
shown in use with
Staunton pendants
Design Series™



P8404-09



P860005-009



P8404-143



P860005-143



P8404-20




P860005-020



Planck LED

Provide a dramatic architectural lighting design to any space with the Planck LED Collection. A smooth, metal beam suspends from the ceiling to add clean, simple visual interest to minimalist residential or commercial settings.

Product No.	Finish	Size	Source	Input
P500276-009-30	Brushed Nickel	47-1/2" W., 1-3/4" D., 1-3/8" ht. Overall ht. w/cord 113"; wire 9'.	39w integrated LED, 3000K, 90CRI, 2900 delivered lumens.	120V 
P500276-028-30	Matte White			
P500276-031-30	Matte Black			

P500276-009-30



P500276-031-30




P500276-028-30



Concourse LED


The Concourse LED linear pendant features minimalist design styling and a slim profile that appears to float along the ceiling. Offering energy efficiency and low maintenance benefits, Concourse LED is suitable for both home and commercial applications providing direct, ambient, beautifully diffused light. A Brushed Nickel frame completes the clean seamless look.

Product No.	Finish	Size	Source	Input
P500002-009-30	Brushed Nickel	40" W., 5-1/4" D., 3" ht. Overall ht. w/cord 113"; wire 9'.	39w integrated LED, 3000K, 90CRI, 2400 delivered lumens.	120V 



Fresnel Lens LED


Industrial roots in form and function. Antique-inspired Fresnel glass lens in Brushed Nickel, Oil Rubbed Bronze, or Chrome. ELV dimming.


Product No.	Finish	Size	Source	Input
P5050-0930K9 P5050-1530K9 P5050-10830K9	Brushed Nickel Polished Chrome Oil Rubbed Bronze	6-1/8" dia., 6-1/4" ht. Overall ht. w/stem 72-1/4"; wire 10'.	One 9w LED module, 3000K, 90CRI, 623 source lumens	120V 
P5188-0930K9 P5188-1530K9 P5188-10830K9	Brushed Nickel Polished Chrome Oil Rubbed Bronze	12-1/8" dia., 10-1/2" ht. Overall ht. w/stem 77"; wire 10'.	One 17w LED module, 3000K, 90CRI, 1211 source lumens	
P5197-0930K9 P5197-1530K9 P5197-10830K9	Brushed Nickel Polished Chrome Oil Rubbed Bronze	16" dia., 13-1/4" ht. Overall ht. w/stem 79"; wire 10'.	One 17w LED module, 3000K, 90CRI, 1211 source lumens	



Brookside LED


Inspired by vintage light fixtures found in early 20th century train stations. Metal shade and double prismatic glass options.

Product No.	Finish	Size	Source	Input
P5024-0930K9	Brushed Nickel	12" dia., 9-1/8" ht. Overall ht. w/stem 65"; wire 10'.	One 17w LED, 3000K, 90CRI, 1211 source lumens.	120V 

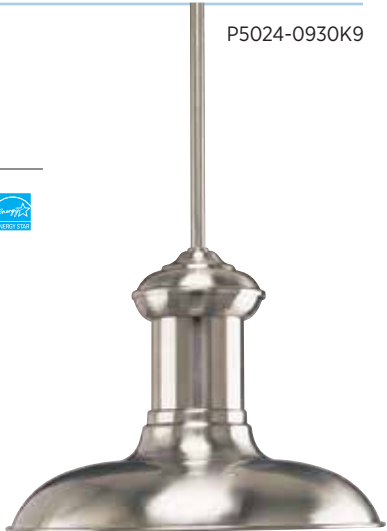

P5024-0930K9

Beaker LED


Product No.	Finish	Size	Source	INPUT
P5344-1530K9	Polished Chrome	5" dia., 11-7/8" ht. Overall ht. w/chain 122"; cord 10'.	One 9w LED module, 3000K, 90CRI, 623 source lumens	120V 



P5344-1530-K9

Dome LED

Inspired to enhance modern home décor, Dome LED pendants come in three intriguing color options and sizes for flexible lighting designs within the home. Satin Aluminum and Gloss White finishes feature a soft silver interior shade while the Antique Bronze dome is complemented with a painted gold interior. ELV dimming.

Product No.	Finish	Size	Source	Input
P5340-1630K9 P5340-2030K9 P5340-3030K9	Satin Aluminum Antique Bronze White	10" dia., 5-5/8" ht. Overall ht. w/cord 125-1/2"; cord 10'.	One 9w LED module, 3000K, 90CRI, 623 source lumens	120V 
P5341-1630K9 P5341-2030K9 P5341-3030K9	Satin Aluminum Antique Bronze White	16" dia., 8-7/8" ht. Overall ht. w/ cord 129"; cord 10'.	One 17w LED module, 3000K, 90CRI, 1211 source lumens	
P5342-1630K9 P5342-2030K9 P5342-3030K9	Satin Aluminum Antique Bronze White	22" dia., 11-3/4" ht. Overall ht. w/ cord 131-1/2"; cord 10'.	One 29w LED module, 3000K, 90CRI, 2197 source lumens	



P5340-1630K9



P5340-2030K9



P5340-3030K9



P5341-1630K9



P5341-2030K9



P5341-3030K9



P5342-1630K9





P5342-2030K9



P5342-3030K9

Globe LED

Distinctive, classic globe pendants are accented by striking metal caps as they top beautiful etched glass shades in the Globe LED Collection. These versatility pendants can be displayed as a single fixture or in groups of two or more by mixing and matching finish options and lengths to create custom lighting designs for the home.

Product No.	Finish	Size	Source	Input
P500147-009-30 P500147-015-30 P500147-109-30 P500147-031-30	Brushed Nickel Polished Chrome Brushed Bronze Matte Black	8" dia., 9-3/4" ht. Overall ht. w/cord 122"; wire 10'.	One 9w LED module, 3000K, 90CRI, 624 source lumens.	120V  
P500148-009-30 P500148-015-30 P500148-109-30 P500148-031-30	Brushed Nickel Polished Chrome Brushed Bronze Matte Black	11-5/8" dia., 13-1/2" ht. Overall ht. w/cord 136-1/2"; wire 10'.	One 17w LED module, 3000K, 90CRI, 1276 source lumens.	



P500148-009-30



P500148-015-30



P500148-109-30



P500147-009-30



P500147-015-30



P500147-109-30





P500147-031-30



P500148-031-30

Prismatic Glass LED

A bold and striking prismatic glass shade is the focal point in these LED pendants. Featuring a sleek Brushed Nickel cap and stems highlighting the industrial styling. Bottom of fixture is enclosed with etched glass diffuser. ELV dimming.



Product No.	Finish	Size	Source	Input
P5143-0930K9	Brushed Nickel	12-3/4" dia., 10-7/8" ht. Overall ht. w/stem 77"; wire 10'.	One 9w LED module, 3000K, 90CRI, 623 source lumens	120V  



P5143-0930K9

Neat LED

These timeless and classic LED pendants feature designer oriented details and polished opal glass. Can be displayed singularly or in groupings of two or more in a variety of spaces, such as Modern Farmhouse, Coastal and Mid-Century Modern environments.

Product No.	Finish	Size	Source	Input
P500065-009-30 P500065-020-30	Brushed Nickel Antique Bronze	4-3/8" dia., 13-1/2" ht. Overall ht. w/cord 124-1/2"; wire 10'.	One 9w LED module, 3000K, 90CRI, 624 source lumens.	120V  
P500066-009-30 P500066-020-30	Brushed Nickel Antique Bronze	6-5/8" dia., 13-1/2" ht. Overall ht. w/cord 124-1/2"; wire 10'.	One 9w LED module, 3000K, 90CRI, 624 source lumens.	



P500065-020-30



P500065-009-30




P500066-020-30



P500066-009-30

Avant LED

A modern LED pendant featuring contrasting textures, including sandblasted glass inside accented by a polished outside surface. ELV dimming.

Product No.	Finish	Size	Source	Input
P5072-0930K9 P5072-2030K9	Brushed Nickel Antique Bronze	9" dia., 4-3/4" ht. Overall ht. w/ cord 125"; wire 10'	One 9w LED module, 3000K, 90CRI, 623 source lumens	120V 





P5072-0930K9



P5072-2030K9

Simple LED

This Simple LED pendant has the LED module tucked inside a frosted acrylic shade. A light commercial pendant ideal for restaurant, bar and hotel applications. ELV dimming.

Product No.	Finish	Size	Source	Input
P5176-0930K9 P5176-2030K9	Brushed Nickel Antique Bronze	5-7/8" dia., 8-5/8" ht. Overall ht. w/cord 130"; wire 10'	One 9w LED module, 3000K, 90CRI, 624 source lumens	120V  




P5176-0930K9



P5176-2030K9

Pure LED

Cord hung LED pendants with design oriented details. Antique Bronze and White have an anodized gold interior. Pistachio and Brushed Nickel have a gloss white interior. ELV dimming.


Product No.	Finish	Size	Source	Input
P5175-0930K9	Brushed Nickel	6-1/2" dia., 8-7/8" ht. Overall ht. w/ cord 130"; wire 10'.	One 9w LED module, 3000K, 90CRI, 623 source lumens	120V 



P5175-0930K9

Warehouse Pendant LED

Smooth cord hung metal shade with white inner-lining. ELV dimming.

Product No.	Finish	Size	Source	Input
P5094-0930K9 P5094-7430K9	Brushed Nickel Venetian Bronze	16" dia., 7-1/2" ht. Overall ht. w/ cord 129"; wire 10'	One 17w LED module, 3000K, 90CRI, 1211 lumens	120V 



P5094-0930K9



P5094-7430K9



Ceiling Fans

POWERFUL, ECONOMIC AIRFLOW
FOR ALL SETTINGS

Today's ceiling fans pair function and technology with the latest design trends to outfit indoor and outdoor public spaces in style and comfort.

Vast

Beautiful and expansive in design, the 72” Vast ceiling fan is ideal for use in large areas and outdoor covered areas for maximum cooling. A white opal shade complements a variety of finish options, including Brushed Nickel with Chrome accents, Antique Bronze, Matte Black, or White with Chrome Accents.

Product No.	Finish	Size	Blades	Source
P2550-0930K	Brushed Nickel	72" dia., 16-3/4" ht. 80" lead wires	Brushed Nickel	18w LED module, 3000K, 90 CRI, 1400 lumens dimmable,
P2550-2030K	Antique Bronze		Antique Bronze	
P2550-3030K	White		White	
P2550-3130K	Matte Black		Black	

T20

Fan

JA8

Light



P2550-0930K shown with
Brushed Nickel blades and
Chrome Accents



P2550-3130K shown with
Black blades



P2550-2030K shown with
Antique Bronze blades



P2550-3030K shown
with White blades and
Chrome Accents





ENERGY INFORMATION AT HIGH SPEED		FEATURES
AIRFLOW	8,100 cubic feet per minute	<ul style="list-style-type: none">Limited lifetime warrantyDual Mount (flat or sloped ceiling-20°)DC MotorAluminum bladesDamp Location RatedWhite opal glassRemote control with batteries is included
ELECTRICITY USE	37 watts (excludes lights)	
AIRFLOW EFFICIENCY	247 CFM/W	



Full Function Remote Control Included
Full-range dimming for light
Six-speed fan operation
Reverse direction control

Sanford

Sanford delivers ultra powerful air movement and energy efficient illumination packaged in a modern design. Ideal for both interior and outdoor settings, this "fandelier" adds a contemporary style to porches, foyers, bath and vanity areas providing a wide range of applications. Sanford includes an integrated 23W LED module, offering both form and function with energy and cost-savings benefits. A three-speed remote control is included.

Product No.	Finish	Size	Source
P2594-0930K P2594-12930K	Brushed Nickel Architectural Bronze	22-7/8" dia., 17-3/4" ht. 80" lead wires.	23w LED Module, 3000K, 90 CRI, dimmable.    



P2594-0930K



P2594-12930K







ENERGY INFORMATION AT HIGH SPEED		FEATURES
AIRFLOW	1,008 cubic feet per minute	<ul style="list-style-type: none">Limited Lifetime WarrantyDual Mount (flat or sloped ceiling-18.5°)AC MotorMetal bladesRemote control with batteries is includedRemote control may be replaced with P2630-30 or P2630-95 wall control
ELECTRICITY USE	37 watts (excludes lights)	
DOE WEIGHTED CFM/W	27 CFM/W	



Three-Speed Remote Control Included
Three-speed fan operation
Full-range dimming for light

Gaze

Three-blade 60" Gaze ceiling fan features an LED light source, offering both form and function with energy- and cost-savings benefits. An opal white shade contains an 18W dimmable, 3000K LED module. Full range dimming and remote control with battery is included.

Product No.	Finish	Size	Blades	Source
P2554-0930K P2554-1530K P2554-2030K P2554-3130K	Brushed Nickel Polished Chrome Antique Bronze Black	60" dia., 13-1/8" ht. 80" lead wires	Silver White Washed Walnut Matte Black        	18w LED module, 3000K, 90CRI, 1400 lumens, dimmable.     Fan Light



P2554-1530K shown with
White Washed blades



P2554-0930K shown with
Cherry blades



P2554-2030K shown with
Walnut blades






ENERGY INFORMATION AT HIGH SPEED		FEATURES	
AIRFLOW	5,902 cubic feet per minute	<ul style="list-style-type: none">Limited lifetime warrantyDual Mount (flat or sloped ceiling-20°)Downrod installation only. Can not be flush mounted.AC MotorManual reverse switch	<ul style="list-style-type: none">Reversible plywood bladesWhite shatterproof lensRemote control with battery is includedRemote control may be replaced with P2630-30 or P2630-95 wall control
ELECTRICITY USE	75 watts (excludes lights)		
AIRFLOW EFFICIENCY	87 CFM/W		



Three-Speed Remote Control Included
Three-speed fan operation
Full-range dimming for light

Oriole

This 60" Oriole ceiling fan is the perfect addition to interior garages, industrial shops or commercial buildings to distribute the right amount of air and keep the space cool and comfortable. Oriole contains an integrated 18W LED module, with an optional finishing cap offering the user the choice to install with or without the light kit. A remote control is included to adjust speed and turn on/off the light or fan. A blank off plate comes standard.

Product No.	Finish	Size	Blades	Source
P2592-0930K P2592-3130K P2592-12930K	Brushed Nickel Black Architectural Bronze	60" dia., 15" ht. 80" lead wires.	Silver Black Architectural Bronze	18w LED Module, 3000K, 90 CRI, 1400 lumens, dimmable.     







ENERGY INFORMATION AT HIGH SPEED		FEATURES
AIRFLOW	6,171 cubic feet per minute	<ul style="list-style-type: none">Limited lifetime warrantyDual Mount (flat or sloped ceiling-18.5°)AC MotorABS bladesWhite opal glass shadeRemote control with battery is includedRemote control may be replaced with P2630-30 or P2630-95 wall control
ELECTRICITY USE	51 watts (excludes lights)	
DOE WEIGHTED CFM/W	132 CFM/W	



Three-Speed Remote Control Included
Three-speed fan operation
Full-range dimming for light

Soar

With a white opal shade and a 17W dimmable LED module, the 54" Soar ceiling fan offers energy and cost-savings benefits for a variety of living spaces. The four-blade fan comes with a remote control and is available in Brushed Nickel, Antique Bronze and White finishes. LED source features a 3000K-color temperature. Soar features a dual mount system and includes a remote control with battery.

Product No.	Finish	Size	Blades	Source
P2542-0930K P2542-2030K P2542-3030K	Brushed Nickel Antique Bronze White	54" dia., 15" ht. 80" lead wires.	Black Walnut White	17w LED Module, 3000K, 90 CRI, 1400 lumens, dimmable.    



ENERGY INFORMATION AT HIGH SPEED		FEATURES
AIRFLOW	4,814 cubic feet per minute	<ul style="list-style-type: none">Limited lifetime warrantyDual Mount (flat or sloped ceiling-20°)AC MotorNon-reversible plywood bladesWhite opal shatterproof lensRemote control with battery is includedRemote control may be replaced with P2630-30 or P2630-95 wall control
ELECTRICITY USE	65 watts (excludes lights)	
DOE WEIGHTED CFM/W	83 CFM/W	



Remote Control Included
Three-speed fan operation
Full-range dimming for light

Gust

This five-blade 54" Gust ceiling fan features a white opal glass shade that is available in a Brushed Nickel, Graphite or Antique Bronze finish. A remote control is included. Gust has a dual mount system to offer greater flexibility when installing. The 18W dimmable, 3000K LED module provides energy and cost-savings benefits to the homeowner.

Product No.	Finish	Size	Blades	Source
P2582-0930K P2582-2030K P2582-14330K	Brushed Nickel Antique Bronze Graphite	54" dia., 16" ht. 80" lead wires.	Silver Walnut Graphite	18w LED Module, 3000K, 90 CRI, 1400 lumens, dimmable. <div>T20JA8WaterWiFi</div>



P2582-2030K shown with Walnut blades



P2582-0930K shown with Silver blades



P2582-14330K shown with Graphite blades

ENERGY INFORMATION AT HIGH SPEED		FEATURES
AIRFLOW	5,242 cubic feet per minute	<ul style="list-style-type: none">Limited Lifetime WarrantyDual Mount (flat or sloped ceiling-18.5°)AC MotorNon-reversible plywood bladesWhite opal glass shadeRemote control with battery is includedRemote control may be replaced with P2630-30 or P2630-95 wall control
ELECTRICITY USE	65 watts (excludes lights)	
DOE WEIGHTED CFM/W	87 CFM/W	



Three-Speed Remote Control Included
Three-speed fan operation
Full-range dimming for light

Kudos

This five-blade 52" Kudos ceiling fan features a clear Fresnel glass shade. Available in a Brushed Nickel, Polished Chrome or Antique Bronze finish and includes a remote control. The Kudos features a dual mount system to offer greater flexibility when installing. The 17W dimmable, 3000K LED module provides energy and cost-savings benefits to the homelowner.

Product No.	Finish	Size	Blades	Source
P2568-0930K P2568-1530K P2568-2030K	Brushed Nicke Polished Chrome Antique Bronze	52" dia., 15-3/4" ht. 80" lead wires	Silver Medium Cherry Walnut	17w LED module, 3000K, 90 CRI, 1400 lumens, dimmable. <div>T20JA8WaterWiFi</div>



P2568-0930K shown with American Walnut blades



P2568-1530K shown with Black blades



P2568-2030K shown with Cherry blades

 













ENERGY INFORMATION AT HIGH SPEED		FEATURES
AIRFLOW	5,160 cubic feet per minute	<ul style="list-style-type: none">Limited Lifetime WarrantyDual Mount (flat or sloped ceiling-18.5°)AC MotorReversible plywood BladesClear Fresnel glass shadeRemote control with battery is includedRemote control may be replaced with P2630-30 or P2630-95 wall control
ELECTRICITY USE	60 watts (excludes lights)	
DOE WEIGHTED CFM/W	91 CFM/W	



Three-Speed Remote Control Included
Three-speed fan operation
Full-range dimming for light

52" Signature Fan

A 52" Signature 5-blade fan features reversible blades and a 30-year limited warranty. A powerful AirPro motor features a 3-speed, triple-capacitor control that can also be reversed to provide year-round comfort. Standard canopy is designed for sloped ceilings with 12:12 pitch and accepts universal light kits.

Product No.	Finish	Size	Blades				
P2521-09	Brushed Nickel	52" dia., 14-5/8" ht. CTC 11-9/16" ht. 80" lead wires	White		Natural Cherry		<div>T20</div> Fan
P2521-09CH	Brushed Nickel		Cherry		Natural Cherry		
P2521-09WA	Brushed Nickel		Classic Walnut		Dark Walnut		
P2521-20	Antique Bronze		Classic Walnut		Medium Cherry		
P2521-77	Forged Bronze		Classic Walnut		Medium Cherry		
P2521-80	Forged Black		Dark Walnut		Dark Cherry		
P2521-81	Antique Nickel		Cherry		Medium Oak		



P2521-09 shown with White Blades



P2521-09 shown with Natural Cherry blades



P2521-09CH shown with Cherry Blades



P2521-09WA shown with Walnut blades



P2521-20 shown with Classic Walnut blades



P2521-81 shown with Medium Oak blades



P2521-80 shown with Dark Cherry blades



P2521-77 shown with Classic Walnut blades


ENERGY INFORMATION AT HIGH SPEED

AIRFLOW	4,701 cubic feet per minute
ELECTRICITY USE	65 watts (excludes lights)
DOE WEIGHTED CFM/W	84 CFM/W

FEATURES

- 30-year limited warranty
- 45° Canopy
- Close-to-ceiling installation
- SureConnect® System
- AC Motor
- Compatible with universal light kits
- Three speed pull-chain switch
- Add a P2630-30 or P2630-95 wall control or P2662-01 hand-held remote control

CTC INSTALLATION

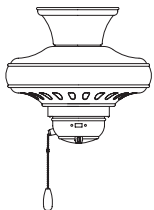

Trevina II 52"

A new addition to a popular ceiling fan collection, the 52" Trevina II features three blades available in Brushed Nickel, Matte White, and Antique Bronze finishes. Coolly modern, the Trevina II ceiling fan offers both form and function with an energy efficient 17w LED source with a 3000K-color temperature. Features a wall control switch.

Product No.	Finish	Size	Blades	Source
P2556-0930K P2556-2030K P2556-3030K	Brushed Nickel Antique Bronze Matte White	52" dia., 15-3/4" ht. 80" lead wires	Silver Medium Cherry Natural Cherry <div><div></div><div></div><div></div></div> Classic Walnut White <div></div>	17w LED module, 3000K, 90 CRI, 1400 lumens, dimmable. <div><div>T20</div><div>JA8</div><div></div><div></div></div>



P2556-3030K shown with White blades

P2556-0930K shown with Silver blades

P2556-2030K shown with Medium Cherry blades

ENERGY INFORMATION AT HIGH SPEED		FEATURES
AIRFLOW	4,916 cubic feet per minute	<ul style="list-style-type: none">• Limited lifetime warranty (LED model)• Dual Mount (flat or sloped ceiling-30°)• AC Motor• White opal glass• Reversible plywood blades
ELECTRICITY USE	62 watts (excludes lights)	
AIRFLOW EFFICIENCY	89 CFM/W	



Wall Control Included
Full-range dimming for light
Four-speed fan operation
Includes switch plate cover

Signature Plus II

Five-blade 54" Signature Plus II ceiling fan features an integrated LED light source, offering both form and function with energy and cost-savings benefits. The light kit contains a white opal shatterproof shade and is comprised of a 17W dimmable 3000K LED module.

Product No.	Finish	Size	Blades	Source
P2539-0930K P2539-2030K P2539-3030K	Brushed Nickel Antique Bronze White	54" dia., 15-1/2" ht. 80" lead wires.	Silver Medium Cherry Walnut <div><div></div><div></div><div></div></div> American Walnut Black Cherry <div></div>	17w LED Module, 3000K, 90 CRI, 1400 lumens, dimmable. <div><div>T20</div><div>JA8</div><div></div><div></div></div>



P2539-0930K shown with Silver blades

P2539-2030K shown with Medium Cherry blades

P2539-3030K shown with White blades

ENERGY INFORMATION AT HIGH SPEED		FEATURES
AIRFLOW	5,331 cubic feet per minute	<ul style="list-style-type: none">• Limited lifetime warranty• 45° Canopy• Downrod mount only• AC Motor• Reversible MDF blades• Opal shatterproof shade• Remote control with battery is included• Remote control may be replaced with P2630-30 or P2630-95 wall control
ELECTRICITY USE	65 watts (excludes lights)	
DOE WEIGHTED CFM/W	92 CFM/W	



Remote Control Included
Three-speed fan operation
Full-range dimming for light

52" Builder Fan

This 52" AirPro fan features 5 reversible blades and a 30-year limited warranty. A powerful AirPro motor contains a 3-speed pull chain switch, and a triple-capacitor that can also be reversed to provide year-round comfort. . Additionally, the fan can be installed without a downrod to accommodate lower ceilings. A quick install canopy securely holds the fan for wiring during installation. The Builder fan will also accept a universal light kit.

Product No.	Finish	Size	Blades
P2501-09 P2501-15 P2501-20 P2501-30 P2501-30W P2501-143	Brushed Nickel Polished Chrome Antique Bronze White White Graphite	52" dia., 13-1/2" ht. 80" lead wires	Cherry Black Medium Cherry White White Graphite

Natural Cherry

Driftwood

Classic Walnut



Washed Oak

White

Black

T20

Fan

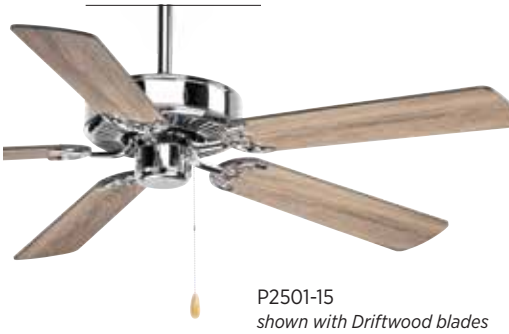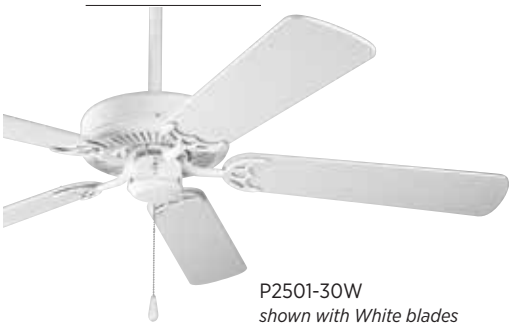

ENERGY INFORMATION AT HIGH SPEED		FEATURES	
AIRFLOW	4,991 cubic feet per minute	• 30-year limited warranty	• AC Motor
ELECTRICITY USE	63 watts (excludes lights)	• Close-to-ceiling installation with accessory	• Compatible with universal light kits
AIRFLOW EFFICIENCY	98 CFM/W	• SureConnect® System	• Add a P2630 wall control or P2662-01 hand-held remote control

42" Builder Fan

42" AirPro ceiling fan with five reversible blades, an integral pull chain and a 15-year limited warranty. A powerful AirPro motor features a 3-speed, triple-capacitor control that can also be reversed to provide year-round comfort. The Builder fan will also accept a universal light kit.

Product No.	Finish	Size	Blades
P2500-09 P2500-20 P2500-30	Brushed Nickel Antique Bronze White	42" dia., 12-1/4" ht. CTC 8-5/16" ht. 72" lead wires	Cherry Classic Walnut White

Natural Cherry

Medium Cherry

Washed Oak

T20

Fan



Quick-Install Bracket




- Securely holds fan for wiring during installation. Installs without removing screws from electrical box.
- Dual-mount for downrod or close-to-ceiling installation.
- Works with sloped ceilings up to 23° (4:12 ceiling pitch)



ENERGY INFORMATION AT HIGH SPEED		FEATURES
AIRFLOW	3,053 cubic feet per minute	• 15-year limited warranty
ELECTRICITY USE	46 watts (excludes lights)	• 23° Canopy
AIRFLOW EFFICIENCY	64 CFM/W	• Close-to-ceiling installation
		• SureConnect® System
		• AC Motor
		• Compatible with universal light kits
		• Three speed pull-chain switch
		• Add a P2630 wall control or P2662-01 hand-held remote control


CTC INSTALLATION

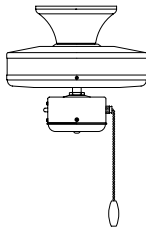

52" Patio Fan

52" indoor/outdoor patio fan from AirPro. Includes 5 blades made with ABS all-weather material and a 15-year limited warranty. A powerful AirPro motor features a 3-speed, triple-capacitor control that can also be reversed to provide year-round comfort. A quick install canopy securely holds the fan for wiring during installation. The Patio fan will also accept a universal outdoor rated light kit.

Product No.	Finish	Size	Blades
P2502-20	Antique Bronze	52" dia.,	Oak
P2502-30	White	12-3/4" ht.	White
P2502-80	Forged Black	CTC 9-11/16" ht.	Toasted Oak
P2502-141	Galvanized	72" lead wires	Silver

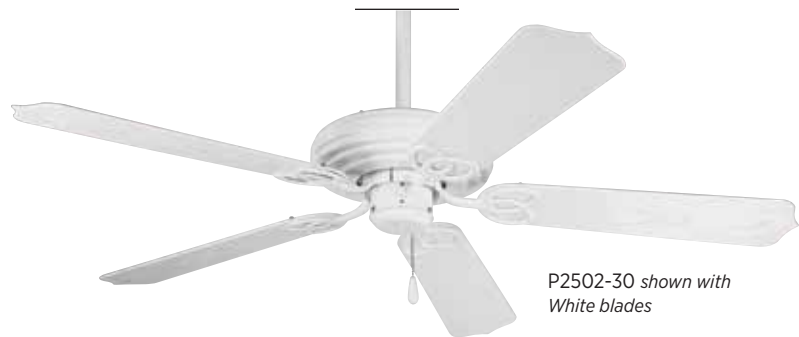

P2502-30 shown with White blades



P2502-80 shown with Toasted Oak blades



P2502-20 shown with Oak blades



P2502-141 shown with Silver blades


ENERGY INFORMATION AT HIGH SPEED

AIRFLOW	4,991 cubic feet per minute
ELECTRICITY USE	64 watts (excludes lights)
AIRFLOW EFFICIENCY	89 CFM/W

FEATURES

- 15-year limited warranty
- Dual Mount (flat or sloped ceiling-23°)
- Close-to-ceiling installation
- SureConnect® System
- Quick-Install canopy
- AC Motor
- ABS all-weather blades
- Compatible with universal light kits
- Three speed pull-chain switch
- Wet location rated
- Add a P2630-30 or P2630-95 wall control or P2662-01 hand-held remote control

CTC INSTALLATION

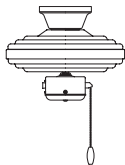

WWW.PROGRESSLIGHTING.COM



STAYING COOL IS A BREEZE!

Progress Lighting offers more sizes and styles of ceiling fans fans for residential and light commercial use than ever before. With options that include integrated LED light kits, WiFi control and many other great features. Perfect for any indoor or outdoor setting!



FIND YOUR PERFECT FAN.
VIEW OUR CATALOG AT
WWW.PROGRESSLIGHTING.COM

Product Index

AA

AA-25	21
AA-39	21
AA-44	21
AA-52	21

P1000

P1841-ICAT	64
P1841-LED	63

P2000

P2142-1530K9	105
P2142-2030K9	105
P2143-1530K9	105
P2143-2030K9	105
P2144-1530K9	105
P2144-2030K9	105
P2145-1530K9	105
P2145-2030K9	105
P2308-0930K9	80
P2318-0930K9	85
P2318-2030K9	85
P2320-0930K9	85
P2320-2030K9	85
P2330-0930K9	85
P2332-0930K9	85
P2500-09	141
P2500-20	141
P2500-30	141
P2501-09	140
P2501-15	140
P2501-20	140
P2501-30	140
P2501-30W	140
P2501-143	140
P2502-20	142
P2502-30	142
P2502-80	142
P2502-141	142
P2521-09	136
P2521-09CH	136
P2521-09WA	136
P2521-20	136
P2521-77	136
P2521-80	136
P2521-81	136
P2539-0930K	139
P2539-2030K	139
P2539-3030K	139
P2542-0930K	133
P2542-2030K	133
P2542-3030K	133
P2550-0930K	128
P2550-2030K	128
P2550-3030K	128
P2550-3130K	128
P2554-0930K	131
P2554-1530K	131
P2554-2030K	131
P2554-3130K	131
P2556-0930K	138
P2556-2030K	138
P2556-3030K	138
P2568-0930K	135
P2568-1530K	135
P2568-2030K	135
P2582-0930K	134
P2582-2030K	134
P2582-14330K	134

P2592-0930K	132
P2592-3130K	132
P2592-12930K	132
P2594-0930K	130
P2594-12930K	130
P2781-0930K9	95, 102
P2782-0930K9	95, 102
P2834-12930K9	95, 102
P2839-0930K9	95, 102
P2839-12930K9	95, 102

P3000/30000

P3408-0930K9	94
P3408-3030K9	94
P3412-0930K9	94
P3447-0930K9	82
P3447-2030K9	82
P3448-0930K9	82
P3448-2030K9	82
P3449-0930K9	82
P3449-2030K9	82
P3610-0930K9	80
P3610-2030K9	80
P3611-0930K9	80
P3611-2030K9	80
P3612-0930K9	80
P3612-2030K9	80
P3631-0930K9	87
P3631-1530K9	87
P3632-0930K9	87
P3632-1530K9	87
P3647-3030K9	40
P3647-3130K9	40
P3648-3030K9	40
P3648-3130K9	40
P3649-3030K9	40
P3649-3130K9	40
P3650-3030K9	40
P3650-3130K9	40
P3658-0930K9	87
P3658-2030K9	87
P3665-3130K9	93
P3673-3130K9	93
P300054-015-30	98
P300055-015-30	98
P300091-020-30	98
P300091-143-30	98
P300092-020-30	98
P300092-143-30	98
P300093-009-30	99
P300094-009-30	99
P300150-009-30	104
P300150-012-30	104
P300150-031-30	104
P300150-150-30	104
P300151-009-30	104
P300151-012-30	104
P300151-031-30	104
P300151-150-30	104
P300152-009-30	99
P300153-009-30	99
P300182-009-30	101
P300182-015-30	101
P300182-129-30	101
P300183-009-30	103
P300183-012-30	103
P300183-015-30	103
P300183-129-30	103
P300184-009-30	103
P300184-012-30	103
P300184-015-30	103

P300184-129-30	103
P300185-009-30	100
P300185-015-30	100
P300186-009-30	100
P300186-015-30	100
P300187-009-30	100
P300187-015-30	100
P300188-009-30	100
P300188-015-30	100
P300205-009-30	106
P300206-009-30	106
P300207-009-30	106
P300208-009-30	107
P300209-009-30	107
P300210-009-30	107
P300211-009-30	107
P300212-009-30	107
P300213-009-30	107
P300223-009-30	106
P300224-009-30	106
P300225-009-30	106
P300239-060-CS	109
P300240-060-CS	109
P300243-009-30	108
P300243-009-30	108
P350005-009-30	94
P350006-009-30	94
P350007-009-30	94
P350008-009-30	94
P350019-009-30	90
P350019-020-30	90
P350020-009-30	90
P350020-020-30	90
P350023-009-30	90
P350023-020-30	90
P350024-009-30	90
P350024-020-30	90
P350051-009-30	89
P350051-020-30	89
P350052-009-30	89
P350052-020-30	89
P350053-009-30	89
P350053-020-30	89
P350054-009-30	89
P350054-020-30	89
P350055-009-30	86
P350056-009-30	86
P350064-009-30	79
P350064-129-30	79
P350065-009-30	79
P350065-129-30	79
P350066-009-30	79
P350066-129-30	79
P350070-009-30	78
P350070-129-30	78
P350071-009-30	78
P350071-129-30	78
P350072-009-30	78
P350072-129-30	78
P350076-009-30	92
P350076-020-30	92
P350076-030-30	92
P350077-009-30	92
P350077-020-30	92
P350077-030-30	92
P350078-009-30	92
P350078-020-30	92
P350081-009-30	93
P350081-020-30	93
P350082-009-30	93
P350082-020-30	93
P350085-009-30	83

P350085-015-30	83
P350085-020-30	83
P350086-009-30	83
P350086-015-30	83
P350086-020-30	83
P350087-009-30	83
P350087-015-30	83
P350087-020-30	83
P350088-009-30	87
P350088-015-30	87
P350088-020-30	87
P350089-078-30	84
P350089-121-30	84
P350089-143-30	84
P350100-009-30	88
P350100-015-30	88
P350100-020-30	88
P350101-009-30	88
P350101-015-30	88
P350101-020-30	88
P350113-009-30	82
P350113-015-30	82
P350113-108-30	82
P350131-009-30	88
P350131-015-30	88
P350131-020-30	88
P350134-009-30	86
P350134-143-30	86
P350135-009-30	86
P350135-143-30	86

P5000/50000

P5024-0930K9	120
P5050-0930K9	119
P5050-10830K9	119
P5050-1530K9	119
P5072-0930K9	124
P5072-2030K9	124
P5094-0930K9	125
P5094-7430K9	125
P5143-0930K9	123
P5175-0930K9	125
P5176-0930K9	124
P5176-2030K9	124
P5188-0930K9	119
P5188-10830K9	119
P5188-1530K9	119
P5197-0930K9	119
P5197-10830K9	119
P5197-1530K9	119
P5198-09	119
P5198-0930K9	113
P5198-12	113
P5198-20	113
P5198-31	113
P5199-09	113
P5199-12	113
P5199-20	113
P5199-31	113
P5245-20	27
P5245-31	27
P5246-31	27
P5247-09	27
P5247-31	27
P5295-31	27
P5296-31	27
P5297-31	27
P5298-31	27
P5299-31	27
P5340-1630K9	121
P5340-2030K9	121

P5340-3030K9	121
P5341-1630K9	121
P5341-2030K9	121
P5341-3030K9	121
P5342-1630K9	121
P5342-2030K9	121
P5342-3030K9	121
P5344-1530K9	120
P5622-2030K9	35
P5622-8230K9	35
P5623-2030K9	35
P5623-8230K9	35
P5634-2030K9	41
P5634-3130K9	41
P5634-8230K9	41
P5635-2030K9	41
P5635-3130K9	41
P5635-8230K9	41
P5641-20/30K	33
P5641-30/30K	33
P5641-31/30K	33
P5641-82/30K	33
P5642-20/30K	33
P5642-30/30K	33
P5642-82/30K	33
P5643-20-30K	34
P5643-30-30K	34
P5643-31-30K	34
P5643-82-30K	34
P5644-20-30K	34
P5644-30-30K	34
P5644-31-30K	34
P5644-82-30K	34
P5674-20/30K	33
P5674-30/30K	33
P5674-31/30K	33
P5674-82/30K	33
P5675-20/30K	33
P5675-30/30K	33
P5675-31/30K	33
P5675-82/30K	33
P5676-13630K9	38
P5676-2030K9	38
P5723-1430K9	35
P5723-7130K9	35
P5723-8130K9	35
P5741-20/30K	33
P5741-30/30K	33
P5741-31/30K	33
P5741-82/30K	33
P5774-20/30K	33
P5774-30/30K	33
P5774-31/30K	33
P5774-82/30K	33
P5800-12930K9	43
P5801-12930K9	43
P5806-0930K9	43
P5806-12930K9	43
P5862-2030K9	39
P5862-3130K9	39
P5863-2030K9	39
P5863-3130K9	39
P5864-2030K9	39
P5864-3130K9	39
P500002-009-30	118
P500065-009-30	123
P500065-020-30	123
P500066-009-30	123
P500066-020-30	123
P500147-009-30	122
P500147-015-30	122
P500147-031-30	122

P500147-109-30	122
P500148-009-30	122
P500148-015-30	122
P500148-031-30	122
P500148-109-30	122
P500276-009-30	117
P500276-028-30	117
P500276-031-30	117
P550070-030	36
P550070-031	36
P550070-039	36
P550070-079	36
P550070-082	36
P550070-091	36
P550071-031-30	45
P560001-129-30	96
P560029-031-30	42
P560029-129-30	42
P560030-031-30	43
P560030-129-30	43
P560051-020-30	42
P560051-030-30	42
P560051-082-30	42
P560056-020-30	42
P560056-030-30	42
P560056-031-30	42
P560056-082-30	42
P560072-031-30	45
P560073-031-30	45
P560090-020-30K	41
P560090-030-30K	41
P560090-031-30K	41
P560090-082-30K	41
P560091-039	37
P560091-079	37
P560091-082	37
P560091-091	37
P560137-028-30	45
P560137-031-30	45
P560208-031-30	44
P560208-082-30	44
P560209-031-30	44
P560209-082-30	44
P560210-031-30	44
P560210-082-30	44
P560211-031-30	44
P560211-082-30	44
P563000-020-30K	32
P563000-030-30K	32
P563000-143-30K	32
P563000-147-30K	32
P563001-020-30K	32
P563001-030-30K	32
P563001-143-30K	32
P563001-147-30K	32

P6000/60000

P6056-3130K9	38
P6057-3130K9	38
P6058-3130K9	38
P6426-3130K9	38
P6827-0930K	26
P6827-2030K	26
P6827-3030K	26
P6827-3130K	26
P6828-0930K	26
P6828-2030K	26
P6828-3030K	26

P6828-3130K	26
P6829-0930K	26
P6829-2030K	26
P6829-3030K	26
P6829-3130K	26
P6832-0930K	26
P6832-2030K	26
P6832-3030K	26
P6832-3130K	26
P660003-009-30K	69
P660003-020-30K	69
P660003-028-30K	69
P660003-031-30K	69

Product Index

PE

PE2EU-30 50
PE2EU-30-RC 50
PE2WL-82 51
PEALE-DG-EM-16 48
PEALE-DR-EM-16 48
PEALE-SG-EM-16 48
PEALE-SR-EM-16 48
PECUE-UG-30 48
PECUE-UG-30-RC 48
PECUE-UR-30 48
PECUE-UR-30-RC 48
PEERE-DG-16 49
PEERE-DR-16 49
PEERE-SG-16 49
PEERE-SR-16 49
PEESE-DG-16 49
PEESE-DR-16 49
PEESE-SG-16 49
PEESE-SR-16 49
PEOEU-EM-20 51

RS/RT/SS

RSA-P 22
RSA-P-CEAK-F 22
RSA-P-CEAK-S 22
RSA-P-CENA-F 22
RSA-P-CENA-S 22
RSA-P-DBE-F 22
RSA-P-DBE-S 22
RSA-P-F 22
RSA-P-FLAK-F 22
RSA-P-FLAK-S 22
RSS-P 22
RTA-P 22
RTC-P-XX-FL 23
RTC-P-XX-SM 23
SSA-P 22
SSS-P 22

Icon Index



Products referencing this logo meet the energy efficiency requirements for light fixtures set forth in ENERGY STAR® product specifications. Please refer to www.energystar.gov for specific product qualifications and list of certified products.



Please note indoor only (dry location) fans should only be used indoors. Even if an outdoor area or screened-in porch is covered, the motor and the blades can be affected when exposed to humidity. You can, however, “bring the outdoors inside” – as using outdoor ceiling fans are perfectly acceptable to use in interior spaces.



If you are selecting a ceiling fan for a space that is outdoors and under a roof, i.e. any covered porches; you should select either a damp rated or wet listed fan. Damp location fans may also be used indoors.



If the fan comes directly into contact with water, you’ll need to ensure that the ceiling fan has a “wet” listing. Ceiling fans designed for damp or wet locations feature elements, such as moisture-resistant motors and all weather blades. Wet location fans may also be used indoors.



This marking indicates fixtures that have an integrated LED or replaceable LED module that has been tested and listed in the California Appliance Database. Check for certified lamps, fixtures or LED light engines by searching the MAEDBS database. Go to cacertappliances.enegy.ca.gov



Outdoor installation only.



Complies with “American with Disabilities Act”



Amber options available to minimize glare onto beaches for sea turtle friendly illumination.



Products referencing this logo have been DesignLights Consortium® (DLC) qualified and are listed in DLC’s Qualified Products List (QPL). Products included in QPL are considered high efficiency and may be eligible for energy rebates with participating energy providers. Please refer to the DLC website for specific product qualifications at www.designlights.org.



Table 150.0A defines products that do not have to meet JA8 and can be used to comply with 2016 Title 24. The most common types include:

- Pin-based linear or compact fluorescent light sources using electronic ballasts
- GU-24 sockets containing light sources other than LEDs
- Inseparable SSL luminaires that are installed outdoors



Products comply with the California Appliance Efficiency Regulations. Certified products are listed on the appliance efficiency database found at www.appliances.energy.ca.gov.



Products with this icon are Dark Sky Friendly and provide full cut-off to minimize glare and avoid light pollution.



The products with this logo have passed the cUL requirements and are available for sale in Canada. These products include the additional safety features needed to comply with the regulations in Canada. Items with the icon are listed with NRCan.



Products with this icon are compatible with our P2667-31 wi-fi control. Easily control your fan with your smart phone, tablet, voice controls or a hand-held remote. Use the Smart by Bond technology to control: on/off function of the fan and light kit, full range dimming, 3 fan speeds, breeze mode and 3 timer settings.



Product is made to order.



Quick ship product.

Every effort has been made to ensure the accuracy of information in this catalog. Progress Lighting reserves the right to make product changes from time to time, without prior notification, which may change the information provided in this catalog. Errors brought to our attention will be corrected in subsequent issues.

UL, CSA, or ETL Listed or Classified unless otherwise noted.Bulbs not included with fixtures unless specified. Specifications subject to change without notice.

Metal finishes not specified as “solid” have quality plated or painted finishes.

Finish representations are high resolution digital reproductions, and, while every effort has been made to render colors accurately, they may vary slightly from the actual product, especially hand-painted finishes, due to the nature of hand craftsmanship.

©Progress Lighting 2020

All rights reserved.
International copyright secured.





PROGRESS LIGHTING

701 Millennium Boulevard
Greenville, SC29607

www.progresslighting.com

