

LED EDGELIT RECESSED LIGHTING

Progress Lighting's Edgelit LED recessed lighting provides the ideal balance of visible comfort and usable light. Edgelit technology is specifically engineered with the LEDs placed on the sides of the fixture cavity. This allows even illumination and softened light output through a frosted lens to provide a consistent glow without glare, creating the ideal balance between task and ambient lighting. Products are offered in 5" and 7" diameter as well as four popular finish options. Edgelit fixtures are low-profile and are air-tight IC/non-IC rated. Edgelit LED recessed products are a perfect solution for energy efficiency and even illumination for use in a variety of retrofit and new construction applications.

FINISH OPTIONS

White

Brushed Nickel

Antique Bronze

Black

PRODUCT FEATURES


- Slim, low profile design
- No housing or J-Box required for installation
- Features a detachable driver box, which can be mounted remotely for shallow ceiling installations
- IC rated and Air-Tight
- Flicker free dimming down to 10% with many Forward Phase (Triac) and Electronic Low Voltage (ELV) dimmers
- Energy efficient design provides up to a 75% energy savings and up 50,000 hours of LED life
- Energy Star Qualified
- Meets California T24 JA8-2016.

PRODUCT DETAILS

Product No.	Finish	Size	Source	Input	Dimming
P800004-009-30	Brushed Nickel	5" dia., 3" ht.	9w LED, 3000K, 550 lumens	120V	Triac or ELV
P800004-020-30	Antique Bronze				
P800004-028-30	White				
P800004-031-30	Black				
P800005-009-30	Brushed Nickel	7" dia., 3" ht.	13w LED, 3000K, 800 lumens	120V	Triac or ELV
P800005-020-30	Antique Bronze				
P800005-028-30	White				
P800005-031-30	Black				

INSTALLATION OPTIONS

DETACHED JUNCTION BOX

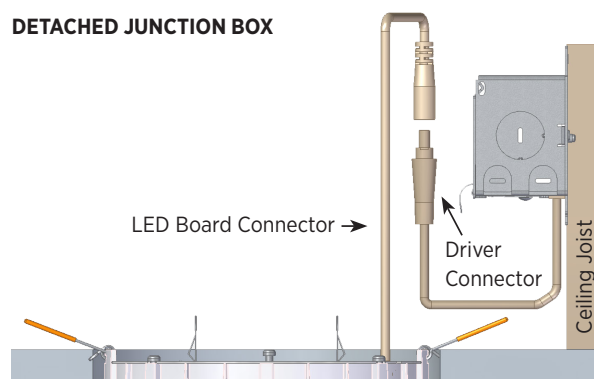

ATTACHED JUNCTION BOX

